

Replacement Parts Reference Book

2016

Mailing Address: P O Box 410
Schofield, WI 54476-0410

Parts Department Phone: 1.800.355.5354

Parts Fax Number: 1.800.355.3119

Greenheck Parts Website: www.greenheck.com/parts

Greenheck Email Format: `firstname.lastname@greenheck.com`



Greenheck Fan Corporation
P.O. Box 410 • 400 Ross Avenue • Schofield, WI 54476-0410

Table of Contents

Who To Contact	5
Parts ordering information	5
Warranty Statement	6
Serial Number Descriptions	7
Dampers	
Actuators	8 - 14
CRD	15
DFD	15
EM	16
ES	16
FD	16
FSD	17-18
MBD-10	18
MBD-15	18
MBDR-50	18
Retainer Plates (FDR/DFDR/FSDR)	19
SMD	20
VCD	21 - 22
WD	23
Drive Components	
Belts	24 - 30
Bushings (Browning)	31 - 32
Bushings (TB Woods)	33 - 34
Pulleys (Browning)	35 - 42
Pulleys (TB Woods)	43 - 46
Fans	
BSQ	47 - 49
BSQ-HP	50
CSP	50 - 52
CUBE	53 - 56
CUBE-HP	57 - 58
CUE	58
CW	59
CWB	60 - 61
DSQ	62
EQB	63
G	64 - 66
GB	66 - 71
GW	65
GWB	72
RSF	73
SBE	73
SDE	74

Fans Continued

SE	74
SFB	75
SP Fans and Grilles	76 - 81
SPFE	82
SQ	82
SQB	83
SWB	84 - 86
TAUB/D	87

Kitchen Ventilation

Filters	88
Miscellaneous Parts	88
Registers	89
Switches	89
Water Spray Fire Protection	89

TAP

Burner Parts for MUA	90
----------------------------	----

Motors

Motor Vendor Information	91
Greenheck part # listing	92 - 95
Vendor part # listing	96 - 100
Obsolete motors	101 - 104
Shock Mounts	105

Spray Paint	106 - 109
-------------------	-----------

Greenheck Parts Department Who to Contact

Parts Sales		Extension – last 4 digits
Mgr, Market Research & Corporate Programs	Dawn Genrich	715.355.2249
Parts Sales Customer Support Team		
Toll Free Number		1.800.355.5354
Fax Number		1.800.355.3119
Email Address		parts@greenheck.com
Parts Coordinator	Andrea Schneider	715.355.2335
Parts Coordinator	Matt Resch	715.355.3189
Parts Coordinator	Rhonda Barta	715.355.3118

Parts Ordering Information

Parts orders can be emailed to: parts@greenheck.com

Parts orders can be faxed to: 1.800.355.5354

Parts orders sent into Greenheck by **1:00 pm Central Standard Time (CST)** will be shipped the same day.

Greenheck Warranty Statement

Greenheck warrants its equipment to be free from defects in material and workmanship for a period of one year from the date of shipment. Many products carry a longer timeframe warranty period based on the type of product and components contained within each unit. For more specific information, all Greenheck product warranties are located on www.greenheck.com on the Warranty tab under each specific product page.

Any units or parts which prove defective during the warranty period will be replaced at our option when returned to the factory, transportation prepaid. Under certain conditions, Greenheck may request the return of a complete unit or specific components for inspection.

Greenheck will not be responsible for any installation or removal costs. Replacement equipment will be shipped ground freight at Greenheck's expense. Air freight costs are not included in the warranty.

Component Warranties

Actuators – Actuators must be returned to the factory in a brand new condition. Actuators should not contain any cosmetic damage, paint overspray, cut wires and must be free from oil, grease or sealant residue. If any of these conditions are present the actuator return will not be accepted under warranty.

Bearings (CVI & Lab Exhaust only) – In order to qualify for a replacement bearing(s) under standard warranty, all bearings installed on a Centrifugal, Vane Axial or Inline product or a Vektor Laboratory Exhaust system must be returned to the factory for evaluation.

Motors (Except for Vari-Green motors) – Motors furnished are warranted by the motor manufacturer for a period of one year after shipment from Greenheck. Should motors provided by Greenheck prove defective during this period, the following warranty procedure will be followed.

Vari-Green Motors – In order to qualify for a replacement motor under standard warranty, all Vari-Green motors must be returned to the factory for an evaluation. An RGA is required.

<u>Motor Vendor</u>	<u>Description</u>
Baldor WEG Toshiba	Follow the motor warranty claim form procedure for motors up to 215T frame. Frame sizes of 254T frame and larger must go to a local service station for evaluation. Frame size of 215T frame and smaller, submit a motor label to Greenheck using the motor warranty claim form located at : www.greenheck.com/Parts/Warranty Claim Form/motor_warranty
General Electric	All motors must be returned to a local service station for evaluation.
Leeson Marathon Electric (Also labeled A.O. Smith or Century)	Follow the motor warranty claim form procedure for motors up to 180T frame. Frame sizes 180T frame and larger must go to a motor service station for evaluation. Frame sizes of 145T frame and smaller, submit a motor label to Greenheck using the motor warranty claim form located at: www.greenheck.com/Parts/Warranty Claim Form/motor_warranty


* For assistance finding a local service station, please visit www.greenheck.com/Parts

Serial Number Designations


The serial number is important to have when ordering replacement parts.

Beginning in 1985, the following nomenclature was implemented

A = Jan.	G = July
B = Feb.	H = Aug.
C = March	I = Sept.
D = April	J = Oct.
E = May	K = Nov.
F = June	L = Dec.

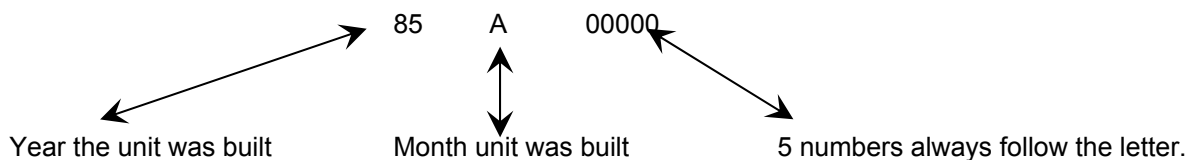

In November 2005, the following nomenclature was implemented for products manufactured out of our new ERP System, SAP.

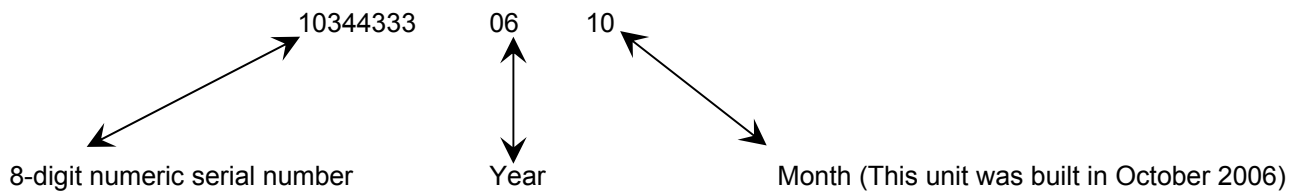

DAMPER ACTUATORS

Belimo		
Actuator	Kit Part Number	Actuator Part #
AF120 (120V)	ACT-AF120	381087
AF120-S (120V)	ACT-AF120S	381151
AF230 (230V)	ACT-AF230	381598
AF230-S (230V)	ACT-AF230S	381599
AF24 (24V/DC)	ACT-AF24	381085
AF24-S (24V/DC)	ACT-AF24S	381152
AF24-SR (24V/DC)	ACT-AF24-SR	381150
AF24-MFT (24V/DC)		381608
AF24-MFT-S (24V/DC)	ACT-AF24-MFT-S	381600
AMB24 (24V/DC)	833289	382132
AMB24 KIT W/ 316SS LINKAGE (24V/DC)	880363	
AMB-24-SR (24V/DC)	833290	382131
AMB24-SR KIT W/ 316SS LINKAGE (24V/DC)	880364	
FSAF24 (24V/DC)		383413
FSLF120 (120V)	832776	383242
FSLF120 KIT W/ 316SS LINKAGE (120V)	880352	
FSLF120-S (120V)	832777	383392
FSLF120-S KIT W/ 316SS LINKAGE (120V)	880353	
FSLF24 (24V)	832778	383241
FSLF24 KIT W/ 316SS LINKAGE (24V)	880350	
FSLF24-S (24V)	832779	383394
FSLF24-S KIT W/ 316SS LINKAGE (24V/DC)	880351	
FSLF230 (230V)	833249	383399
FSLF230 KIT W/ 316SS LINKAGE (230V)	880354	
FSLF230-S (230V)	833250	383400
FSLF230-S KIT W/ 316SS LINKAGE (230V)	880355	
FSNF120 (120V)	ACT-FSNF120	382888
FSNF120 KIT W/ 316SS LINKAGE (120V)	SEACT-FSNF120	
FSNF120-S (120V)	ACT-FSNF120S	382965
FSNF120-S KIT W/ 316SS LINKAGE (120V)	SEACT-FSNF120S	
FSNF24 (24V)	ACT-FSNF24	382889
FSNF24 KIT W/ 316SS LINKAGE (24V)	SEACT-FSNF24	
FSNF24-S (24V)	ACT-FSNF24S	382966
FSNF24-S KIT W/ 316SS LINKAGE (24V)	SEACT-FSNF24S	
FSNF230 (230V)	ACT-FSNF230	382963

DAMPER ACTUATORS

<u>Belimo Continued</u>		
<u>Actuator</u>	<u>Kit Part Number</u>	<u>Actuator Part #</u>
FSNF230 KIT W/ 316SS LINKAGE (230V)	SEACT-FSNF230	
FSNF230-S (230V)	ACT-FSNF230S	382964
FSNF230-S KIT W/ 316SS LINKAGE (230V)	SEACT-FSNF230S	
GMB24 (24V/DC)		383246
GMB24-SR (24V/DC)		381308
LF24-SR (24V/DC)	833252	381737
LF24-SR KIT W/ 316SS LINKAGE (24V/DC)	880356	
LF24-SR-S (24V/DC)	833253	383011
LF24-SR-S KIT W/ 316SS LINKAGE (24V/DC)	880357	
LMB24 (24V/DC)	833284	381726
LMB24 KIT W/ 316SS LINKAGE (24V/DC)	880358	
LMB24-S (24V/DC)	833285	381727
LMB24-S KIT W/ 316SS LINKAGE (24V/DC)	880359	
LMB24-SR (24V/DC)	833286	381728
LMB24-SR KIT W/ 316SS LINKAGE (24V/DC)	880360	
NF24-SR (24V/DC)	ACT-NF24SR	381736
NF24-SR-S (24V/DC)		383012
NMB24 (24V/DC)	833287	381601
NMB24 KIT W/ 316SS LINKAGE (24V/DC)	880361	
NMB24-SR (24V/DC)	833288	381138
NMB24-SR KIT W/ 316SS LINKAGE (24V/DC)	880362	
ZS-300	Belimo NEMA 4X housing (For use with a Belimo act, non-jackshafted)	851994
ZS-260	Belimo NEMA 7 housing (For use with a Belimo act, non-jackshafted)	851996
Belimo ZG-R01 Resistor	4-20mA adaptor 500W 1/2 W resistor with 6" pigtail wires, Resistor (Convert 4-20mA to 2-10 Vdc)	381309

<u>Bettis</u>		
<u>Actuator</u>	<u>Kit Part Number</u>	<u>Actuator Part #</u>
SR5F-10-C4-02-307	N/A - SDR REQD	383532
SR5F-15-C4-02-307	N/A - SDR REQD	383533
SR5F-30-C4-02-307	N/A - SDR REQD	383534

DAMPER ACTUATORS

Bray		
<u>Actuator</u>	<u>Kit Part Number</u>	<u>Actuator Part #</u>
70-0051-113A0536/AC (120V)	N/A - SDR REQD	383537
70-0051-113A0536/AE (120V)	N/A - SDR REQD	383538
70-0121-113A0536/AC (120V)	N/A - SDR REQD	383541
70-0121-113A0536/AE (120V)	N/A - SDR REQD	383542
70-0201-113A0536/AC (120V)	N/A - SDR REQD	383543
70-0201-113A0536/AE (120V)	N/A - SDR REQD	383544
70-0301-113A0536/AC (120V)	N/A - SDR REQD	383545
70-0301-113A0536/AE (120V)	N/A - SDR REQD	383546

Honeywell		
<u>Actuator</u>	<u>Kit Part Number</u>	<u>Actuator Part #</u>
M9185D-1004 (24V)	ACT-M9185D1012-24V	380949
M6184D-1035 (24V)		381715
M9185D-1012 (24V)	obsolete	obsolete
ML4202F1000 (120V / CW)	829877	383260
ML4302F1008 (120V / CCW)	829876	383261
ML4802F1007 (230V / CCW)	829878	383263
ML4702F1009 (230V / CW)	829879	383262
ML8202F1006 (24V / CW)	829881	383264
ML8302F1004 (24V / CCW)	829880	383265
MS4120F1006 (115V)	880347	382823
MS4120F1204 (115V)	831681	383024
MS4209F1007 (115V)	ACT-MS4209-115V	382731
MS4309F1005 (115V)	ACT-MS4309-115V	382732
MS4620F1005 (230V)	880348	382825
MS4620F1203 (230V)	831683	383254
MS4709F1014 (230V)	ACT-MS4709-230V	382735
MS4809F1012 (230V)	ACT-MS4809-230V	382736
MS7505A2008 (24V)		383740
MS7510A2206 (24V)		383213
MS7510A2008 (24V)		383739
MS7520A2007 (24V)		383214
MS7520A2015/B (24V)		383785
MS7520A2205 (24V)		383738
MS7520A2213/B (24V)		383784
MS8120F1002 (24V)	880349	382824
MS8120F1200 (24V)	831682	383255
MS8209F1003 (24V)	ACT-MS8209-24V	382733
MS8309F1001 (24V)	ACT-MS8309-24V	382734
Honeywell Module Q7230A1005	Interface Module with selectable control (2-10Vdc or 4-20 mA)	382930
Honeywell Transformer 50017460-001	Internal transformer used to convert Honeywell M9185D-1012 to 120/208/240 Vac (previous model 198162AA)	381043
Honeywell Dual Auxillary Switch	Honeywell part # 32003532003	383033

DAMPER ACTUATORS

Honeywell continued		
Actuator	Kit Part Number	Actuator Part #
ML4105B1009-R	discontinued-see MS4209F1007	
ML4105A1000-L	discontinued-see MS4309F1005	
ML4115B1008-R	obsolete - see ML4202	
ML4115A1009-L	obsolete - see ML4302	
ML4115C1007	obsolete- see ML4802	
ML4115D1006	obsolete- see ML4702	
ML8105A1006-L	discontinued-see MS8309F1001	
ML8105B1005-R	discontinued- see MS8209F1003	
ML8115B1004-R	obsolete - see ML8202	
ML8115A1005-L	obsolete - see ML8302	

Invensys		
Actuator	Kit Part Number	Actuator Part #
MA40-7170 (115V)		383247
MA40-7171 (230V)		383248
MA40-7173 (24V)		383188
MA-305 (24V)	ACT-MA305-24V	380712
MA-305-500 (24V)	ACT-MA305-500-24V	380720
MA-318 (24V)	ACT-MA318-24V	380713
MA-318-500 (24V)	ACT-MA318-500-24V	380721
MA-405 (120V)	ACT-MA405-120V	380708
MA-405-500 (120V)	ACT-MA405-500-120V	380722
MA-418 (120V)	ACT-MA418-120V	380709
MA-418-500 (120V)	ACT-MA418-500-120V	380723
MA-419 (230V)	ACT-MA419-230V	380813
MA-419-500 (240V)	ACT-MA419-500-240V	381593
MA5-419	ACT-MA5-419-220V	381205
MA5-419-500	ACT-MA5419500-240V	381594
MA6-318-500	ACT-MA6318500-24V	381661
MA6-405-500	ACT-MA6405500-120V	380811
MA6-418-500	ACT-MA6418500-120V	380806
MA6-419-500	ACT-MA6419500-240V	381595
MA7-419-500	ACT-MA7419500-240V	381597
MC-431	ACT-MC431-120V	381149
MK2-7121	ACT-MK2-7121-P	454138
MK4-7121		382845
MP-381		380714
MP-485		380715
MS40-7170 (115V)		383250
MS40-7171 (230V)		383251
MS40-7173 (24V)		383252
MS41-6340 (115V)		383253
AE-201 TRANSFORMER 120V PRIMARY/24V SECONDARY	Invensys transformer COMPATIBLE ON ANY 24V	381477
T-249 TRANSFORMER PRIMARY 480/277/240/208 V , 120V SECONDARY	Invensys transformer COMPATIBLE ON ANY 120V (formerly known as AE-249)	380842

DAMPER ACTUATORS

<u>Jamesbury</u>		
<u>Actuator</u>	<u>Kit Part Number</u>	<u>Actuator Part #</u>
VPVL200DAB Pneumatic, 80 Psi, 2 Pos., PO/PC VPVL200DAB	N/A - SDR REQD	468903
VPVL200DAB Pneumatic, 80 Psi, Mod., PO/PC 4-20 mAdc VPVL200DAB-PMV EP5	N/A - SDR REQD	468904
VPVL200DAB Pneumatic, 80 Psi, Mod., PO/PC 3-15 Psi VPVL200DAB-PMV P5	N/A - SDR REQD	468905
VPVL250DAB Pneumatic, 80 Psi, 2 Pos., PO/PC VPVL250DAB	N/A - SDR REQD	468906
VPVL250DAB Pneumatic, 80 Psi, Mod., PO/PC 4-20 mAdc VPVL250DAB-PMV EP5	N/A - SDR REQD	468907
VPVL250DAB Pneumatic, 80 Psi, Mod., PO/PC 3-15 Psi VPVL250DAB-PMV P5	N/A - SDR REQD	468908
VPVL250SR6B Pneumatic, 80 Psi, 2 Pos., Spring Return VPVL250SR6B	N/A - SDR REQD	468909
VPVL250SR6B Pneumatic, 80 Psi, Mod., Spring Return 4-20 mAdc VPVL250SR6B-PMV EP5	N/A - SDR REQD	468910
VPVL250SR6B Pneumatic, 80 Psi, Mod., Spring Return 3-15 Psi VPVL250SR6B-PMV P5	N/A - SDR REQD	468911
VPVL300DAB Pneumatic, 80 Psi, 2 Pos., PO/PC VPVL300DAB	N/A - SDR REQD	468912
VPVL300DAB Pneumatic, 80 Psi, Mod., PO/PC 4-20 mAdc VPVL300DAB-PMV EP5	N/A - SDR REQD	468913
VPVL300DAB Pneumatic, 80 Psi, Mod., PO/PC 3-15 Psi VPVL300DAB-PMV P5	N/A - SDR REQD	468914
VPVL300SR6B Pneumatic, 80 Psi, 2 Pos., Spring Return VPVL300SR6B	N/A - SDR REQD	468915
VPVL300SR6B Pneumatic, 80 Psi, Mod., Spring Return 4-20 mAdc VPVL300SR6B-PMV EP5	N/A - SDR REQD	468916
VPVL300SR6B Pneumatic, 80 Psi, Mod., Spring Return 3-15 Psi VPVL300SR6B-PMV P5	N/A - SDR REQD	468917
VPVL350DAB Pneumatic, 80 Psi, 2 Pos., PO/PC VPVL350DAB	N/A - SDR REQD	468918
VPVL350DAB Pneumatic, 80 Psi, Mod., PO/PC 4-20 mAdc VPVL350DAB-PMV EP5	N/A - SDR REQD	468919

DAMPER ACTUATORS

Jamesbury continued		
<u>Actuator</u>	<u>Kit Part Number</u>	<u>Actuator Part #</u>
VPVL350DAB Pneumatic, 80 Psi, Mod., PO/PC 3-15 Psi VPVL350DAB-PMV P5	N/A - SDR REQD	468920
VPVL350SR6B Pneumatic, 80 Psi, 2 Pos., Spring Return VPVL350SR6B	N/A - SDR REQD	468921
VPVL350SR6B Pneumatic, 80 Psi, Mod., Spring Return 4-20 mAdc VPVL350SR6B-PMV EP5	N/A - SDR REQD	468922
VPVL350SR6B Pneumatic, 80 Psi, Mod., Spring Return 3-15 Psi VPVL350SR6B-PMV P5	N/A - SDR REQD	468923
VPVL400DAB Pneumatic, 80 Psi, 2 Pos., PO/PC VPVL400DAB	N/A - SDR REQD	468924
VPVL400DAB Pneumatic, 80 Psi, Mod., PO/PC 4-20 mAdc VPVL400DAB-PMV EP5	N/A - SDR REQD	468925
VPVL400DAB Pneumatic, 80 Psi, Mod., PO/PC 3-15 Psi VPVL400DAB-PMV P5	N/A - SDR REQD	468926
VPVL400SR6B Pneumatic, 80 Psi, 2 Pos., Spring Return VPVL400SR6B	N/A - SDR REQD	468927
VPVL400SR6B Pneumatic, 80 Psi, Mod., Spring Return 4-20 mAdc VPVL400SR6B-PMV EP5	N/A - SDR REQD	468928
VPVL400SR6B Pneumatic, 80 Psi, Mod., Spring Return 3-15 Psi VPVL400SR6B-PMV P5	N/A - SDR REQD	468929
VPVL450SR6B Pneumatic, 80 Psi, 2 Pos., Spring Return VPVL450SR6B	N/A - SDR REQD	468930
VPVL450SR6B Pneumatic, 80 Psi, Mod., Spring Return 4-20 mAdc VPVL450SR6B-PMV EP5	N/A - SDR REQD	468931
VPVL450SR6B Pneumatic, 80 Psi, Mod., Spring Return 3-15 Psi VPVL450SR6B-PMV P5	N/A - SDR REQD	468932
VPVL500SR6B Pneumatic, 80 Psi, 2 Pos., Spring Return VPVL500SR6B	N/A - SDR REQD	468933
VPVL500SR6B Pneumatic, 80 Psi, Mod., Spring Return 4-20 mAdc VPVL500SR6B-PMV EP5	N/A - SDR REQD	468934
VPVL500SR6B Pneumatic, 80 Psi, Mod., Spring Return 3-15 Psi VPVL500SR6B-PMV P5	N/A - SDR REQD	468935

DAMPER ACTUATORS

Jamesbury continued		
<u>Actuator</u>	<u>Kit Part Number</u>	<u>Actuator Part #</u>
VPVL600SR6B Pneumatic, 80 Psi, 2 Pos., Spring Return VPVL600SR6B	N/A - SDR REQD	468936
VPVL600SR6B Pneumatic, 80 Psi, Mod., Spring Return 4-20 mAdc VPVL600SR6B-PMV EP5	N/A - SDR REQD	468937
VPVL600SR6B Pneumatic, 80 Psi, Mod., Spring Return 3-15 Psi VPVL600SR6B-PMV P5	N/A - SDR REQD	468938

Johnson Controls		
<u>Actuator</u>	<u>Kit Part Number</u>	<u>Actuator Part #</u>
D3244-3	N/A - SDR REQD	468943
D3244-4	N/A - SDR REQD	468940
D3246-1	N/A - SDR REQD	468941
D3246-2	N/A - SDR REQD	468944
D3153-4	N/A - SDR REQD	468942
D3153-5	N/A - SDR REQD	468939

Multi Products		
<u>Actuator</u>	<u>Kit Part Number</u>	<u>Actuator Part #</u>
MP-3756 (24V)	826859 (replaces MP2986A)	382975
MP-3754 (120V)	826862 (replaces MP2985E)	382973
MP-3755	460V	382974
MP-2985	obsolete, see new MP-3754	-
MP-2986	obsolete, see new MP-3756	-

Siemens		
<u>Actuator</u>	<u>Kit Part Number</u>	<u>Actuator Part #</u>
331-2856	ACT-331-2856-P	451919
331-2968		451918
331-2976	ACT-331-2976-P	454129
331-4551	ACT-331-4551-P	454130
332-2856	ACT-332-2856-P	457407
332-2976	ACT-332-2976-P	457384
332-4551	ACT-332-4551-P	457043
GGD121.1U	ACT-GGD121.1U-24V	382279
GGD221.1U	ACT-GGD221.1U-115V	382188
GGD321.1U	ACT-GGD321.1U-230V	382737
GND121.1U 24V		383774
GND126.1U 24V		383775
GND221.1U 120V		383776
GND226.1U 120V		383777
GND321.1U 230V		383778
GND326.1U 230V		383779

CRDs

Part #	Description
451801	Small fusible link(165°) 1-1/2 fusible link used on CRD-1, CRD-2, CRD-3
451802	Small fusible link(212°) 1-1/2 fusible link used on CRD-1, CRD-2, CRD-3
452904	Large fusible link (165°) 2-3/4 fusible link used on CRD-60, CRD-300 series
452905	Large fusible link (212°) 2-3/4 fusible link used on CRD-60, CRD-300 series
693058	Mineral Wool thermal blanket (24"x24")
693057	Refractory Ceramic fiber thermal blanket (24"x24")
822503	Volume Controller 165° for dampers ≤8.25" high
822505	Volume Controller 212° for dampers ≤ 8.25" high
822504	Volume Controller 165° for dampers > 8.25" high
822506	Volume Controller 212° for dampers > 8.25" high

DFD

Part #	Description
452904	Elsie 'D' Link(large fusible link) 165° 2-3/4 fusible link-used on FD-150,FD-150X, FD-155,FD-350, FD-355,DFD-150, DFDTF-210
452905	Elsie 'D' Link(large fusible link) 212° 2-3/4 fusible link used on FD-150,FD-150x, FD-155,FD-350, FD-355,DFD-150, DFDTF-210
809780	Elsie 'B' Link(small fusible link w/ hooks)165° 1-1/2 Fusible link w/ hooks-used on FD-100,FD-110,FD-300,FD-310, DFD-110, DFD-310
809781	Elsie 'B' Link(small fusible link w/ hooks) 212° 1-1/2 Fusible link w/ hooks-used on FD-100,FD-110,FD-300,FD-310
818868	Elsie 'B' Link(small fusible link w/hooks) 286° 1-1/2 Fusible link w/ hooks-used on all FD's and DFD's
(1) 458201 (2) 451588 E-Clips	Elsie 'E' Links, (small fusible link) 165°, requires (2) e-clips per link 1-1/2 fusible link used on DFD-210
(1) 458202 (2) 451588 E-Clips	Elsie 'E' Links, (small fusible link) 212°, requires (2) e-clips per link 1-1/2 fusible link used on DFD-210
(1) 458316 (2) 451588 E-Clips	Elsie 'E' Links, (small fusible link) 350°, requires (2) e-clips per link 1-1/2 fusible link used on DFD-210
451801	Elsie Type B (small fusible link) 165° 1-1/2 fusible link used on DFDR
451802	Elsie Type B (small fusible link) 212° 1-1/2 fusible link used on DFDR
832444	10 piece Versa Cleat Hardware kit
832345	25 piece Versa Cleat Hardware kit
832346	50 piece Versa Cleat Hardware kit
829462	Micro Switch(End Switch) Open/Closed Indicator Switch (not UL approved, must ship loose) Order 1 per section
452081	Electro Thermal Link (ETL) minimum order quantity of 5
701108	Latch Release Tool

EM & ES's

Part #	Type of Kit	Description
829414	APC Kit	Adjustable Pressure Controller used on EM's
453043	ES Left Side Bearing	Also Need Retaining Ring
453041	ES Right Side Bearing	Also Need Retaining Ring
453719	Retaining Ring for Bearing	Ring for ES Bearing

FD's

Part #	Description
452904	Elsie 'D' Link(large fusible link) 165° 2-3/4 fusible link-used on FD-150,FD-150X, FD-155,FD-350, FD-355,DFD-150, DFDTF-210
452905	Elsie 'D' Link(large fusible link) 212° 2-3/4 fusible link used on FD-150,FD-150x, FD-155,FD-350, FD-355,DFD-150, DFDTF-210
809780	Elsie 'B' Link(small fusible link w/ hooks)165° 1-1/2 Fusible link w/ hooks-used on FD-100,FD-110,FD-300,FD-310, DFD-110, DFD-310
809781	Elsie 'B' Link(small fusible link w/ hooks) 212° 1-1/2 Fusible link w/ hooks-used on FD-100,FD-110,FD-300,FD-310
818868	Elsie 'B' Link(small fusible link w/hooks) 286° 1-1/2 Fusible link w/ hooks-used on all FD's and DFD's
(1) 458201 (2) 451588 E-Clips	Elsie 'E' Links, (small fusible link) 165°, requires (2) e-clips per link 1-1/2 fusible link used on DFD-210
(1) 458202 (2) 451588 E-Clips	Elsie 'E' Links, (small fusible link) 212°, requires (2) e-clips per link 1-1/2 fusible link used on DFD-210
(1) 458316 (2) 451588 E-Clips	Elsie 'E' Links, (small fusible link) 350°, requires (2) e-clips per link 1-1/2 fusible link used on DFD-210
451801	Elsie Type B (small fusible link) 165° 1-1/2 fusible link used on DFDR
451802	Elsie Type B (small fusible link) 212° 1-1/2 fusible link used on DFDR
832444	10 piece Versa Cleat Hardware kit
832345	25 piece Versa Cleat Hardware kit
832346	50 piece Versa Cleat Hardware kit
893279	Micro Switch(End Switch) Open/Closed Indicator Switch (not UL approved, must ship loose) Order 1 per section
452081	Electro Thermal Link (ETL) minimum order quantity of 5

FSD's

Part #	Type of Kit	Description
829385	GTS-1 **can only accommodate 115V circuits	3 position toggle switch with open and close lights, GTS-1 requires a TOR for the closure device
843120	GTS-1 **can only accommodate 24V circuits	3 position toggle switch with open and close lights, GTS-1 requires a TOR for the closure device
834500	GTS-2 **can only accommodate 115V circuits	3 position key switch with open and close lights, GTS-2 requires a TOR for the closure device
843121	GTS-2 **can only accommodate 24V circuits	3 position key switch with open and close lights, GTS-2 requires a TOR for the closure device
837641	GTS-3 **can only accommodate 115V circuits	Momentary test switch with open/close indicator lights. GTS-3 requires a RRL/OCI or OCI
843122	GTS-3 **can only accommodate 24V circuits	Momentary test switch with open/close indicator lights. GTS-3 requires a RRL/OCI or OCI
829807	GTS-4 **can only accommodate 115V circuits	Open and close lights
843123	GTS-4 **can only accommodate 24V circuits	Open and close lights
861228	Toggle Switch	Toggle Switch Assembly
829095	Jump over Jackshaft coupler	
SDR Required	High Temp Smoke Detector	DH400ACDCIHT NEMA 3R High Temp Smoke Detector
SDR Required	All Weather Outdoor Enclosure for Smoke Detector	DH400 OE-1 All Weather Enclosure for High Temp. Smoke Detector
829672 383227	No flow smoke detector No flow smoke detector sensor	Base with Lead Wires Photoelectronic Sensor
** Each order requires a detector plus a sampling tube see below.		
384111 **	D4120 ACDPC Smoke Detector ** Each order requires a detector plus a sampling tube see below.	Photo electronic Smoke Detector
384112	Tube Sampling 1.5 ft (for dampers <24" width)	Sampling Tube for D4120 smoke detector-1.5 ft
384113	Tube Sampling 3 ft (for dampers >=24" and <47" width)	Sampling Tube for D4120 smoke detector-3 ft
384114	Tube Sampling 5 ft (for dampers >=47" and <80" width)	Sampling Tube for D4120 smoke detector-5 ft
385115	Tube Sampling 10 ft (for dampers >=80" width)	Sampling Tube for D4120 smoke detector-10 ft
832344	Versa Cleat Hardware Kit - 10 piece	
832345	Versa Cleat Hardware Kit - 25 piece	
832346	Versa Cleat Hardware Kit - 50 piece	
840812	ASCO SOLENOID VALVE ASSEMBLY, 24VDC	EP SWITCH
840811	ASCO SOLENOID VALVE ASSEMBLY, 24VAC	EP SWITCH
840810	ASCO SOLENOID VALVE ASSEMBLY, 120V60	EP SWITCH
(2) 451588 E-Clips (1) 458201	Elsie 'E' Links, Small Fusible Link (165°), W/E-clips	1-1/2 fusible link used on CFSD, FSD, OFSD, & FSDR
(2) 451588 E-Clips (1) 458202	Elsie 'E' Links, Small Fusible Link (212°), W/E-clips	1-1/2 fusible link used on CFSD, FSD, OFSD, & FSDR
(2) 451588 E-Clips (1) 458316	Elsie 'E' Links, Small Fusible Link (350°), W/E-clips	1-1/2 fusible link used on CFSD, FSD, OFSD, & FSDR
(2) 451588 E-Clips (1) 458402	Elsie 'E' Links, Small Fusible Link (286°), W/E-clips	1-1/2 fusible link used on CFSD, FSD, OFSD, & FSDR
851848	OCI Field Kit	Open/Close Indicator kit for field installation. Note**On units less than 11" high with 'A' dimension of less than 10.5" there is no room to mount an OCI**
See website page for parts list	165°/250° TOR	Temperature Override Control
See website page for parts list	212°/350° TOR	Temperature Override Control

FSD's

Part #	Type of Kit	Description
852291	165° RRL/OCI Field kit	RRL/OCI field kit for field installation
852468	350° RRL/OCI Field kit	RRL/OCI field kit for field installation
820733	165° RRL/OCI assembly only (Not a Kit!)	
821277	212° RRL/OCI assembly only (Not a Kit!)	
824673	250° RRL/OCI assembly only (Not a Kit!)	
820734	RRL 165°	
821278	RRL 212°	
824671	RRL 250°	
824672	RRL 350°	
824896	PRV 165°	
824897	PRV 212°	

MBD-10

PART #	DESCRIPTION
868560	Manual Quadrant Kit with 1.5" standoff bracket & extension pin
868559	Manual Quadrant kit with extension pin, no standoff bracket
452899	Extension pin only (5.5" long), also order ring below
451890	Ring used to hold pin on damper
451813	8" x .375 Longer Axle Pin, order with ring above
464409	SS Standard Pin, 5.5" Axle Pin
742523	1.5" Standoff Bracket Only
475679	Manual Hand Quadrant Only
742525	2" Standoff Bracket Only
868561	Manual Quadrant Kit with 2" standoff bracket & extension pin

MBD-15

PART #	DESCRIPTION
809735	Extension Pin Kit
828599	Extension Pin Kit with Manual Quadrant Kit (this kit uses the 3.5" synthetic pin)
452509	Extension Pin only, 6" long, requires retaining clip below
455431	Extension Pin, 2.375" Polymer Pin
451738	Retaining clip used to hold shaft to pin on damper
824265	Extension pin kit with 2" standoff bracket
829873	Extension pin kit with 2" standoff bracket & Manual Quadrant Kit
651812	1 1/2" standoff bracket without ball bearing-used with hand quadrant operation
717731	2" standoff bracket without ball bearing - used with hand quadrant operation

MBDR-50

PART #	DESCRIPTION
868560	Manual Quadrant Kit with 1.5" standoff bracket & extension pin
868559	Manual Quadrant kit with extension pin, no standoff bracket
452899	Extension pin only (5.5" long), also order ring below
451890	Ring used to hold pin on damper
463332	8.625" Longer Axle Pin, order with ring above
742523	1.5" Standoff Bracket Only
475679	Manual Hand Quadrant Only
742525	2" Standoff Bracket Only
868561	Manual Quadrant Kit with 2" standoff bracket & extension pin

Retainer Plates for use with FDR/DFDR/FSDR Series

Part #	Description
844512	Galvanized Retainer plate for 4" dia
844514	Galvanized Retainer plate for 5" dia
826339	Galvanized Retainer plate for 6" dia
833201	Galvanized Retainer plate for 7" dia
826343	Galvanized Retainer plate for 8" dia
833203	Galvanized Retainer plate for 9" dia
826347	Galvanized Retainer plate for 10" dia
833205	Galvanized Retainer plate for 11" dia
826351	Galvanized Retainer plate for 12" dia
833207	Galvanized Retainer plate for 13" dia
833208	Galvanized Retainer plate for 14" dia
833209	Galvanized Retainer plate for 15" dia
833210	Galvanized Retainer plate for 16" dia
833211	Galvanized Retainer plate for 17" dia
833212	Galvanized Retainer plate for 18" dia
833213	Galvanized Retainer plate for 19" dia
833214	Galvanized Retainer plate for 20" dia
833215	Galvanized Retainer plate for 21" dia
833216	Galvanized Retainer plate for 22" dia
833217	Galvanized Retainer plate for 23" dia
833218	Galvanized Retainer plate for 24" dia
844513	Stainless Steel Retainer plate for 4" dia
844515	Stainless Steel Retainer plate for 5" dia
833200	Stainless Steel Retainer plate for 6" dia
833202	Stainless Steel Retainer plate for 7" dia
833204	Stainless Steel Retainer plate for 8" dia
833206	Stainless Steel Retainer plate for 9" dia
833221	Stainless Steel Retainer plate for 10" dia
833222	Stainless Steel Retainer plate for 11" dia
833223	Stainless Steel Retainer plate for 12" dia
833224	Stainless Steel Retainer plate for 13" dia
833225	Stainless Steel Retainer plate for 14" dia
833226	Stainless Steel Retainer plate for 15" dia
833227	Stainless Steel Retainer plate for 16" dia
883228	Stainless Steel Retainer plate for 17" dia
833229	Stainless Steel Retainer plate for 18" dia
833230	Stainless Steel Retainer plate for 19" dia
833231	Stainless Steel Retainer plate for 20" dia
833232	Stainless Steel Retainer plate for 21" dia
833233	Stainless Steel Retainer plate for 22" dia
833234	Stainless Steel Retainer plate for 23" dia
833235	Stainless Steel Retainer plate for 24" dia

SMD's

Part #	Type of Kit	Description
840812	ASCO Solenoid Valve Assembly (24v DC)	EP Switch
840811	ASCO Solenoid Valve Assembly (24v AC)	EP Switch
840810	ASCO Solenoid Valve Assembly (120v AC)	EP Switch
SDR Required	Smoke Detector	DH100ACDCI Ionization Smoke Detector
SDR Required	All Weather Outdoor Enclosure for Smoke Detector	DH400 OE-1 All Weather Enclosure for High Temp. Smoke Detector
**384111	Smoke Detector	D4120 ACDPC Photoelectronic Smoke Detector **also requires sampling tubing (see below)
384112	Tube Sampling 1.5 ft (for dampers <24" width)	Sampling Tube for D4120 smoke detector-1.5 ft
384113	Tube Sampling 3 ft (for dampers >=24" and <47" width)	Sampling Tube for D4120 smoke detector-3 ft
384114	Tube Sampling 5 ft (for dampers >=47" and <80" width)	Sampling Tube for D4120 smoke detector-5 ft
385115	Tube Sampling 10 ft (for dampers >=80" width)	Sampling Tube for D4120 smoke detector-10 ft
(2) 451588 E-Clips (1) 458201	Elsie 'E' Links, Small Fusible Link (165°), W/E-clips	1-1/2 fusible link used on CFSD, FSD, OFSD, & FSDR
(2) 451588 E-Clips (1) 458202	Elsie 'E' Links, Small Fusible Link (212°), W/E-clips	1-1/2 fusible link used on CFSD, FSD, OFSD, & FSDR
(2) 451588 E-Clips (1) 458402	Elsie 'E' Links, Small Fusible Link (286°), W/E-clips	1-1/2 fusible link used on CFSD, FSD, OFSD, & FSDR
(2) 451588 E-Clips (1) 458316	Elsie 'E' Links, Small Fusible Link (350°), W/E-clips	1-1/2 fusible link used on CFSD, FSD, OFSD, & FSDR
820733	165° RRL/OCI assembly only (Not a Kit!)	
821277	212° RRL/OCI assembly only (Not a Kit!)	
824673	250° RRL/OCI assembly only (Not a Kit!)	
820734	RRL 165°	
821278	RRL 212°	
824671	RRL 250°	
824672	RRL 350°	
824896	PRV 165°	
824897	PRV 212°	
851848	OCI Field Kit	Open/Close Indicator kit for field installation. Note**On units less than 11" high with 'A' dimension of less than 10.5" there is no room to mount an OCI**
852291	165° RRL/OCI Field kit	RRL/OCI field kit for field installation
852468	350° RRL/OCI Field kit	RRL/OCI field kit for field installation
See website page for parts list	165°/250° TOR	Temperature Override Control
See website page for parts list	212°/350° TOR	Temperature Override Control

VCD's

Part #	Type of Kit	Description
809735	Extension Pin Kit (for 5" frames)	Includes 1 1/2" stand-off bracket & 6" extension pin with clip
816288	VCD-40 Extension pin kit	standoff bracket, pin and clip
812097	1/2" Crank Arm Assy	1/2" Crank Arm Assy
811518	1/2" Manual Quadrant	1/2" manual quadrant only
816252	1" Crank Arm Assy	1" crank arm assy
815607	Extension Pin Kit with 1/2" Manual Quadrant	1 1/2" stand-off bracket, 6" shaft, hand quadrant with labels & screws
813938	1" Manual Quadrant Kit	1" Manual Quadrant with labels & screws(no standoff bracket required)
815027	Stand off bracket with ball bearing	1 1/2" bracket with ball bearing-only required for use with actuators
830609	2" Standoff bracket with ball bearing	2" bracket with ball bearing-only required for use with actuators
651812	Stand off bracket without ball bearing	1 1/2" bracket without ball bearing-used with hand quadrant operation
717731	2" standoff bracket without ball bearing	2" bracket without ball bearing-used with hand quadrant operation
846031	Extension Pin w/ Clip Kit	Steel
452509	Extended Control Shaft	6" extension shaft used to mount actuators-must be shipped with retaining clip
451738	Retaining Clip	Retaining clip used to hold extension shaft to pin on damper
455064	8 1/2" Extension Pin (also send retaining clip from above)	8.5" extension shaft used to mount actuators-must be shipped with retaining clip
824265	2" Standoff Bracket/Extension Pin Kit	Includes 2"Stand Off Bracket & 6" Extension Pin W/ Clip
829873	1/2" Manual Quadrant kit with 2" standoff bracket	2" stand-off bracket, 6" shaft, hand quadrant with labels & screws
829038	316SS Extension Pin Kit	Includes 1 1/2" 316SS stand-off bracket & 6" 316SS extension pin with clip
687784	316SS 1.5" standoff bracket (no bearing)	
846032	316SS Extension Pin w/ Clip Kit	316SS
463921	316SS extension pin	order 451738 retaining clip w/ ext pin
454204	316SS Retaining clip	Retaining clip used to hold extension shaft to pin on damper
829039	316 SS Extension Pin Kit with 1/2" Manual Quadrant	1 1/2" stand-off bracket, 6" shaft, hand quadrant with labels & screws
840812	ASCO Solenoid Valve Assembly, 24VDC	EP Switch
840811	ASCO Solenoid Valve Assembly, 24VAC	EP Switch
840810	ASCO Solenoid Valve Assembly, 120V60	EP Switch
851038	End Switch Kit	
851848	OCI field kit Need to know internal or external mount (extra mounting brackets might be required)	OCI field kit for field installation*** Units less than 11" high w/ "A" dimension of less than 10.5" there will be no room to mount the OCI
704953 & 704954	internal brackets for VCD with OCI kit greater than 12x12	

VCD's

Part #	Type of Kit	Description
SDR Required	Pull Chain Operator	Pull chain operator is priced per section- includes 10 ft of chain ***NOT AVAILABLE ON VCD-15 & VCD-18***
SDR Required	Extra Chain	Extra chain is available for the above pull chain operator (price is per ft)
816141	Crossover jumper brackets (used on VCD-15 & VCD-18)	
824698	Internal manual quad kit(non-jackshafted)	Only for VCD's 17" high or less.
814902	MA6-418-500 Internal Linkage Kit (without actuator)	
829402	MP3754 & MP3756 Internal Linkage Kit (no actuator)	For use on non-jackshafted VCD's - fail closed only
816765	MP3754 Internal Linkage Kit (with actuator)	For use on non-jackshafted VCD's - fail closed only
821900	MA300 & MA400 Series External Linkage Kit (no actuator)	
829403	MA-4XX Internal Linkage Kit (without actuator)	For single section only
829404	Internal ML-XXXX Actuator Kit w/o actuator	>17" HIGH
829405	ML-XXXX External kit w/o actuator	
829406	Belimo large housing only internal actuator kit (without actuator)	Belimo internal linkage for VCD's ≥ 17 " high that are not jackshafted
849839	Belimo large housing only external kit (without actuator)	
829407	GGD Internal Linkage Kit (no actuator)	Siemens GGD internal actuator linkage, for VCD's ≥ 17 " high that are not jackshafted
822511	GGD External Linkage Kit (no actuator)	
829723	MS Internal linkage for VCD ≥ 17 " high (no actuator)	
829724	MS Internal linkage for VCD < 17" high (no actuator)	
839938	NEMA 4X ENCLOSURE	EXTERNAL KIT

WD's

Part #	Type of Kit	Description
851038	End Switch Kit	
826848	MP-100 24 V motor pack kit	motor pack
826840	MP-100 115 V motor pack kit	motor pack
826840	MP-100 208V motor pack kit	motor pack
826840	MP-100 230V motor pack kit	motor pack
826844	MP-100 460V motor pack kit	motor pack
826840 with #380711	MP-100 575/600V w/ Micron Transformer	motor pack w/ transformer
826851	MP-210 24 V motor pack	motor pack
826842	MP-210 115 V motor pack	motor pack
826842	MP-210 208 V motor pack	motor pack
826842	MP-210 230 V motor pack	motor pack
826847	MP-210 460 V motor pack	motor pack
826842 with #380711	MP-210 575/600V w/ Micron Transformer	motor pack w/ transformer
826851	MP-220A-24V motor pack	motor pack
826842	MP-220A-115V motor pack	motor pack
826842	MP-220A-230/460V motor pack	motor pack
826842	MP-220A-208V motor pack	motor pack
826850	MP-310 24V motor pack kit	motor pack
826841	MP-310 115V motor pack kit	motor pack
826841	MP-310 208V motor pack kit	motor pack
826841	MP-310 230V motor pack kit	motor pack
826846	MP-310 460V motor pack kit	motor pack
826841 with #380711	MP-310 575/600V w/ Micron Transformer	motor pack w/ transformer
826844	MP-323 24V motor pack kit	motor pack
826843	MP-323 115V motor pack kit	motor pack
826843	MP-323 208V motor pack kit	motor pack
826843	MP-323 230V motor pack kit	motor pack
826845	MP-323 460V motor pack kit	motor pack
826843 with #380711	MP-323 575/600V w/ Micron Transformer	motor pack w/ transformer

Browning Belt Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
A20	345628	A65	345185
A23	345358	A66	345186
A24	345127	A67	345251
A25	345128	A68	345187
A26	345129	A69	345238
A27	345229	A70	345188
A28	345130	A71	345189
A29	345100	A72	345226
A30	345131	A73	345219
A31	345132	A74	345046
A32	345133	A75	345190
A33	345134	A76	345047
A34	345039	A77	345252
A35	345136	A78	345191
A36	345040	A79	345104
A37	345138	A80	345192
A38	345172	A81	345244
A39	345211	A82	345194
A40	345041	A83	345242
A41	345212	A84	345236
A42	345173	A85	345193
A43	345174	A86	345235
A44	345042	A87	345221
A45	345043	A88	345234
A46	345175	A89	345118
A47	345237	A90	345195
A48	345176	A91	345253
A49	345225	A92	345109
A50	345044	A93	345196
A51	345177	A94	345048
A52	345045	A95	345254
A53	345178	A96	345197
A54	345179	A97	345049
A55	345103	A98	345084
A56	345180	A100	345085
A57	345232	A103	345086
A58	345181	A105	345199
A59	345249	A110	345231
A60	345182	A112	345201
A61	345250	A116	345120
A62	345183	A120	345202
A63	345116	A128	345203
A64	345184		

Browning Belt Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
A136	345204	AX55	345087
A144	345255	AX56	345155
A158	345256	AX57	345540
A173	345257	AX58	345539
A180	345258	AX59D	345533
		AX60	345156
AX21	345515	AX61	345541
AX22D	345516	AX62	345157
AX23D	345517	AX63	345537
AX24D	345518	AX64	345158
AX26	345327	AX65	345548
AX27D	345519	AX66	345159
AX28	345504	AX67	345546
AX29D	345520	AX68	345160
AX30D	345521	AX69	345538
AX31	345140	AX70	345161
AX32D	345522	AX71	345162
AX33	345141	AX71D	345565
AX34	345142	AX72	345594
AX35	345143	AX73	345552
AX36	345144	AX75	345163
AX37	345145	AX77	345549
AX38	345146	AX78	345164
AX39D	345523	AX79	345543
AX40D	345524	AX80	345165
AX41D	345525	AX82	345534
AX42	345147	AX83	345550
AX43	345148	AX85	345166
AX44D	345526	AX86	345542
AX45D	345527	AX87	345569
AX46	345149	AX88	345547
AX47D	345528	AX90	345167
AX48	345150	AX92	345121
AX49D	345529	AX94	345544
AX50D	345530	AX95	345604
AX51	345151	AX96	345168
AX52D	345531	AX98	345551
AX53	345152	AX100D	345532
AX54	345153	AX103	345559
AX55	345087	AX105	345106
AX56	345155	AX110	345248
AX57	345540	AX112	345088

Browning Belt Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
AX120	345171	B61	345450
AX128	345329	B62	345422
AX144	345405	B63	345274
AX173	345406	B64	345275
		B65	345276
B25	345259	B66	345277
B26	345260	B67	345278
B27	345289	B68	345279
B28	345261	B69	345280
B29	345439	B70	345281
B30	345398	B71	345282
B31	345397	B72	345283
B32	345262	B73	345428
B33	345404	B74	345284
B34	345414	B75	345446
B35	345421	B76	345285
B36	345402	B77	345286
B37	345440	B78	345287
B38	345263	B79	345288
B39	345264	B80	345289
B40	345265	B81	345290
B41	345266	B82	345291
B42	345267	B83	345292
B43	345473	B84	345293
B44	345486	B85	345294
B45	345456	B86	345295
B46	345487	B87	345296
B47	345430	B88	345297
B48	345488	B89	345298
B49	345400	B90	345299
B50	345417	B91	345300
B51	345408	B92	345301
B52	345431	B93	345302
B53	345268	B94	345303
B54	345269	B95	345304
B55	345270	B96	345305
B56	345271	B97	345395
B57	345272	B98	345306
B58	345361	B99	345423
B59	345437	B100	345307
B60	345273	B101	345449
		B103	345308

Browning Belt Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
B105	345309	BX53	345338
B108	345310	BX54	345239
B111	345311	BX55	345339
B112	345312	BX56	345112
B116	345089	BX57	345468
B120	345313	BX59	345091
B124	345090	BX60	345429
B128	345314	BX61	345360
B133	345315	BX62	345092
B136	345316	BX63	345340
B140	345317	BX64	345124
B144	345318	BX65	345113
B148	345319	BX66	345223
B150	345399	BX67	345341
B154	345320	BX68	345241
B158	345321	BX70	345342
B162	345394	BX71	345093
B173	345322	BX72	345570
B180	345323	BX73	345554
B190	345324	BX74	345566
B195	345325	BX75	345108
B205	345409	BX76	345574
B210	345573	BX77	345122
B225	345410	BX78	345094
B255	345326	BX79	345343
		BX80	345240
BX34	345425	BX81	345095
BX35	345330	BX82	345390
BX38	345331	BX83	345096
BX40	345558	BX85	345224
BX42	345332	BX87	345555
BX44	345553	BX90	345097
BX46	345333	BX92	345561
BX48	345334	BX93	345222
BX50	345335	BX95	345233
BX51	345336	BX96	345117
BX52	345337	BX97	345230
BX53	345338	BX98	345602
BX54	345239	BX99	345344
BX55	345339	BX103	345243
BX56	345112	BX101	345247
BX57	345468	BX105	345119

Browning Belt Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
BX106	345556	CX81	345442
BX108	345126	CX85	345432
BX112	345246	CX90	345403
BX113	345427	CX96	345359
BX115	345418	CX105	345447
BX116	345114	CX109	345363
BX120	345115	CX112	345452
BX124	345245	CX120	345364
BX126	345557	CX128	345365
BX128	345346	CX136	345336
BX133	345347	CX144	345451
BX136	345391	CX150	345367
BX144	345348	CX158	345506
BX148	345597	CX162	345368
BX150	345349	CX173	345369
BX158	345350	CX180	345501
BX162	345351	CX195	345461
BX173	345352	CX210	345458
BX180	345353	CX240	345582
BX195	345411	CX270	345497
BX210	345354		
BX225	345563	3L170	345479
BX240	345426	3L180	345227
		3L190	345000
C55	345598	3L200	345001
C81	345355	3L210	345002
C90	345444	3L220	345003
C96	345412	3L230	345004
C108	345454	3L240	345005
C115	345478	3L250	345006
C120	345453	3L260	345007
C124	345584	3L270	345008
C144	345356	3L280	345009
C150	345455	3L290	345010
C158	345507	3L300	345011
C195	345357	3L310	345012
C225	345413	3L320	345013
C240	345503	3L330	345014
C255	345499	3L340	345015
		3L350	345016
CX68	345535	3L360	345017
CX75	345362	3L370	345018

Browning Belt Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
3L380	345019	4L210	345618**
3L390	345020	4L210	345509
3L400	345021	4L210	345415
3L410	345022	4L220	345228
3L420	345023	4L225	345567
3L430	345024	4L230	345050
3L440	345025	4L240	345051
3L450	345026	4L250	345511
3L460	345027	4L260	345053
3L470	345028	4L270	345512
3L480	345029	4L280	345055
3L490	345030	4L290	345056
3L500	345031	4L300	345057
3L510	345032	4L310	345058
3L520	345033	4L320	345059
3L530	345034	4L330	345060
3L540	345035	4L340	345061
3L550	345036	4L350	345062
3L560	345037	4L360	345063
3L570	345038	4L370	345064
3L580	345101	4L380	345065
3L590	345580	4L390	345066
3L600	345099	4L400	345067
3L630	345448	4L410	345068
		4L420	345069
3VX265	345587	4L430	345070
3VX300	345591	4L440	345071
3VX335	345589	4L450	345072
3VX355	345583	4L460	345073
3VX425	345600	4L470	345074
3VX500	345603	4L480	345075
3VX530	345590	4L490	345076
3VX560	345575	4L500	345077
3VX630	345571	4L510	345078
3VX750	345416	4L520	345079
3VX950	345592	4L530	345080
3VX1060	345586	4L540	345081
		4L550	345082
4L170	345483	4L560	345083
4L180	345484	4L570	345433
4L190	345508	4L580	345371
4L200	345625**	4L590	345372
4L200	345510	4L610	345392

NOTE: * = Notched Belt

Browning Belt Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
4L630	345493	5VX960	345562
4L640	345494	5VX1000	345379
4L710	345490	5VX1030	345467
4L720	345491	5VX1060	345380
4L730	345492	5VX1080	345465
		5VX1120	345396
5L280	345373	5VX1150	345466
5L450	345472	5VX1180	345381
		5VX1230	345464
5VX450	345572	5VX1250	345382
5VX470	345495	5VX1320	345383
5VX490	345514	5VX1400	345384
5VX500	345560	5VX1500	345385
5VX510	345475	5VX1600	345401
5VX530	345476	5VX1700	345393
5VX540	345513	5VX1800	345386
5VX550	345500	5VX1900	345387
5VX560	345445	5VX2000	345388
5VX570	345498	5V2120	345389
5VX580	345505	5V2240	345435
5VX590	345545	5V2360	345438
5VX600	345443	5V2500	345496
5VX610	345579	5V2650	345436
5VX630	345441		
5VX650	345502	8V2360	345601
5VX660	345481	8V2500	345581
5VX670	345419		
5VX680	345482		
5VX690	345477		
5VX710	345424		
5VX730	345459		
5VX740	345469		
5VX750	345374		
5VX780	345463		
5VX800	345375		
5VX810	345460		
5VX830	345474		
5VX840	345470		
5VX850	345376		
5VX860	345462		
5VX880	345471		
5VX900	345377		
5VX930	345457		
5VX950	345378		

Browning Bushings Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
B x 3/4	351317	P1 x 1 1/8	350084
B x 7/8	351568	P1 x 1 3/16	350762
B x 1	351118	P1 x 1 1/4	350085
B x 1 1/8	351247	P1 x 1 3/8 x 5/16	350086
B x 1 3/8	351145	P1 x 1 7/16	350301
B x 1 1/4	351208	P1 x 1 1/2	350093
B x 1 5/8	351051	P1 x 1 5/8	350092
B x 1 3/4	351132	P1 x 1 11/16	350302
B x 1 3/16	351337	P1 x 1 3/4	350611
B x 1 7/16	351100	P1 x 28MM	351433
B x 1 11/16	351027	P2 x 1 1/8	351102
B x 1 7/8	351039	P2 x 1 3/8 x 3/8	350658
B x 1 15/16	351030	P2 x 1 3/8 x 5/16	351199
B x 2	351087	P2 x 1 3/16	351107
B x 2 1/8	351023	P2 x 1 7/16	350303
B x 2 3/16	351026	P2 x 1 1/2	350224
B x 2 3/8	351074	P2 x 1 5/8	350240
B x 2 7/16	351046		
B x 42MM	351431	Q1 x 1	350334
		Q1 x 1 1/8	351569
H x 1/2	350076	Q1 x 1 3/16	351513
H x 5/8	350077	Q1 x 1 1/4	350071
H x 3/4	350075	Q1 x 1 3/8	351470
H x 7/8	350078	Q1 x 1 7/16	350304
H x 1	351878	Q1 x 1 1/2	350070
H x 1 1/8	350079	Q1 x 1 5/8	350604
H x 1 3/16	350147	Q1 x 1 11/16	350305
H x 1 1/4	351880	Q1 x 1 3/4	350069
H x 1 3/8	350149	Q1 x 1 7/8	350605
H x 1 1/2 SPCL	351596	Q1 x 1 3/16	350648
H x 1 17/16 SPCL	351595	Q1 x 1 5/16	350306
H x 24MM	351365	Q1 x 2	350137
H x 28MM	352561	Q1 x 2 1/8	350606
H x 38MM	351378	Q1 x 2 3/16	350307
		Q1 x 2 3/8	350839
P1 x 1/2	350080	Q1 x 2 7/16	350323
P1 x 5/8	350081	Q1 x 2 11/16	350640
P1 x 3/4	350318	Q2 x 1 1/8	350236
P1 x 7/8	350082	Q2 x 1 3/16	350638
P1 x 1	350083	Q2 x 1 1/4	350091
P1 x 1 1/16	350645	Q2 x 1 3/8	350087

Browning Bushings Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
Q2 x 1 3/8 x 5/16	351258		
Q2 x 1 1/2	350088		
Q2 x 1 5/8	350089		
Q2 x 1 3/4	350267		
Q2 x 1 7/8	350090		
Q2 x 1 11/16	351351		
Q2 x 2	350317		
Q2 x 2 1/8	350608		
Q2 x 1 15/16	351272		
Q2 x 2 3/16	350659		
Q2 x 2 3/8	350609		
Q2 x 2 7/16	350610		
Q3 x 2 1/8	351275		
Q3 x 2 3/8	350962		
Shaft adaptors			
1/2 x 1/2	450011		
5/8 x 5/8	454815		

T.B. Woods Bushings Cross Reference

TB Woods Number	Greenheck Number	TB Woods Number	Greenheck Number
E x 1-1/8	352163	SD x 1-5/8	352119
E x 1-3/8	352164	SD x 1-11/16	352120
E x 1-5/8	352165		
E x 1-7/8	352166	SDS x 3/4	351940
E x 1-7/16	352169	SDS x 1	351877
E x 1-11/16	352170	SDS x 1-3/8	352198
E x 1-15/16	352171	SDS x 1-1/4	351941
E x 2-1/8	352167	SDS x 1 7/16	351844
E x 2-3/8	352168		
E x 2-11/16	350944	SDS x 1-1/2	351942
E x 2-15/16	350792	SDS x 1-5/8	351691
E x 2-7/16	352172	SDS x 1-11/16	351845
E x 2-3/16	352173	SDS x 1-3/4	351943
E x 3-7/16	350986		
		SF x 3/4	351939
F x 2-7/8	352210	SF x 1-1/8	352156
F x 3-3/8	352214	SF x 1-3/8	352157
		SF x 1-5/8	352158
J x 1-5/8	352174	SF x 1-7/8	352159
J x 1-7/8	352175	SF x 1-7/16	352161
J x 1-15/16	352182	SF x 1-11/16	352162
J x 2-1/8	352176	SF x 1-1/4	351769
J x 2-3/16	352183	SF x 1-1/2	351882
J x 2-3/8	352177	SF x 1-3/4	351883
J x 2-7/16	352184	SF x 2-1/8	352160
J x 2-7/8	352178	SF x 2-11/16	352128
J x 2-11/16	352185	SF x 2-7/16	352188
J x 3-3/8	352179		
J x 3-5/8	352186	SH x 3/4	351876
J x 3-7/8	352180	SH x 1	351936
J x 4-1/8	352181	SH x 1-1/8	351846
		SH x 1-3/16	351964
M x 4-15/16	352211	SH x 1-1/4	351937
		SH x 1-7/16	351847
QT x 3/4	351946	SH x 1-1/2	351938
QT x 5/8	352196		
QT x 1	351878	SK x 3/4	351944
QT x 1-3/16	351963	SK x 1	351879
QT x 1-1/4	351880	SK x 1-3/16	351965
QT x 1-7/16	351884	SK x 1-1/4	351881
QT x 1-1/2	351947	SK x 1-7/16	351966
		SK x 1-7/8	352134

T.B. Woods
Bushings
Cross Reference

TB Woods Number	Greenheck Number	TB Woods Number	Greenheck Number
SK x 1-11/16	352133		
SK x 1-15/16	352118		
SK x 1-1/2	351945		
SK x 1-3/4	352132		
SK x 2	352123		
SK x 2-1/8	352117		
SK x 2-3/16	352121		
SK x 2-7/16	352116		
U1 x 3-7/16	352143		

Browning Pulleys (Sheaves) Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
AK30H	352216	AK32 X 3/4	351781
AK32H	351955	AK34 X 5/8	350195
AK34H	352050	AK34 X 3/4	351782
AK39H	351976	AK39 X 3/4	351783
AK41H	351977	AK39 X 1	351962
AK44H	351968	AK41 X 3/4	351949
AK46H	351969	AK41 X 1	352033
AK49H	352816	AK44 X 3/4	351784
AK51H	352202	AK44 X 1	352034
AK54H	351967	AK46 X 3/4	351785
AK56H	352379	AK46 X 1	352004
AK59H	352430	AK49 X 3/4	351789
AK61H	351990	AK49 X 1	351950
AK64H	351988	AK51 X 3/4	351787
AK66H	351991	AK51 X 1	351993
AK69H	352260	AK54 X 3/4	351788
AK71H	352288	AK54 X 1	351950
AK74H	352244	AK56 X 3/4	351789
AK79H	352093	AK56 X 1	351992
AK84H	351970	AK59 X 3/4	351790
AK89H	352431	AK59 X 1	351995
AK94H	351971	AK61 X 3/4	351791
AK99H	351978	AK61 X 1	351951
AK104H	351979	AK54 X 3/4	351792
AK109H	351983	AK64 X 1	352017
AK114H	351980	AK66 X 3/4	351793
AK124H	351981	AK66 X 1	351998
AK134H	351860	AK69 X 3/4	351794
AK144H	351776	AK69 X 1	352041
AK154H	351777	AK71 X 3/4	351795
AK184H	351778	AK71 X 1	351796
		AK71 X 1 7/16	350350
AK20 X 3/4	352290	AK74 X 3/4	351797
AK22 X 3/4	352191	AK74 X 1	351798
AK23 X 5/8	351485	AK74 X 1 1/4	350884
AK23 X 3/4	352190	AK79 X 3/4	352078
AK21 X 3/4	352012	AK79 X 1	351799
AK25 X 3/4	351958	AK84 X 3/4	351800
AK26 X 5/8	350193	AK84 X 1	351801
AK26 X 3/4	351961	AK84 X 1 7/16	350922
AK27 X 3/4	351959	AK89 X 3/4	352028
AK28 X 5/8	350194	AK89 X 1	351802
AK28 X 3/4	351779	AK94 X 3/4	352065
AK30 X 3/4	351780	AK94 X 1	351803

Browning Pulleys (Sheaves) Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
AK94 X 1 7/16	350351	BK70H	352567
AK99 X 3/4	352032	BK72H	352554
AK99 X 1	351997	BK75H	352553
AK104 X 3/4	353654	BK77H	352552
AK104 X 1	351771	BK80H	352072
AK104 X 1 1/4	350352	BK85H	352550
AK109 X 3/4	352066	BK90H	352549
AK109 X 1	351772	BK95H	352548
AK114 X 3/4	352067	BK105H	352578
AK114 X 1	351773	BK110H	353325
AK124 X 3/4	350875	BK120H	352576
AK124 X 1 1/4	351774	BK140H	352574
AK134 X 3/4	350887	BK150H	352573
AK134 X 1	352064	BK190H	352571
AK144 X 3/4	352015		
AK144 X 1	352063	BK28 X 3/4	352011
AK144 X 1 7/16	351775	BK34 X 3/4	351113
AK144 X1	350981	BK34 X 1	350386
AK154 X 3/4	350879	BK36 X 1	350387
AK154 X 1	352062	BK40 X 1	350388
AK184 X 1	350888	BK45 X 1	350389
		BK47 X 1	352563
AS28 X 5/8	351176	BK50 X 1 1/8	350391
AS28 X 7/8	351177	BK55 X 1 3/16	350392
AS30 X 5/8	351178	BK60 X 1 3/16	350393
AS30 X 7/8	351179	BK70 X 1 7/16	350989
AS30 X 1	350530	BK72 X 1 3/8	350394
AS32 X 1	350531	BK72 X 1 7/16	350395
AS34 X 1	350532	BK75 X 1	354159
BK30H	352570	BK80 X 3/4	352907
BK32H	352569	BK80 X 1 7/16	350885
BK34H	352568	BK90 X 1	354163
BK36H	352567	BK90 X 1 7/16	350396
BK40H	352566	BK95 X 3/4	351663
BK45H	352565	BK95 X 1	354164
BK47H	352564	BK120 X 1	354169
BK50H	352563	BK140 X 1	354171
BK52H	352562	BK160 X 1 7/16	354183
BK55H	352561		
BK57H	352560	CDC-300A X 3/4	351780
BK60H	352559	CDC-350A X 3/4	351858
BK62H	352558	CDC-400A X 3/4	351859
BK65H	352557	CDC-500A X 3/4	350150
BK67H	352067		

Browning Pulleys (Sheaves) Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
OK25 X 3/4	350798	1B64SDS	351898
OK30 X 3/4	351857	1B68SDS	351900
OK35 X 1/2	351560	1B70SDS	351901
OK35 X 3/8	351561	1B80SDS	351903
OK35 X 3/4	351858	1B86SDS	351904
OK40 X 3/4	351859	1B94SDS	351905
OK40 X 1	350131	1B110SDS	351906
OK45 X 3/4	350150		
OK45 X 1	350218	1TA30	351418
OK50 X 3/4	350045	1TA34	350671
OK50 X 1	350130	1TA36	351271
OK60 X 3/4	350044	1TA38	351004
OK60 X 1	350881	1TA40	351008
OK70 X 3/4	350043	1TA42	351174
OK70 X 1	350151	1TA44	351154
OK80 X 3/4	350042	1TA46	350841
OK90 X 3/4	352032	1TA48	350758
		1TA50	351498
1B5V46	351613	1TA52	350273
1B5V48	351242	1TA54	350272
1B5V50	351325	1TA56	350404
1B5V56	351058	1TA58	351269
1B5V58	351698	1TA60	350405
1B5V60	351172	1TA62	350996
1B5V62	351453	1TA64	350309
1B5V64	351720	1TA70	350275
1B5V66	351104	1TA82	350276
1B5V68	351574	1TA90	350274
1B5V70	351607	1TA106	350937
1B5V74	351290	1TA120	350013
1B5V80	351099	1TA150	350014
1B5V86	351115	1TA180	350015
1B5V90	351157	1TA195	350016
1B5V94	351054	1TA245	350017
1B5V110	351340		
1B5V124	341344	1TB38	351563
1B5V136	351109	1TB40	350742
1B5V154	351357	1TB42	350416
1B5V160	351207	1TB46	351531
1B5V184	351131	1TB48	350789
1B5V200	351348	1TB52	350311
1B5V234	351352	1TB56	350413
1B5V250	351387	1TB60	351784

Browning Pulley (Sheaves) Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
1TB62	350414	1VP60 X 1 1/8	352050
1TB68	351900	1VP60 X 1 3/8	352941
1TB70	350331	1VP62 X 5/8	352046
1TB74	350417	1VP62 X 7/8	352047
1TB80	350293	1VP65 X 7/8	352043
1TB86	350418	1VP65 X 1 7/8	352240
1TB90	350297	1VP65 X 1 3/8	352940
1TB94	350419	1VP65A	350654 352079-
1TB110	350420	1VP68 X 5/8	352195
1TB124	350421	1VP68 X 7/8	352043
1TB136	350332	1VP71 X 7/8	352938
1TB154	350423		
1TB160	350424	2AK30H	350693
1TB184	350425	2AK32H	352256
1TB200	350426	2AK34H	352236
1TB250	351533	2AK39H	352201
1TB300	350427	2AK41H	352100
		2AK44H	352097
1VL25 X 1/2	351849	2AK46H	352107
1VL25 X 5/8	351850	2AK49H	352125
1VL30 X 1/2	351815	2AK51H	352234
1VL30 X 5/8	351851	2AK54H	352344
1VL34 X 1/2	352328	2AK56H	351989
1VL34 X 5/8	352329	2AK59H	351810
1VL40 X 1/2	351852	2AK61H	352918
1VL40 X 5/8	351818	2AK64H	352340
1VL40 X 7/8	351853	2AK74H	351984
1VL44 X 1/2	351854	2AK84H	352003
1VL44 X 5/8	351819	2AK94H	352018
1VL44 X 7/8	351820	2AK104H	352008
		2AK114H	352019
1VM50 X 1/2	351855	2AK124H	351861
1VM50 X 5/8	351821	2AK134H	351806
1VM50 X 7/8	351822	2AK144H	351807
1VP34 X 7/8	350168	2AK154H	352002
1VP44 X 1 1/8	351823	2AK184H	351862
1VP50 X 5/8	351821		
1VP50 X 1 1/8	351824		
1VP56 X 1/2	352245		
1VP56 X 5/8	351953		
1VP56 X 7/8	351952		
1VP56 X 1 1/8	351999		
1VP60 X 5/8	353280		
1VP60 X 7/8	352049		

Browning Pulleys (Sheaves) Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
2AK20 X 5/8	351182	2AK61 X 1 3/8	351295
2AK22 X 3/4	350932	2AK61 X 1 7/16	350365
2AK23 X 5/8	351456	2AK64 X 3/4	352129
2AK23 X 3/4	350931	2AK64 X 1	350893
2AK23 X 1	353158	2AK64 X 1 3/8	351103
2AK25 X 3/4	350907	2AK64 X 1 7/16	350366
2AK25 X 7/8	351181	2AK74 X 1	351811
2AK25 X 1	350935	2AK74 X 1 7/16	350911
2AK26 X 3/4	352271	2AK84 X 1	352029
2AK26 X 7/8	351186	2AK84 X 1 7/16	350367
2AKX26 X 1	350926	2AK94 X 1	351812
2AK27 X 3/4	350997	2AK104 X 1	351804
2AK27 X 1	352760	2AK114 X 1	352001
2AK28 X 3/4	350743	2AK124 X 1	351805
2AK27 X 7/8	351180	2AK134 X 1 7/16	350960
2AK28 X 1	350942		
2AK30 X 1	350361	2B54Q	350706
2AK32 X 3/4	350209	2B58Q	350473
2AK32 X 1	353158	2B60Q	350474
2AK34 X 3/4	350953	2B64Q	350475
2AK34 X 1	353327	2B66Q	350476
2AK34 X 1 1/8	351460	2B68Q	350477
2AK39 X 3/4	352085	2B54Q	
2AK39 X 1	352068		
2AK39 X 1 1/8	352001	2B154R	350478
2AK41 X 1	352061	2B160R	350479
2AK44 X 3/4	352199	2B184R	350749
2AK44 X 1	352040	2B200R	350480
2AK49 X 3/4	351506	2B250R	350481
2AK49 X 1	352013	2B300R	350482
2AK49 X 1 3/8	350998	2B380R	350768
2AK51 X 1	353655		
2AK51 X 1 1/8	351481	2B5V42	351190
2AK51 X 1 3/8	350363	2B5V44	351149
2AK54 X 3/4	352131	2B5V46	351049
2AK54 X 1	351808	2B5V48	351202
2AK54 X 1 1/8	350994	2B5V50	351141
2AK54 X 1 3/8	350364	2B5V52	351127
2AK56 X 1	351809	2B5V54	351029
2AK 56 X 1 3/8	350958	2B5V56	351062
2AK59 X 1	352020	2B5V58	351082
2AK59 1 3/8	351105	2B5V60	351078
2AK61 X 1	352007	2B5V62	351111

Browning Pulleys (Sheaves) Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
2B5V64	351031	2BK32H	352305
2B5V66	351025	2BK34H	352915
2B5V68	351034	2BK36H	352914
2B5V70	351041	2BK40H	352913
2B5V80	351044	2BK45H	352912
2B5V86	351050	2BK47H	352911
2B5V90	351040	2BK50H	352910
2B5V94	351035	2BK52H	352909
2B5V110	351045	2BK55H	352908
2B5V124	351036	2BK57H	352907
2B5V136	351025	2BK60H	352906
2B5V154	351043	2BK62H	352905
2B5V160	351079	2BK65H	352904
2B5V184	351068	2BK67H	352903
2B5V200	351059	2BK70H	352902
2B5V234	351123	2BK80H	351814
2B5V250	351097	2BK90H	352124
2B5V278	351126	2BK100H	352042
		2BK110H	351813
2BK25 X 7/8	351183	2BK120H	352053
2BK28 X 5/8	351184	2BK130H	352426
2BK28 X 7/8	351185	2BK140H	352917
2BK28 X 3/4	350731	2BK160H	352440
2BK28 X 1	350397	2BK190H	352071
2BK28 X 1 1/8	351248		
2BK30 X 5/8	351249	2MVP35B49 X 1 1/8	350336
2BK30 X 7/8	351250	2MVP35B49 X 7/8	351461
2BK30 X 1	351452	2MVP35B49 X 1 3/8	350123
2BK30 X 1 1/8	351187	2MVP40B54 X 1 3/8	350173
2BK32 X 1 1/8	351188	2MVP40B54 X 1 5/8	350174
2BK36 X 1 3/8	351439	2MVP54B59 X 1 3/8	350175
2BK45 X 1 3/8	350398	2MVP45B59 X 1 1/8	351175
2BK47 X 1 3/8	350400	2MVP45B59 X 1 5/8	350176
2BK50 X 1 3/8	350987	2MVP50B64 X 1 3/8	350214
2BK52 X 1 3/8	350401	2MVP50B64 X 1 5/8	350200
2BK55 X 1 3/8	351013	2MVP55B69 X 1 3/8	351500
2BK57 X 1 3/8	350983		
2BK60 X 1 3/8	351094	2Q5V46	351380
2BK62 X 1 3/8	351436	2Q5V52	351009
2BK65 X 1 3/8	351432	2Q5V59	351503
2BK67 X 1 3/8	351018	2Q5V63	351471
2BK100 X 1	350967	2Q5V71	350801
		2Q5V75	350845

Browning Pulleys (Sheaves) Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
2Q5V80	350556	2TB42	350290
2Q5V85	350557	2TB44	350703
2Q5V90	350661	2TB46	350429
2Q5V92	350739	2TB48	350430
2Q5V97	350558	2TB50	350431
2Q5V103	350559	2TB52	350292
2Q5V109	350560	2TB54	350432
2Q5V118	350561	2TB56	350294
2Q5V125	350562	2TB58	350296
2Q5V132	350783	2TB60	350316
		2TB62	350434
2TA30	350951	2TB64	350435
2TA32	351296	2TB66	350295
2TA34	350315	2TB68	350436
2TA36	350761	2TB70	350183
2TA38	350777	2TB74	350299
2TA40	351000	2TB80	350298
2TA42	350277	2TB86	350300
2TA44	350788	2TB90	350184
2TA46	350278	2TB94	350185
2TA48	350737	2TB110	350186
2TA50	350406	2TB124	350124
2TA52	350928	2TB136	350322
2TA54	350909	2TB154Q	350206
2TA56	350407	2TB160	350310
2TA58	350628	2TB184Q	350207
2TA60	350235	2TB200	350187
2TA62	350408	2TB250Q	350202
2TA64	350409	2TB300	350707
2TA70	350321		
2TA82	350279	2VP36 X 1/2	352429
2TA90	350228	2VP36 X 5/8	352006
2TA106	350188	2VP36 X 7/8	352008
2TA120	350103	2VP42 X 5/8	350137
2TA150	350104	2VP42 X 7/8	352000
2TA180	350105	2VP42 X 1 1/8	351825
2TA195	350021	2VP50 X 5/8	352094
2TA245	350022	2VP50 X 7/8	351987
		2VP50 X 1 1/8	351767
2TB34	351220	2VP56 X 5/8	352443
2TB36	350289	2VP56 X 7/8	352051
2TB38	350428	2VP56 X 1 1/8	351827
2TB40	350288	2VP60 X 7/8	352045
		2VP60 X 1 1/8	351828

Browning Pulleys (Sheaves) Cross Reference

Browning Number	Greenheck Number	Browning Number	Greenheck Number
2VP60 X 1 3/8	351829		
2VP60A X 1 5/8	352424		
2VP65 X 7/8	382901		
2VP65 X 1 1/8	351832		
2VP65 X 1 3/8	351833		
2VP65 X 1 5/8	352442		
2VP68 X 1 3/8	351834		
2VP71 X 1 1/8	352900		
2VP71 X 1 3/8	351835		
2VP71 X 1 5/8	351836		
2VP75 X 1 1/8	352899		
2VP75 X 1 3/8	351838		
2VP75A X 1 5/8	351856		

T.B. Woods Pulleys (Sheaves) Cross Reference

TB Woods Number	Greenheck Number	TB Woods Number	Greenheck Number
AK21 x 3/4	352012	AK84 x 1	351801
AK22 x 3/4	352191	AK84 x 3/4	351800
AK23 x 3/4	352190	AK89 x 3/4	352028
AK25 x 3/4	351958	AK89 x 1	351802
AK26 x 3/4	351961	AK94 x 3/4	352065
AK27 x 3/4	351959	AK94 x 1	351803
AK28 x 3/4	351779	AK99 x 3/4	352032
AK30 x 3/4	351780	AK99 x 1	351997
AK32 x 3/4	351781	AK104 x 1	351771
AK34 x 3/4	351782	AK109 x 3/4	352066
AK35 x 3/4	352263	AK109 x 1	351772
AK39 x 3/4	351783	AK114 x 3/4	352067
AK39 x 1	351962	AK114 x 1	351773
AK41 x 3/4	351949	AK124 x 1	351774
AK41 x 1	352033	AK134 x 3/4	352064
AK44 x 3/4	351784	AK134 x 1	352015
AK44 x 1	352034	AK144 x 3/4	352063
AK46 x 3/4	351785	AK144 x 1	351775
AK46 x 1	352004	AK154 x 1	352062
AK49 x 3/4	351786		
AK49 x 1	351950	AK30QT	352216
AK51 x 3/4	351787	AK32QT	351955
AK51 x 1	351993	AK34QT	352080
AK54 x 3/4	351788	AK39QT	351976
AK54 x 1	351994	AK41QT	351977
AK56 x 3/4	351789	AK44QT	351968
AK56 x 1	351992	AK46QT	351969
AK59 x 3/4	351790	AK49QT	352016
AK59 x 1	351995	AK51QT	352202
AK61 x 3/4	351791	AK54QT	351967
AK61 x 1	351951	AK61QT	351990
AK64 x 3/4	351792	AK64QT	351988
AK64 x 1	352017	AK66QT	351991
AK66 x 3/4	351793	AK79QT	352093
AK66 x 1	351998	AK84QT	351970
AK69 x 3/4	351794	AK94QT	351971
AK69 x 1	352041	AK99QT	351978
AK71 x 1	351796	AK104QT	351979
AK71 x 3/4	351795	AK109QT	351983
AK74 x 1	351798	AK114QT	351980
AK74 x 3/4	351797	AK124QT	351981
AK79 x 3/4	352078	AK134QT	351860
AK79 x 1	351799	AK144QT	351776

T.B. Woods Pulleys (Sheaves) Cross Reference

TB Woods Number	Greenheck Number	TB Woods Number	Greenheck Number
AK154QT	351777	2AK39 x 1	352068
AK184QT	351778	2AK41 x 3/4	352009
		2AK41 x 1	352061
JVS1902 x 1-7/8	352217	2AK44 x 3/4	352199
JVS2102178	352126	2AK44 x 1	352040
JVS2302 x 1-7/8	352108	2AK46 x 1	352010
JVS2302 x 2-1/8	352151	2AK49 x 1	352013
		2AK51 x 3/4	352099
SVS84B4 x 2-1/8	352135	2AK54 x 3/4	352131
SVS59B3 x 1-5/8	352136	2AK54 x 1	351808
		2AK56 x 1	351809
1VP25 x 1/2	351849	2AK59 x 1	352020
1VP25 x 5/8	351850	2AK61 x 3/4	352030
1VP30 x 1/2	351815	2AK61 x 1	352007
1VP30 x 5/8	351851	2AK64 x 3/4	352129
1VP34 x 7/8	352203	2AK64 x 1	352014
1VP40 x 1/2	351852	2AK74 x 3/4	352130
1VP40 x 5/8	351818	2AK74 x 1	351811
1VP40 x 7/8	351853	2AK84 x 1	352029
1VP40 x 1-1/8	352204	2AK94 x 1	351812
1VP44 x 1/2	351854	2AK104 x 1	351804
1VP44 x 5/8	351819	2AK114 x 1	352001
1VP44 x 7/8	351820	2AK124 x 1	351805
1VP44 x 1-1/8	351823		
1VP50 x 1/2	351855	2AK39QT	352201
1VP50 x 5/8	351821	2AK41QT	352100
1VP50 x 7/8	351822	2AK44QT	352097
1VP50 x 1-1/8	351824	2AK46QT	352107
1VP56 x 5/8	351953	2AK49QT	352125
1VP56 x 7/8	351952	2AK51QT	352234
1VP56 x 1-1/8	351999	2AK56QT	351989
1VP60 x 7/8	352049	2AK59QT	351810
1VP60 x 1-1/8	352050	2AK74QT	351984
1VP62 x 5/8	352046	2AK84QT	352003
1VP62 x 7/8	352047	2AK94QT	352018
1VP62 x 1-1/8	352048	2AK104QT	352005
1VP68 x 7/8	352043	2AK114QT	352019
1VP68 x 1-1/8	352044	2AK124QT	351861
1VP68 x 5/8	352195	2AK134QT	351806
1VP71 x 1-1/8	352205	2AK144QT	351807
		2AK154QT	352002
2AK25 x 5/8	352215	2AK184QT	351862
2AK39 x 3/4	352085		

T.B. Woods Pulleys (Sheaves) Cross Reference

TB Woods Number	Greenheck Number	TB Woods Number	Greenheck Number
2BK80QT	351814	4.8 x 1B SDS	351870
2BK90QT	352124	4.6 x 1B SDS	351890
2BK100QT	352042		
2BK110QT	351813	4.6 x 2B SDS	351918
2BK120QT	352053	4.8 x 2B SDS	352197
2BK190QT	352071		
		4.0 x 1B SH	351888
2VP36 x 5/8	352006	4.2 x 1B SH	351889
2VP36 x 7/8	352008	4.4 x 1B SH	352148
2VP42 x 5/8	352060		
2VP42 x 7/8	352000	4.0 x 2B SH	351915
2VP42 x 1-1/8	351825	4.2 x 2B SH	351916
2VP50 x 5/8	352094	4.4 x 2B SH	351917
2VP50 x 7/8	351987		
2VP50 x 1-1/8	351767	5V7.1 x 2 (SK)	352139
2VP56 x 7/8	352051	5V7.5 x 2 (SK)	352140
2VP56 x 1-1/8	351827	5V8.5 x 2SK	352218
2VP56 x 1-3/8	352150	5V10.3 x 2	352109
2VP56 x 1-5/8	352189	5V13.2 x 2 (SF)	352187
2VP60 x 7/8	352045	5V1402	352127
2VP60 x 1-1/8	351828	5VS-265 x 2 (SK)	352141
2VP60 x 1-3/8	351829	5V11.8 x 2 (SK)	352152
2VP62 x 1-3/8	351831		
2VP62 x 1-1/8	351830	5.4 x 3B SD	352113
2VP65 x 1-1/8	351832		
2VP65 x 1-3/8	351833	5.0 x 1B SDS	351891
2VP68 x 1-1/8	351986	5.2 x 1B SDS	351892
2VP68 x 1-3/8	351834	5.4 x 1B SDS	351893
2VP68 x 1-5/8	352110	5.6 x 1B SDS	351894
2VP71 x 1-5/8	351836	5.8 x 1B SDS	351895
2VP71 x 1-3/8	351835		
2VP75 x 1-3/8	351838	5.0 x 2B SDS	351842
2VP75 x 1-5/8	351856	5.2 x 2B SDS	351868
		5.4 x 2B SDS	351920
3.4 x 1B SH	351885	5.6 x 2B SDS	351921
3.6 x 1B SH	351886	5.8 x 2B SDS	351841
3.8 x 1B SH	351887		
		6.0 x 1B SDS	351896
3.4 x 2B SH	351912	6.2 x 1B SDS	351897
3.6 x 2B SH	351913	6.4 x 1B SDS	351898
3.8 x 2B SH	351914	6.6 x 1B SDS	351899
		6.8 x 1B SDS	351900

T.B. Woods Pulleys (Sheaves) Cross Reference

TB Woods Number	Greenheck Number	TB Woods Number	Greenheck Number
6.0 x 2B SDS	351923	13.0 x 7C-F	352212
6.2 x 2B SDS	351924		
6.4 x 2B SDS	351840	13.6 x 1B SDS	351908
6.6 x 2B SDS	351925		
6.8 x 2B SDS	351869	13.6 x 2B SK	351864
7.0 x 1B SDS	351901	15.4 x 1B SK	351909
7.4 x 1B SDS	351902		
		15.4 x 2B SK	351932
7.0 x 2B SK	351926		
7.4 x 2B SK	351927	15.4 x 4B SF	352137
8V12.5 x 4-F	352208	16.0 x 1B SK	351910
8V14.0 x 6-F	352219		
8V20.0 x 6-M	352220	16.0 x 2B SK	351865
8V30.0 x 4-M	352209		
		18.4 x 1B SK	351911
8.0 x 1B SDS	351903		
8.6 x 1B SDS	351904	18.4 x 2B SK	351933
8.0 x 2B SK	351928	20.0 x 1B SK	351863
8.6 x 2B SK	351867		
		20.0 x 2B SF	351766
8.6 x 4B SK	352111		
		25.0 x 1B SF	351874
9.4 x 1B SDS	351905		
		25.0 x 2B SF	351866
9.4 x 2B SK	351929		
		27.8 x 2B SF	351956
9.4 x 3B SK	352138		
		30.0 x 1B SF	351875
9.4 x 4B SK	352112		
		30.0 x 2B SF	351934
11.0 x 1B SDS	351906		
		38.0 x 2B SF	351935
11.0 x 2B SK	351930		
		44.0 x 7C-M	352213
11.0 x 4B SK	352114		
12.0 x 1B SDS	351907		
12.4 x 2B SK	351931		

Model BSQ

September 1990 through present

Model Size	Shaft Part #	Description	Bearing Part #	Description	Wheel Part #	Bore Size	Emb Std or Reinf.
BSQ 130 HP	365027	3/4x15	360099	PB 3/4" Dodge	862852	3/4	S
BSQ 140 HP	365025	3/4x17	360099	PB 3/4" Dodge	862680	3/4	S
	365041	3/4x14 1/2					
BSQ 160 HP	365431	1x19	360100	PB 1" Dodge	862616	1	S
BSQ 180 HP	365017	1x20	360100	PB 1" Dodge	807693	1	S
BSQ 200 HP	365018	1x24	360100	PB 1" Dodge	807696	1	S
BSQ 240 HP	365018	1x24	360100	PB 1" Dodge	806168	1	S
BSQ-300 HP	365555	1 1/4x1X27 1S 1KH	360101	PB 1 1/4 Dodge	822357	1	S
	366308	1.25x26 1S 1K	360101	PB 1 1/4 Dodge	822357	1	S
BSQ-360 HP	366450	1 1/2x1 1/4X29	360102	PB 1 1/2 Dodge	826749	1.25	S
	366450	1 1/2x1 1/4x30 2K 1S					

Notes:

Two bearings required per fan

When ordering 822357 wheel, shaft part # 366308 is required. ECN 1891, dated 7-31-2000.

When ordering wheel part #826749, stepped shaft part #366450 is also required. (ECN 2171 dated 03-31-03)

September 1990 through present

Model Size	Shaft Part #	Description	Bearing Part #	Description	Wheel Part #	Bore Size	Emb Std or Reinf. Emb.
BSQ 70, 80	365063	3/4x13 1/2	360422	PB SS 3/4"	862456	3/4	S
BSQ 90,100	365043	3/4x12	360422	PB SS 3/4"	870762	3/4	S
BSQ 120	365030	3/4x13	360099	PB 3/4 " Dodge	862879	3/4	S
BSQ 130	365030	3/4x13	360099	PB 3/4 " Dodge	862895	3/4	E
BSQ 140	365043	3/4x12	360099	PB 3/4 " Dodge	862694	3/4	E
BSQ 160	365036	1x16	360100	PB 1 " Dodge	862653	1	E
BSQ 180	365422	1x17	360100	PB 1 " Dodge	811454*	1	E
BSQ 200	365366	1x20 3/4	360100	PB 1 " Dodge		1	E
BSQ 240	365366	1x20 3/5	360100	PB 1 " Dodge	811442*	1	E
BSQ 300	365557	1 1/4x1x22 w/hole	360101	PB 1 1/4" Dodge	822356*	1	2E
	366307	1 1/4x1x20.5 1s 2k	360101	PB 1 1/4" Dodge			
	366446	1 1/4X20.5 2K					
BSQ 300	ECN 2161 4-10-03		360311	PB 1 1/4" Dodge	ECN 2161 4-10-03		
BSQ 360	365554	1 1/2x1 1/4x22	360102	PB 1 1/2" Dodge	Consult	Factory	
	366451	1 1/2X1 1/4X23 2K	360102	PB 1 1/2" Dodge			
BSQ 420	365553	1 1/2x1 1/4x29	360102	PB 1 1/2" Dodge	826564	1 1/4	2E
	366450	1 1/2x1 1/4x30 2K	360102	PB 1 1/2" Dodge		1 1/4	2E

Notes:

Two bearings required per fan.

* Where applicable, all replacement wheels furnished will be reinforced or embossed type. Where higher fan rpm's are indicated, a double reinforced wheel (2R) should be selected.

*366307 must be ordered with wheel 822356 for fan manufactured prior to 7-1-2000 ECN 1891.

*366451 must be ordered with wheels 826595 & 826574 for fan manufactured prior to 5-1-03. ECN 2171

*366446 must be ordered with wheel 825035 for fan manufactured prior to 4-10-03. ECN 2161

When ordering replacement wheels for BSQ 300, 360 and 420 also required to order shafts due to design changes

*366450 must be ordered with wheel 826564 for fan manufactured prior to 5-1-03. ECN 2171

Model BSQ

September 1990 through present

Model Size	Shaft Part #	Description	Bearing Part #	Description	Wheel Part #	Bore Size	Emb Std or Reinf. Emb.
BSQ 7, 8, 9, 10	365093	3/4x12 1/2	360422	PB SS 3/4"	870762	3/4"	S
BSQ 12	365093	3/4x12 1/2	360422 or 360099*	PB SS 3/4"	OBS.		
BSQ 12	365420	1x13.5 2K Serial #'s 87C - 87J use 1" bore	360100*	PB 3/4" Dodge PB 1" Dodge	1 " OBS Note: Cannot use BSQ-120 wheel		
BSQ 13	365093	3/4x12 1/2	360422 or 360099*	SS 3/4" NBR PB 3/4" Dodge	862895*	3/4"	E
BSQ 13	365420	1x13 1/2 Serial #'s 87C - 87J use 1" bore	360100*	PB 1" Dodge	Obsolete	1"	E
BSQ 14	365063	3/4x13 1/2	360422 or 360099*	SS 3/4" NBR PB 3/4" Dodge	862694	3/4"	E
BSQ 14	365036	1x16 Serial #'s 87C - 87J use 1" bore	360100*	PB 1" Dodge	1 " OBS, must replace with 3/4" wheel shaft brgs & shaft pulley		
BSQ 16	365063	3/4x13 1/2	360422 or 360099*	SS 3/4" NBR PB 3/4" Dodge	obsolete	3/4"	E
BSQ 16	365036	1x16 Serial #'s 87C - 87J use 1" bore	360100*	PB 1" Dodge	obsolete	1"	E
BSQ 18	365041	3/4x14 1/2	360422 or 360099*	SS 3/4" NBR PB 3/4" Dodge	obsolete *	3/4"	E
BSQ 18	365036	1x16 Serial #'s 87C - 88L use 1" bore	360100*	PB 1" Dodge	811454*	1"	E
BSQ 21	365025	3/4x17	360422 or 360099*	SS 3/4" NBR PB 3/4" Dodge	811459	3/4"	E
BSQ 21	365021	1x17 1/2 Serial #'s 87C - 87J use 1" bore	360100*	PB 1" Dodge			
BSQ 24	365021	1x17 1/2	360100*	PB 1" Dodge	811442*	1"	E
BSQ 30	365557	1 1/4x1X22 (original)	360101	PB 1 1/4 Dodge	822356	1"	2E
	366307	1s 2k	360101	PB 1 1/4 Dodge			
	366446	1 1/4x20.5 2k ECN 2161	360311		ECN 2161	1 1/4"	
BSQ 36	365554	1 1/2x1 1/4x22	360102	PB 1 1/2 Dodge	Consult	Factory	
	365007	1 1/2x21 2k (original)			ECN 2171 5-1-03	1 1/4"	2R
		1 1/2x1 1/4x23					
	366451	2k	360102	PB 1 1/2 Dodge	FRPM above 640		

Notes:

Shaft diameters increased on the dates indicated. To insure the correct shaft is ordered, verify shaft diameter and length prior to ordering. Two bearings required per fan. 1/4 to 1 HP use NBR 360422. 1 1/2 HP and above must use Dodge cast bearings.

* Where applicable, all replacement wheels furnished will be reinforced or embossed type. Where higher fan rpm's are indicated, a double reinforced wheel (2R) should be selected.

*366307 must be ordered with wheel 822356 for fan manufactured prior to 7-1-2000 ECN 1891.

*366446 must be ordered with wheel 825035 for fan manufactured prior to 4-10-03. ECN 2161.

*366451 must be ordered with wheels 826595 & 826574 for fan manufactured prior to 5-1-03. ECN 2171

When ordering replacement wheels for BSQ 300, 360 and 420 also required to order shafts due to design changes.

Confirm hub size 1 1/4 should order 365554 and 1 1/2 should order 365007.

+Please contact the Parts Department when ordering replacement wheels and shafts for BSQ 7 through 36.

Model BSQ-HP

Manufactured 1984 through August 1999

Model Size	Shaft Part #	Description	Bearing Part #	Description	Wheel Part #	Bore Size	Emb Std or Reinf. Emb.
BSQ 13 HP	365041	3/4x14 1/2	390099*	PB 3/4" Dodge	862852	3/4	S
BSQ 13 HP	365036	1x16	360100*	PB 1" Dodge	N/A	1	
BSQ 14 HP	365026	3/4x16	360099*	PB 3/4" Dodge	862680	3/4	S
BSQ 14 HP	365036	1x16	360100*	PB 1" Dodge	N/A	1	
BSQ 16 HP	365026	3/4x16	360099*	PB 3/4" Dodge	obsolete	3/4	S
BSQ 16 HP	365422	1x17	360100*	PB 1" Dodge	862616	1	S
BSQ 18 HP	365025	3/4x17	360099*	PB 3/4" Dodge	obsolete	3/4	S
BSQ 18 HP	365021	1x17 1/2	360100*	PB 1" Dodge	807693*	1	S
BSQ 21 HP	365095	3/4x18 1/2	360099&*	PB 3/4" Dodge	811458	3/4	S
BSQ 21 HP	365020	1x18 1/2	360100*	PB 1" Dodge	807696	1	S
BSQ 24 HP	365017	1x20	360100*	PB 1" Dodge	806168*	1	S
BSQ 30 HP	365555	1 1/4x1x27 1S 1KH	360101	PB 1 1/4 Dodge	822357*	1	S
	366308	1.25x26 1S 2K	360101	PB 1 1/4 Dodge	822357*	1	S
BSQ 36 HP	366450	1 1/2x1 1/4x29	360102	PB 1 1/2 Dodge	826749	1 1/4	S
	366450	1 1/2x1 1/4x30 2K 1S					

Notes:

Shaft diameters were changed on the dates indicated. To ensure the correct shaft is ordered, verify shaft diameter and length prior to ordering.

Two bearings required per fan.

* When ordering 826749 wheel, shaft part # 366450 is required. ECN 2171, dated 3-31-2003.

When ordering wheel part #810802, stepped shaft part #365556 is also required. (ECN 1140 dated 02-15-91)

Model CSP

QD Units

Manufactured July 2002 through present

Model Size	Motor Part #	Vendor	Vendor #	Grommets *	Wheel Part #	Bore Size
CSP-B110	302172	Fasco	7173-0008	370108, 370109, 455433 4 per unit	473304 456676	5/16 Hub Clip
CSP-B150	310198	Fasco	7173-0007	370108, 370109, 455433 4 per unit	473304 456676	5/16 Hub Clip
CSP-B200	302424	Fasco	7173-0099	370108, 370109, 455433 4 per unit	473304 456676	5/16 Hub Clip
CSP-A110	312499	MC	F0810B4221	370108, 370109, 455433 4 per unit	473303 456676	5/16 Hub Clip
CSP-A125	303039	MC	F0408B2782	370108, 370109, 455433 4 per unit	473303 456676	5/16 Hub Clip
CSP-A190	311559	MC	F0410B2783	370108, 370109, 455433 4 per unit	473303 456676	5/16 Hub Clip
CSP-A200	304983	Fasco	71902737	370108, 370109, 455433, 4 per unit	335290 456676	3/8 Hub Clip
CSP-A250	304983	Fasco	71902341	370108, 370109, 455433 4 per unit	335290 456676	3/8 Hub Clip
CSP-A290	304843	MC	A0810B3215	370108, 370109, 455433, 4 per unit	335290	3/8
CSP-A390	304842	MC	A0810B3214	370108, 370109, 455433 4 per unit	335290	3/8
CSP-A410	301817	MC	F0516B2512	370108, 370109, 455433 4 per unit	335122	1/2
CSP-A510	310225	MC	F0516B3868	370108, 370109, 455433 4 per unit	335304	1/2
CSP-A700	304970	Fasco	71902773	370108, 370109, 455433 4 per unit	335493	3/8 2 per unit
CSP-A710	301816	MC	F0524B2511	370108, 370109, 455433 4 per unit	335304	1/2
CSP-A780	309133	MC	D0824B3755	370108, 370109, 455433 4 per unit	335304	½ 2 per unit
CSP-A900	301833	Fasco	71513783	None required	335304	
CSP-A1050	301832	MC	F0532B3753	None required	335304	½ 2 per unit
CSP-A1410	302490	Fasco	71241796	None required	335304	½ 2 per unit
CSP-A1550	302022	Fasco	71241696	None required	335304	½ 2 per unit
CSP-A1750	302021	Fasco	71263623	None required	335071	½ 2 per unit
CSP-A2150	302021	Fasco	71263623	None required	335071	½ 2 per unit
CSP-A3600	303875	CE	8-194086-00		455457	5/8 2 per unit
		115-208-230 V		None required		

Notes:

*All 3 part #'s required to make one complete shock mount. 3 or 4 shock mounts are required per unit.

*Part number 304924 is superseded by part number 304984 (71902737)

Conversion Kits (CSP to SP)

Part #	Description
826688	CSP-B50 thru CSP-200
826684	CSP-A110 thru CSP-A190
826685	CSP-A200 thru CSP-A390
826686	CSP-A410, A510, A710, A780
826687	CSP-A900 thru CSP-A1550

Model CSP

See Note #2 at the bottom
for all motors on this page

February 1996 through June 2002

Model Size	Motor Part #	Vendor	Vendor part number	Shock Mount Part #	Description	Wheel Part #	Bore Size
CSP-7	302172	Fasco	7173-0008	370108 370109 455433	4/unit	473304 456676	5/16 Hub Clip
CSP-9	310198	Fasco	7173-0007	370108 370109 455433	4/unit	473304 456676	5/16 Hub Clip
CSP-12	302424	Fasco	7173-0099	370108 370109 455433	4/unit	473304 456676	5/16 Hub Clip
CSP-210	312499	MC	F0810B4221	370108 370109 455433	4/unit	473303 456676	5/16 Hub Clip
CSP-216	303039	MC	F0408B2782	370108 370109 455433	4/unit	473303 456676	5/16 Hub Clip
CSP-218	311559	MC	F0410B2783	370108 370109 455433	4/unit	473303 456676	5/16 Hub Clip
CSP-224	304983	Fasco	71902341	370108 370109 455433	4/unit	335290 456676	3/8 Hub Clip
CSP-226	304843	MC	A01810B3215	370108 370109 455433	4/unit	335290	3/8
CSP-228	304842	MC	A0810B3214	370108 370109 455433	4/unit	335290	3/8
CSP-250	301817	MC	F0516B2512	370108 370109 455433	4/unit	335122	1/2
CSP-252	310225 ZZ41199a	MC Fasco	F0516B3868 71513785	370108 370109 455433	4/unit	335123 335204	1/2 3/8
	3/8 shaft used 99G-00D					used from 99G-00D	
CSP-255	301816	MC	F0524B2511	370108 370109 455433	4/unit	335086	1/2
CSP-258	309133	MC	D0824B3755	370108 370109 455433	4/unit	335123	½ 2 per unit
CSP-260	301833	Fasco	71513783	None required		335123	½ 2 per unit
CSP-262	302490	Fasco	71513782	None required also need 382861		335123	½ 2 per unit
CSP-264	302490	Fasco	71241796	None required		335123	½ 2 per unit
CSP-265	302022	Fasco	71241696	None required		335123	½ 2 per unit
CSP-270	302021	Fasco	71263623	None required		335071*	½ 2 per unit
CSP-275	302021	Fasco	71263623	None required		335071*	½ 2 per unit
CSP-280	303875	CE	8-194086-00	None required		455457	5/8 2 per unit
	115-208-230 V						

Notes:

*304338 has been replaced with 304983 (1-1-03). New wheel 335290 required due to bore size change. 5/16" to 3/8".

Note #2: Order adapter part # 382861 at N/C with all motors on this page.

Model CSP

See Note #2 at the bottom
for all motors on this page

Manufactured April 1989 through January 1996

Model Size	Motor Part #	Vendor part Number	Shock Mount Part #	Description	Wheel Part #	Bore Size	Rotation
CSP-108A	301814 MC	F0408B2509	869365	DUR 40	335009	5/16	CCW
CSP-115A	301813 MC	F0508B2508	869365	DUR 40	335120	3/8	CCW
CSP-117A	301814 MC	F0408B2509	869365	DUR 40	335124	5/16	CCW
CSP-125A	301813 MC	F0508B2508	869365	DUR 40	335121	3/8	CCW
CSP-127A	301839 Fasco	71086922	370064	Gasket	335121	3/8	CCW
CSP-150A	301817 MC	F0516B2512	869365	DUR 40	335122	1/2	CCW
CSP-152A	310225 Fasco	71513785	869365	DUR 40	335123	1/2	CCW
CSP-158A	309133 Fasco	71840078	370108* 370109 455433		335123	1/2	CCW
CSP-160A	301833 Fasco	71513783	None Required		335123	1/2	2/Unit
CSP-162A	302490 MC	F0532B3753	None Required		335123	1/2	2/Unit
CSP-165A	302022 Fasco	71241696	None Required		335123	1/2	2/Unit
CSP-170	302021 Fasco	71263623	None Required		335071	1/2	2/Unit
CSP-175	302021 Fasco	71263623	None Required		335071	1/2	2/Unit

Notes:

Four shock mounts required per unit.

SP 160 - 165/ CSP 160A - 175 have two wheels per unit

*All 3 part #'s required to make one complete shock mount. 3 or 4 shock mounts are required per unit.

Note #2: Order adapter part # 382861 at N/C with all motors on this page

Hinge Kits (CUBE)

Model	CAPS Model	Part # (New)	Part # (Old)
CUBE-220/240	HC-22-24	853442	851396
CUBE-300	HC-30	853443	851398
CUBE-360	HC-36	853444	851400
CUBE-420	HC-42	853445	851402
CUBE-480	HC-48	853446	851404

Model CUBE

Manufactured May 2003 through present

Model Size	Shaft Part #	Description	Bearing Part #	Description	Wheel Part #	Bore Size	Description
CUBE 098	365030	3/4X13	360099	PB 3/4" Dodge	809835	3/4"	Standard
CUBE 098-T	365025	3/4X17			820207	3/4"	Teflon Coated
CUBE 101	365030	3/4X13	360099	PB 3/4" Dodge	870762	3/4"	Standard
CUBE 101-T	365025	3/4X17					
CUBE 121	365041	3/4X4 1/2	360099	PB 3/4" Dodge	862879	3/4"	Standard
CUBE 121-T	365095	3/4X18 1/2			862881	3/4"	Teflon Coated
CUBE 131	365063	3/4X13 1/2	360099	PB 3/4" Dodge	862895	3/4"	Standard
CUBE 131-T	365025	3/4X17			862897	3/4"	Teflon Coated
CUBE 141	365041	3/4X14 1/2	360099	PB 3/4" Dodge	862688	3/4"	Standard
CUBE 141-T	365025	3/4X17			820211	3/4"	Teflon Coated
CUBE 161	365041	3/4X14 1/2	360099	PB 3/4" Dodge	862644	3/4"	Standard
CUBE 161-T	365025	3/4X17			862646	3/4"	Teflon Coated
CUBE 180	365025	3/4X17	360099	PB 3/4" Dodge	811457	3/4"	Standard
CUBE 180-T	365001	3/4X20			820215	3/4"	Teflon Coated
CUBE 200	365025	3/4X17	360099	PB 3/4" Dodge	811458	3/4"	Standard
CUBE 200-T	365001	3/4X20			820217	3/4"	Teflon Coated
CUBE 220	365020	1X18 1/2	360100	PB 1" Dodge	811739	1"	Standard
CUBE 220-T	365031	1X22			820219	1"	Teflon Coated
CUBE 240	365020	1X18 1/2	360100	PB 1" Dodge	811739	1"	Standard
CUBE 240-T	365031	1X22			820219	1"	Teflon Coated
CUBE 300	365031	1X22K	360100	PB 1" Dodge	822358	1"	Standard
CUBE 300-T	365084	1X25.5 2K			822361	1"	Teflon Coated
CUBE 360	365089	1 1/4X22 1/4 W/H	360311	* PB 1 1/4" Dodge	826577	1 1/4"	Standard
CUBE 360-T	365103	1 1/4X25 W/H					
	365010	1 1/4X23 2K					
	365015	1 1/4X26 2K					
CUBE 420	365090	1 1/4X23 3/4 W/H	360311	* PB 1 1/4" Dodge	826564	1 1/4"	Standard
CUBE 420-T	365105	1 1/4X25 W/H					
	365078	1 1/4X24 2K					
	365071	1 1/4X28.5 2K					
CUBE 480	365092	1 1/2X26 W/H	360102	* PB 1 1/2" Dodge	826838	1 1/2"	Standard
CUBE 480-T	365111	1 1/2X29 W/H					
	365091	1 1/2X27 2K					
	365068	1 1/2X30 2K					

Notes:

* 1 1/4" Bearings for units built as of 4-1-97 not interchangeable with 360101

The "T" (tall unit) designation does not appear in the unit model number. Shaft length must be measured prior to ordering replacement shaft.

Where applicable, all replacement wheels furnished will be reinforced type or embossed.

365010, 365015 are required with wheel 826577 for fan manufactured prior to 5-1-2003. ECN 2171

365078, 365071 are required with wheel 826563 for fan manufactured prior to 5-1-2003. ECN 2171

365091 or 365068 are required with wheel 826838 for fan manufactured prior to 8/11/03. ECN 2201

Model CUBE

Manufactured September 1990 through January 2000

Model Size	Shaft Part #	Description	Bearing Part #	Description	Wheel Part #	Bore Size	Description
CUBE 95/98	365030	3/4X13	360099	PB 3/4" Dodge	809835	3/4"	Standard
CUBE 95-T/98-T	365025	3/4X17			820207	3/4"	Teflon Coated
CUBE 100	365030	3/4X13	360099		870762	3/4"	Standard
CUBE 100-T	365025	3/4X17					Teflon Coated
CUBE 120	365041	3/4X4 1/2	360099	18-19	862879	3/4"	Standard
CUBE 120-T	365095	3/4X18 1/2			862881	3/4"	Teflon Coated
CUBE 130	365063	3/4X13 1/2	360099	24-28	862895	3/4"	Standard
CUBE 130-T	365025	3/4X17			862897	3/4"	Teflon Coated
CUBE 140	365041	3/4X14 1/2	360099	PB 3/4" Dodge	862688	3/4"	Standard
CUBE 140-T	365025	3/4X17			820211	3/4"	Teflon Coated
CUBE 160	365041	3/4X14 1/2	360099		862644	3/4"	Standard
CUBE 160-T	365025	3/4X17			862646	3/4"	Teflon Coated
CUBE 180	365025	3/4X17	360099	PB 3/4" Dodge	811457	3/4"	Standard
CUBE 180-T	365001	3/4X20			820215	3/4"	Teflon Coated
CUBE 200	365025	3/4X17	360099	PB 3/4" Dodge	811458	3/4"	Standard
CUBE 200-T	365001	3/4X20			820217	3/4"	Teflon Coated
CUBE 220	365020	1X18 1/2	360100	PB 1" Dodge	811739	1"	Standard
CUBE 220-T	365031	1X22			820219	1"	Teflon Coated
CUBE 240	365020	1X18 1/2	360100	PB 1" Dodge	811739	1"	Standard
CUBE 240-T	365031	1X22			820219	1"	Teflon Coated
CUBE 300	365088	1/22 W/H	360100	PB 1" Dodge	822358	1"	Standard
CUBE 300-T	365884	1X26 W/H			822361	1"	Teflon Coated
	365031	1X22K					
	365084	1X25.5 2K					
CUBE 360	365089	1 1/4X22 1/4 W/H	360101	* PB 1 1/4" Dodge	Obsolete	1 1/4"	
CUBE 360-T	365103	1 1/4X25 W/H	360311				
CUBE 420	365090	1 1/4X23 3/4 W/H	360101	* PB 1 1/4" Dodge	Obsolete	1 1/4"	Standard
CUBE 420-T	365105	1 1/4X25 W/H	360311				
CUBE 480	365092	1 1/2X26 W/H	360102	PB 1 1/2" Dodge	826838	1 1/2"	Standard
CUBE 480-T	365111	1 1/2X29 W/H	360102	PB 1 1/2" Dodge			
	365091	1 1/2X27 2K					
	365068	1 1/2X30 2K					

Notes:

* 1 1/4" Bearings for units built as of 4-1-97 not interchangeable with 360101

The "T" (tall unit) designation does not appear in the unit model number. Shaft length must be measured prior to ordering replacement shaft.

Where applicable, all replacement wheels furnished will be reinforced type or embossed.

365084 & 365031 must be used with 822358 wheel, manufactured prior to 7-1-2000 ECN 1891

365091 or 365068 must be used with wheel 826838 manufactured prior to 8/11/03. ECN 2201

Model CUBE

Manufactured 1979 through 1989

Model Size	Shaft Part #	Description	Date Changed	Bearing Part #	Description	Wheel Part #	Bore Size	Emb Std or Reinf
CUBE 10	365093	3/4x12 ½		360099	PB 3/4 Dodge	870762	3/4	S
CUBE 10T	365026	3/4x16				870762	3/4	S
CUBE 14	365063	3/4x13 ½				862881	3/4	S
CUBE 14T	365026	3/4x16		360099	PB 3/4 Dodge	862688	3/4	S
CUBE 18	365026	3/4x16		360099	PB 3/4 Dodge	811457	3/4	E
CUBE 18T	365001	3/4x20	Serial # 87D			811457	3/4	E
CUBE 18T	365366	1X20 ¾	thru 87I use 1" bore	360100	PB 1" Dodge	1" OBS. w/ 3/4" bearings & shaft pulley	Must replace wheel, shaft shaft pulley	
CUBE 21	365025	3/4X17		360099	PB 3/4 Dodge	811458	3/4	E
CUBE 21T	365001	3/4X20				811458	3/4	E
CUBE 21T	365366	1X20 ¾	Serial # 87D thru 87I use 1" bore	360100	PB 1" Dodge	1" OBS. w/ 3/4" bearings & shaft pulley	Must replace wheel, shaft shaft pulley	
CUBE 24	365095	3/4x18 ½	Contact parts depart. with serial # verify shaft size	360099	PB 3/4 Dodge	Obsolete	3/4	E
CUBE 24T	365094	34x22						
CUBE 24	365020	1x18 ½		360100	PB 1" Dodge	811739	1 "	E
CUBE 24T	365031	1x22						
CUBE 30	365088	1x22 w/h		360100	PB 1" Dodge	822358	1"	E
CUBE 30T	365884	1x26 w/h	1980-81 units used 1 1/4 shaft			822361	1"	E
	365031	1x22 2k						
	365084	1x25.5 2k						
CUBE 36	365089	1 1/4x22 ¼ w/h	1980-81 units used 1 1/2 shaft	360101	PB 1 1/4 Dodge	Obsolete	1 1/4	E
CUBE 36T	365103	1 1/4x25 w/h					1 1/4	E
CUBE 42	365090	1 1/4x23 ¾ w/h	1980-81 units used 1 1/2 shaft	360101	PB 1 1/4 Dodge	Obsolete	1 1/4	E
CUBE 42T	365105	1 1/4x28 w/h					1 1/4	E
CUBE 48	365092	1 1/2X26 w/h	1980-81 units used 1 3/4 shaft	360102	PB 1 1/2 Dodge	826838	1 1/2	E
CUBE 48T	365111	1 1/2X29 w/h						
	365091	1 1/2X27 2K						
	365068	1 1/2X30 2K						

Notes:

The "T" (tall unit) designation does not appear in the unit model number. Shaft length must be measured prior to ordering replacement shaft.

Shaft diameters were changed on the dates indicated. Shaft length must be measured prior to ordering replacement.

Where applicable, all replacement wheels furnished will be reinforced type or embossed.

365084 & 365031 must be used with 822358 wheel, manufactured prior to 7-1-2000 ECN 1891

365091 or 365068 must be used with wheel 826838 manufactured prior to 8/11/03. ECN 2201

Model CUBE

Manufactured 1979 through 1989

Model Size	Shaft Part #	Description	Date Changed	Bearing Part #	Description	Wheel Part #	Bore Size
CUBE-14HP-3G-QD	365093	3/4x12 1/2		360099	PB 3/4" Dodge	862677	3/4
CUBE-14HP-7G-QD	365001	3/4x20		360099	PB 3/4" Dodge	862677	3/4
CUBE-14HP		For Burger King		360099	PB 3/4" Dodge	862679	3/4
CUBE-18HP	365095	3/4x18 1/2	Units built thru	36099	PB 3/4" Dodge	Obsolete	
CUBE-18HPT	365099	3/4x22	87I use 3/4"	360099	PB 3/4" Dodge	Obsolete	
CUBE-18HP-10G-QD3	365431	1x19		360100	PB 1" Dodge	807693	1 "
CUBE-18HP-10G-QD	365031	1x22		360100	PB 1" Dodge	807693	1"
CUBE-21HP	365095	3/4x18 1/2	Units built thru	360099	PB 3/4" Dodge	811458	3/4
CUBE-21HPT	365094	3/4x22	87F use 3/4"	360099	PB 3/4" Dodge	811458	3/4
CUBE-21HP-15G-QD3	365431	1x19		360100	PB 1" Dodge	807696	1 "
CUBE-21HP-15G-QD	365031	1x22		360100	PB 1" Dodge	807696	1"
CUBE-24HP	365099	3/4x21	Units built thru	360099	PB 3/4" Dodge	obsolete	3/4
CUBE-24HPT	365100	3/4x24	87F use 3/4"	360099	PB 3/4" Dodge	obsolete	3/4
CUBE-24HP	365031	1x22		360100	PB 1" Dodge	806168	1 "
CUBE-24HP-30G-QD3	365084	1x25 1/2		360100	PB 1" Dodge	806168	1"
CUBE-30HP	365884	1x26 w/hole		360100	PB 1" Dodge	822357	1 "
CUBE-30HPT	365104	1x28 w/hole		360100	PB 1" Dodge	822357	1"
	365084	1x25.5 2K					
	365736	1x28 2K					
CUBE-36HP	365103	1 1/4x2 w/hole		360101	PB 1 1/4 Dodge	826580	1 1/4
CUBE-36HPT	365105	1 1/4x28 w/whole		360101	PB 1 1/4 Dodge	826580	1 1/4
	365015	1 1/4x26 2K		360311		826580	
	365071	1 1/4x28.5 2K		360311		826580	

Notes:

The "T" (tall unit) designation does not appear in the unit model number. Shaft length must be measured prior to ordering replacement shaft.

Shaft diameters were changed on the dates indicated. Shaft length must be measured prior to ordering replacement.

Where applicable, all replacement wheels furnished will be reinforced type or embossed.

365084 & 365736 are required with wheel 822357, manufactured prior to 7-1-2000 ECN 1891

365015, 365071 are required with wheel 826580, manufactured prior to 5-1-2003. ECN 2171

Model CUBE-HP

Manufactured February 2000 through present

Model Size	Shaft Part #	Description	Bearing Part #	Description	Wheel Part #	Bore Size	Emb Std or Reinf
CUBE 141HP	365024	¾ x18	360099	PB ¾" Dodge	862677	¾	S
CUBE 141HP7GQD	365001	¾ x20	360099	PB ¾" Dodge	862677	¾	S
CUBE 141HP		For Burger King	360099	PB ¾" Dodge	862679	¾	Teflon
SD-CUBE-141HP-7G	365862	1X21.25	360100	PB 1" Dodge	825818	1"	Teflon
CUBE-161HP-LMDG-QD	365024	¾ X18	360099	PB ¾" Dodge	862594	¾	S
					862596	¾	Teflon
CUBE 180HP 10GQD3	365431	1X19	360100	PB 1" Dodge	807693	1"	S
CUBE 180HPT	365031	1X22	360100	PB 1" Dodge	820216	1"	Teflon
CUBE 200HP 15GQD3	365431	1X19	360100	PB 1" Dodge	807696	1"	S
CUBE 200HPT	365031	1X22	360100	PB 1" Dodge	820218	1"	Teflon
CUBE 220HP	365031	1X22	360100	PB 1" Dodge	806168	1"	S
CUBE 220HPT	365084	1X25 ½	360100	PB 1" Dodge	820220	1"	Teflon
CUBE 240HP	365031	1X22	360100	PB 1" Dodge	806168	1"	S
CUBE 240HP 30GQD3	365084	1X25 ½	360100	PB 1" Dodge	820220	1"	Teflon
CUBE 300HP	365884	1x26 w/hole	360100	PB 1" Dodge	822357	1"	S
CUBE 300HPT	365104	1x28 w/hole	360100	PB 1" Dodge	822360	1"	Teflon
	365084	1X25.5 2K					
	365736	1X28 2K					
CUBE 360HP	365103	1 ¼ x25 ¼ w/hole	360101	PB 1 1/4 Dodge	826580	1 ¼	S
CUBE 360HPT	365105	1 ¼ x28 w/hole	360311		826580	1 ¼	S
	365015	1 ¼ X26 2K	360311		826580		
	365071	1 ¼ X28.5 2K	360311		826580		

Notes:

* 1 1/4" Bearings for units built as of 4-1-97 not interchangeable with 360101

The "T" (tall unit) designation does not appear in the unit model number. Shaft length must be measured prior to ordering replacement shaft.

Shaft diameters were changed on the dates indicated. Shaft length must be measured prior to ordering replacement.

365084 & 365736 are required with wheel 822357, manufactured prior to 7-1-2000 ECN 1891

365015, 365071 are required with wheel 826580, manufactured prior to 5-1-2003. ECN 2171

Model CUBE-HP

Manufactured March 1990 through January 2000

Manufactured March 1986 through January 2000						
Model Size	Shaft Part #	Description	Bearing Part #	Description	Wheel Part #	Bore Size
CUBE 140HP	365024	¾ x18	360099	PB ¾ " Dodge	862677	¾
CUBE 140HP7GQD	365001	¾ x20	360099	PB ¾ " Dodge	862677	¾
CUBE 140HP		For Burger King	360099	PB ¾ " Dodge	862679	¾
SD-CUBE-140HP-7G	365862	1x21.25	360100	PB 1" Dodge	825818	1"
CUBE-160HP-LMDG-QD	365024	¾ x18	360099	PB 3/4" Dodge	862594	¾
					862596	¾
CUBE 180HP 10GQD3	365431	1x19	360100	PB 1" Dodge	807693	1"
CUBE 180HPT	365031	1x22			820216	1"
CUBE 200HP 15GQD3	365431	1x19	360100	PB 1" Dodge	807696	1"
CUBE 200HPT	365031	1x22			820218	1"
CUBE 220HP	365031	1x22	360100	PB 1" Dodge	806168	1"
CUBE 220HPT	365084	1x25 ½			820220	1"
CUBE 240HP	365031	1x22	360100	PB 1" Dodge	806168	1"
CUBE 240HP 30GQD3	365084	1x25 ½			820220	1"
CUBE 300HP	365884	1x26 W/hole	360100	PB 1" Dodge	822357	1"
CUBE 300HPT	365104	1x29 W/hole			822360	1"
	365084	1x25.5 2k				
	365736	1x28 2k				
CUBE 360HP	365103	1 ¼ x25 ¼ w/ hole	360101	PB 1 ¼ Dodge	826580	1 ¼
CUBE 360HPT	365105	1 ¼ x28 w/ hole	360311		826580	1 ¼
	365015	1 ¼ Xx6 2K	360311		826580	
	365071	1 ¼ x28.5 2K			826580	

Notes:

* 1 1/4" Bearings for units built as of 4-1-97 not interchangeable with 360101

The "T" (tall unit) designation does not appear in the unit model number. Shaft length must be measured prior to ordering replacement shaft.
 Shaft diameters were changed on the dates indicated. Shaft length must be measured prior to ordering replacement.

365084 & 365736 are required with wheel 822357, manufactured prior to 7-1-2000 ECN 1891

365015, 365071 are required with wheel 826580, manufactured prior to 5-1-2003. ECN 2171

Model CUE

Model Size	Wheel Part #	Bore Size
60	819618	5/16
75	819621	5/16
95	820546	1/2
	821354	5/8
98	821353	1/2
	821354	5/8
120	862873	1/2
140	862682	1/2
	812000	5/8

Model CW

QD Units

Manufactured February 2000 through present

Model Size	Motor Part #	HP	Vendor	Vendor #	Motor RPM	Voltage Phase	Shock Mount Part #	Wheel Part #	Bore Size
CW 060	300457	1/60	Fasco	71635387	1050/1300/1550	115	370084*	819618*	5/16
CW 065	300453	1/30	Fasco	71635375	1050/1300/1550	115	370084*	819619*	5/16
CW 070	300453	1/30	Fasco	71635375	1050/1300/1550	115	370084*	819620*	5/16
CW 075	302529*	1/25	MC	F0412B2690	1050/1300/1550	115	370084*	819621*	5/16
CW 080	301639	1/20	Fasco	71086857	1050/1300/1550	115	370084*	820543*	1/2
CW 085	301639	1/20	Fasco	71086857	1050/1300/1550	115	370084*	820544*	1/2
CW 090	301638	1/15	Fasco	71086848	1050/1300/1550	115	370084*	820545*	1/2
CW 095	308318	1/8	MC	A0820B3680	1050/1300/1550	115	370084*	820546*	1/2
CW 098-B	300010	1/6	ME	48A11O251	1140	115	370007	820931*	1/2
CW 101-B	300010	1/6	ME	48A11O251	1140	115	370007	820931*	1/2
CW 121-B	300010	1/6	ME	48A11O251	1140	115	370007	862873	1/2
CW 131-B	300010	1/6	ME	48A11O251	1140	115	370007	862875	1/2
CW 141-B	311340	1/4	Fasco	71264304	1140	115	370007	862682	1/2

Notes: *Drill new holes

302529 supersedes part#300451 (Fasco 71635376), part #300451 (MC F0412690)

301639 supersedes part #302530 (McMillan D0810B2691)

308318 supersedes part#302336 (McMillan A0820B2633)

300010 supersedes part# 311585 (ME 048A110251), 303442 (Fasco 7264107), 304207 (Fasco 71264304), part #300012 (ME 48A110186)

QD Units

Manufactured January 1999 through January 2000

Model Size	Motor Part #	HP	Description	Vendor #	Motor RPM	Voltage Phase	Shock Mount Part #	Wheel Part #	Bore Size
CW 60	300457	1/60	Fasco	71635387	1050/1300/1550	115	370084*	819618*	5/16
CW 65	300453	1/30	Fasco	71635375	1050/1300/1550	115	370084*	819619*	5/16
CW 70	300453	1/30	Fasco	71635375	1050/1300/1550	115	370084*	819620*	5/16
CW 75	302529*	1/25	MC	F0412B2690	1050/1300/1550	115	370084*	819621*	5/16
CW 80	301639	1/20	Fasco	71086857	1050/1300/1550	115	370084*	820543*	1/2
CW 85	301639	1/20	Fasco	71086857	1050/1300/1550	115	370084*	820544*	1/2
CW 90	301638	1/15	Fasco	71086848	1050/1300/1550	115	370084*	820545*	1/2
CW 95	308318	1/8	MC	A0820B2633	1050/1300/1550	115	370084*	820546*	1/2
CW 98-B	300010	1/6	ME	48A11O251	1140	115	370007	820931*	1/2
CW 100-B	300010	1/6	ME	48A11O251	1140	115	370007	820931*	1/2
CW 120-B	300010	1/6	ME	48A11O251	1140	115	370007	862873	1/2
CW 130-B	300010	1/6	ME	48A11O251	1140	115	370007	862875	1/2
CW 140-B	311340	1/4	Fasco	71264304	1140	115	370007	862682	1/2

Notes: *Drill new holes

302529 supersedes part#300451 (Fasco 71635376), part #300451 (MC F0412690) See Note above.

301639 supersedes part #302530 (MC D0810B2691)

300010 supersedes part# 311585 (ME 048A110251), part# 303442 (Fasco 7264107), 304207 (Fasco 71264304), part #300012 (ME 48A110186)

Model CWB

Manufactured February 2000 through present

Model Size	Shaft Part #	Description	Bearing Part #	Description	Wheel Part #	Bore Size	Emb Std or Reinf
CWB-098	365030	3/4x13	360099*	PB 3/4" Dodge	809835	3/4 "	STD
	365025	3/4x17					
CWB-101	365093	3/4x12 1/2	360099*	PB 3/4" Dodge	870762	3/4 "	STD
	365026	3/4x16					
CWB-121	365041	3/4x14 1/2	360099*	PB 3/4" Dodge	862879	3/4 "	STD
	365095	3/4x18 1/2					
CWB-131	365041	3/4x13 1/2	360099*	PB 3/4" Dodge	862895	3/4 "	STD
	365025	3/4x17					
CWB-141	365041	3/4x14 1/2	360099*	PB 3/4" Dodge	862688	3/4 "	STD
	365025	3/4x17					
CWB-141HP	365024	3/4x18 1/2	360099*	PB 3/4" Dodge	862677	3/4 "	STD
	365001	3/4x20					
CWB-161	365041	3/4x14 1/2	360099*	PB 3/4" Dodge	862644	3/4 "	STD
	365025	3/4x17					
CWB-161HP	365986	3/4x16 1/2	360099*	PB 3/4" Dodge	862594	3/4 "	STD
	365095	3/4x18 1/2					
CWB-180	365986	3/4x16 1/2	360099*	PB 3/4" Dodge	811457	3/4 "	STD
	365001	3/4x20					
CWB-180HP	365431	1x19	360100*	PB 1" Dodge	807693	1 "	STD
	365031	1x22					
CWB-200	365020	3/4x16 1/2	360099*	PB 1" Dodge	811458	1 "	STD
	365031	3/4x20					
CWB-200HP	365031	1x19	360100*	PB 1" Dodge	807696	1 "	STD
	365084	1x22					
CWB-220	365020	1x18 1/2	360100*	PB 1" Dodge	811739	1 "	STD
	365031	1x22					
CWB-220HP	365031	1x22	360100*	PB 1" Dodge	806168	1 "	STD
	365084	1x25 1/2					
CWB-240	365020	1x1801/2	360100*	PB 1" Dodge	811739	1 "	STD
	365031	1x22					
CWB-240HP	365031	1x22	360100*	PB 1" Dodge	806168	1 "	STD
	365084	1x25 1/2					
CWB-300	365031	1x22 1/2 w/ hole	360100*	PB 1" Dodge	822358	1 "	STD
	365884	1x26 w/ hole					
CWB-300HP	365884	1x26 w/ hole	360100*	PB 1" Dodge	822357	1 "	STD
	365736	1x29 w/ hole					

Model CWB

Manufactured January 1999 through January 2000

Model Size	Shaft Part #	Description	Bearing Part #	Description	Wheel Part #	Size	Emb Std or Reinf
CWB-98	365030	3/4x13	360099	PB 3/4" Dodge	809835	3/4"	STD
	365025 *	3/4x17					
CWB-100	365093	3/4x12 1/2	360099	PB 3/4" Dodge	870762	3/4"	STD
	365026	3/4x16					
CWB-120	365041	3/4x14 1/2	360099	PB 3/4" Dodge	862879	3/4"	STD
	365095	3/4x18 1/2					
CWB-130	365041 *	3/4x18 1/2	360099	PB 3/4" Dodge	862895	3/4"	STD
	365025 *	3/4x17					
CWB-140	365041	3/4x14 1/2	360099	PB 3/4" Dodge	862688	3/4"	STD
	365025 *	3/4x17					
CWB-140HP	365024	3/4x18 1/2	360099	PB 3/4" Dodge	862677	3/4"	STD
	365001 *	3/4x20					
CWB-160	365041	3/4x14 1/2	360099	PB 3/4" Dodge	862644	3/4"	STD
	365025 *	3/4x17					
CWB-160HP	365986	3/4x16 1/2	360099	PB 3/4" Dodge	862594	3/4"	STD
	365095	3/4x18 1/2					
CWB-180	365986	3/4x16 1/2	360099	PB 3/4" Dodge	811457	3/4"	STD
	365001 *	3/4x20					
CWB-180HP	365431	1x19	360100	PB 1" Dodge	807693	1 "	STD
	365031	1x22					
CWB-200	365020	3/4x16 1/2	360099	PB 1" Dodge	811458	1 "	STD
	365031	3/4x20					
CWB-200HP	365031	1x19	360100	PB 1" Dodge	807696	1 "	STD
	365084	1x22					
CWB-220	365020	1x18 1/2	360100	PB 1" Dodge	811739	1 "	STD
	365031	1x22					
CWB-220HP	365031	1x22	360100	PB 1" Dodge	806168	1 "	STD
	365084	1x25 1/2					
CWB-240	365020	1x180 1/2	360100	PB 1" Dodge	811739	1 "	STD
	365031	1x22					
CWB-240HP	365031	1x22	360100	PB 1" Dodge	806168	1 "	STD
	365084	1x25 1/2					
CWB-300	365031	1x22 1/2 w/hole	360100	PB 1" Dodge	822358	1 "	STD
	365884	1x26 w/hole					
CWB-300HP	365884	1x26 w/hole	360100	PB 1" Dodge	822357	1 "	STD
	365736	1x29 w/hole					

Notes:

*The "T" (tall unit) designation does not appear in the unit model number. Shaft length must be measured prior to ordering replacement shaft.

Shaft diameters were changed on the dates indicated. Shaft length must be measured prior to ordering replacement.

Where applicable, all replacement wheels furnished will be reinforced type or embossed.

Model DSQ

Manufactured 1984 through August 1990

Model Size	Motor Part #	Vendor	Vendor #	Shock Mount Part #	Description	Wheel Part #	Size	Emb Std or Reinf.
DSQ-70-DGE	301462	1/25 Fasco	71637303	370007	Grom 7/8-5/16	819632	5/16	S
DSQ-75-DGE	Contact the parts department with serial #			370007	Grom 7/8-5/16	819633	* 5/16	S
						820554	* 1/2	S
DSQ-80-DGE	300760	1/15 Fasco	71086431	370007	Grom 7/8-5/16	820928	* 1/2	S
DSQ-85-DGE	300760	1/15 Fasco	71086431	370007	Grom 7/8-5/16	820930	* 1/2	S
DSQ-90-DGE	302603	1/14 MC	D0816A2676	370007	Grom 7/8-5/16	820924	* 1/2	S
DSQ-95-DGE	311742	1/8 MC	A0816A4075	370007	Grom 7/8-5/16	820926	* 1/2	S
DSQ-100-B	301772	1/6 1140	ME48A1101640	None required		862493	* 1/2	S
DSQ-100-A	300016	1/4 ME	ME48S17D2055	None required		862493	* 1/2	S
DSQ-120-B	301772	1/6 1140	ME48A1101640	None required		862885	1/2	S
DSQ-130-B	311340	1/4 1140	ME48A110186	None required		862899	* 1/2	E
DSQ-140-B	301643	1/3 1140	ME56A11D65	None required			5/8	E

Notes:

* Four shock mounts required per unit.

Model EQB

Manufactured 2014 through Present

Model Size	Shaft Part #	Description	Key	Bearing Part #	Description	Wheel Part #
EQB-12	365986 366011	3/4x16 1/2 - Steel 3/4x17 – 316 SS	450034 (2)	360099 (2)	PB 3/4" Dodge	871551
EQB-15	365024	3/4x18 - Steel	450034 (2)	360099 (2)	PB 3/4" Dodge	871552
EQB-18	365017 365620	1x20 - Steel 1x20.75 - Steel	450033 (2) 454864 (2)	360100 (2)	PB 1" Dodge	871554
EQB-22	366495	1.25x25 - Steel	450033 (2)	360311 (2)	PB 1" Dodge	871556
EQB-27	365070 365624	1.25x28 – Steel 1.25x28 – Spec. SS	450033 (2) 454864 (2)	360311 (2)	PB 1" Dodge	871558
EQB-30	367729 367730	1.25x32.5 - Steel 1.25x32.5 -316 SS	450033 (2) 454864 (2)	360099 (2)	PB 3/4" Dodge	871559

Model G Units

QD Units

Manufactured February 2000 through the present

Model Size	Motor Part #	HP	Vendor	Vendor #	Motor RPM	Voltage Phase	Shock Mount Part #	Description	Wheel Part #	Bore Size	S or R
G 060	300457*	1/60	Fasco	71635387	1050/1300/1550	115-60-1	370084	Dur 60	819618	5/16	S
G 065	300453*	1/30	Fasco	71635375	1050/1300/1550	115-60-1	370084	Dur 60	819619	5/16	S
G 070	300453*	1/30	Fasco	71635375	1050/1300/1550	115-60-1	370084	Dur 60	819620	5/16	S
G 075	302529*	1/25	MC	F0412B2690	1050/1300/1550	115-60-1	370084	Dur 60	819621	5/16	S
G 080	301639*	1/20	Fasco	71086857	1050/1300/1550	115-60-1	370084	Dur 60	820543	1/2	S
G 085	301639*	1/20	Fasco	71086857	1050/1300/1550	115-60-1	370084	Dur 60	820544	1/2	S
G 090	301638*	1/15	Fasco	71086848	1050/1300/1550	115-60-1	370084	Dur 60	820545	1/2	S
G 095	308318*	1/8	MC	A0820B3680	1050/1300/1550	115-60-1	370084	Dur 60	820546	1/2	S
G 101-A	311338	1/4	ME	48A170286	1725	115-60-1			820931	1/2	S
G 101-B	300010	1/6	ME	48A110251	1140	115-60-1			820931	1/2	S
G 101-C	300008	1/8	ME	48A8011005	860	115-60-1			820931	1/2	S
G 121-A	311338	1/4	ME	48A170286	1725	115-60-1			820932	1/2	S
G 121-B	300010	1/6	ME	48A110251	1140	115-60-1			820932	1/2	S
G 121-C	300008	1/8	ME	48A8011005	860	115-60-1			820932	1/2	S
G 131-A	311588	1/2	ME	48S17D2058	1725	115-60-1			820933	1/2	S
G 131-B	300010	1/6	ME	48A110251	1140	115-60-1			820933	1/2	S
G 131-C	300008	1/8	ME	48A8011005	860	115-60-1			820933	1/2	S
G 141-B	300010	1/6	ME	48A110251	1140	115-60-1			820934	1/2	S
G 141-C	300008*	1/8	ME	48A8011005	860	115-60-1			820934	1/3	S
G 150-C	300008*	1/8	ME	48A8011005	860	115-60-1			804631	1/2	S
G 150-B	311340	1/4	ME	48A110186	1140	115-60-1			804631	1/2	S
G 160-B	301643	1/3	ME	56A11D65	1140	115-60-1			804707	5/8	S

Notes:

311340 supersedes part # 300012 (ME 48A110186)

300010 supersedes part #311585 (ME 48A110251), 303442 (ME48A110251)

300008 supersedes part #303443 (ME 48A80151)

301639 supersedes part #302530 (MC D0810B2691), 300120 (Fasco 71082425),

300190 (Franklin 8414010270), 300192 (Franklin 8424010250), and 300461 (Universal Electric CA2G173N)

300453 supersedes part #300452 (Franklin 8264110430) and 300118 (Fasco 71632491)

*308318 supersedes part #302336 (McMillan A0820B2633), part #301652 (Fasco 1/8 HP 71241411), 300455 (Fasco 71240360) & 300454 (Franklin 8743810240)

300457 supersedes part #300456 (Franklin 8263710160) and 300119 (Fasco 71632492)

301638 supersedes part #300459 (Fasco 71086194) and 300460 (Universal Electric CA2G174N)

302529 supersedes part #300451 (MC F0412690), 300451 (Fasco 71635376 & 300450 (Franklin 8264110420)

301643 supersedes part #300239 (ME 56A11D33)

304751 supersedes part #301778 (ME 48A170227), 300218 (GE KCP37KN143)

*300455 will require new bolt pattern to be drilled

Model G/GW

QD Units

Manufactured before February 2000

Model Size	Motor Part #	HP	Vendor	Vendor #	Motor RPM	Voltage Phase	Shock Mount Part #	Description	Wheel Part#	Bore Size	S or R
G/GW60	300457	1/60	Fasco	71635387	1050/1300/1550	116-60-1	370084	Dur 60	819618	5/16	S
G/GW65	300453	1/30	Fasco	71635375	1050/1300/1550	115-60-1	370084	Dur 60	819619	5/16	S
G/GW70	300453	1/30	Fasco	71635375	1050/1300/1550	115-60-1	370084	Dur 60	819620	5/16	S
G/GW75	302529	1/25	MC	F0412B2690	1050/1300/1550	115-60-1	370084	Dur 60	819621	5/16	S
G/GW80	301639	1/20	Fasco	71086857	1050/1300/1550	115-60-1	370084	Dur 60	820543	1/2	S
G/GW85	301639	1/20	Fasco	71086857	1050/1300/1550	115-60-1	370084	Dur 60	820544	1/2	S
G/GW90	301638	1/15	Fasco	71086848	1050/1300/1550	115-60-1	370084	Dur 60	820545	1/2	S
G/GW95	308318	1/8	MC	A0820B3680	1050/1300/1550	115-60-1	370084	Dur 60	820546	1/2	S
G/GW100-B	311388	1/6	ME	48A110251	1140	115-60-1			820931	1/2	S
G100-A	304751	1/4	ME	48A170286	1725	115-60-1			820931	1/2	S
G120-C	300008	1/8	ME	48A8011005	860	115-60-1			820932	1/2	S
G/GW120-B	300010	1/6	ME	48A110251	1140	115-60-1			820932	1/2	S
G120-A	311338	1/4	ME	48A170286	1725	115-60-1			820932	1/2	S
G/GW130-B	300010	1/6	ME	48A110251	1140	115-60-1			820933*	1/2	S
G/GW140-B	300010	1/6	ME	48A110251	1140	115-60-1			820934	1/2	S
G150-C	300008	1/8	Fasco	71280469	860	115-60-1			804631	1/2	S
G/GW150-B	311340	1/4	ME	48A110186	1140	115-60-1			804631	1/2	S
G160-B	301643	1/3	ME	56A11D65	1140	115-60-1			804707	5/8	S

Notes:

311340 supersedes part #300012 (ME A48110186)

300010 supersedes part #300010 (ME 48A110251), 303442 (ME48A110251)

300008 supersedes part #303443 (ME 48A80151)

301639 supersedes part #302530 (MC D0810B2691), 300120 (Fasco 71082425),

300190 (Franklin 8414010270), 300192 (Franklin 8424010250), and 300461 (Universal Electric CA2G173N)

300453 supersedes part #300452 (Franklin 8264110430) and 300118 (Fasco 71632491)

308318 supersedes part #302336 (McMillan A0820B2633), part #301652 (Fasco 1/8 HP 71241411), 300455 (Fasco 71240360) & 300454 (Franklin 8743810240)

300457 supersedes part #300456 (Franklin 8263710160) and 300119 (Fasco 71632492)

301638 supersedes part #300459 (Fasco 71086194) and 300460 (Universal Electric CA2G174N)

302529 supersedes part #308318 (MC F0412690), 300451 (Fasco 71635376 & 300450 (Franklin 8264110420)

301643 supersedes part #300239 (ME 56A11D33)

304751 supersedes part #301778 (ME 48A170227), 300218 (GE KCP37KN143)


*300455 and 302529 will require new bolt pattern to be drilled

G and GB Hoods and Hood Clips

These units have either a motor cover OR a hood/hoodband assembly.

Clips & Screws Descriptions

469585 – plastic hood clip
 415729 – screw used to attach motor cover OR hood/hoodband assembly to hood clip
 415014 – screw used to attach the hood to the hoodband
 852020 – aluminum hood clip
 852065 – aluminum hood clip
 415034 – bolt used to attach aluminum hood clips to shroud

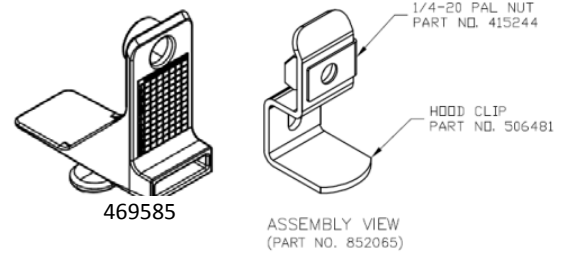

Model	Size	Motor Cover Part No.	Hood Part No.	Motor Cover/ Hood Inside Dia. (in.)	Clips & Screws	Qty of each
G	060-075	503465	n/a	11.563	469585, 415729	4
G	080-095	503472	n/a	14.438	469585, 415729	4
G	100-121 Std	506478	n/a	19.608	469585, 415729	4
G	100-121 Tall	506467	n/a	19.608	469585, 415729	4
G	130-141 Std	506521	n/a	22.188	469585, 415729	4
G	130-141 Tall	n/a	502108	22.250	469585, 415729, 415014	4
G	150-170	507096	n/a	26.295	469585, 415729	6
G	180 Std	507094	n/a	26.295	469585, 415729	6
G	180 Tall	n/a	502109	26.483	469585, 415729, 415014	4

Model	Size	Motor Cover Part No.	Hood Part No.	Motor Cover/ Hood Inside Dia. (in.)	Clips & Screws	Qty of each
GB	070-090	506342	n/a	17.5	469585, 415729	4
GB	101-131	506467	n/a	19.607	469585, 415729	4
GB	141-161 STD	506520	n/a	22.188	469585, 415729	4
GB	141-161 TALL, X-TALL	n/a	502108	22.25	469585, 415729, 415014	4
GB	180-200 STD	507094	n/a	26.295	469585, 415729	6
GB	180-200 TALL, X-TALL	n/a	502109	26.438	469585, 415729, 415014	6
GB	220-240 STD	507002	n/a	30	469585, 415729	6
GB	220-240 TALL	507003	n/a	30	469585, 415729	6
GB	220-240 X-TALL	n/a	511185	30.143	469585, 415729, 415014	4
GB	260-300	n/a	503303	36.25	469585, 415729, 415014	4
GB	330-360	n/a	508166	46.125	852020, 415034, 415729, 415014	6
GB	420	n/a	502113	49.812	852065, 415034, 415729, 415014	8
GB	480	n/a	502114	56.875	852065, 415034, 415729, 415014	8
GB	500	n/a	504611	63.25	852065, 415034, 415729, 415014	8
GB	540	n/a	504611	63.25	852065, 415034, 415729, 415014	8

Hinge Kits (GB)

Model	CAPS Model	Part # (New)	Part # (Old)
GB-220/240	HG-22-24	853436	852250
GB-260/300	HG-26-30	853437	852249
GB-330/360	HG-33-36	853438	852251
GB-420	HG-42	853439	852252
GB-480	HG-48	853440	852253
GB-500/540	HG-50-54	853441	

Model GB

Manufactured May 2003 through July 2003

Model Size	Shaft Part #	Description	Bearing Part #	Description		Wheel Part #	Bore Size	Emb Std or Reinf
GB 070	365063	3/4X13 1/2	360422	PB SS 3/4"		862456	3/4"	S
GB 080	365063	3/4X13 1/2	360422	PB SS 3/4"		862456	3/4"	S
GB 090	365063	3/4X13 1/2	360422	PB SS 3/4"		870762	3/4"	S
GB 101	365063	3/4X13 1/2	360422	PB SS 3/4"		870762	3/4"	S
GB 101-T	365026	3/4X16	360099	PB 3/4"	Dodge	870762	3/4"	S
GB 121	365041	3/4x14 1/2	360422	PB SS 3/4"		862879	3/4"	S
GB 121-T	365024	3/4x18	360099	PB 3/4"	Dodge	862879	3/4"	S
GB 131	365063	3/4x13 1/2	360422	PB SS 3/4"		862895	3/4"	E
GB 131-T	365024	3/4x18	360099	PB 3/4"	Dodge	862895	3/4"	E
GB 141	365030	3/4X13 1/2	360099	PB 3/4"	Dodge	862688	3/4"	E
GB 141-T	365026	3/4x16	360099	PB 3/4"	Dodge	862688	3/4"	E
GB 160	365041	3/4x14 1/2	360099	PB 3/4"	Dodge	862644	3/4"	E
GB 160-T	365026	3/4x16	360099	PB 3/4"	Dodge	862644	3/4"	E
GB 180	365025	3/4x17	360099	PB 3/4"	Dodge	811457	3/4"	E
GB 180-T	365001	3/4x20	360099	PB 3/4"	Dodge	811457	3/4"	E
GB 200	365025	3/4x17	360099	PB 3/4"	Dodge	811458	3/4"	E
GB 200-T	365001	3/4x20	360099	PB 3/4"	Dodge	811458	3/4"	E
GB 220	365431	1x19	360100	PB 1"	Dodge	811917	1"	E
GB 220-T	365031	1x22	360100	PB 1"	Dodge	811917	1"	E
GB 240	365021	1x17 1/2	360100	PB 1"	Dodge	811739	1"	E
GB 240-T	365017	1x20	360100	PB 1"	Dodge	811739	1"	E
GB 260	365088	1x22 w/hole	360100	PB 1"	Dodge	822354	1"	S
GB 260-T	365018	1x24 2k	360100	PB 1"	Dodge	822354	1"	S

Notes:

* 1 1/4" Bearings for units built as of 4-1-97 not interchangeable with 360101

+ If wheel has been changed, use bearing #360515

^ If wheel has been changed, use bearing #365071

~ If wheel has been changed, use bearing #365068

The "T" designation does not appear in the unit model number. Shaft length must be measured prior to ordering replacement shaft.

365078, 365013 are required with wheel 826582 for fan manufactured prior to 5-1-03, ECN 2171

365010, 365015 are required with wheel 826577 for fan manufactured prior to 5-1-03, ECN 2171

365078, 365071 are required with wheel 826563 for fan manufactured prior to 5-1-03, ECN 2171

365091 or 365068 must be used with wheel 826838 manufactured prior to 8/11/03. ECN 2201

Model GB continued

Manufactured May 2003 through July 2003

Model Size	Shaft Part #	Description	Bearing Part #	Description		Wheel Part #	Bore Size	Emb Std or Reinf
GB 300	365088	1x22 w/hole	360100	PB 1"	Dodge	822358	1	E
GB 300-T	365031	1x22 2k	360100	PB 1"	Dodge	822358	1	E
GB 330	365090	1 1/4X23 3/4 w/hole	360101	*	PB 1 1/4 Dodge	826582	1 1/4	E
GB 330-T	365491	1 1/4X26 1/2 w/hole	360311	*		826582	1 1/4	E
	365078	1 1/4X24 2K	360311	*		826582	1 1/4	E
	365013	1 1/4X27 2K	360311	*		826582	1 1/4	E
GB 360	365089	1 1/4X22 1/4 w/hole	360101	*	PB 1 1/4 Dodge	826577	1 1/4	E
GB 360-T	365103	+ 1 1/4X25 w/hole	360311	*		826577	1 1/4	E
	365010	1 1/4X23 2K	360311	*		826577	1 1/4	E
	365015	1 1/4X26 2K	360311	*		826577	1 1/4	E
GB 420	365090	1 1/4X23 3/4 w	360101	*	PB 1 1/4 Dodge	826564	1 1/4	E
GB 420-T	365105	^ 1 1/4X28 w/hole	360311	*		826564	1 1/4	E
	365078	1 1/4X24 2K	360311	*		826564	1 1/4	E
	365071	1 1/4X28.5 2K	360311	*		826564	1 1/4	E
GB 480	365092	1 1/2X26 w/hole	360102	PB 1 1/2	Dodge	826838	1 1/2	S
GB 480-T	365111	~ 1 1/2X29 w/hole	360102	PB 1 1/2	Dodge	826838	1 1/2	S
	365091	1 1/2X27 2K						
	365068	1 1/2X30 2K						
GB-500	366275	1 3/4X30 2K	360093	PB 1 3/4"				
GB 500-T	365072	1 3/4X34.25 2K	360093	PB 1 3/4				
GB 540	365106	1 3/4X28	360093	PB 1 3/4	Dodge	805439	1 3/4	S
GB 540-T	365072	1 3/4X34.25 2K	360093	PB 1 3/4	Dodge	805439	1 3/4	S

Notes:

* 1 1/4" Bearings for units built as of 4-1-97 not interchangeable with 360101

+ If wheel has been changed, use bearing #360515

^ If wheel has been changed, use bearing #365071

~ If wheel has been changed, use bearing #365068

The "T" designation does not appear in the unit model number. Shaft length must be measured prior to ordering replacement shaft.

365078, 365013 are required with wheel 826582 for fan manufactured prior to 5-1-03, ECN 2171

365010, 365015 are required with wheel 826577 for fan manufactured prior to 5-1-03, ECN 2171

365078, 365071 are required with wheel 826563 for fan manufactured prior to 5-1-03, ECN 2171

365091 or 365068 must be used with wheel 826838 manufactured prior to 8/11/03. ECN 2201

Model GB

Manufactured July 2003 through present

Model Size	Shaft Part #	Description	Bearing Part #	Description		Wheel Part #	Bore Size	Emb Std or Reinf
GB 071	365027	3/4X15	360422	PB SS 3/4"		862422	3/4"	S
GB 071 T	365024	3/4X18						
GB 081	365027	3/4X15	360422	PB SS 3/4"		862422	3/4"	S
GB 081 T	365024	3/4X18						
GB 091	365063	3/4X13 1/2	360422	PB SS 3/4"		862463	3/4"	S
GB 091 T	365025	3/4X17						
GB 101	365063	3/4X13 1/2	360422	PB SS 3/4"		870762	3/4"	S
GB 101-T	365026	3/4X16	360099	PB 3/4"	Dodge	870762	3/4"	S
GB 121	365041	3/4x14 1/2	360422	PB SS 3/4"		862879	3/4"	S
GB 121-T	365024	3/4x18	360099	PB 3/4"	Dodge	862879	3/4"	S
GB 131	365063	3/4x13 1/2	360422	PB SS 3/4"		862875	3/4"	E
GB 131-T	365024	3/4x18	360099	PB 3/4"	Dodge	862875	3/4"	E
GB 141	365030	3/4X13 1/2	360099	PB 3/4"	Dodge	862688	3/4"	E
GB 141-T	365026	3/4x16	360099	PB 3/4"	Dodge	862688	3/4"	E
GB 160	365041	3/4x15 1/2	360099	PB 3/4"	Dodge	862644	3/4"	E
GB 160-T	365026	3/4x16	360099	PB 3/4"	Dodge	862644	3/4"	E
GB 180	365025	3/4x17	360099	PB 3/4"	Dodge	811457	3/4"	E
GB 180-T	365001	3/4x20	360099	PB 3/4"	Dodge	811457	3/4"	E
GB 200	365025	3/4x17	360099	PB 3/4"	Dodge	811458	3/4"	E
GB 200-T	365001	3/4x20	360099	PB 3/4"	Dodge	811458	3/4"	E
GB 220	365431	1x19	360100	PB 1"	Dodge	811917	1"	E
GB 220-T	365031	1x22	360100	PB 1"	Dodge	811917	1"	E
GB 240	365021	1x17 1/2	360100	PB 1"	Dodge	811739	1"	E
GB 240-T	365017	1x20	360100	PB 1"	Dodge	811739	1"	E
GB 260	365088	1x22 w/hole	360100	PB 1"	Dodge	822354	1"	S
GB 260-T	365018	1x24 2k	360100	PB 1"	Dodge	822354	1"	S
GB 300	365088	1x22 w/hole	360100	PB 1"	Dodge	822358	1	E
GB 300-T	365031	1x22 2k	360100	PB 1"	Dodge	822358	1	E
GB 330	365090	1 1/4X23 3/4 w/hole	360101 *	PB 1 1/4 Dodge		826582	1 1/4	E
GB 330-T	365491	1 1/4X26 1/2 w/hole	360311 *			826582	1 1/4	E
	365078	1 1/4X24 2K	360311 *			826582	1 1/4	E
	365013	1 1/4X27 2K	360311 *			826582	1 1/4	E
GB 360	365089	1 1/4X22 1/4 w/hole	360101 *	PB 1 1/4 Dodge		826577	1 1/4	E
GB 360-T	365103	1 1/4X25 w/hole	360311 *			826577	1 1/4	E
See Note	365010	1 1/4X23 2K	360311 *			826577	1 1/4	E
	365015	1 1/4X26 2K	360311 *			826577	1 1/4	E
GB 420	365090	1 1/4X23 3/4 w	360101 *	PB 1 1/4 Dodge		826564	1 1/4	E
GB 420-T	365105	1 1/4X28 w/hole	360311 *			826564	1 1/4	E
See Note	365078	1 1/4X24 2K	360311 *			826564	1 1/4	E
	365071	1 1/4X28.5 2K	360311 *			826564	1 1/4	E
GB 480	365092	1 1/2X26 w/hole	360102	PB 1 1/2	Dodge	826838	1 1/2	S
GB 480-T	365111	1 1/2X29 w/hole	360102	PB 1 1/2 Dodge		826838	1 1/2	S
	365091	1 1/2X27 2K						
	365068	1 1/2X30 2K						
GB-500	366275	1 3/4X30 2K	360093	PB 1 3/4"				
GB 500-T	365072	1 3/4X34.25 2K	360093	PB 1 3/4				
GB 540	365106	1 3/4X28	360093	PB 1 3/4	Dodge	805439	1 3/4	S
GB 540-T	365072	1 3/4X34.25 2K	360093	PB 1 3/4	Dodge	805439	1 3/4	S

Notes:

* 1 1/4" Bearings for units built as of 4-1-97 not interchangeable with 360101

The "T" designation does not appear in the unit model number. Shaft length must be measured prior to ordering replacement shaft.

365078, 365013 are required with wheel 826582 for fan manufactured prior to 5-1-03, ECN 2171

365010, 365015 are required with wheel 826577 for fan manufactured prior to 5-1-03, ECN 2171

365078, 365071 are required with wheel 826563 for fan manufactured prior to 5-1-03, ECN 2171

365091 or 365068 must be used with wheel 826838 manufactured prior to 8/11/03. ECN 2201

Model GB

Manufactured September 1989 through January 2000

Model Size	Shaft Part#	Description	Bearing Part #	Description	Wheel Part #	Bore Size	Emb Std or Reinf
GB 70, 80	365063	3/4X13 1/2	360422	PB SS 3/4"	862456	3/4"	S
GB 90	365063	3/4X13 1/2	360422	PB SS 3/4"	870762	3/4"	S
GB 100	365063	3/4X13 1/2	360422	PB SS 3/4"	870762	3/4"	S
GB 100-T	365026	3/4X16	360099	PB 3/4" Dodge	870762	3/4"	S
GB 120	365041	3/4X14 1/2	360422	PB SS 3/4"	862879	3/4"	S
GB 120-T	365024	3/4X18	360099	PB 3/4" Dodge	862879	3/4"	S
GB 130	365063	3/4X13 1/2	360422	PB SS 3/4"	862895	3/4"	E
GB 130-T	365024	3/4X18	360099	PB 3/4" Dodge	862895	3/4"	E
GB 140	365030	3/4X13 1/2	360099	PB 3/4" Dodge	862688	3/4"	E
GB 140-T	365026	3/4X16	360099	PB 3/4" Dodge	862688	3/4"	E
GB 160	365041	3/4X15 1/2	360099	PB 3/4" Dodge	862644	3/4"	E
GB 160-T	365026	3/4X16	360099	PB 3/4" Dodge	862644	3/4"	E
GB 180	365025	3/4X17	360099	PB 3/4" Dodge	811457	3/4"	E
GB 180-T	365001	3/4X20	360099	PB 3/4" Dodge	811457	3/4"	E
GB 200	365025	3/4X17	360099	PB 3/4" Dodge	811458	3/4"	E
GB 200-T	365001	3/4X20	360099	PB 3/4" Dodge	811458	3/4"	E
GB 220	365431	1x19	360100	PB 1" Dodge	811917	1"	E
GB 220-T	365031	1x22	360100	PB 1" Dodge	811917	1"	E
GB 240	365021	1x17 1/2	360100	PB 1" Dodge	811739	1"	E
GB 240-T	365017	1x20	360100	PB 1" Dodge	811739	1"	E
GB 260	365088	1x22 w/hole	360100	PB 1" Dodge	822354	1"	S
GB 260-T	365018	1x24 2k	360100	PB 1" Dodge	822354	1"	S
	365490	1x27 1/2 w/hole					
	365084	1x25.5 2k					
GB 300	365088	1x22 w/hole	360100	PB 1" Dodge	822358	1	E
GB 300-T	365031	1x22 2k	360100	PB 1" Dodge	822358	1	E
	365884	1x26 w/hole					
	365084	1x25.5 2k					
GB 330	365090	1 1/4X23 3/4 w/hole	360101	* PB 1 1/4 Dodge		1 1/4	E
GB 330-T	365491	1 1/4X26 1/2 w/hole	360311			1 1/4	E
GB 360	365089	1 1/4X22 1/4 w/hole	360101	* PB 1 1/4		1 1/4	E
GB 360-T	365103	1 1/4X25 w/hole	360311			1 1/4	E
GB 420	365090	1 1/4X23 3/4 w	360101	* PB 1 1/4		1 1/4	E
GB 420-T	365105	1 1/4X28 w/hole	360311			1 1/4	E
GB 480	365092	1 1/2X26 w/hole	360102	PB 1 1/2 Dodge	826838	1 1/2	S
GB 480-T	365111	1 1/2X29 w/hole	360102	PB 1 1/2 Dodge	826838	1 1/2	S
	365091	1 1/2X27 2K					
	365068	1 1/2X30 2K					
GB-500	366275	1 3/4X30 2K	360093	PB 1 3/4"			
GB-500-T	365072	1 3/4X34.25 2K	360093	PB 1 3/4"			
GB 540	365106	1 3/4X28	360093	PB 1 3/4 Dodge	805439	1 3/4	S
GB 540-T	365072	1 3/4X34.25 2K	360093	PB 1 3/4 Dodge	805439	1 3/4	S

Notes:

* 1 1/4" Bearings for units built as of 4-1-97 not interchangeable with 360101

The "T" (tall unit) designation does not appear in the unit model number. Shaft length must be measured prior to ordering replacement shaft.

Where applicable, all replacement wheels furnished will be reinforced type.

365031, 365084 & 365018 must be used with 822358 & 822354 wheels manufactured prior to 7-1-2000 ECN 1891

365091 or 365068 must be used with wheel 826838 manufactured prior to 8/11/03. ECN 2201

Model GB

Manufactured 1980 through 1989

Model Size	Shaft Part #	Description	Date Changed	Bearing Part #	Description	Wheel Part #	Bore Size	Emb Std or Reinf
GB 7, 8, 9, 10	365093	3/4 X12-1/2		360422	SS 3/4 NBR	870762	3/4"	S
GB 7, 8, 9, 10	365026	3/4X16		360422	SS 3/4 NBR	870762	3/4"	S
GB 14	365063	3/4X13 1/2		360099	PB 3/4 Dodge	862688	3/4"	S
GB 14-T	365026	3/14X16		360099	PB 3/4 Dodge	862688	3/4"	S
GB 18	365026	3/4X16		360099	PB 3/4 Dodge	811457	3/4"	E
GB 18-T	365095	3/4X18 1/2		360099	PB 3/4 Dodge	811457	3/4"	E
GB 18	365422	1X17	Serial #'s 87E - 87I use	360100	PB 1" Dodge	1" Obs. - Must replace with 3/4 wheel, shaft, brgs & shaft pulleys.		
GB 18-T	365431	1X19	1" Bore?	360100	PB 1" Dodge			
GB 21	365026	3/4X16		360099	PB 3/4 Dodge	811458	3/4"	E
GB 21-T	365095	3/4X18 1/2		360099	PB 3/4 Dodge	811458	3/4"	E
GB 21	365422	1X17	Serial #'s 87D - 87I use	360100	PB 1" Dodge	1" Obs. - Must replace with 3/4 wheel, shaft, brgs & shaft pulleys.		
GB 21-T	365431	1X19	1" Bore ?	360100	PB 1" Dodge			
GB 24	365025	3/4X17	Call Parts Department with serial # size	360099	PB 3/4 Dodge	Obsolete	3/4"	E
GB 24-T	365001	3/4X20		360099	PB 3/4 Dodge	Obsolete	3/4"	E
GB 24	365021	1X17 1/2		360100	PB 1" Dodge	811739	1"	E
GB 24-T	365017	1X20		360100	PB 1" Dodge	811739	1'	E
GB 30	365088	1x22 w/hole	(1980-81 units used 1 ¼ shaft)	360100	PB 1" Dodge	822358	1"	E
GB 30-T	365884	1x26 w/hole		360100	PB 1" Dodge	822358	1"	E
GB 30	365031	1x22 2k		360100	PB 1" Dodge	822358	1"	E
GB 30-T	365084	1x25.5 2k		360100	PB 1" Dodge	822358	1"	E
GB 36	365089	1 1/4X22 1/4 w/hole	(1980-81 units used 1 ½ shaft)	360101	PB 1 1/4 Dodge		1 1/4"	E
GB 36-T	365103	1 1/4X25 w/hole		360101	PB 1 1/4 Dodge		1 1/4"	E
GB 42	365090	1X1 1/4X23 3/4 w/hole	(1980-81 units used 1 ½ shaft)	360101	PB 1 1/4 Dodge		1 1/4"	E
GB 42-T	365105	1 1/4X28 w/hole		360101	PB 1 1/4 Dodge		1 1/4"	E
GB 48	365092	1 1/2X26 w/hole	(1980-81 units used 1 ¾ shaft)	360102	PB 1 1/2 Dodge	826838	1 1/2"	S
GB 48-T	365111	1 1/2X29 w/hole		360102	PB 1 1/2 Dodge	826838	1 1/2"	S
	365091	1 1/2X27 2K						
	365068	1 1/2X30 2K						
GB 54	365106	1 3/4X28		360093	PB 1 3/4 Dodge	805439	1 3/4"	S
GB-54-T	365072	1 3/4X33 1/2		360093	PB 1 3/4 Dodge	805439	1 3/4"	S

Notes:

The "T" (tall unit) designation does not appear in the unit model number. Shaft length must be measured prior to ordering replacement shaft.

Shaft diameters were changed on the dates indicated. Shaft length must be measured prior to ordering replacement.

365084 & 365031 must be used with 822358 wheel, manufactured prior to 7-1-2000 ECN 1891

365091 or 365068 must be used with wheel 826838 manufactured prior to 8/11/03. ECN 2201

Model GWB

Manufactured 1984 through 1998

Model Size	Shaft Part #	Description	Date Changed	Bearing Part #	Description	Wheel Part #	Bore Size	Emb Std or Reinf
GWB 14	365041	3/4 x 14 1/2		360099	PB 3/4" Dodge	862688	3/4"	S
GWB 14-T	365025	3/4 x 17		360099	PB 3/4" Dodge	862688	3/4"	S
GWB 18	365025	3/4 x 17		360099	PB 3/4" Dodge	811457	3/4"	E
GWB 18-T	365001	3/4 x 20		360099	PB 3/4" Dodge	811457	3/4"	E
GWB 18	365422	1 x 17	Serial #'s 87D thru 87J use 1" bore	360100	PB 1" Dodge	1" bearing obsolete. Must replace with 3/4" bearing, wheel, shaft and shaft pulley		
GWB 18-T	365017	1 x 20	Serial #'s 87D thru 87J use 1" bore	360100	PB 1" Dodge	1" bearing obsolete. Must replace with 3/4" bearing, wheel, shaft and shaft pulley		
GWB 21	365025	3/4 x 17		360099	PB 3/4" Dodge	811458	3/4"	E
GWB 21-T	365001	3/4 x 20			PB 3/4" Dodge	811458	3/4"	E
GWB 21	365422	1 x 18 1/2	Serial #'s 87D thru 87J use 1" bore	360100	PB 1" Dodge	1" bearing obsolete. Must replace with 3/4" bearing, wheel, shaft and shaft pulley		
GWB 21-T	365366	1 x 22	Serial #'s 87D thru 87J use 1" bore	360100	PB 1" Dodge	1" bearing obsolete. Must replace with 3/4" bearing, wheel, shaft and shaft pulley		
GWB 24	365095	3/4 x 18 1/2		360099	PB 3/4" Dodge	Obsolete	3/4"	E
GWB 24-T	365094	3/4 x 22		360099	PB 3/4" Dodge	Obsolete	3/4"	E
GWB 24	365020	1 x 18 1/2	With unit serial #	360100	PB 1" Dodge	811739	1"	E
GWB 24-T	365031	1 x 22	Parts Dept. to verify shaft size	360100	PB 1" Dodge	811739	1'	E

Model RSF

Blowers

QD Units

Model Size	Blower Part #	Bearing Part #
RSF-90	450691	458071
RSF-100	450692	458071
RSF-120	450693	458072
RSF-150	450694	458072
RSF-180	450695	458072
RSF-200	451771	360267

Notes:

The blower part no. listed above is a purchased assembly consisting of wheel scroll, shaft, and bearings. The bearings are the only part of this assembly that is sold separately as a replacement.

Aluminum Filters

Model Size	Alum Filter Part #	Nominal Dimension	Qty per Unit
RSF-90	451764	12 X 20 X 1	4
RSF-100	451765	12 X 25 X 1	4
RSF-120	450231	16 X 25 X 1	4
RSF-150	450232	16 X 20 X 1	8
RSF-180	450232	16 X 20 X 1	4
RSF-180	450313	20 X 20 X 1	4
RSF-200	450233	20 X 25 X 1	8

Notes:

RSF-180 takes a total of eight filters, but two different sizes.

Filters for RSF-9, 10, 12, 15, 18 & 20, contact Parts Department with unit serial # to get part number price and availability.

Model SBE

Model Size	Prop Part #	Bore Size	Shaft Part #	Bearing Part #	Description
SBE-1L20-QD	Consult Factory	3/4"	Welded to prop	360422	PB SS 3/4"
SBE-2L20-QD		3/4"	Welded to Prop	360099 *	PB 3/4" Dodge
SBE-1L24-QD		3/4"	Welded to Prop	360422	PB SS 3/4"
SBE-2L24-QD		3/4"	Welded to prop	360099 *	PB 3/4" Dodge
SBE-3L24-QD		3/4"	365026 * 3/4 x16	360099 *	PB 3/4" Dodge
SBE-1L30-QD		3/4"	Welded to Prop	360422	PB SS 3/4"
SBE-2L30-QD		1"	Welded to Prop	360100 *	PB 1" Dodge
SBE-3L30-QD		1"	365021 1x17 1/2	360100 *	PB 1" Dodge
SBE-1L36-QD		3/4"	Welded to Prop	360422	PB SS 3/4"
SBE-2L36-QD		1"	Welded to Prop	360100 *	PB 1" Dodge
SBE-3L36-QD		1 1/4"	365479 1 1/4 x18	360101	PB 1 1/4" Dodge
SBE-1L42-QD		1"	Welded to Prop	360100 *	PB 1" Dodge
SBE-2L42-QD		1 1/4"	Welded to Prop	360101	PB 1 1/4" Dodge
SBE-3L42-QD		1 1/2"	365004 1 1/2 x26 1/2	360102	PB 1 1/2" Dodge
SBE-1L48-QD		1"	Welded to Prop	360100 *	PB 1" Dodge
SBE-2L48-QD		1 1/4"	Welded to Prop	360101	PB 1 1/4" Dodge
SBE-3L48-QD		1 1/2"	365004 1 1/2 x26 1/2	360102	PB 1 1/2" Dodge

Notes:

Shaft is part of the welded prop assembly and cannot be ordered separately.

*Two bearings required per fan. 1/4 to 1 HP use NBR 360422. 1 1/2 HP and above must use Dodge cast bearings.

Model SDE

QD Units

Manufactured 1963 through January 1995

Model Size	Motor Part #	HP	Vendor Number	Shock Mount Part #	Description	Prop Part #	Bore Size
SDE-8-32-DGE	300757	1/40	Fasco 71636832	370006	Grom 1 1/4 -5/16	335134	5/16
SDE-10-24-DE	With serial # contact Parts Department			370006	Grom 1 1/4 -5/16	335126 335277	5/16 1/2
SDE-10-32-DE	With serial # contact Parts Department			370006	Grom 1 1/4 -5/16	335126	5/16 1/2
SDE-12-24-DGE	302603	1/4	MC D0816A2676	370006	Grom 1 1/4 -5/16	335138	1/2
SDE-14-32-B	301772	1/6	ME 48A1101640	370006	Grom 1 1/4 -5/16	335143	1/2
1140 115/60/1 needs 4 thru bolts #415201							
SDE-16-24-B	301772	1/6	ME 48A1101640	370006	Grom 1 1/4 -5/16	335410	1/2
1140 115/60/1 needs 4 thru bolts #415201							
SDE-18-24-B	301772	1/6	ME 48A1101640	370006	Grom 1 1/4 -5/16	335129	1/2
1140 115/60/1 needs 4 thru bolts #415201							
SDE-20-24-B	311340	1/4	ME 48A110186	370006	Grom 1 1/4 -5/16	335131	1/2
1140 115/60/1 needs 4 thru bolts #415201							

Notes:

301462RK Note- Still Active (Fasco 71637303) and 300759RK (Franklin 8264310350) 5/16" diameter shaft

302603 supersedes 300761RK (Fasco 71896247) and 30005 (Fasco 71080077) 1/2" diameter shaft

301772 supersedes 300010 (ME 48A110251)

311340 supersedes 300012 (ME 48A110186)

Model SE

Model Size	Motor Part #	HP	Voltage Cycle Phase	Vendor Number	Shock Mount Part #	Description	Wheel Part#	Bore Size
SE1-8-QD	301462	1/25	115-60-1	Fasco 71637303	370006	Grom 1 1/4x5/16	335176	5/16
SE1-10-QD	300760	1/15	115-60-1	Fasco 71086431	370006	Grom 1 1/4x5/16	335178	1/2
SE1-12-QD	311742	1/8	115-60-1	MC A0816A4075	370006	Grom 1 1/4x5/16	335180	1/2
SE1-14-440-BB-QD	300010	1/6	115-60-1	ME 48A11O251	370006	Grom 1 1/4x5/16	335182	1/2
SE1-16-428-B6-QD	300010	1/6	115-60-1	ME 48A11O251	370006	Grom 1 1/4x5/16	335409	1/2
SE1-18-429-B4-QD	311340	1/4 Must send 4 thru bolts #415201	115-60-1	ME48A110186	370006	Grom 1 1/4x5/16	335224	5/8
SE1-20-428-B3-QD	301643	1/3 Must send 4 thru bolts #415201	115-60-1	ME56A11D66	370006	Grom 1 1/4x5/16	335228	5/8
SE1-24-428-85-QD	301644	1/2	115-60-1	ME56A11D66	370006	Grom 1 1/4x5/16	335252	5/8

Notes:

303441 supersedes 300901rk (ME 48A110251)

300010 supersedes 311585 (ME 48A110251), supersedes 303442 (ME 48A110251)

311340 supersedes 300012 (ME48A110186)

Model SFB

Model Size	Shaft Part #	Description	Bearing Part #	Description	Steel Wheel Part #	Bore Size	Rotation
SFB 9	365026 *	3/4X16	360099*	PB 3/4" Dodge	335091 335092	3/4" 3/4"	CW CCW
SFB 10	365024	3/4X18	360099	PB 3/4" Dodge	335047 335056	3/4" 3/4"	CW CCW
SFB 12	365020	1 X18 1/2	360100	PB 1" Dodge	335048 335057	1" 1"	CW CCW
SFB 15	365017	1X20	360100	PB 1" Dodge	335049 335058	1" 1"	CW CCW
SFB 18	365085	1 1/4X 1X25 1/2	360101 360311	PB 1 1/4" Dodge	335050 335059	1" 1"	CW CCW
SFB 20	365083	1 1/4X1 3/16X28 1/2	360101 360311	PB 1 1/4" Dodge	335051 335060	1 3/16" 1 3/16"	CW CCW
SFB 22	365083	1 1/4X1 3/16X28 1/2	360101 360311	PB 1 1/4" Dodge	335052 335061	1 3/16" 1 3/16"	CW CCW
SFB 25	365082	1 1/2X1 3/16X30	360102	PB 1 1/2" Dodge	335053 335062	1 3/16" 1 3/16"	CW CCW
SFB 27	365081	1 1/2X1 7/16X34	360102	PB 1 1/2" Dodge	335054 335063	1 7/16" 1 7/16"	CW CCW
SFB 30	365081	1 1/2X1 7/16X34	360102	PB 1 1/2" Dodge	335055 335064	1 7/16" 1 7/16"	CW CCW

Notes:

Due to ECN #2013, AUG. 2001, in which bearing part # 360101 was changed to part # 360311.

Bearing part # 360311 is not interchangeable with previous part # 360101. Need unit serial # to verify correct bearings.

Weatherhoods SFB/SWB for Series 200 (Painted Permatector Gray)

Model	Size	Part #	Model	Size	Part #
SWB/SFB	9	850365	SWB/SFB	24	842599
SWB/SFB	10	842572	SWB/SFB	27	842600
SWB/SFB	12	842572	SWB/SFB	30	850127
SWB/SFB	16	842575	SWB/SFB	33	850128
SWB/SFB	20	842597	SWB/SFB	36	850129
SWB/SFB	22	842598			

Model SP

QD Units Only

Manufactured July of 2002 through present

Model Size	Motor Part #	Vendor	Vendor Number	Shock Mount Part #	Description	Wheel Part #	Bore Size
SP-C50	451376	Broan	99080223	None Required		451378	
SP-B50 XXX	309732 Newly designed unit	CHIKEE	S33G182BB-02	370108 370109 455433	4/unit	473304 456676	5/16 Hub Clip
SP-B70 XXX SP-B70-FL	304916 Newly designed unit/with light See accessories below	FASCO	7173-1462	370108 370109 455433	4/unit	473304 456676	5/16 Hub Clip
SP-B80 XXX	304920 Newly designed unit	FASCO	F950	370108 370109 455433	4/unit	473304 456676	5/16 Hub Clip
SP-B90 XXX SP-B90-FL	304680 Newly designed unit/with light See accessories below	FASCO	7173-1362	370108 370109 455433	4/unit	473304 456676	5/16 Hub Clip
SP-B110 XXX SP-B110-FL	302172 Newly designed unit/with light See accessories below	Fasco	7173-0008	370108 370109 455433	4/unit	473304 456676	5/16 Hub Clip
SP-B150	310198	Fasco	7173-0007	370108 370109 455433	4/unit	473304 456676	5/16 Hub Clip
SP-B200	302424	Fasco	7173-0099	370108 370109 455433	4/unit	473304 456676	5/16 Hub Clip
SP-A50 XXX	304923 Newly designed unit	MC	MS7174	370108 370109 455433	4/unit	473303 456676	5/16 Hub Clip
SP-A70 XXX	304918 Newly designed unit	MC	MS7113	370108 370109 455433	4/unit	473303 456676	5/16 Hub Clip
SP-A90 XXX	304917 Newly designed unit	MC	MS7112	370108 370109 455433	4/unit	473303 456676	5/16 Hub Clip
SP-A110	312499	MC	F0810B4221	370108 370109 455433	4/unit	473303 456676	5/16 Hub Clip
SP-A125	303039	MC	F0408B2782	370108 370109 455433	4/unit	473303 456676	5/16 Hub Clip

Notes:

*All 3 part #'s required to make one complete shock mount. 3 or 4 shock mounts are required per unit.

XXX = Newly designed units did not replace any other unit.

SP Replacement Parts

These replacement part #'s are used only for SP-B70-FL, SP-B90-FL & SP-B110-FL (QD UNITS ONLY)

Part #	Description
860990	Fluorescent Grille with light (includes 2 screw covers)
825868	Frosted Lens (SP Grille) Translucent
383744	Fluorescent light bulb
461956	Prismatic Lens
459208	Plastic grill, Standard with QD Fans
463246	Designer grill screw cover

***Designer grille part # 825862 can be ordered as a replacement, for all QD, SP units, but must be ordered separately. QD units come only with standard grille.

***Grille assembly part # 825866 can also be ordered as a replacement part. This would include grille, fluorescent lens, light bulb, ballast, lamp base, fluorescent box and all of the hardware.

Model SP (Cont'd)

QD Units Only

Manufactured July of 2002 through present

Model Size	Motor Part #	Vendor	Vendor Number	Shock Mount Part #	Description	Wheel Part #	Bore Size
SP-A190	311559	MC	F0410B2783	370108 370109 455433	4/unit	473303 05456676	5/16 Hub Clip
SP-A200 XXX	304984 Newly designed unit	Fasco	7190-2737	370108 370109 455433	4/unit	335290 05456676	5/16 Hub Clip
SP-A250	304338 Obsolete 5/16 shaft used 02G-03A 304983 effective 01/01/2003 3/8"shaft	Fasco	71902341	370108 370109 455433	4/unit	335290 05456676 5/16 shaft used 02G-03A 335290 Eff. 1/1/03	5/16 Hub Clip
SP-A290	304843	MC	A0810B3215	370108 370109 455433	4/unit	335290	3/8
SP-A390	304842	MC	A0810B3214	370108 370109 455433	4/unit	335290	3/8
SP-A410	301817	MC	F0516B2512	370108 370109 455433	4/unit	335122	1/2
SP-A510	310225	MC	F0516B3868	370108 370109 455433	4/unit	335304	1/2
SP-A700	304970	Fasco	7190-2773	370108 370109 455433	4/unit	335493	3/8 2 unit
SP-A710	301816	MC	F0524B2511	370108 370109 455433	4/unit	335304	1/2
SP-A780	309133	MC	D0824B3755	370108 370109 455433	4/unit	335304	1/2
SP-A900	301833	Fasco	71513783	None required		335304	1/2
SP-A1050	302490	MC	F0532B3753	None required		335304	1/2
SP-A1410	302490	Fasco	71241796	None required		335304	1/2
SP-A1550	302022	Fasco	71241696	None required		335304	1/2

Notes:

* All 3 part #'s required to make one complete shock mount. 3 or 4 shock mounts are required per unit.

XXX = Newly designed units did not replace any other unit.

Model SP

See Note #2 at the bottom
for all motors on this page

Manufactured February 1996 through June 2002

Model Size	Motor Part #	Vendor	Vendor Number	Shock Mount Part #	Description	Wheel Part #	Bore Size
SP-5	451376	Broan	99080254	None required		451378	7/32
SP-6	451389	Broan	99080518			451388	1/4
SP-7	302172	Fasco	7173-0008		370108 370109 455433	473304 456676	5/16 Hub Clip
SP-9	310198	Fasco	7173-0007	370108 370109 455433	4 per unit	473304 456676	5/16 Hub Clip
SP-12	302424	Fasco	7173-0099	370108 370109 455433	4 per unit	473304 456676	5/16 Hub Clip
SP-210	312499	MC	F0810B4221	370108 370109 455433	4 per unit	473303 456676	5/16 Hub Clip
SP-216	303039	MC	F0408B2782	370108 370109 455433	4 per unit	473303 456676	5/16 Hub Clip
SP-218	311559	MC	F0410B2783	370108 370109 455433	4 per unit	473303 456676	5/16 Hub Clip
SP-224	304983	Fasco	71902341	370108 370109 455433	4 per unit	335290 456676	3/8 Hub Clip
SP-226	304843	MC	A0810B3215	370108 370109 455433	4 per unit	335290	3/8
SP-228	304842	MC	A0810B3214	370108 370109 455433	4 per unit	335290	3/8
SP-250	301817	MC	F0516B2512	370108 370109 455433	4 per unit	335122	1/2
SP-252	310225 ZZ41199a	Fasco Fasco	71513785 71513785	370108 370109 455433	4 per unit	335123* N/A used from 99G-00D	1/2 3/8
SP-255	301816	MC	F0524B2511	370108 370109 455433	4 per unit	335086*	1/2
SP-258	309133	MC	D0824B3755	370108 370109 455433	4 per unit	335304*	1/2" 2 per unit
SP-260	301833	Fasco	71513783	None required		335304*	1/2" 2 per unit
SP-262	301832	MC	F0532B3753				
SP-264	302490	Fasco	71241796				
SP-265	302022	Fasco	71241696				

Notes:

*Power Pack assembly, part # ZZ50757 is available for the SP/CSP 252 ONLY

*304338 has been replaced by 304983. New wheel 335290 required due to bore size change. 5/16" to 3/8".

Note #2: Order adapter part # 382861 at N/C with all motors on this page

Model SP

QD Units

Manufactured April 1989 through January 1996

Model Size	Motor Part #	Description	Shock Mount Part #	Description	Wheel Part #	Bore Size	Rotation	
SP-5	451376	Broan	99080254	None Required	451378	7/32	CCW	
SP-6	451389	Broan	99080518		451388	1/4	CCW	
SP-108	301814	MC	F0408B2509	869365	DUR 40	335009	5/16	CCW
SP-115	301812	MC	F0508B2507	869365	DUR 40	335120	3/8	CCW
SP-117	301814	MC	F0408B2509	869365	DUR 40	335124	5/16	CCW
SP-125	301813	MC	F0508B2508	869365	DUR 40	335121	3/8	CCW
SP-127	301839	Fasco	71086922	869365	DUR 40	335121	3/8	CCW
SP-150	301817	MC	F0516B2512	869365	DUR 40	335122	1/2	CCW
SP-152	310225	MC	F0516B3868	869365	DUR 40	335123	1/2	CCW
SP-155	653658	Motor plate required	F0524B2511	370108		335086	1/2	CCW
	301816	MC		370109 455433				
SP-158	653658	Motor plate required	71840078	370108		335122	1/2	CCW
	309133	Fasco		370109 455433				
SP-160	301833	Fasco	71513783	None Required	335123	1/2	2/Unit	
SP-162	809766	Motor plate required	F0532B3753	None Required	335123	1/2	2/Unit	
	302490	MC						
SP-165	302022	Fasco	71241696	None Required				

Model SP

See Note #2 at the bottom
for all motors on this page

QD Units

Manufactured 1982 through March 13, 1989

Model Size	Motor Part #	Vendor Number	Shock Mount Part #	Description	Wheel Part #	Bore Size	Rotation
SP-5	451376	Broan 99080254	None Required		451378	7/32	CCW
SP-6	451389	Broan 99080518			451388	1/4	CCW
SP/CSP-8	N/A	Motor not available	869365	DUR 40	335009	5/16	CCW
	Buy unit SP/CSP A110						
SP/CSP-15	301812	MC F0508B2507	869365	DUR 40	335120	3/8	CCW
SP/CSP-17	N/A	Motor not available	869365	DUR 40	335124	5/16	CCW
	Buy unit SP/CSP A190						
SP/CSP-25	301813	MC F0508B2508	869365	DUR 40	335121	3/8	CCW
SP/CSP-27	301839	Fasco 71086922	869365	DUR 40	335121	3/8	CCW
SP/CSP-50	310225	MC F0516B3868	869365	DUR 40	335123	1/2	CCW
	809477	Motor bracket req'd					
SP/CSP-55	301816	MC F0524B2511	370108		335086	1/2	CCW
	05653658	Motor plate req'd	370109 455433				
SP/CSP-60	301832	MC F0532B3753		None required	335123	1/2	CCW
	809766	Motor bracket req'd					
SP/CSP-70, 75	302021	Fasco 71263623		None required	335071	1/2	CCW

Notes:

Motors are no longer available for the SP-8 AND SP 17

*All 3 part #'s required to make one complete shock mount. 3 or 4 shock mounts are required per unit.

300203 Franklin 8413810400 - no replacement available. Used on FWH units in mid 60's (Fan Wausau Homes)

Note #2: Order adapter part # 382861 at N/C with all motors on this page

Model SP

Manufactured 1970 through 1981

Model Size	Motor Part #	Vendor Number	Wheel Part #	Rotation
SP-7	300910	Broan 97008342	335117	
SP-10	300910	Broan 99080048	335117	
SP-20	Not available	97007389	335118	CCW
			335119	CW
SP-30	Not available	97007387	335118	CCW
			335119	CW

SP Grilles

Model Size	Greenheck Part Number	Description
SP-A50	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A70	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A90	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A110	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A125	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A190	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A200	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A250	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A290	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A390	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A410	826253	Metal Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A510	826253	Metal Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A700	826253	Metal Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A780	826253	Metal Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A900	826253	Metal Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-A1050	825862	Metal Grill Standard
	825866	Decorative Grill (Grill Only)
	826253	Decorative Grill Assembly
SP-A1410	826253	Metal Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly

Model Size	Greenheck Part Number	Description
SP-A1550	826253	Metal Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-B50	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-B70	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-B70-FL	459208	Designer Grill Standard
	491957	Frosted Lens Translucent
	492956	Decorative Grill Assembly
SP-B80	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-B90	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-B90-FL	459208	Designer Grill Standard
	491957	Frosted Lens Translucent
	492956	Decorative Grill Assembly
SP-B110	459208	Designer Grill Standard
	825862	Decorative Grill (Grill Only)
	825866	Decorative Grill Assembly
SP-B110-FL	459208	Designer Grill Standard
	491957	Frosted Lens Translucent
	492956	Decorative Grill Assembly
SP-B150	459208	Designer Grill Standard
	491957	Decorative Grill (Grill Only)
	492956	Decorative Grill Assembly
SP-B200	459208	Designer Grill Standard
	491957	Decorative Grill (Grill Only)
	492956	Decorative Grill Assembly
SP-C50	459208	Designer Grill Standard
	491957	Decorative Grill (Grill Only)
	492956	Decorative Grill Assembly

SP Grilles

Grilles (In stock at all warehouses)

NOTES: Requires all 3 part #'s to make one complete shock mount. 3 or 4 shock

Model	Standard Plastic Part #	Option Al, Metal Part #
SP 5	455478	N/A
SP 6	455645	N/A
SP 108	N/A	N/A
SP 6.5, 7, 9, 12, 15, 125, 127, 224, 226, 228	459208	504879
SP 115, 117, 210, 216, 218	459208	504878
SP150, 158, 250, 258	N/A	504880
SP 160, 165, 260, 265	N/A	504881

mounts are required per unit.
 * screw 415940 with white head

Model SPFE

QD Units

Manufactured 1987 through January 1995

Model Size	Shaft	Bore	Shaft Part #	Description	Bearing Part #	Description
SPFE-20	Obsolete	3/4"	365025	3/4x17	360422	PB SS ¾
SPFE/S-24	Obsolete	3/4"	365025	3/4x17	360422	PB SS ¾
SPFE-30	Obsolete	1"	365021	1X17 1/2	360100	PB 1" Dodge
SPFE/S-36	Obsolete	1"	365021	1X17 1/2	360100	PB 1" Dodge
SPFE-42	Obsolete	1"	365020	1X18 1/2	360100	PB 1" Dodge
SPFE-48	Obsolete	1 1/4"	365558	1 1/4X19	360101	PB 1 ¼ " Dodge
SPFE-54	Obsolete	1 1/4"	365012	1 1/4X20	360101	PB 1 ¼ " Dodge

Notes:

Increase the FRPM by 1.08 times to get the same performance as the original prop. Per ECN #1395 - August 1995

Model SQ

QD Units

September 1990 and through present

Model Size	Motor Part #	Description	Shock Mount Part #	Description	Wheel Part #	Size	Emb Std or Reinf
SQ-60-DGE	300757	1/40 Fasco 71636832	370007	Grom 7/8-5/16	819626	5/16	S
SQ-70-DGE	301462	1/25 Fasco 71637303	370007	Grom 7/8-5/16	819632	5/16	S
SQ-75-DGE	301462	1/25 Fasco 71637303	370007	Grom 7/8-5/16	819633	5/16	S
SQ-80-DGE	300760	1/15 Fasco 71086431	370007	Grom 7/8-5/16	820928	1/2	S
SQ-85-DGE	300760	1/15 Fasco 71086431	370007	Grom 7/8-5/16	820930	1/2	S
SQ-90-DGE	302603	1/14 MC D0816A2676	370007	Grom 7/8-5/16	820924	1/2	S
SQ-95-DGE	311742	1/8 MC A0816A4075	370007	Grom 7/8-5/16	820926	1/2	S
SQ-97-DGE			370007	Grom 7/8-5/16			
SQ-98-DGE			370007	Grom 7/8-5/16			
SQ-99-DGE			370007	Grom 7/8-5/16			
SQ-100-B	301772	1/6 ME 48A1101640	None required		862493	1/2	S
SQ-100-A	300016	1/4 ME ME48S17D2055	None required		862493	1/2	S
SQ-120-B	301772	1/6 ME ME48A1101640	None required		862885	1/2	S
SQ-130-B	311340	1/4 ME ME48A110186	None required		862899	1/2	E
SQ-140-B	301643	1/3 ME ME56A11D65	None required		862699	5/8	E

Model SQB

Replaced by model BSQ

Model Size	Shaft Part #	Description	Bearing Part #	Description	Wheel Part #	Bore Size	Std or Emb.
SQB 10	365063	3/4x13 1/2	360099	PB 3/4" Dodge	870762	3/4"	S
SQB 12	365063	3/4x13 1/2	360099	PB 3/4" Dodge	obsolete		
SQB 13	365063	3/4x13 1/2	360099	PB 3/4" Dodge	862895	3/4"	E
SQB 14	365063	3/4x13 1/2	360099	PB 3/4" Dodge	862688	3/4"	E
SQB 16	365026	3/4x16	360099	PB 3/4" Dodge	obsolete	3/4"	E
SQB 18	365026	3/4x16	360099	PB 3/4" Dodge	obsolete	3/4"	E
SQB 24	365019	1 1/4x1x19	360101	PB 1 1/4" Dodge	811442	1"	E
SQB 30	365557	1 1/4x22 w/hole	360101	PB 1 1/4" Dodge	obsolete	1"	E
	365016	1 1/2x1 1/4x20 1/2	360102	PB 1 1/2" Dodge	obsolete	1 1/4"	E
	(original)	w/hole					
SQB 36	365554	1 1/2x1 1/4x22	360102	PB 1 1/2" Dodge	obsolete	1 1/4"	R
		w/hole			obsolete	1 1/4"	2R

RRPM above 690

Notes:

Where applicable, all replacement wheels furnished will be reinforced or embossed type.

Where higher fan rpm's are indicated, a double reinforced wheel (2R) should be selected.

Due to design changes, replacement wheels are no longer available for SQB-12, SQB-30 AND SQB-36.

Model SWB (100 Series)

2002 through present

Model Size	Shaft Part #	Description	Bearing Part #	Description	Aluminum Wheel Part #	Bore Size	Rotation
SWB 110	365025*	3/4X17 2K	360099*	PB 3/4" Dodge	870762	3/4"	CW
SWB 113	365099*	3/4X21 2K	360099*	PB 3/4" Dodge	862895	3/4"	CW
					825026	3/4"	CCW
SWB 115	365094*	3/4X22 2K	360099*	PB 3/4" Dodge	862694	3/4"	CW
					825027	3/4"	CCW
SWB 116	365735*	1X25 2K	360100*	PB 1" Dodge	862653	1"	CW
					825028	1"	CCW
SWB 118	366346*	1X26 2K	360100*	PB 1" Dodge	811454	1"	CW
					825029	1"	CCW
SWB 120	366291*	1X29 2K	360100*	PB 1" Dodge	825065	1"	CCW
SWB 124	366348*	1X31.5 2K	360100*	PB 1" Dodge	811442	1"	CW
					825066	1"	CCW
SWB 130	366349*	1X35 2K	360100*	PB 1" Dodge	822356	1"	CW
SWB 136	366449*	1 1/4X39 2K	360311*	PB 1/4" Dodge	826576	1 1/4"	CCW
					826583	1 1/4"	CCW

Notes:

Two bearings required per fan

Dodge bearings are cast steel with grease zerk standard

Weatherhoods SFB/SWB for Series 200

(Painted Permatector Gray)

Model	Size	Part #		Model	Size	Part #
SWB/SFB	9	Consult Factory		SWB/SFB	20	Consult Factory
SWB/SFB	10			SWB/SFB	22	
SWB/SFB	12			SWB/SFB	24	
SWB/SFB	13			SWB/SFB	27	
SFB	15			SWB/SFB	30	
SWB	15			SWB/SFB	33	
SWB/SFB	16			SWB/SFB	36	
SWB/SFB	18					

Model SWB (200 Series)

2002 through present

Model Size	Shaft Part #	Description	Bearing Part #	Description
SWB 210	365026 *	3/4X16	360099 *	PB 3/4" Dodge
SWB 212			360100 *	PB 1" Dodge
SWB 212*	365021	1X17 1/2	360100 *	PB 1" Dodge
SWB 213	365431	1X19 2K	360100 *	PB 1" Dodge
SWB 213*	365020	1x18 1/2	360100 *	PB 1" Dodge
SWB 215			360100 *	PB 1" Dodge
SWB 215*	365366	1 X 20 3/4	360100 *	PB 1" Dodge
SWB 216			360311 *	PB 1 1/4 " Dodge
SWB 216*	365010	1 1/4 x 23	360311 *	PB 1 1/4 " Dodge
SWB 218	365015	1 1/4 x 26	360311	PB 1 1/4 " Dodge
SWB 220	365070	1 1/4 x 28	360311	PB 1 1/4 " Dodge
SWB 222	365070	1 1/4 x 28	360311	PB 1 1/4 " Dodge
SWB 224			360102	PB 1 1/2 " Dodge
SWB 224*	365488	1 1/2 X 29	360102	PB 1 1/2" Dodge
SWB 227	365069	1 1/2 x 33 1/2	360102	PB 1 1/2" Dodge
SWB 227*	365367	1 1/2 x 32	360102	PB 1 1/2" Dodge
SWB 230	365072	1 3/4 x 34 1/2	360093	PB 1 3/4" Dodge
SWB 233	365073	1 3/4 x 36 1/2	390093	PB 1 3/4" Dodge
SWB 236	365067	2 x 38 1/2	360106	PB 2" Dodge

Notes:

* Shafts were changed on selected sizes for serial no's. indicated. To ensure the correct shaft is ordered, verify shaft length prior to ordering.

Two bearings required per fan

Dodge bearings are cast steel with grease zerk standard

Weatherhoods SFB/SWB for Series 200 (Painted Permatector Gray)

Model	Size	Part #
SWB/SFB	9	850365
SWB/SFB	16	842575

Model SWB

Manufactured 1990 through 2002

Model Size	Shaft Part #	Description	Bearing Part #	Description
SWB 10	365026 *	3/4x16	360099 *	PB 3/4" Dodge
SWB 12	365020	1 x 18 1/2	360100 *	PB 1" Dodge
SWB 12*	365021	1 x 17 1/2 (Serial# 's 87I & after)	360100 *	PB 1" Dodge
SWB 13	365017	1 x 20	360100 *	PB 1" Dodge
SWB 13*	365020	1 x 18 1/2 (Serial# 's 87D & after)	360100 *	PB 1" Dodge
SWB 15	365031	1 x 22	360100 *	PB 1" Dodge
SWB 15*	365366	1 x 20 3/4 (Serial# 's 87I & after)	360100 *	PB 1" Dodge
SWB 16	365078	1 1/4 x 24	360101 *	PB 1 1/4 " Dodge
SWB 16*	365010	1 1/4 x 23 (Serial# 's 87I & after)	360101 *	PB 1 1/4 " Dodge
			360311	
SWB 18	365015	1 1/4 x 26	360101	PB 1 1/4 " Dodge
			360311	
SWB 20	365070	1 1/4 x 28	360101	PB 1 1/4 " Dodge
			360311	
SWB 22	365070	1 1/4 x 28	360101	PB 1 1/4 " Dodge
			360311	
SWB 24	365068	1 1/2 x 30	360102	PB 1 1/2 " Dodge
SWB 24*	365488	1 1/2 x 29 (Serial# 's 87J & after)	360102	PB 1 1/2 " Dodge
SWB 27	365069	1 1/2 x 33 1/2	360102	PB 1 1/2 " Dodge
SWB 27*	365367	1 1/2 x 32 (Serial# 's 87I & after)	360102	PB 1 1/2 " Dodge
SWB 30	365072	1 3/4 x 34 1/2	360093	PB 1 3/4 " Dodge
SWB 33	365073	1 3/4 x 36 1/2	360093	PB 1 3/4 " Dodge
SWB 36	365067	2 x 38 1/2	360106	PB 2" Dodge

Notes

* Shafts were changed on selected sizes for serial numbers indicated. To ensure the correct shaft is ordered, verify shaft length prior to ordering

Two bearings required per fan

Dodge bearings are cast steel with grease zerk standard

Due to ECN #2013, AUG. 2001, in which bearing part no. 360101 was changed to part no. 360311

Bearing part # 360311 is not interchangeable with previous part # 360101. Need unit serial number to verify correct bearings

Weatherhoods SFB/SWB for Series 200 (Painted Permatector Gray)

Model	Size	Part #
SWB/SFB	9	850365
SWB/SFB	16	842575

Model TAUB/TAUD

Magnetic Damper Latch Kits

Model Description / Size	Material	Part #
TAUB/TAUD 18-30, & TAUB-HT 24-30	Alum	850843
TAUB/TAUD 18-30, & TAUB-HT 24-30	Steel	850840
TAUB/TAUD-HT 36 & RBU/RBUMO, RDU/RGU 18-48	Alum	851219
TAUB/TAUD-HT 36 & RBU/RBUMO, RDU/RGU 18-48	Steel	851220
TAUB/TAUD, TAUB-HT 42-48	Alum	850841
TAUB/TAUD, TAUB-HT 42-48	Steel	850844
TAUB/TAUB-HT, RBU/RBUMO, RGU 54-60	Alum	850842
TAUB/TAUB-HT, RBU/RBUMO, RGU 54-60	Steel	850845

KITCHEN VENTILATION

Filters

Part #	Filter Material	Filter Type	Height	Width
851703	Alum.	Grease-X-Tractor	16	16
851704	Alum.	Grease-X-Tractor	16	20
851706	Alum.	Grease-X-Tractor	20	16
851707	Alum.	Grease-X-Tractor	20	20
851709	SS	Grease-X-Tractor	16	16
851710	SS	Grease-X-Tractor	16	20
851712	SS	Grease-X-Tractor	20	16
851713	SS	Grease-X-Tractor	20	20
852881	Alum	Grease Grabber	16	16
852880	Alum	Grease Grabber	16	20
852879	Alum	Grease Grabber	20	16
852878	Alum	Grease Grabber	20	20
851656	SS	High Velocity	16	16
851657	SS	High Velocity	16	20
851659	SS	High Velocity	20	16
851660	SS	High Velocity	20	20
457626	Alum.	Baffle	16	16
457628	Alum.	Baffle	16	20
457632	Alum.	Baffle	20	16
457634	Alum.	Baffle	20	20
457627	SS	Baffle	16	16
457629	SS	Baffle	16	20
457633	SS	Baffle	20	16
457635	SS	Baffle	20	20

Miscellaneous Parts

Description	Part Number
Grease Trap Package	475538
Replacement Grease Absorbers	460263
Lube Line Kit (for all units)	811178
Belt Tension Cam-Arm/Pulley only	456724
Belt Tension Assembly Kit	818912
KSU-Maxon Flame Rod (flame sensor) NP-1 & LE	452942
KSU-Maxon Spark Rod (spark igniter)NP-1	452943
KSU Flame Rod Wire	462118
KSU-Fenual Flame Rod (flame sensor), since 2005	460508
KSU-Fenual Spark Rod (spark igniter) since 2005	460508
KSU Flame Rod igniter since 2005 NP-LE	383368
DG-Eclipse Flame Rod (flame sensor)	461660
DG-Eclipse Spark Rod (spark igniter) 170171	461661
Eclipse Spark Rod Wire	462413
KSU Air Flow - Pressure SMD	452857
KSU Flame Rod Wire	851211
Glass Globe for hood lights	453498
Globe and Fixture	382741
Grease Cup for GH and Gk Hoods	451131
1/4 turns fastener set for perforated face supply	Obsolete
Dry Cartridge Removal Tool	Obsolete
GK Filter Removal Tool (Kings Mtn Only)	851747
Baffle Filter Removal Tool (Kings Mtn Only)	851834
Replacement Filter Handle (Spring SS Steel Style) (Kings Mtn Only)	473569

Registers

Size	Description	Part Number
24 x 8	Aluminum Single Deflection H -OB	452700
36 x 8	Aluminum Single Deflection H -OB	452701
38 x 8	Aluminum Single Deflection H -OB	452702
44 x 8	Aluminum Single Deflection H -OB	452703
24 x 12	Aluminum Single Deflection H -OB	453796
36 x 12	Aluminum Single Deflection H -OB	453797
38 x 12	Aluminum Single Deflection H -OB	453798
44 x 12	Aluminum Single Deflection H -OB	453799
24 x 8	Aluminum 38 degree Fixed Blade RA -OB	452729
30 x 8	Aluminum 38 degree Fixed Blade RA -OB	452730
36 x 8	Aluminum 38 degree Fixed Blade RA -OB	452731
38 x 8	Aluminum 38 degree Fixed Blade RA -OB	452732
44 x 8	Aluminum 38 degree Fixed Blade RA -OB	452733

Switches

Description	Part Number
Switch L - lights only	850551
Switch F - combined	851776
Switch LF - Combined with lights	851777
Switch FH - Combined	851778
Switch ES - Separate	851779
Switch LFH - Combined with lights	851780
Switch LES - Separate with lights	851781
Switch ESH - Separate	851782
Switch LESH - Separate with lights	851783
Switch FT - Combined	851784
Switch LFT - Combined with lights	851785
Switch EST - Separate	851786
Switch LEST - Separate with lights	851787
Switch AD - Automatic Fire Damper	851618

(L = Lights, F=Fans, E=Exhaust, S=Supply, H=Heater)

Water Spray Fire Protection Nozzles

Description	Part Number
325° F brass	455264
325° F chrome	455265
500° F chrome	455336
Nozzle wrench for WSFP nozzles	455266
Water wash nozzles	453675
Continuous cold water mist nozzles	456767

Burner Parts for MUA units

Burner Type	Part Description	Part Number
Indirect gas	Flame Rod	460508
Indirect gas	Spark Rod	460508
Indirect gas	Spark Rod Wire	n/a (use standard 18ga wire)
Eclipse	Flame Rod	461660
Eclipse	Spark Rod	461661
Eclipse	Flame Rod Wire	461662
Eclipse	Spark Rod Wire	462413
Maxon	Flame Rod	452942 NP-1 and NP-LE
Maxon	Spark Rod	452943 NP-1 383368 NP-LE
Maxon	Flame Rod Wire	851211
Maxon	Spark Rod Wire	462118
DG	Mount Kit	853643

Motor Information

Enclosures	Vendors	Special Purpose
OP = Open	AS = A.O. Smith	AS = Automotive Spec
TF = Totally Enclosed Fan Cooled	BA = Baldor	CS = Capacitor Start
TA = Totally Enclosed Air Over Totally Enclosed	CE = Century	EE = Energy Efficient
TN = Nonventilated	FA = Fasco	JE = High Efficiency
EX = Explosion Resistant	GE = General Electric	MC = Mill and Chem
	LE = Leeson	PSC = Perm Split Capacitor
	MC = McMillan	SD = Severe Duty
	ME = Marathon Electric	TO = Thermal Overload
	RE = Reliance	
	SM = Siemens	
	TB = Toshiba	

Replacement Motors by Greenheck Part

GFC Part #	Motor Mfg.	HP	RPM	Description	Voltage-Cycle Phase	Motor Mfg. Part #	Frame Size
301316	Fasco	SP	1150	TF	115-60-1	71241066	N/A
301812	MC	SP	1050	OP	115-60-1	F0508B2508	N/A
301814	MC	SP	1050	OP	115-60-1	F0408B2509	N/A
301816	MC	SP	1050	OP	115-60-1	F0524B2511	N/A
301817	MC	SP	1000	OP	115-60-1	F0516B2512	N/A
301832	Fasco	SP	1095	OP	115-60-1	71513782	N/A
301833	Fasco	SP	1050	OP	115-60-1	71513783	N/A
310225	Fasco	SP	1070	OP	115-60-1	71513785	N/A
301839	Fasco	SP	1550	OP	115-60-1	71086922	N/A
301980	Fasco	SP	1550	TF	115-60-1	71086742	N/A
311732	Fasco	SP	1550	TF	220/230-60-3	71086741	N/A
302021	Fasco	SP	1050	OP	115-60-1	71233623	N/A
302022	Fasco	SP	1610	OP	115-60-1	71241696	N/A
302172	Fasco	SP	950	OP	115-60-1	71730008	N/A
310198	Fasco	SP	1050	OP	115-60-1	71730007	N/A
302424	Fasco	SP	1100	OP	115-60-1	71730099	N/A
304843	MC	SP	1050	OP	115-60-1	A0810B3215	N/A
304842	MC	SP	1300	OP	115-60-1	A0810B3214	N/A
302490	Fasco	SP	1450	115-60-1	115-60-1	71241796	N/A
311734	McMillan	SP	1400	OP	230-60-1	F0412B4160	N/A
311389	McMillan	SP	1350	OP	230-60-1	D0810B4251	N/A
303039	MC	SP	1100	OP	115-60-1	F0408B2782	N/A
311559	MC	SP	1400	OP	115-60-1	D0810B4076	N/A
312499	MC	SP	950	OP	115-60-1	F08010B4221	N/A
303875	CE	SP	1100	TF	115/208/230	8-194086-00	N/A
304333	Fasco	SP	1050	OP	277-60-1	71731099	N/A
304336	Fasco	SP	1550	OP	277-60-1	71731323	N/A
304983	Fasco	SP	1100	OP	115-60-1	71902341	N/A
451376	Broan	SP		FiSt SP-5	115-60-1	99080223	N/A
451389	Broan	SP		FiSt SP-6	115-60-1	99080095	N/A
300757	Fasco	SP	3 SP ***	TF	115-60-1	71636832	N/A
301462	Fasco	SP	3 SP ***	TF	115-60-1	71637303	N/A

Notes:

SP = Horsepower are too small to be determined (less than 1/8)

For all replacement motors, other than those shown, consult factory for availability and pricing

Replacement Motors by Greenheck Part

GFC Part #	Motor Mfg.	HP	RPM	Description	Voltage-Cycle -Phase	Motor Mfg. Part #	Frame Size
300757	Fasco	1/40	3 SP ***	TF	115-60-1	71086832	N/A
300457	Fasco	1/30	3 SP ***	OP	115-60-1	71635387	N/A
302529	McMillan	1/25	3 SP ***	OP	115-60-1	F0412B2690	N/A
301639	Fasco	1/20	3 SP ***	OP	115-60-1	71086857	N/A
300760	Fasco	1/15	3 SP ***	TF	115-60-1	71086431	N/A
301638	Fasco	1/15	3 SP ***	OP - TO - PSC	115-60-1	71086848	N/A
302603	MC	1/14	3 SP ***	TF	115-60-1	D0816A2676	N/A
300453	Fasco	1/8	860	OP - TO - PSC	115-60-1	71635375	N/A
311742	Fasco	1/8	3 SP ***	TF	115-60-1	71241967	N/A
308318	MC	1/8	3 SP ***	OP - TO - PSC	115-60-1	A0820B2633	N/A
300008	FA	1/8	860	OP - TO - PSC	115-60-1	71280469	48
301983	ME	1/6	860	EX-TF	115-60-1	59B8G5500	56
300116	GE	1/6	1140	TF	115-60-1	KH36PN109	48
301772	ME	1/6	1140	OP	115-60-1	48A110251	48
300010	ME	1/6	1140	OP-TO-PSC	115-60-1	048A110251	48
304240	ME	1/6	1725	OP-TO	115-60-1	48S17D2053	48
304287	FA	1/6	1725	OP-TO	115-60-1	48S17D1279A	48
302309	GE	1/6	1140/860	OP	115-60-1	5KH49PN6133	56
311340	CH	1/4	1140	OP-TO-PSC	115-60-01	CK48BS06KS12	48
300016	ME	1/4	1725	OP-TO	115-60-1	048S17D2055	48
300124	ME	1/4	1725	OP-TO-CS	115-208/230-60-1	48C17D2042	48
304804	ME	1/4	1725	TF-TO	115-60-1	48S17F10	48
301292	BA	1/4	1725	TF	208/230/460-60-3	M3454	48
301336	ME	1/4	1725	OP	208-230/460-60-3	V48T17D2000	48
300017	ME	1/4	1725/1140	OP	115-60-1	48S17D7200	48
301640	ME	1/4	860	TF	115/230-60-1	56C8F5500	56
301641	ME	1/4	860	OP-TO-PSC	115-60-1	56A8D5503	56
300494	BA	1/4	1140	TEFC	115/230-60-01	L3500	56
302094	ME	1/4	1140	EX-TO	115-60-01	56C11G5303	56
309133	Fasco	1/4	1600	OP	115-60-1	71840078	N/A
305319	ME	1/4	1725	EX-TO	115-208/230-60-1	56C17E5518	56
309153	FA	1/4	1725	OP-TO	115-60-1	71250390	48
311338	CH	1/4	1725	OP-TO-PSC	115-60-1	CK48HB08KF14	48
301642	ME	1/3	1140	OP-PSC	115-60-1	56A8D5502	56
301643	ME	1/3	1140	OP-PSC	115-60-1	56A11D65	56
300024	ME	1/3	1725	OP-TO-CS	115/230-60-1	Q48C17D2044	48
309108	ME	1/3	1725	TF-TO	115-60-1	56S17F5305	56
311587	ME	1/3	1725	OP-TO	115-60-1	48S17D2057	48
308213	ME	1/3	1725	OP	208-230/460-60-3	V56T17D2095	56
302983	ME	1/3	1725	EX-TO-CS	115/230-60-1	56C17G5315	56
310109	ME	1/3	1725	TF-TO	208/230/460	56T17F2034	56
300025	ME	1/3	1725/1140	OP	115-60-1	56S17D7202	+56

Notes:

+56 = 48 frame with 5/8 diameter shaft (like a 56 frame).

For all replacement motors, other than those shown, consult factory for availability and pricing

Replacement Motors by Greenheck Part

GFC Part #	Motor Mfg.	HP	RPM	Description	Voltage-Cycle -Phase	Motor Mfg. Part #	Frame Size
301644	ME	1/2	1140	OP	115-60-1	56A11D66	56
300029	ME	1/2	1725	OP-TO-CS	115-208/230-60-1	Q5617D2072	56
311588	ME	1/2	1725	OP	115-60-1	48S17D2058	48
311351	WEG	1/2	1725	TEFC	115/230-60-1	.5018ES1RCH056	56
304853	ME	1/2	1725	OP-TO	115-60-1	45S17D1299	48
302653	ME	1/2	1725	TF	208-230/460-60-3	56T17D2035	56
308214	ME	1/2	1725	OP	208-230/460-60-3	V56T17D2094	56
302984	ME	1/2	1725	EX-CS	115-208/230-60-1	56C17G5316	56
304853	ME	1/2	1725	OP	115/208/230-1	48S17D1299	48
304225	ME	1/2	1725	EX-TO	208-230/460-60-3	56T17G5312	56
311589	ME	3/4	1725	OP-TO-CS	115-208/230-60-1	Q56C17D2074	56
300220	ME	3/4	1140	OP	208-230/460-60-3	110025	56
300949	ME	3/4	1725/1140	OP	208/230-60-3	111958	56
309104	ME	3/4	1725	TF-CS	115-208/230-60-1	56C17F2306	56
310110	ME	3/4	1725	TF	208-230/460-60-3	56T17F2037	56
301008	ME	3/4	1725/1140	OP-CS	115-60-1	111954	56
301231	GE	3/4	1725/1140	OP-CS	208/230-60-1	C448	56
308215	ME	3/4	1725	OP	208-230/460-60-3	56T17D2093	56
309116	ME	3/4	1725/1140	OP	460-60-3	56T17D5705	56
304218	ME	3/4	1725	EX-CS	115/230-60-1	56C17G5317	56
304232	ME	3/4	1725	EX	230/460-60-3	56T17G5313	56
309735	LE	3/4	1140	OP-TO	115-208/230-60-1	114770	56
304303	GE	1	1725	EX	208-230/460-60-3	K43PG5281X	56
300923	LE	1	1725/1140	OP	208/230-60-3	111960	56
302043	ME	1	1725	OP-EE	230/460-60-3	143TTDR5347	143T
301045	ME	1	1725	OP-EE	200/208-60-3	143TTDR5348	143T
301106	LE	1	1725/1140	OP	460-60-3	111961	56
303463	ME	1	1725	OP-TO-CAP	115/208/230-60-1	56C17D5322	56
309102	ME	1	1725	OP/CAP	115/208/230-60-1	56C17D5321	56
301340	ME	1	1725	OP	208-230/460-60-3	56T17D2092	56
301879	TB	1	1725	OP	208-230/460-60-3	B0014DLF2AMH	143T
304888	ME	1	1725	TF-EE	230/460-60-3	143TTFR4028	143T
303258	A.O Smith	1	1725	TF-EE	208-230/460-60-3	AS143TE164	143T
303322	ME	1	1725	TF-EE	200/208-60-3	143TTFR4028	143T
302045	ME	1 1/2	1725	OP-EE	230/460-60-3	145TTDR5630	145T
301047	ME	1 1/2	1725	OP-EE	200/208-60-3	145TTDR5632	145T
301076	LE	1 1/2	1725/1140	OP	460-60-3	111963	56
301087	LE	1 1/2	1725	OP	115-208/230-60-1	120001	145T
301366	ME	1 1/2	1725/1140	OP	200/230-60-3	56T17D5708	56
302046	LE	1 1/2	1725	OP-TO-PE	208-230/460-60-3	145T121004	145T
303004	ME	1 1/2	1725	TF-EE	230/460-60-3	145TTFR4026	145T
303677	ME	1 1/2	1725	OP-CS	115-208/230-60-1	56B17D5570	56
303323	ME	1 1/2	1725	TF-EE	200/208-60-3	145TTFR4029	145T
303677	ME	1 1/2	1725	OP-CS	115-208/230-60-1	ME56B17D5570	56
311395	ME	1 1/2	1725	EX	230/460-3	145TTGN4026	145T

Notes: Review shaft length with customer relative to old fan application. This motor has a 1 7/8" long shaft.
For all replacement motors, other than those shown, consult factory for availability and pricing.

For all replacement motors, other than those shown, consult factory for availability and pricing

Replacement Motors by Greenheck Part

GFC Part #	Motor Mfg.	HP	RPM	Description	Voltage-Cycle -Phase	Motor Mfg. Part #	Frame Size
311508	ME	2	1725	OP-EE	230/460-60-3	145TTDR5631	145T
301049	ME	2	1725	OP-EE	200/208-60-3	145TTDR5633	145T
301882	TB	2	1725	OP	208-230/460-60-3	B0024DLF2AMH	145T
302047	ME	2	1725	TF-EE	230/460-60-3	145TTFR4029	145T
302982	ME	2	1725	OP	200-230/460-60-3	56T17D5310	56
311422	ME	2	1725	EXP	230/460-60-3	145TTGN4027	145T
300158	ME	3	1725/1140	OP-HE	460-60-3	184TTDR7215	184T
301288	ME	3	1725	OP-CS	115-208/230-60-1	184TCDR7026	184T
302053	ME	3	1725	OP-EE	200/208-60-3	182TTDR4027	182T
302113	CE	3	1725	TF-EE	208-230/460-60-3	182TTFR4026ER	182T
311390	ME	3	1725	EX	230.460-60-3	182TTGS4026	182T
302054	ME	3	1725	OP-EE	208/230/460-60-3	182TTDB4026	182T
301265	ME	5	1725	OP-EE	200/208-60-3	184TTDR4027	184T
302059	A.O. Smith	5	1725	OP-EE	208-230/460-60-3	AS184T E227	184T
310928	A.O. Smith	5	1725	TF	208-230/460-60-3	AS184T	184T
302059	ME	5	1725	OP-EE	208-230/460-60-3	184TTDB4026	184T
303326	ME	5	1725	TF-EE	200/208-60-3	184TTFR4038	184T
311400	ME	5	1725	TF	208/230/460-60-3	184TTGN6526	184T
307965	BA	5	1725	TF-EE	208-230/460-60-3	EM3665T	184T
302088	ME	7 1/2	1725	OP-EE	208/230/460-60-3	213TTDB4026	213T
311746	ME	7 1/2	1725	OP-EE	200/208-60-3	213TTDW4028	213T
302067	CE	10	1725	OP-EE	208-230/460-60-3	E301	215T
302867	CE	10	1725	OP-EE	230/460-3	215TTDB4026	215T
302073	ME	15	1725	OP	208-230/460-60-3	EM2513T	254T

Replacement Motors by Motor Vendor Part

AO Smith

Vendor Part #	Greenheck Part #	Status	New Greenheck Part #	New Vendor Part #'s		New Greenheck Part #
F56A13B74	302547	Obsolete	303875	AS	8-194086-00	

Broan

Vendor Part #	Greenheck Part #	Status	New Greenheck Part #	New Vendor Part #'s		New Greenheck Part #
99080095	451389	Active				
99080223	451376	Active				

Century

Vendor Part #	Greenheck Part #	Status	New Greenheck Part #	New Vendor Part #'s		New Greenheck Part #
8-194086-00E	303875	Active				

Fasco

Vendor Part #	Greenheck Part #	Status	New Greenheck Part #	New Vendor Part #'s		
71080077	300005	Obsolete	302603	MC	D0816A3676	
71082425	300120	Obsolete	301639	Fasco	71086857	
71086194	300459	Obsolete	301638	Fasco	71086848	
71086431	300760	Active				
71086641	301136	Obsolete	301839	Fasco	71086922	
71086742	301980	Active				
71086832	300757	Active				
71086848	301638	Active				
71086857	301639	Active				
71086922	301839	Active				
71086984	302578	Obsolete	311389	MC	A0810B4014	
71086985	302576	Obsolete	304842	MC	A0810B3214	
71233623	302021	Active				
71240360	300455	Obsolete	308318	MC	A0820B3680	
71241066	301316	Active				
71241411	301652	Obsolete	308318	MC	A0820B3680	
71241696	302022	Active				
71241796	302490	Active				
71241967	303441	Obsolete	311742	MC	A0816A4075	
71250368	303723	Obsolete	309153	CHK	CK48HB02K01	
71250369	303859	Obsolete	311587	ME	048S17D2057	

Replacement Motors by Motor Vendor Part

Fasco continued

Vendor Part #	Greenheck Part #	Status	New Greenheck Part #	New Vendor Part #'s		
71250376	304220	Obsolete	304853	ME	48517D1299	
71250379	304222	Obsolete	304287	ME	48S17D1279A	
71250390	304387	Obsolete	309153	CHK	CK48HB02K01	
71263623	302021	Active				
71264107	303442	Obsolete	300010	ME	048A11O251	
71264304	304207	Obsolete	300012	ME	48A11O186	
71280469	303443	Obsolete	300008	ME	48A8O11005	
71512577	300144	Obsolete	301812	MC	F0508B2507	
71512585	300145	Obsolete	301813	MC	F0508B2508	
71512587	301139	Obsolete	301817	MC	F0516B2512	
71513487	301146	Obsolete	309132	MC	F0532B3753	
71513566	301136	Obsolete	301839	Fasco	71086922	
71513585	301145	Obsolete	310225	MC	F0516B3868	
71513567	301140	Obsolete	301833	Fasco	71513783	
71513782	301832	Active				
71513783	301833	Active				
71513785	301835	Obsolete	310225	MC	F0516B3868	
71632491	300118	Obsolete	300453	Fasco	71635375	
71632492	300119	Obsolete	300457	Fasco	71635387	
71635375	300453	Active				
71635376	300451	Obsolete	302529	MC	F0412B2690	
71635387	300457	Active				
71636832	300757RK	Obsolete	300757	FA	7163-6832	
71637303	301462RK	Obsolete	301462	FA	7163-7303	
71730007	302173	Active				
71730008	302172	Active				
71730099	302424	Active				
71730258	302575	Obsolete	311559	MC	D0810B4076	
71730259	302577	Active				
71730349	302827	Active	303039	MC	F0408B2782	
71731097	304332	Obsolete	304333	FA	7173-1099	
71731098	304331	Obsolete	304333	FA	7173-1099	
71731099	304333	Active				
71731323	304336	Active				
71731325	304334	Obsolete	304336	FA	7173-1323	
71731327	304335	Obsolete	304336	FA	7173-1323	
71742661	301151	Obsolete	309133	MC	D0824B3755	
71742829	301840	Obsolete	309133	MC	D0824B3755	
71840078	303854	Obsolete	309133	MC	D0824B3755	

Replacement Motors by Motor Vendor Part

Fasco (Continued)

Vendor Part #	Greenheck Part #	Status	New Greenheck Part #	New Vendor Part #'s	
71896247	300761rk	Obsolete	302603	MC	D0816A2676
71902142	304201	Active			
71902330	304202	Obsolete			
71902341	304338	Obsolete	304983	Fasco	71902341

Franklin

Vendor	Greenheck Part #	Status	Greenheck Part #	New Vendor Part #'s	
873610130	300752	Obsolete	302021	Fasco	71263623
8263710160	300456	Obsolete	300457	Fasco	71635387
8264110420	300450	Obsolete	302529	MC	F0412B2690
8264110430	300452	Obsolete	300453	Fasco	71635375
8264110460	300758	Obsolete	301462	Fasco	71637303
8264310350	300759	Obsolete	301462	Fasco	71637303
8413810270	300172	Obsolete	301839	Fasco	71086922
8413810400	300203	Obsolete		NO LONGER AVAILABLE	
8414010270	300190	Obsolete	301639	Fasco	71086848
8416010220	300176	Obsolete	310225	MC	F0516B3868
8424010250	300192	Obsolete	301639	Fasco	71086848
8715410140	300458	Obsolete	310225	MC	F0516B3868
8715810300	300756	Obsolete	301816	MC	F0524B2511
8716010370	300177	Obsolete	309132	MC	F0532B3753
8733810010	301162	Obsolete	309133	MC	D0824B3755
8743810240	300454	Obsolete	308318	MC	A0820B3680
8743810370	300762RK	Obsolete	311742	MC	A0816A4075
8745610010	301163	Obsolete	300016	ME	48S17D2055

General Electric

Vendor	Greenheck Part #	Status	New Greenheck Part #	New Vendor Part #'s	
KCP37KN143GE	300218KCP37KN143	Obsolete	311338	CK	CK48HB08KF14

Magnatek

Vendor	Greenheck Part #	Status	New Greenheck Part #	New Vendor Part #'s	
JA2M437N	302474	Obsolete	311559	MC	D0810B4076
JA2M439N	302470	Obsolete	310928	WEG	00518ET3ERS184T
JA2M439N	302447	Obsolete	312499	MC	F0810B4221
JE2H053N	302478	Obsolete	304842	MC	A0810B3214
JE2H054N	302477	Obsolete	304843	MC	A0810B3215

Replacement Motors by Motor Vendor Part

Marathon Electric

Vendor	Greenheck Part #	Status	New Greenheck Part #	New Vendor Part #'s		
48A80151	300008	Active				
48A110251	300901RK	Obsolete	311742	MC	A0816A4075	
48A110251	300010	Active				
48A170178	300185	Obsolete	304992	ME	254TTDB4026	
48A17T848	300901	Obsolete	311742	MC	A0816A4075	
48A1101073	300917	Obsolete	302021	Fasco	7126-3623	
48A1101640	301772	Active				
48S17D2054	300014	Obsolete	300016	ME	48S17D2055	
48S17D2055	300016	Active				
56A11D33	300239	Obsolete	301643	ME	56A11D65	
56A11D65	301643	Active				
56A11D66	301644	Active				

McMillan

Vendor	Greenheck Part #	Status	New Greenheck Part #	New Vendor Part #'s		
48A110186	300012	Active	311340	CK	CK48BS06KS12	
48A170227	301778	Obsolete	311338	CK	CK48HB08KF14	
A0408B2173	301134	Obsolete	301814	MC	F0408B2509	
A0508B2171	301133	Obsolete	301812	MC	F0508B2507	
A0508B2172	301135	Obsolete	301813	MC	F0508B2508	
A0516B2317	301377	Obsolete	301817	MC	F0516B2512	
A0524B2282	301350	Obsolete	301816	MC	F0524B2511	
A0820B2633	302336	Obsolete	308318	MC	A0820B3680	
A0810B3214	304842	Active				
A0810B3215	304843	Active				
D0408B2556	301850	Obsolete	301814	MC	F0408B2509	
D0508B2555	301849	Obsolete	301813	MC	F0508B2508	
D0516B2559	301853	Obsolete	301817	MC	F0516B2512	
D0524B2558	301852	Obsolete	301816	MC	F0524B2511	
D0810B2691	302530	Active				
D0816A2676	302603	Active				
F0408B2509	301814	Active				
F0408B2782	303039	Active				
F0408B2791	303041	Obsolete	312499	MC	F0810B4221	
F0410B2783	303040	Obsolete	311559	MC	D0810B4076	
F0412B2690	302529	Active				
F0508B2507	301812	Active				
F0508B2508	301813	Active				
F0516B2512	301817	Active				
F0524B2511	301816	Active				

Replacement Motors by Motor Vendor Part

Universal Electric

Vendor	Vendor Part #	Status	Greenheck Part #	New Vendor Part #'s		
CA2G173N	300461	Obsolete	301639	Fasco	71086857	
CA2G174N	300460	Obsolete	301638	Fasco	71086848	

Obsolete Greenheck Part Numbers and their Replacement

GFC Part #	Motor Mfg.	HP	RPM	Description	Voltage-Cycle Phase	Motor Mfg. Part #	Frame Size	Replacement Motor Part #
300005	Fasco	1/14	3 SP ***	TF	115-60-1	71080077		302603
300007	GE	1/8	860	OP-TO-PSC	115-60-1	5KCP33GN277	48	300008
300016	ME	1/4	1725	OP	115-60-1	48S17D2055	48	300010
300009	GE	1/6	1140	OP-TO-PSC	115-60-1	KCP33GN288S	48	300010
300010	ME	1/6	1140	OP-TO-PSC	115-60-1	48A110251	48	300010
300011	ME	1/4	860	OP-TO-PSC	115-60-1	56AD5503	56	301641
300013	GE	1/4	1725	OP-TO	115-60-1	KH33FN7	48	300016
300014	ME	1/4	1725	OP	115-60-1	48S17D2054	48	300016
300015	GE	1/4	1725	OP	115-60-1	KH33FN7X	48	300016
300017	GE	1/4	1725/1140	OP	115-60-1	GE/KH37PN33	48	300017
300021	ME	1/3	1140	OP-PSC	115-60-1	56A8D42	56	301642
300022	GE	1/3	1725	OP	115-60-1	KH35JN10	48	311587
300023	ME	1/3	1725	OP	115-60-1	48S17D2056	48	311587
300035		1/3	1140			5KH48PG45E		301643
300047	ME	1	1725	OP	208-230/460-60-3	143TTDR7026	143T	301879
300048	ME	1 1/2	1725	OP	200/208-60-3	145TTDR7926	143T	301047
300051	ME	2	1725	OP	208-230/460-60-3	145TTDR7026	145T	310327
300052	ME	3	1725	OP-EE	200/3	182TTDR7627	182T	302053
300053	ME	3	1725	OP	208-230/460-60-3	182TTDR7026	182T	302053
300054	ME	5	1725	OP-EE	200/208-60-3	184TTDR7627		310265
300055	ME	5	1725	OP-EE	208-230/460-60-3	184TTDR7026		302059
300057	GE	1/6	1140/860	OP	115-60-1	KH45PG89	56	302309
300059	GE	1/4	1140/860	OP	115-60-1	5H49SN3048	56	301960
300060	ME	1/6	860	EX-TF	115-60-1	56S8E26	56	301983
300063	ME	1/3	1725	EX-TO-CS	115/230-60-1	56C17G15	56	302983
300065	ME	1/6	1725	OP	115-60-1	48S17D2052	48	304240
300069	ME	7 1/2	1725	OP-EE	208/230/460-60-3	213TTDR7026		302088
300077	ME	1	1725	TF-EE	208-230/460-60-3	143TTFR7726	143T	303258
300079	ME	2	1725	TF	208-230/460-60-3	145TTFR7727	145T	302047
300080	ME	3	1725	TF	208-230/460-60-3	182TTFR7726	182	302113
300081	ME	5	1725	TF-EE	208-230/460-60-3	184TTFR7726	184T	302118
300083	GE	1/2	1725	OP	208-230/460-60-3	K36MN4	56	308214
300087	GE	3/4	1725	OP	208-230/460-60-3	5K49QG9747	56	308215
300105	ME	1/8	1140	EX - TO	115-60-1	S11E129	56	302094
300109	ME	3/4	1725	TF	208-230/460-60-3	56T17F5301	56	310164
300111	ME	7 1/2	1725	OP-EE	200-60-3	213TTDR7359		311746
300113	ME	1/2	1725	TF	208-230/460-60-3	56T17F5300	56	302653
300114	GE	1/4	1140	TEFC	115-60-01	KH49MN6060	56	300494
300115	ME	1/3	1725	OP	208-230/460-60-3	56T17D2060	56	308213
300118	Fasco		3SP ***		115/60/1	71632491	N/A	300453
300119	Fasco	1/30	3 SP ***	OP	115/60/1	71632492	N/A	300457
300120	Fasco	1/20	3 SP ***	OP	115/60/1	71082425	N/A	301639
300126		1/2	1140		115-60-1	56A11D29	56	301644
300128	ME	3/4	1725	TF-CS	115-208/230-60-1	56C17F42	56	309104
300129	ME	3/4	1725	EX	208-230/460-3	56T17G5300	56	304232
300140		1/2	1140	TF	115-60-1	KH47UG88		301891
300144	Fasco		1050		115-60-1	71512577	N/A	301812
300145	Fasco	1/4	1050	OP	115-60-1	71512585	N/A	301813
300146	ME	1/2	1725	EX-CS	115-208/230-60-1	56T17D712		308214
300159	ME	10	1725	OP	208-230-460/60/1	215TTDR7026	215T	302067
300403	GE	1/4	1725	TF	115-60-1	KH36PN108	48	300025

Obsolete Greenheck Part Numbers and their Replacement

GFC Part #	Motor Mfg.	HP	RPM	Description	Voltage-Cycle Phase	Motor Mfg. Part #	Frame Size	Replacement Motor Part #
300147	ME	3/4	1725	OP	208-230/460-60-3	56T17D713	56	308215
300148	ME	1/4	1140	EX-TO	115-60-01	56S11E70	56	302094
300150	ME	1/2	1725	TF-CS	115-208/230-60-1	56C17F5303		311351
300154	ME	1 1/2	1725	EX	230/460-3	145TTGN7026		311395
300156	ME	2	1725	EXP	230/460-60-3	145TTGN7027		311442
300161	GE	1/4	1725	EX-TO	115-60-1	KH35PN202X	48	310281
300172	Franklin		1550	OP	115-60-1	8413810270	N/A	301839
300175	GE	1/3	1725	OP-TO	115-60-1	KH35JN10X	48	311587
300176	Franklin		1070	OP	115-60-1	8416010220	N/A	310225
300177	Franklin		1095	OP	115-60-1	8716010370	N/A	301832
300179	ME	1 1/2	1725	TF-EE	208-230/460-60-3	145TTFR7726	145T	303323
300183	ME	3	1725	EX	230.460-60-3	182TTGS7026	182T	311390
300184	ME	5	1725	EX	230/460-60-3	184TTGS7026		311400
300185	ME		1610	115	115-60-1	48A170178	N/A	304992
300187	ME	1/2	1725	EX-TO	208-230/460-60-3	56T17E72		304225
300190	Franklin	1/20	3 SP ***	OP	115-60-1	8414010270	N/A	301639
300192	Franklin	1/20	3 SP ***	OP	115-60-1	8424010250	N/A	301639
300203	Franklin					8413810400 no longer available		
300205	GE	1/4	1725	TF-TO	115-60-1	5KH39QN9105X	48	304804
300218	GE	1/4	1725	OP-TO-PSC	115-60-1	KCP37KN143	48	311338
300233	GE	1	1725/1140	OP	208/230-60-3	K48UG882		300923
300239	ME	1/3	1140	OP-PSC	115-60-1	56A11D33	56	301643
300257	LE	1/4	1725	OP	208-230/460-60-3	100027	56	301336
300275	CE	7 1/2	1725	OP-EE	208-230/460-60-3	E300	213T	302088
300333	ME	1/2	1725	OP-TO	115-60-1	P48517D2059	48	304853
300450	Franklin	1/25	3 SP ***	OP	115-60-1	8264110420	N/A	302529*
300452	Franklin	1/8	860	OP - TO - PSC	115-60-1	8264110430	N/A	300453
300454	Franklin	1/8	3 SP ***	OP - TO - PSC	115-60-1	8743810240	N/A	308318
300455	Fasco	1/8	3 SP ***	OP - TO - PSC	115-60-1	71240360	N/A	308318
300456	Franklin	1/30	3 SP ***	OP	115-60-1	8263710160	N/A	300457
300458	Franklin		1070	OP	115-60-1	8715410140	N/A	310225
300459	Fasco	1/15	3 SP ***	OP - TO - PSC	115-60-1	71086194	N/A	301638
300460	Univ. E	1/15	3 SP ***	OP - TO - PSC	115-60-1	CA2G174N	N/A	301638
300461	Univ. E	1/20	3 SP ***	OP	115-60-1	CA2G173N	N/A	301639
300524	GE	1/4	1725	TF-TO	115-60-1	5KH32GN428	48	304804
300752	Franklin		1050	OP	115-60-1	873610130	N/A	302021
300756	Franklin		1050	OP	115-60-1	8715810300	N/A	301816
300758	Franklin		1725	OP-TO-CS	115/230-60-1	8264110460	48	301462
300765	GE	1/4	1725	OP	208-230/460-60-3	K38GN2	48	301336
300908	ME	1 1/2	1725	OP-CS	115-208/230-60-1	56C17D5316	56	309100
300917	ME		1050	OP	115-60-1	48A1101073	N/A	302021
300960	ME	1	1725	OP	208-230/460-60-3	143TTDR5326	143T	301879
300963	ME	1	1725	TF-EE	208-230/460-60-3	14377FR5326	143T	304888
300965	ME	1 1/2	1725	OP	200/208-60-3	145TTDR5327	143T	301047
300967	ME	1 1/2	1725	TF-EE	208-230/460-60-3	145TTFR5326	145T	If 230/460 use 303004
300968	ME	2	1725	OP	208-230/460-60-3	145TTDR5331	145T	311508

*Requires new bolt circles to be drilled.

Obsolete Greenheck Part Numbers and their Replacement

GFC Part #	Motor Mfg.	HP	RPM	Description	Voltage-Cycle Phase	Motor Mfg. Part #	Frame Size	Replacement Motor Part #
300969	ME	2	1725	OP	200-60-3	145TTDR5332	145T	301049
300971	ME	2	1725	TF	208-230/460-60-3	145TTFR5327	145T	302047
300979	ME	1 1/2	1725	OP-TO-PE	208-230/460-60-3	145TTDR5329	145T	302045
300987	ME	1/3	1725	OP	208-230/460-60-3	56T17D5300	56	308213
300989	ME	1/2	1725	EX-CS	115-208/230-60-1	56T17D5301		308214
300992	ME	3/4	1725	OP	208-230/460-60-3	56T17D304	56	308215
301012	ME	1	1725	OP	208-230/460-60-3	56T17D5307	56	308216
301032	ME	1/2	1725	OP	277-60-1	184TTDR4026	184T	304858
301050	ME	3	1725	OP-EE	230/460-60-3	182TTDR4026	182T	302053
301051	ME	3	1725	OP-EE	200/208-60-3	182TTDR4027	182T	302053
301052	ME	5	1725	OPEE	460/3	184TTDR4026	184T	302059
301082	ME	1	1725	OP	200-208	56T17D5308	N/A	308216
301133	MC					A0508B2171	N/A	301812
301134	MC					A0408B2173	N/A	301814
301135	MC	1/4	1550	OP	115-60-1	A0508B2172	N/A	301813
301136	Fasco		1550	OP	115-60-1	71086641	N/A	301839
301139	Fasco		1000	OP	115-60-1	71512587	N/A	301817
301140	Fasco		1050	OP	115-60-1	71513567	N/A	301833
301145	Fasco		1070	OP	115-60-1	71513566	N/A	310225
301146	Fasco		1095	OP	115-60-1	71513487	N/A	309132
301151	Fasco		1600	OP	115-60-1	71742661	N/A	309133
301162	Franklin		1600	OP	115-60-1	8733810010	N/A	309133
301163	Franklin		1095	OP	115-60-1	8745610010	N/A	300016
301186	GE	1/4	1725	OP	115-60-1	KH39QN9090	48	300016
301187	GE	1/4	1725	OP-TO	115-60-1	5KH32FN3083X	48	300016
301228	LE	1/2	1725	EX-TO	200-60-3	111929	56	N/A
301253	ME	1/2	1725	TF	240-50-1	56C14F55	N/A	303175 (export)
301258	ME	1/4	1725	OP-TO-PSC	115-60-1	48A170185	48	311338
301350	MC		1050	OP	115-60-1	A0524B2282	N/A	301816
301377	MC		1000	OP	115-60-1	A0516B2317	N/A	301817
301378	GE	1/4	1725	OP	115-60-1	5KH39QN010	48	300016
301395	ME	1/4	860	TF	115/230-60-1	56S8F4	56	301640
301416	GE	1/2	1725	OP-TO-CS	115-208/230-60-1	5KC49GN0022AX	56	300029
301417	GE	3/4	1725	OP-TO-CS	115-208/230-60-1	KC46JN0023	56	311589
301652	Fasco	1/8	3 SP**	OP-TO-PSC	115-60-1	71241411	N/A	308318
301729	ME	1/4	1725	OP	115-60-1	48S17D1218	48	300016
301763	ME	1/4	1726	TF-TO	115/208/230	56C17F5301	56	309108
301778	MC	1/4	1725	OP	115-60-1	48A170286	48	311338
301840	Fasco		1600	OP	115-60-1	71742829	N/A	309133
301849	MC	1/4	1050	OP	115-60-1	D0508B2555	N/A	301813
301850	MC					D0408B2556	N/A	301814
301852	MC		1050	OP	115-60-1	D0524B2558	N/A	301816
301853	MC		1000	OP	115-60-1	D0516B2559	N/A	301817
301866	ME	1	1725	OP	208-230/460-60-3	56T17D2113	56	308216
301893		1 1/2	1725	OP	115/208/230/1	KCR49SN0068	56	303677
301902	ME	1/3	1725	EX-TO-CS	115/230-60-1	56C17G5300	56	302983
301903	ME	1/2	1725	EX-CS	115-208/230-60-1	56C17G5301	56	302984
301904	ME	3/4	1725	EX-CS	115/230-60-1	56C17G5302	56	304218
301905	ME	1	1725	EX	208-230/460-60-3	56T17G5305	56	304303
301907	ME	1/2	1725	EX-TO	208-230/460-60-3	56T17G5302	56	304225
301971	AS	1/4	1725	OP	115-60-1	48SB57B74	48	300016
302191	ME	1/4	1725	TF-TO	115-60-1	48S17F7	48	304804

Obsolete Greenheck Part Numbers and their Replacement

GFC Part #	Motor Mfg.	HP	RPM	Description	Voltage-Cycle Phase	Motor Mfg. Part #	Frame Size	Replacement Motor Part #
302438	AS	1/2	1725	OP-TO	208/230/1	C56A76B74	56	304853
302447	Mag		950	OP	115-60-1	JA2M439N	N/A	312499
302474	Mag		1400	OP	115-60-1	JA2M437N	N/A	311559
302477	Mag	SP	1050	OP	115-60-1	JE2H054N	N/A	304843
302478	Mag	SP	1300	OP	115-60-1	JE2H053N	N/A	304842
302479	Fasco		1100	OP	115-60-1	2868-505-138	N/A	303039
302494	Mag		1100	OP	115-60-1	SA2N264N	N/A	304983
302502	ME	3	1725	OP	208-230/460-60-3	182TTDR5326	182T	302054
302529	MC	1/25	3 SP *	OP	115-60-1	F0412B2690	N/A	302529
302530	MC	1/20	3 SP *	OP	115-60-1	D0810B2691	N/A	302530
302547	AO Smith	1	1100	TF	208/230-460-3	F56A13B74	N/A	303875
302604	ME	3	1725	TF	208-230/460-60-3	182TFR5326	182T	302113
302608	CE	3	1725	OP-EE	208-230/460-60-3	R206	182T	302053
302790	ME	7 1/2	1725	OP-EE	208/230/460-60-3	213TTDW7026		302088
302794	ME	10	1725	OP	208-230/460-60-3	215TTDW7026	215T	302067
302827	Fasco		1100	OP	115	71730349	N/A	303039
302905	ME	3	1725	OP-EE	230/460-60-3	182TTDB4026	182T	302054
302906	ME	5	1725	OP-EE	208-230/460-60-3	184TTDB4026	184T	302059
303041	MC			OP	115-60-1	F0408B2791	N/A	312499
303181	AO Smith	1 1/2	1725	OP-CS	115-208/230-60-1	CE56 C689	56	303677
303322	ME	1	1725	TF-EE	200/208-60-3	143TTFR4028	143T	304888
303324	ME	2	1725	TF-EE	200/208-60-3	145TTDR4032	145T	311508
303411	CE	2	1725	OP	208-230-460/60-3	H181		302982 *
303723	FA	1/4	1725	OP-TO	115-60-1	71250368	48	309153
303859	Fasco	1/3	1725	OP	115-60-1	71250369	48	311587
304049	Fasco	1/2	1725	OP	115-60-1	71250373	48	304272
304070	ME	1/3	1725	OP	115-208-230/60/1	56C17D5680	56	306626
304075	ME	1/3	1725	TF	115-208-230/60/1	56C17F5920	56	304075
304197	AS	1/4	1725	OP	115-208-230/1	HF2K034	48	304276
304198	AO Smith	3/4	1725	OP	115/208/230/1	HF2K035N	48	304277
304220	FASIO	1/2	1725	OP	115-60-1	71250376	48	304853
304222	Fasco	1/6	1725	OP-TO	115-60-1	71250379	48	304287
304252	ME	1/2	1725	TF	208-230/460-60-3	57T17T5319	56	302653
304266	ME	5	1725	EX	208/230/460-60-3	184TTGS4026	184T	311400
304271	ME	1/4	1725	OP	115-60-1	48S17D1281	48	309153
304305	ME	1/4	1725	EX-TO	115-208/230-60-1	56C17E5314	56	305319
304338	Fasco	SP	1100	OP	115-60-1	71902341	N/A	304983
304663	ME	7 1/2	1725	OP-EE	208/230/460-60-3	213TTDW4067	213T	No Replacement
304751	ME	1/4	1725	OP	115-60-1	48A170286	48	311338
304808	ME	15	1725	OP	208-230/460-60-3	254TTDC4026	254T	302073
304851	RE	1/3	1725	OP	115-60-1	C56S3024	56	306626
304946	ME	3	1725	OP-EE	208/230/460-60-3	182TTDR4026	182T	302054
304947	ME	5	1725	OP-EE	208/230/460-60-3	182TTDR4026	184T	302059
305024	ME	1/4	1725	EX-TO	115-208-230/1	56C17G5315MOD	56	305319
300759RK	Franklin		3 SP ***	TF	115	8264310350	N/A	301462
300761RK	Fasco		3 SP ***	TF	115	71896247	N/A	301889
300762RK	Franklin		3 SP ***	TF	115	8743810370	N/A	311742
300901RK	ME		3 SP ***	TF	115	48A110251	N/A	311742

Notes:

* if manufactured before 01/03/2003

Motor Shock Mounts

Model Size	Part #	Description
SP/CSP 108, 115, 117, 125, 150, 152 SP/CSP 8, 15, 17, 25, 27 CX/CE 5, 6, 7, 7.5, 8, 9,	869365	DUR 40
C/GW/CW 100, 120, 130, 1400, 150, 160, 170, 180 For units built after January 1, 1990	370058 & 450040	Grommet 7/8 - 3/8 Sleeve
SP/CSP 210, 216, 218 (3 per unit) SP 7, 9, 12, 224, 226, 228 (4 per unit)	370108 & 370109 455433	Bushing B-434 Blue Ring B-434 Blue Sleeve
G/GW/LD/LDP 60, 65, 70, 80, 85, 90, 95	370084	DUR 60 Black
G/GW 100, 120, 130, 140, 150, 160, 170, 170, 180 For G/GW units built before January 1, 1990 CUE All sizes SQ/DSQ 60, 65, 70, 75, 80, 85, 90, 95 CX/CE 10, 12, 13, 14, 16, 18 SQD 6, 7.5, 9 AI 8, 12, 14, 16, 18, 20 LD/LDP 100, 120	370058 & 450040	Grommet 7/8 - 5/16 Sleeve
SP/CSP 155, 158 CSP 252, 255, 258 SP/CSP 50, 55 SP 255, 258	370108 & 370109 455433	Bushing B-434 Blue Ring B-434 Blue Sleeve
SP 127 (only one per unit)	869365	Dur 40
SDE 8, 10, 12, 14, 16, 18, 20 SE 1, 8, 10, 12, 14, 16, 18, 20, 24	370006 & 450041	Grommet 1 1/4 x 5/16 Sleeve
GB 70, 80, 90, 100, 120, 130, (3) Qty. GB 120, 130, (4)Qty (3/4 HP motor & greater GB 140, 160, 180, 200, 220, 240 GB 7, 8, 9, 10, 14, 18, 21, 24 RSF 9, 10, 12, 15, 18 MSU 15, 18 CBE 10, 14, 18	370002 *	1/4"-20 DBL Stud
CUBE 95, 100, 120, 130, 140 (hp), 160(hp), 180 (hp) 200 (hp), 220 (hp), 240(hp) CUBE 10, 14, 18, 21	370061	1/4"-20 DBL Stud 1/2" Studs (for use with heat baffle)
CUBE 180, (hp), 200(hp), 220(hp), 240 (hp) (3 hp and greater) CUBE 300 (hp), 360(hp), 420 (hp), 480(hp) GB 120, 130, 140, 160, 180, 200, 220, 240 (3/4 hp and greater) GB 30 CUBE 24 (hp) GWB 14, 18, 21, 24 GWB/CWB 98, 100, 120, 130, 140	370041	5/16 DBL, Stud R-25 (Used on special applications for higher horsepower units
CUBE 300 (hp), 360(hp), 420 (hp), 480(hp) (3 hp and greater) GB 260, 300, 330, 360, 420, 480 Note: GB 540 uses (2) qty. 370001 and (2) qty. 370029 per unit. CUBE-30-LMDG-QD GB-30-LMDX-QD GB-36-LMDG-QD	370029	Red R-2 Used on special applicatins for higher horse power units.
GB 30, 36, 42, 48, 54 CUBE 30, 36, 42, 48 CBE 30, 36, 48 LBE 30, 36, 48, 54 W4 30, 36, 48 (3) qty RCX 30, 36, 48 (3) qty UCBE 30, 36, 48	370001 *	Black R-2
CBH, CBE, UCBE, CE, 24 MSU 15, 18 W4 10, 14, 18, 24 (3)qty NYB 10, 14, 18, 24 NYD 7.5, 9, 10, 12, 13, 14, 16, 18 RCX 10, 14, 18, 24 (3) qty	370000 *	Green R-1

NOTES:

* Requires qty of (4) shock mounts per part number unless other quantities are specified.

No shock mounts required for LBE 10, 14, 18, 24 | SQD 10, 12, 13, 14, 16, 18 | SQ 70, 75, 80, 85, 90, 95
SP 160, 162, 165 | CSP 162, 165, 170, 175.
(HP) after the size indicates high pressure unit.

Replacement Touch-Up Paint

Special Freight Considerations

* Touch-up paint is considered a hazardous material and cannot ship via air freight.

Paint shipping outside the continental United States may take 2-3 weeks by ocean freight.

* Requests for touch-up paint to Canada, Hawaii and Alaska, please go to the Sherwin Williams website: www.Sherwin-williams.com store locator to find a local store. If re-order is for a field problem. We need to create a Field Problem and provide FP# to the Rep/Customer. Rep/Customer will then provide that information (stating it needs to be on the invoice to Greenheck) to the local paint vendor where they are placing their paint order.

Aerosol Paint (Standard Colors)

Following colors are available to order in iParts

PART #	DESCRIPTION	COLOR #	ADJ LIST
			PRICE
HAZ2596	PNT,LQD,ACRYENML,RAL7023 CONCRETE GRAY,PRIMER, CAN	RAL7023	\$ 119
*HAZ1124	PNT,LQD,ACRYENML,040 GRAY,PRIMER, CAN	040	\$ 119
HAZ1230-32	PNT,LQD,ACRYENML,032 MARBLE,CAN	032	\$ 119
HAZ1230-33	PNT,LQD,ACRYENML,033 DESERT SAND,CAN	033	\$ 119
HAZ1230-34	PNT,LQD,ACRYENML,034 BEECHNUT,CAN	034	\$ 119
HAZ1230-35	PNT,LQD,ACRYENML,035 TAUPE,CAN	035	\$ 119
HAZ1230-36	PNT,LQD,ACRYENML,036 MED BRONZE,CAN	036	\$ 119
HAZ1230-38	PNT,LQD,ACRYENML,038 HRZN BLUE,CAN	038	\$ 119
HAZ1230-39	PNT,LQD,ACRYENML,039 COLONIAL BLUE,CAN	039	\$ 119
*HAZ1230-41	PNT,LQD,ACRYENML,041 DARK GRAY, PRIMER, CAN	041	\$ 362
HAZ1230-42	PNT,LQD,ACRYENML,042 CHARCOAL,CAN	042	\$ 119
HAZ1230-43	PNT,LQD,ACRYENML,043 MACHINE TOOL,CAN	043	\$ 119
HAZ1308	PNT,LQD,ACRYENML,GFC LIGHT TAN,CAN	- - -	\$ 119
HAZ2101	PNT,LQD,ACRYENML,101 IVY,CAN	GF101	\$ 119
HAZ2102	PNT,LQD,ACRYENML,102 BONE WHITE,CAN	GF102	\$ 119
HAZ2103	PNT,LQD,ACRYENML,103 STONE GRAY,CAN	GF103	\$ 119
HAZ2104	PNT,LQD,ACRYENML,104 SMOKE,CAN	GF104	\$ 119
HAZ2105	PNT,LQD,ACRYENML,105 HAMPTON BROWN,CAN	GF105	\$ 119
HAZ2106	PNT,LQD,ACRYENML,106 CAPRI BLUE,CAN	GF106	\$ 119
HAZ2107	PNT,LQD,ACRYENML,107 HERRING BONE,CAN	GF107	\$ 119
HAZ2108	PNT,LQD,ACRYENML,108 CLASSIC BRONZE,CAN	GF108	\$ 119
HAZ2109	PNT,LQD,ACRYENML,109 MILITARY BLUE,CAN	GF109	\$ 119
HAZ2111	PNT,LQD,ACRYENML,110 CAMBRIDGE WHITE,CAN	GF110	\$ 119
HAZ2112	PNT,LQD,ACRYENML,111 BRANDY WINE,CAN	GF111	\$ 119
HAZ2113	PNT,LQD,ACRYENML,112 SANDSTONE,CAN	GF112	\$ 119
HAZ2114	PNT,LQD,ACRYENML,113 SPARTAN BRONZE,CAN	GF113	\$ 119
HAZ2115	PNT,LQD,ACRYENML,114 PATINA GREEN,CAN	GF114	\$ 119
HAZ2116	PNT,LQD,ACRYENML,115 PORTLAND STONE,CAN	GF115	\$ 119
HAZ2117	PNT,LQD,ACRYENML,116 PUEBLO TAN,CAN	GF116	\$ 119
HAZ2118	PNT,LQD,ACRYENML,117 FOREST GREEN,CAN	GF117	\$ 119

Aerosol Paint (Standard Colors)

Following colors are available to order in iParts

(Cont'd)

HAZ2119	PNT,LQD,ACRYENML,118 SIERRA TAN,CAN	GF118	\$ 119
HAZ2120	PNT,LQD,ACRYENML,119 WEDGEWOOD BLUE,CAN	GF119	\$ 119
HAZ2121	PNT,LQD,ACRYENML,120 ASCOT WHITE,CAN	GF120	\$ 119
HAZ2122	PNT,LQD,ACRYENML,121 CORONADO RED,CAN	GF121	\$ 119
HAZ2124	PNT,LQD,ACRYENML,044 FLAT BLACK,CAN	044	\$ 119
HAZ2125	PNT,LQD,ACRYENML,045 GLOSS BLACK,CAN	045	\$ 119
HAZ2026	PNT,LQD,ENML,031 IVORY,CAN	031	\$ 119
HAZ2296	PNT,LQD,ENML,GRAY PRIMER,CAN	---	\$ 119
HAZ2513	PNT,LQD,KYNAR,MCD GRAY PRIMER,CAN^	---	\$ 119
HAZ2514	PNT,LQD,KYNAR,MCD CLEAR ANODIZED,CAN^	---	\$ 119

^ MCD - Abbreviation for McDonalds

*As standard offering this will convert to HAZ2596 for newly built units ordered from CAPS 4.14

Aerosol Paint (Match/Custom Colors)

*Enter a iParts Quote - Ref iParts User Guide

*Information requires Serial/Production Order No.

PART #	DESCRIPTION	COLOR #	ADJ LIST PRICE
HAZ2262	PNT,LQD,ACRYENML,CUSTOM COLOR MATCH,CAN	---	Quote
HAZ2264	PNT,LQD,ACRYENML,CUSTOM COLOR MATCH,GAL	---	Quote

Field Repair Kits - (Standard Colors)

Following colors are available to order in iParts

PART #	DESCRIPTION	COLOR #	ADJ LIST
			PRICE
HAZ2045	PNT FIELD REPAIR KIT,029 SPARTAN WHITE	029	\$ 1,598
HAZ2047	PNT FIELD REPAIR KIT,042 CHARCOAL	042	\$ 1,598
HAZ2048	PNT FIELD REPAIR KIT,043 MACHINE TOOL	043	\$ 1,598
HAZ2049	PNT FIELD REPAIR KIT,033 DESERT SAND	033	\$ 1,598
HAZ2050	PNT FIELD REPAIR KIT,032 MARBLE	033	\$ 1,598
HAZ2051	PNT FIELD REPAIR KIT,036 MEDIUM BRONZE	036	\$ 1,598
HAZ2052	PNT FIELD REPAIR KIT,035 TAUPE	035	\$ 1,598
HAZ2053	PNT FIELD REPAIR KIT,031 IVORY	031	\$ 1,143
HAZ2054	PNT FIELD REPAIR KIT,GFC LIMESTONE	Limestone	\$ 1,062
*HAZ2203	PNT FIELD REPAIR KIT,041 DARK GRAY	041	\$ 3,397
HAZ2597	PNT FIELD REPAIR KIT,RAL7023 CONCRETE GRAY	RAL7023	\$ 1,598
HAZ2632	PNT, FIELD REPAIR KIT, 040 GRAY	040	\$ 1,598

*As standard offering this will convert to HAZ2597 for newly built units ordered from CAPS 4.14

Field Repair Kits - (Match/Custom Colors)

*Enter a iParts Quote - Ref iParts User Guide

* Information requires Serial/Production Order No.

PART #	DESCRIPTION	COLOR #	ADJ LIST
			PRICE
HAZ2038	PNT FIELD REPAIR KIT,CUSTOM COLOR MATCH	---	Quote

Contents of Field Repair Kit
1 Zinc Clad Aerosol Can 1 pint (Recoatable epoxy primer gray) with 1 pint (Recoatable epoxy primer catalyst) 1 quart - H.S. Polyurethane w/ 8 oz. 1 - Scotch-Brite Scratch Pad 2 - 1.5" Wide Paint Brushes 4 - Pint-sized empty size can for mixing 1 - Quart-size empty size can for mixing Zinc Repair Instructions MSDS Sheets

*NOTE: Items shown below apply to Standard and Custom colors

Minimum Quantity Required

* Enter a iParts Quote - Ref iParts User Guide

PART #	DESCRIPTION	COLOR #	ADJ LIST
			PRICE
HAZ2624	PNT,LQD,POL,RAL7023 CONCRETE GRAY,PEN^	RAL7023	Quote
*HAZ2299	PNT,LQD,POL,040 GRAY,PEN^	040	Quote
HAZ2336	PNT,LQD,POL,033 DESERT SAND,PEN^	033	Quote

^ 100 pen minimum order

*As standard offering this will convert to HAZ2624 for newly built units ordered from CAPS 4.14

PART #	DESCRIPTION	COLOR #	ADJ LIST
			PRICE
HAZ2523	PNT,LQD,ACRYENML,RAL6007 MOSS GREEN,CAN^	RAL6007	Quote

^Used only for OEM Turf Breeze products

^ 12-can minimum order

If you have questions about this chart or information shown, contact Brenda Zastrow @ 2307 or Dawn Genrich @ x2249.