



Model: XG-H4002SS-1 Supply - Single Deflection Adjustable Horizontal Blades - Flush Surface Mount

XG-H4002SS-1 - Flush Surface Mount

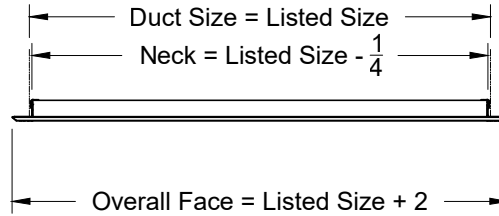


End View

Neck Size		
	Min	Max
Width	4	48
Depth	4	48

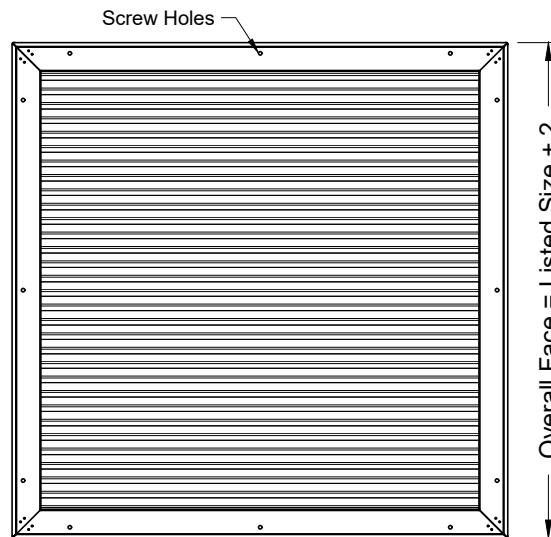

Face View

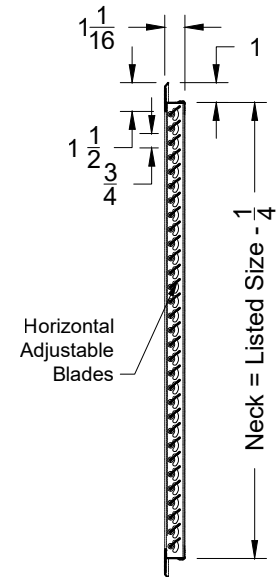


Side View

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish: 23 Satin Polish	XG-OBDS - S.S. Opposed Blade Damper XG-PFSS - S.S. Plaster Frame XG-LIPFSS - S.S. Lay-In Plaster Frame	IS-SS - Insect Screen NSH - No Screw Holes 316SS - 316 Stainless Steel	<ul style="list-style-type: none"> 304 Stainless Steel Construction (Standard) Only Available in Listed Sizes
All Dimensions $\pm 1/16"$			


Model: XG-H4002SS-6 Supply - Single Deflection Adjustable Horizontal Blades - Lay In T-Bar

XG-H4002SS-6 - T-Bar Lay-In

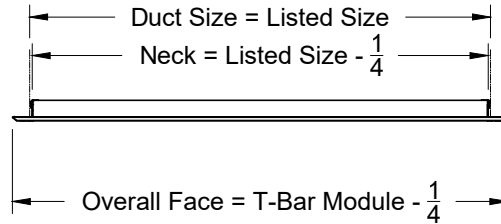


End View

Neck Size		
	Min	Max
Width	4	46
Depth	4	22

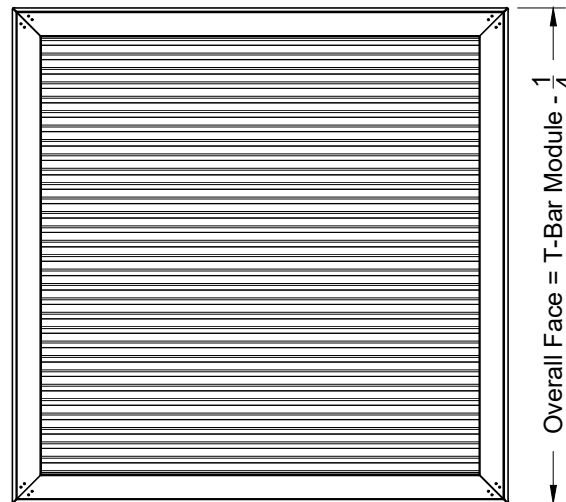

Face View

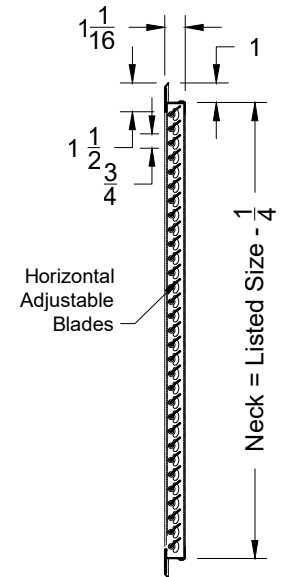

Side View


Listed Sizes
12 x 12
12 x 24
24 x 24
48 x 24

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish: 23 Satin Polish	XG-OBDSS - S.S. Opposed Blade Damper XG-PFSS - S.S. Plaster Frame XG-LIPFSS - S.S. Lay-In Plaster Frame	IS-SS - Insect Screen 316SS - 316 Stainless Steel	<ul style="list-style-type: none"> 304 Stainless Steel Construction (Standard) Only Available in Listed Sizes



All Dimensions $\pm 1/16"$

Model: XG-V4002SS-1 Supply - Single Deflection Adjustable Vertical Blades - Flush Surface Mount

XG-V4002SS-1 - Flush Surface Mount

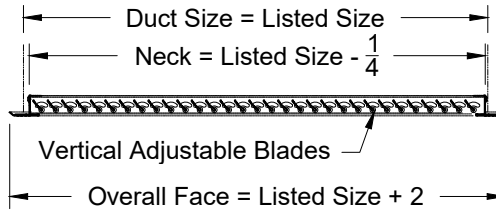


Neck Size		
	Min	Max
Width	4	48
Depth	4	48

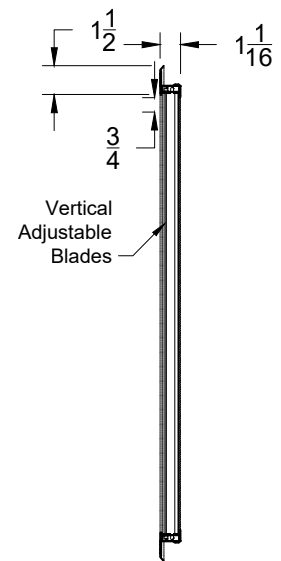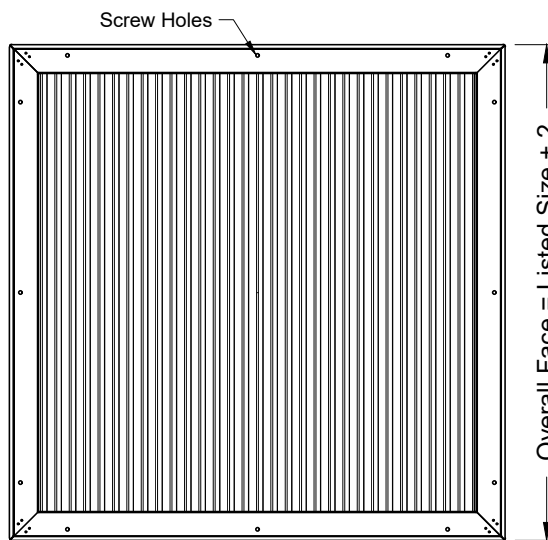

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish: 23 Satin Polish	XG-OBDS - S.S. Opposed Blade Damper XG-PFSS - S.S. Plaster Frame XG-LIPFSS - S.S. Lay-In Plaster Frame	IS-SS - Insect Screen NSH - No Screw Holes 316SS - 316 Stainless Steel	<ul style="list-style-type: none"> 304 Stainless Steel Construction (Standard) Only Available in Listed Sizes
All Dimensions ±1/16"			


Model: XG-V4002SS-6 Supply - Single Deflection Adjustable Vertical Blades - Lay In T-Bar

XG-V4002SS-6 - T-Bar Lay-In

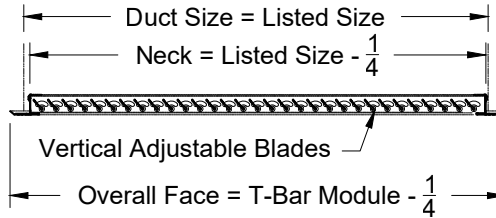


End View

Neck Size		
	Min	Max
Width	4	46
Depth	4	22

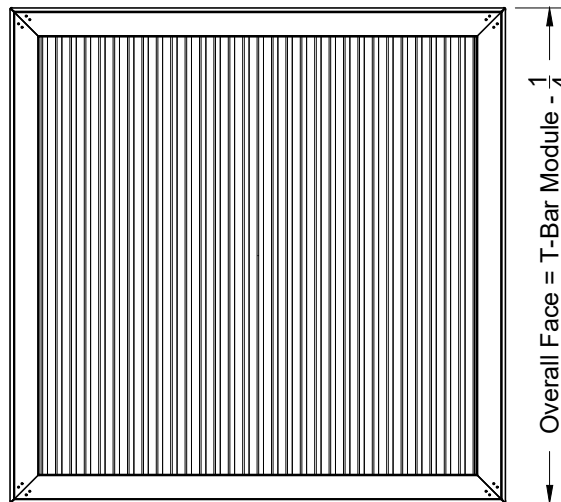

Face View

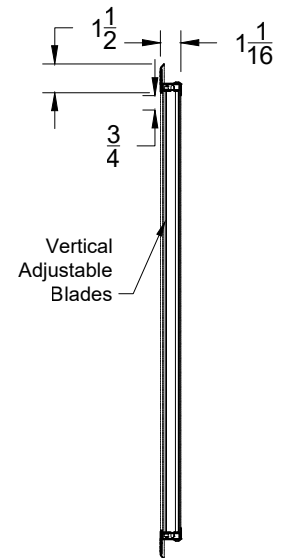

Side View

Listed Sizes
12 x 12
12 x 24
24 x 24
48 x 24

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish: 23 Satin Polish	XG-OBDSS - S.S. Opposed Blade Damper XG-PFSS - S.S. Plaster Frame XG-LIPFSS - S.S. Lay-In Plaster Frame	IS-SS - Insect Screen 316SS - 316 Stainless Steel	<ul style="list-style-type: none"> 304 Stainless Steel Construction (Standard) Only Available in Listed Sizes

All Dimensions $\pm 1/16"$