

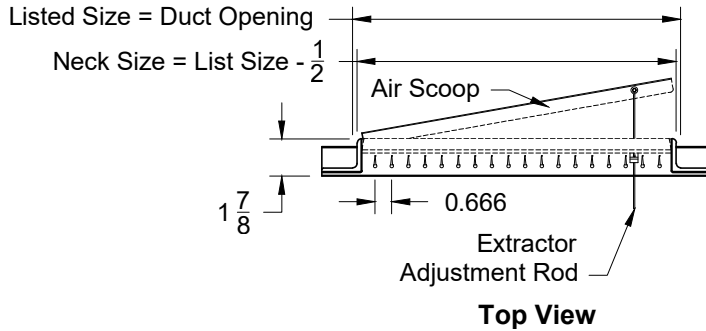
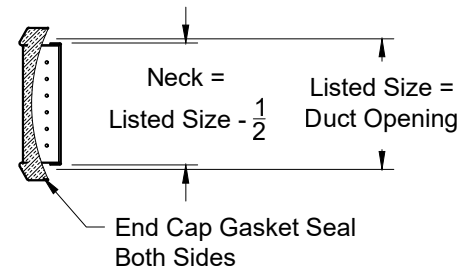


Model: XG-4004P-1 Double Deflection - Universal Frame - Vertical Front Blades - Flush Mount

XG-4004P-1 - Flush Mount

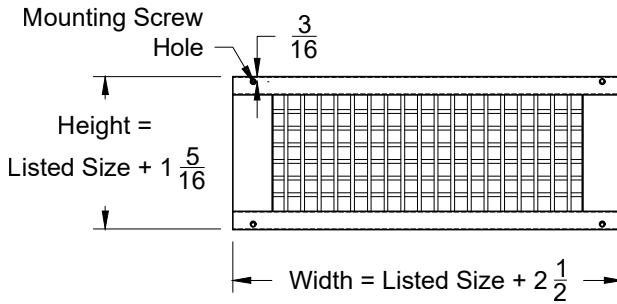

Isometric View

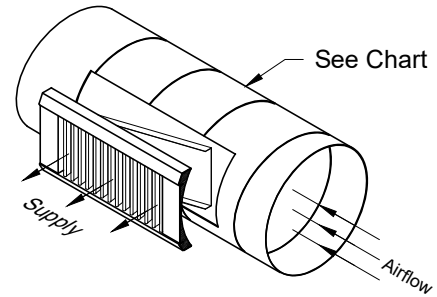

Height	Width														
	10"	12"	14"	16"	18"	20"	24"	30"	36"	38"	40"	42"	44"	46"	48"
	Minimum / Maximum Duct Diameter														
3"	6/24	6/24	6/24	6/24	6/24	6/24	6/24	6/24	6/24	6/24	6/24	6/24	6/24	6/24	6/24
4"	8/24	8/24	8/24	8/24	8/24	8/24	8/24	8/24	8/24	8/24	8/24	8/24	8/24	8/24	8/24
6"	12/24	12/24	12/24	12/24	12/24	12/24	12/24	12/24	12/24	12/24	12/24	12/24	12/24	12/24	12/24
8"	N/A	N/A	20/36	20/36	20/36	20/36	20/36	20/36	20/36	20/36	20/36	20/36	20/36	20/36	20/36
10"	N/A	N/A	N/A	N/A	30/48	30/48	30/48	30/48	30/48	30/48	30/48	30/48	30/48	30/48	30/48
12"	N/A	N/A	N/A	N/A	42/48	42/48	42/48	42/48	42/48	42/48	42/48	42/48	42/48	42/48	42/48

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White		AS - Air Scoop NAS - No Air Scoop	<ul style="list-style-type: none"> • Air Scoop includes wire handle for operation • Ends are supplied with foam gasket to seal around duct • Units are surface mount, provided with screw template to mount into duct • Available in Listed Sizes Only

All Dimensions ±1/16"