


Model: XG-5500SS-1 Louvered Face Directional Ceiling Diffuser - Flush Surface Mount


XG-5500SS-1 - Flush Surface Mount

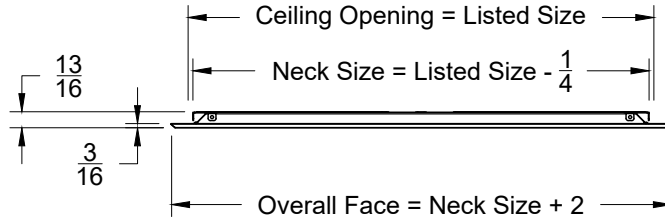


End View

Neck Size		
	Min	Max
Width	6	48
Depth	6	48


Louver Face Number of Blades Vary by Size

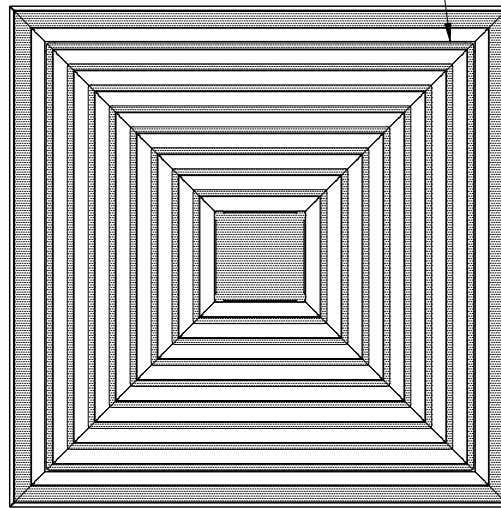

Face View

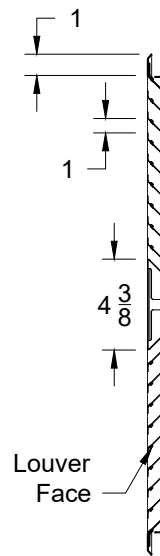

Side View

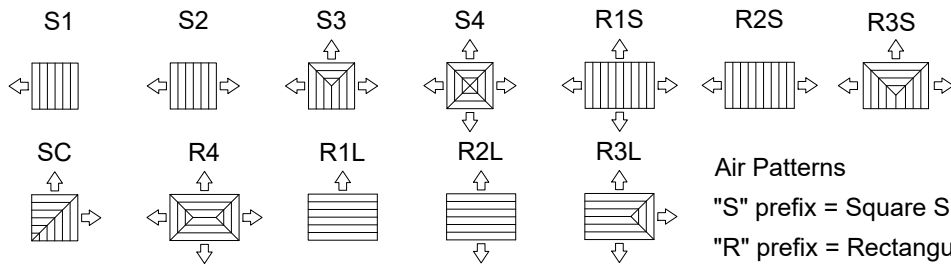


1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White 24 Mill	XG-OBDSS - S.S. Opposed Blade Damper XG-LIPFSS - S.S. Lay In Plaster Frame	316SS - 316 Stainless Steel SH - Screw Holes	<ul style="list-style-type: none"> 304 Stainless Steel Construction (Standard) Only Available in Listed Sizes

All Dimensions ±1/16"

Model: XG-5500SS-6 Louvered Face Directional Ceiling Diffuser - Lay In T-Bar


XG-5500SS-6 - T-Bar Lay-In

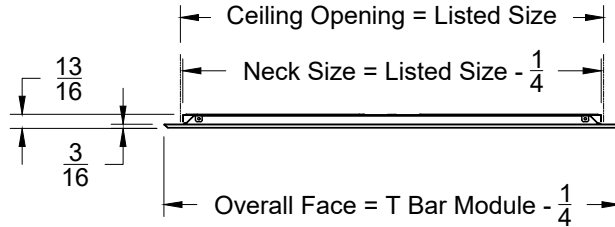


End View

Listed Sizes	Neck Size	
	Min	Max
12 x 12	6	18
12 x 24	6	18
24 x 24	6	18


Louver Face Number of Blades Vary by Size

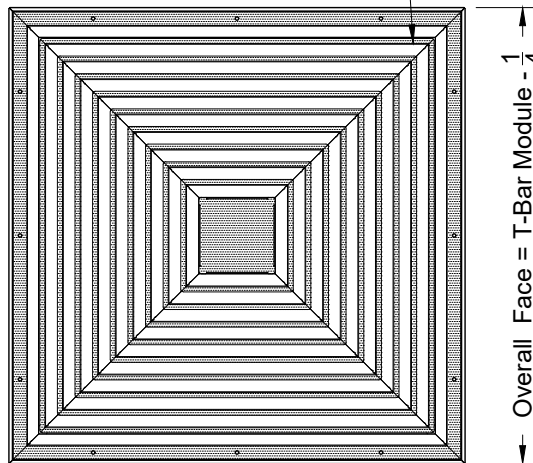

Face View

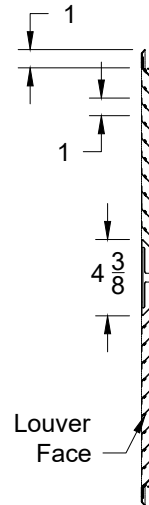

Side View

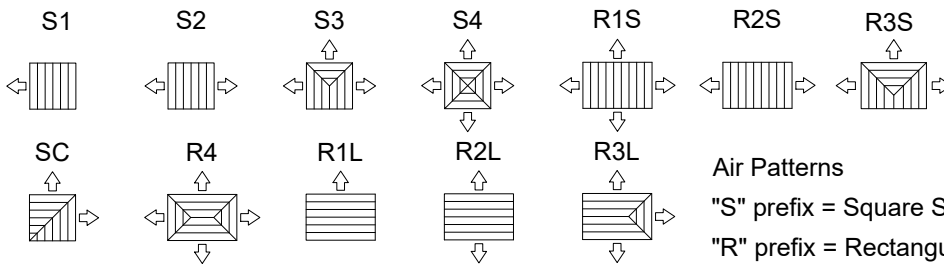

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White 24 Mill	XG-OBDSS - S.S. Opposed Blade Damper XG-LIPFSS - S.S. Lay In Plaster Frame	316SS - 316 Stainless Steel SH - Screw Holes	<ul style="list-style-type: none"> 304 Stainless Steel Construction (Standard) Only Available in Listed Sizes

All Dimensions ±1/16"