



Model: XG-DGDFSS Exhaust and Return - Door Transfer Grille - Double Flange Frame - Surface Mount

### XG-DGDFSS - Surface Mount

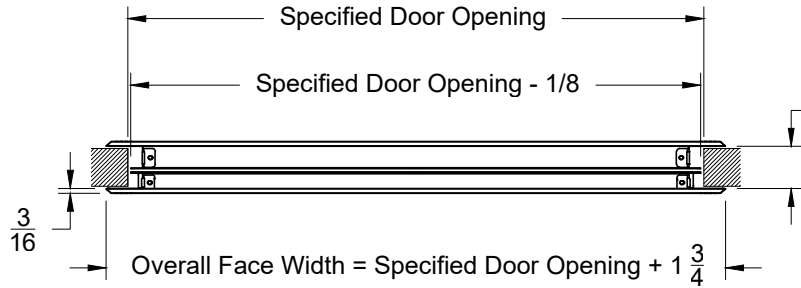

Face View

Neck Size	
	Min Max
Width	4 48
Depth	4 48

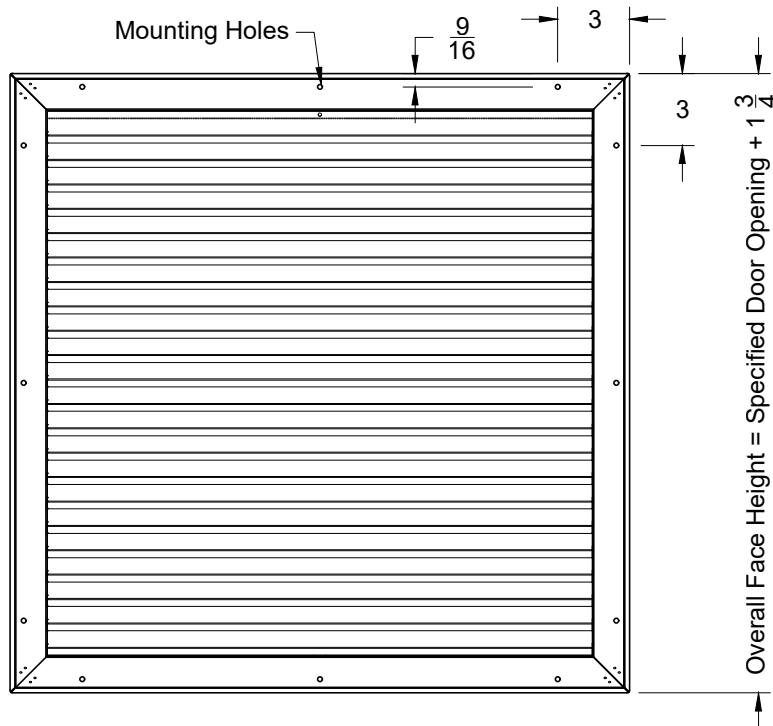

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White 24 Mill		316SS - 316 Stainless Steel	<ul style="list-style-type: none"> <li>304 Stainless Steel Construction (Standard)</li> <li>Only Available in Listed Sizes</li> </ul>

All Dimensions ±1/16"