
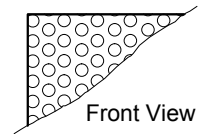




## Perforated Screen - Non Ducted - Return Aluminum or Steel

- Models: **XG-PRTB-6** Aluminum - Lay in T-Bar  
**XG-PRTB-8** Aluminum - Tegular T-Bar  
**XG-PRTB-9** Aluminum - Donn Finline (USG) Ceiling Grid.  
**XG-SPRTB-6** Steel - Lay in T-Bar  
**XG-SPRTB-8** Steel - Tegular T-Bar  
**XG-SPRTB-9** Steel - Donn Finline (USG) Ceiling Grid

### Models: XG-PRTB-6 and XG-SPRTB-6 ( Lay in T-Bar )


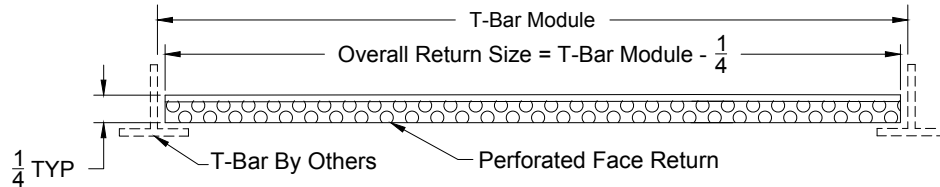


### Models: XG-PRTB-8 and XG-SPRTB-8 ( Tegular T-Bar )

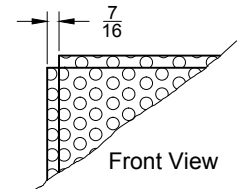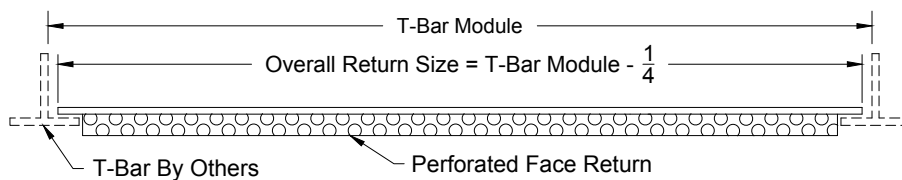

Perforated Face Return  
3/16 Diameter Holes ON  
1/4 Staggered Centers

### Models: XG-PRTB-9 and XG-SPRTB-9 ( Donn Finline Ceiling Grid )

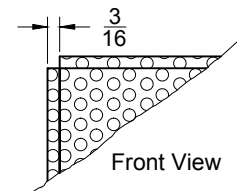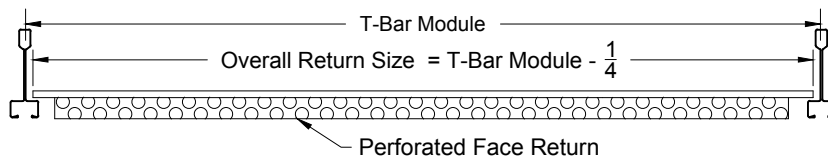

Available Sizes (Width x Height)

Perimeter Style	T-Bar Spacing	Actual Face Size		
		- 6	- 8	- 9
- 6	12 x 12	11 3/4 x 11 3/4		
- 6, - 8, - 9	24 x 12	23 3/4 x 11 3/4	22 7/8 x 10 7/8	23 3/8 x 11 3/8
- 6, - 8, - 9	24 x 24	23 3/4 x 23 3/4	22 7/8 x 22 7/8	23 3/8 x 23 3/8
- 6	36 x 24	35 3/4 x 23 3/4		
- 6	48 x 12	47 3/4 x 11 3/4		
- 6	48 x 24	47 3/4 x 23 3/4		

Notes:  (check if provided)

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
<b>Standard Finish 01 White.</b> <b>Optional Finish:</b> 02 Satin Silver <b>Optional Finishes ( Additional charge ):</b> 03 Black. 28 Custom color			• Available only in sizes listed in Table.