



Model: XG-RHFSS-1 Hinged Core 45° Louvered Face - Flush Surface Mount

XG-RHFSS-1 - Flush Surface Mount

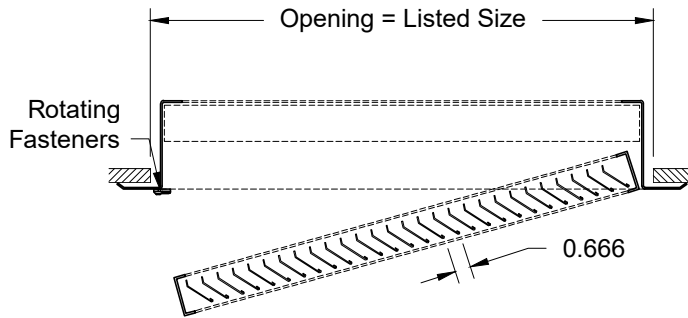

Side View

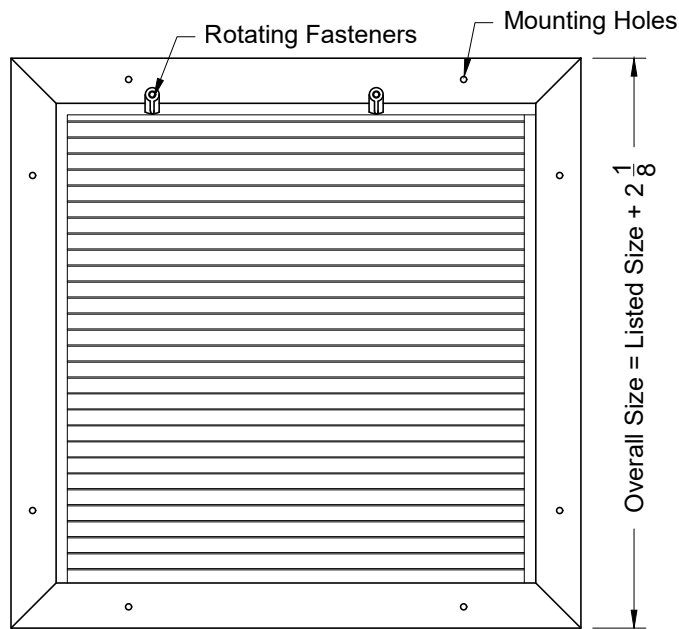

Face View

Neck Size		
	Min	Max
Width	4	48
Depth	4	48

Filter Depth	H
1"	2 7/16"
2"	2 3/8"


Overall Size = Listed Size + 2 1/8"

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White 23 Satin Polish	XG-OBDS - S.S. Opposed Blade Damper XG-TBPFSS - S.S. T-Bar Plaster Frame XG-LIPFSS - S.S. Lay In Plaster Frame XG-PFSS - S.S. Plaster Frame	316SS - 316 Stainless Steel IS-SS - Insect Screen S.S. 1" FF - 1" Filter Rack 2" FF - 2" Filter Rack	<ul style="list-style-type: none"> 304 Stainless Steel Construction (Standard) Only Available in Listed Sizes


All Dimensions ±1/16"

Model: XG-RHFSS-6 Hinged Core 45° Louvered Face - T-Bar Lay-In

XG-RHFSS-6 - T-Bar Lay-In

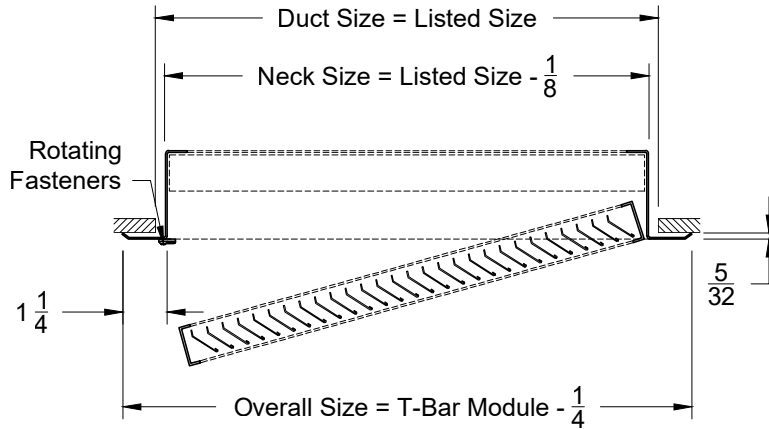

Listed Sizes	
12 x 12	
12 x 24	
24 x 24	
48 x 24	

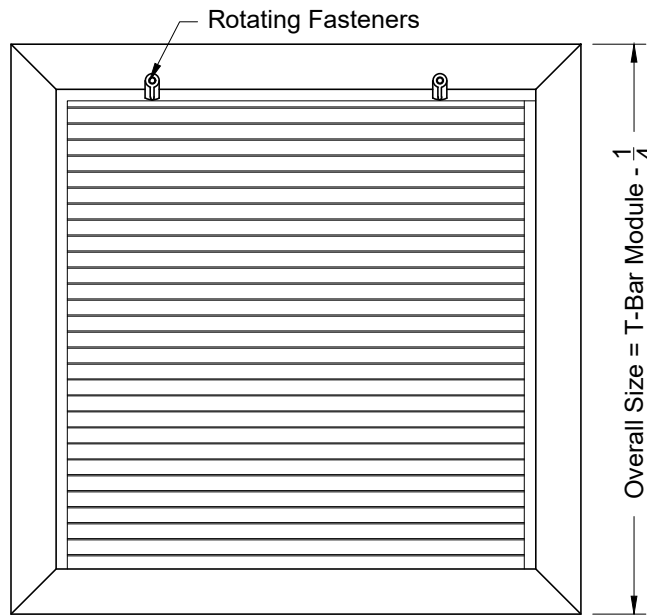

Neck Size		
	Min	Max
Width	4	46
Depth	4	22

Filter Depth	H
1"	2 7/16"
2"	2 3/8"

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White 23 Satin Polish	XG-OBDS - S.S. Opposed Blade Damper XG-TBPFSS - S.S. T-Bar Plaster Frame XG-LIPFSS - S.S. Lay In Plaster Frame XG-PFSS - S.S. Plaster Frame	316SS - 316 Stainless Steel IS-SS - Insect Screen S.S. 1" FF - 1" Filter Rack 2" FF - 2" Filter Rack	<ul style="list-style-type: none"> 304 Stainless Steel Construction (Standard) Only Available in Listed Sizes

All Dimensions ±1/16"