
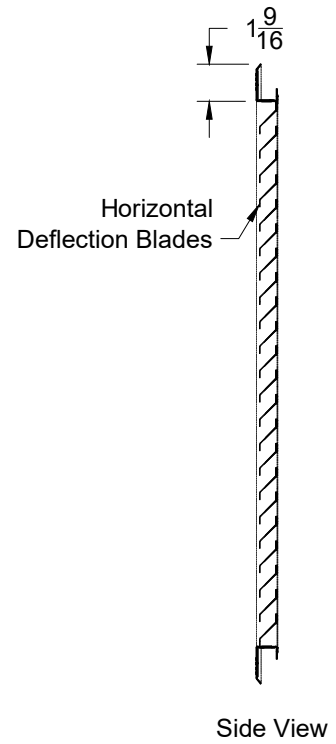
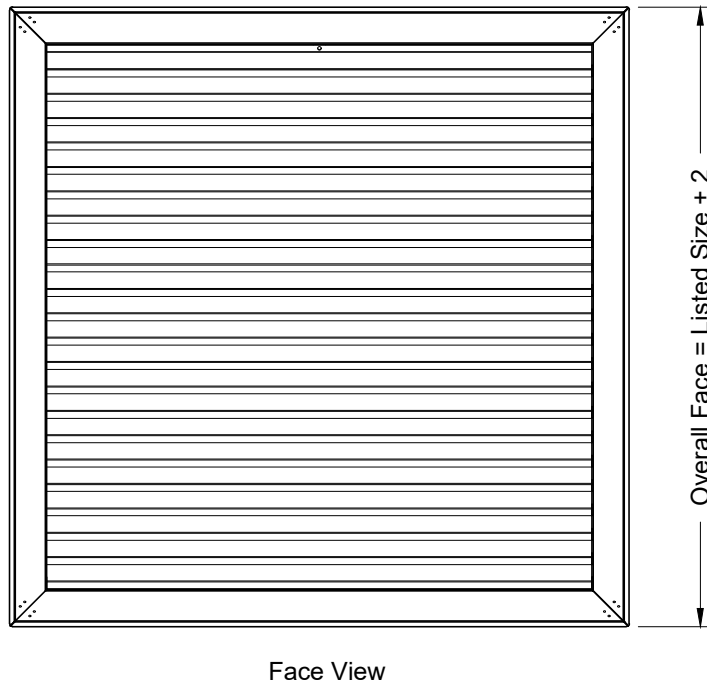


Model: XG-RHSS-1 45° Horizontal Fixed Blade - Flush Surface Mount

XG-RHSS-1 - Flush Surface Mount

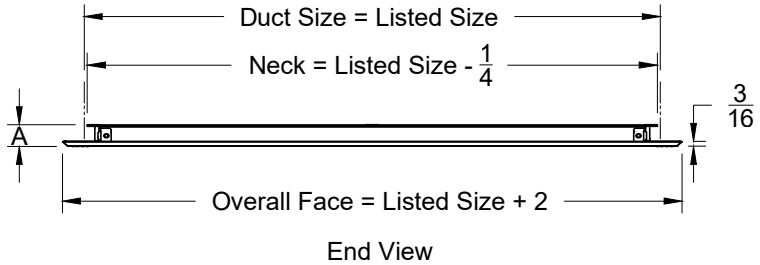

	Neck Size	
	Min	Max
Width	4	48
Depth	4	48


Filter Depth	H
1"	2 7/16"
2"	2 3/8"

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White 23 Satin Polish	XG-OBDS - S.S. Opposed Blade Damper XG-PFSS - S.S. Plaster Frame XG-LIPFSS - S.S. Lay-In Plaster Frame	IS-SS - Insect Screen NSH - No Screw Holes 316SS - 316 Stainless Steel	<ul style="list-style-type: none"> 304 Stainless Steel Construction (Standard) Only Available in Listed Sizes


All Dimensions ±1/16"

Model: XG-RHSS-6 45° Horizontal Fixed Blade - T-Bar Lay-in


XG-RHSS-6 - T-Bar Lay-in

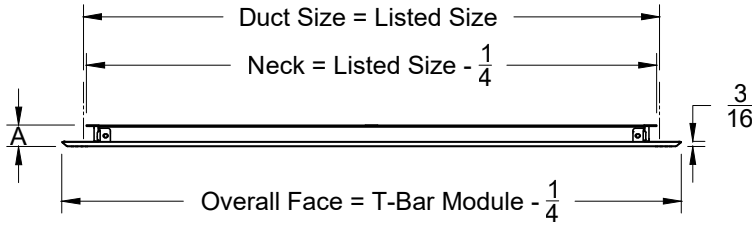

End View

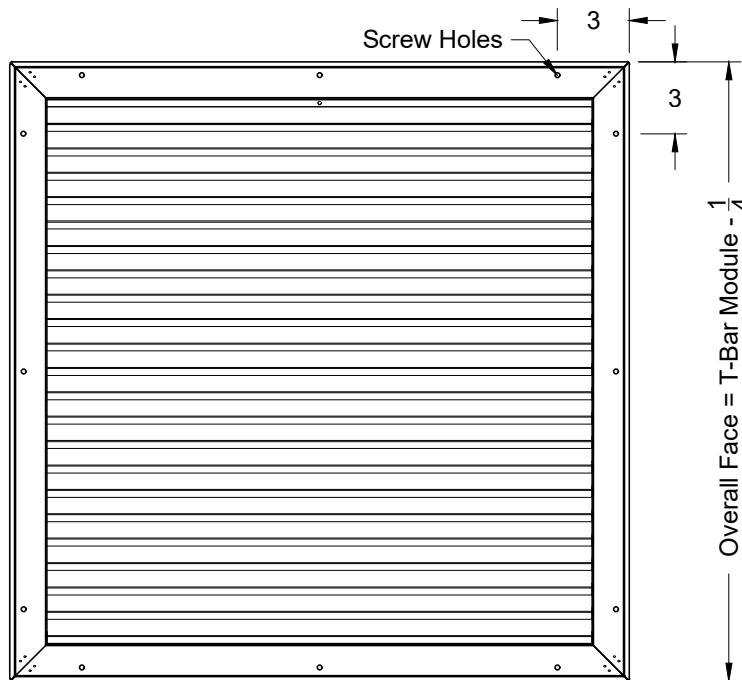

Face View

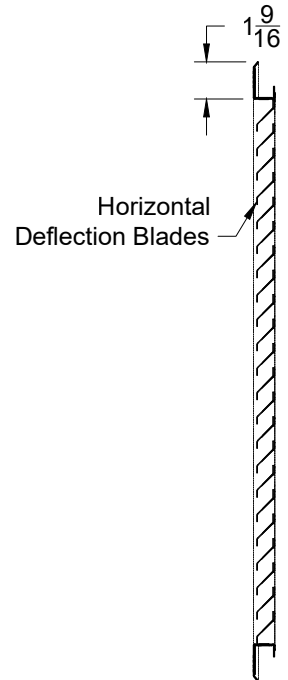

Side View

Listed Sizes
12 x 12
12 x 24
24 x 24
48 x 24

	Neck Size	
	Min	Max
Width	4	46
Depth	4	22

Filter Depth	H
1"	2 7/16"
2"	2 3/8"

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White 23 Satin Polish	XG-OBDS - S.S. Opposed Blade Damper XG-PFSS - S.S. Plaster Frame XG-LIPFSS - S.S. Lay-In Plaster Frame	IS-SS - Insect Screen 316SS - 316 Stainless Steel	<ul style="list-style-type: none"> 304 Stainless Steel Construction (Standard) Only Available in Listed Sizes

All Dimensions $\pm 1/16"$