
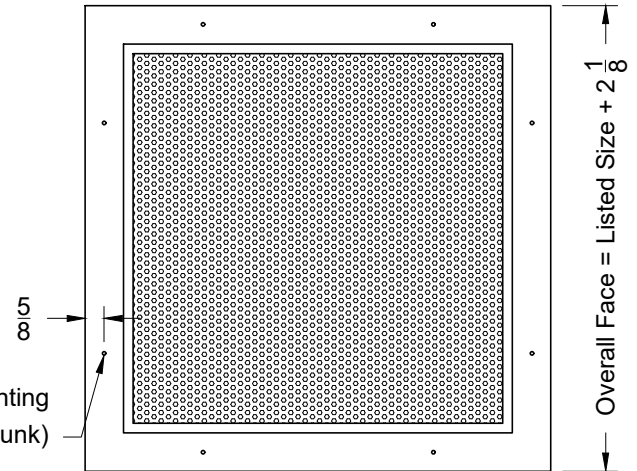


Model: XG-SRP-1 Perforated Face Grille - Flush Surface Mount
 XG-SRP-6 Perforated Face Grille - T-Bar Lay-In



XG-SRP-1 - Perforated Grille - Flush Surface Mount

Face View

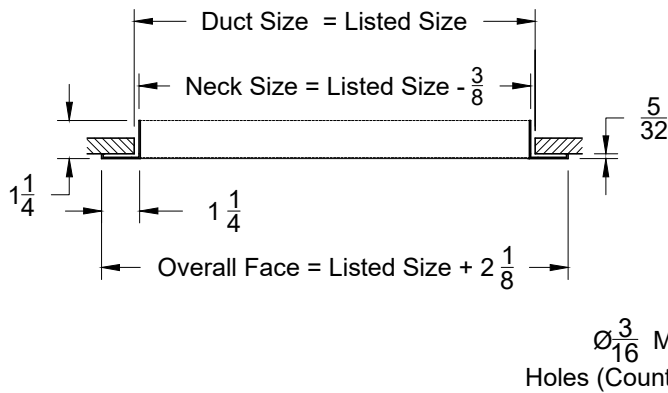

XG-SRP-6 - Perforated Grille - T-Bar Lay-In

Face View

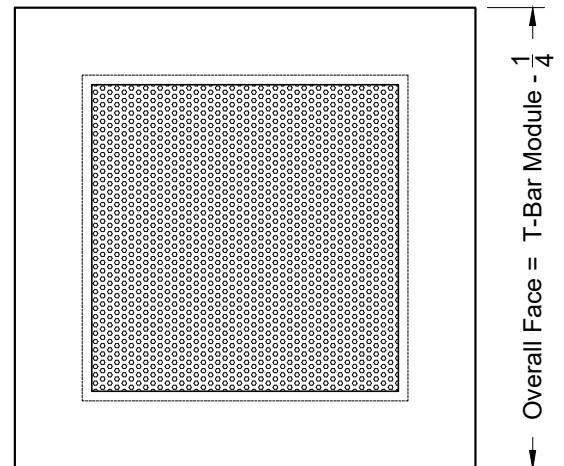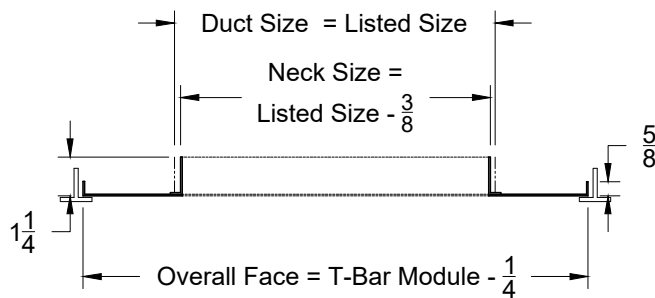

Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Finish 24 Mill Finish Optional Finish 02 Satin Silver 03 Black 28 Custom Color	XG-OBDA - Steel Opposed Blade Damper XG-OBDA - Aluminum OBD XG-L9 - Equalizing Grid XG-PF - Plaster Frame XG-TBPF - T-Bar Plaster Frame XG-LIPF - Lay-In Plaster Frame	IS - Insect Screen NSH - No Screw Holes	<ul style="list-style-type: none"> • Oversized Units made in multiple sections • Largest single section is 24x48 • Mullion strips provided for joining units in field • Available to fit standard T-Bar.

All Dimensions $\pm 1/16"$