



Model: XG-TBPFSS T-Bar Plaster Frame - Surface Mount

XG-TBPFSS - Surface Mounted

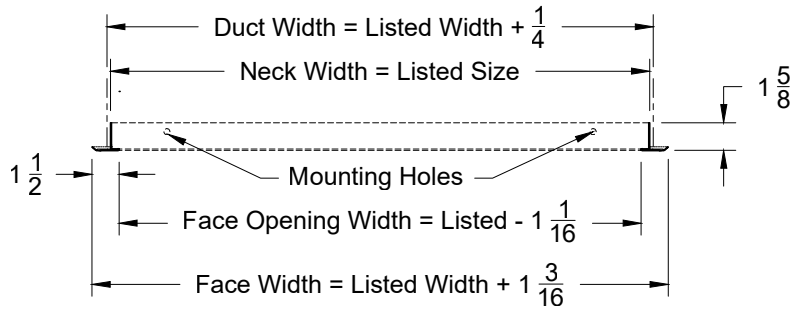

Side View

Neck Size		
	Min	Max
Width	4	48
Depth	4	48

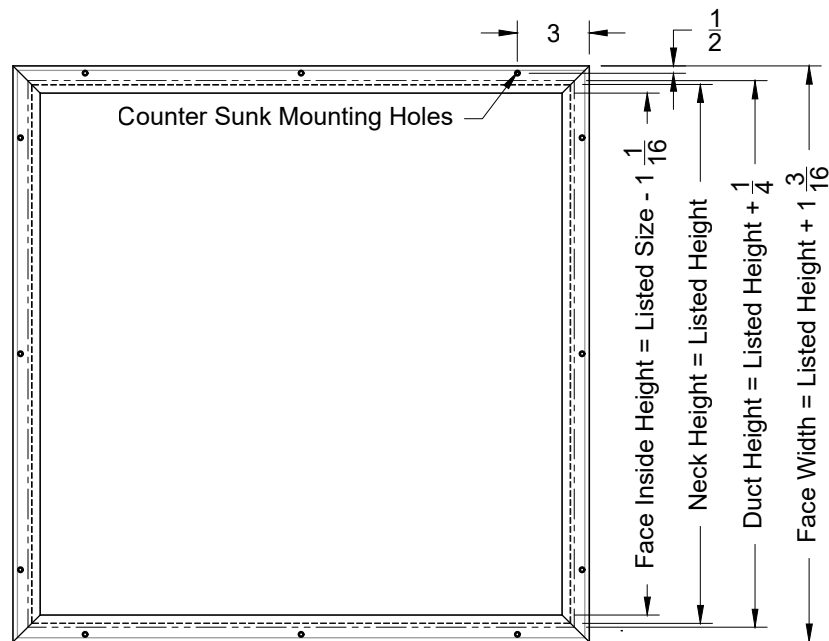

Face View

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 23 Satin Polish		316SS - 316 Stainless Steel	<ul style="list-style-type: none"> • 304 Stainless Steel Construction (Standard) • Only Available in Listed Sizes • Mounting Holes located on the Frame

All Dimensions $\pm 1/16"$