


Model: XG-2000CO Core Only - 7/32" Bars on 1/2" Center - 0°, 15° and 30° Deflection


XG-2000CO - Core Only

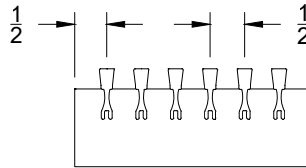

End View




Side View

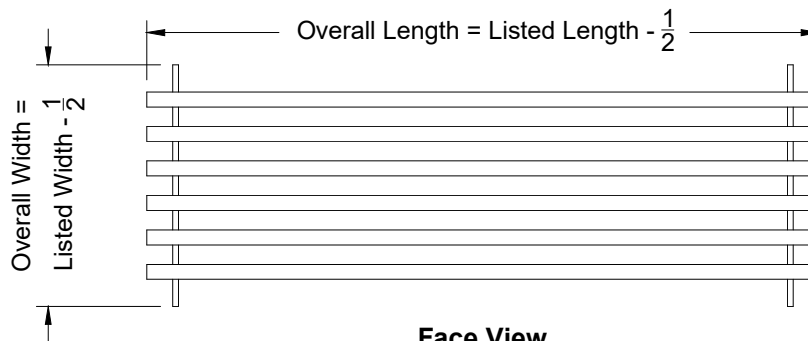


Face View

 
0° Deflection



15° Deflection

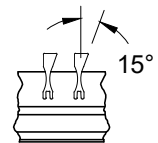


30° Deflection

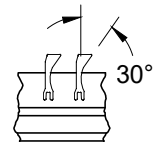


1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 - White Optional Finish: (extra charge) 02 - Satin Silver 03 - Black 04 - Clear Anodized 28 - Special/Setup Charge Optional Finish (no charge) 04 Mill Finish			<ul style="list-style-type: none"> Widths available in 1/2" increments from 1 1/2" to 24" for series 2000-CO Lengths available in single pieces to to 72" Longer sections are available only as separate non-connected sections. For lengths less than 72" round up to the next listed size. <p style="text-align: right;">All Dimensions ±1/16"</p>

Model: XG-2000PCO Pencil Proof Core Only - 17/64" Bars on 1/2" Spacing - 0°, 15° and 30° Deflection


XG-2000PCO - Pencil Proof Core Only

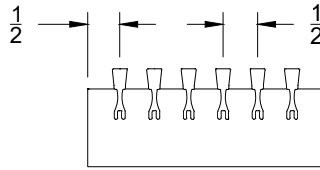

End View

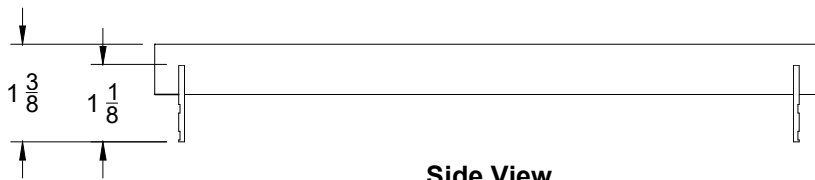


Side View

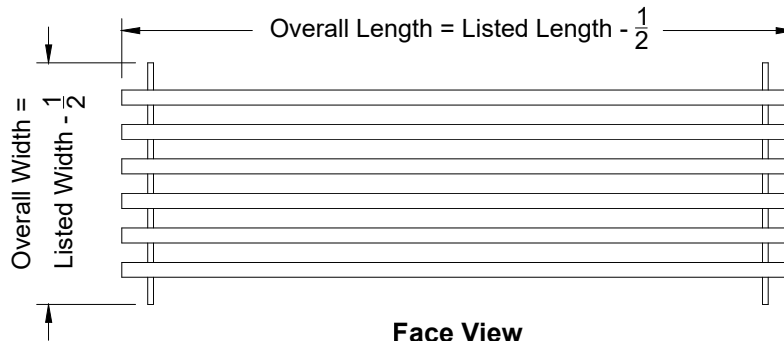


Face View

 
0° Deflection



15° Deflection

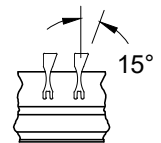

30° Deflection

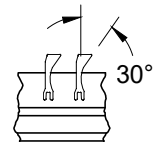

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 - White Optional Finish: (extra charge) 02 - Satin Silver 03 - Black 04 - Clear Anodized 28 - Special/Setup Charge Optional Finish (no charge) 04 Mill Finish			<ul style="list-style-type: none"> Widths available in 1/2" increments from 1 1/2" to 24" for series 2000-CO Lengths available in single pieces to to 72" Longer sections are available only as separate non-connected sections. For lengths less than 72" round up to the next listed size. <p style="text-align: right;">All Dimensions ±1/16"</p>