



Model: XG-2400

1/8" Bars on 1/4" Center - 0°, 15° and 30° Deflection - Wall Mounted


XG-2400 - Wall Mounted

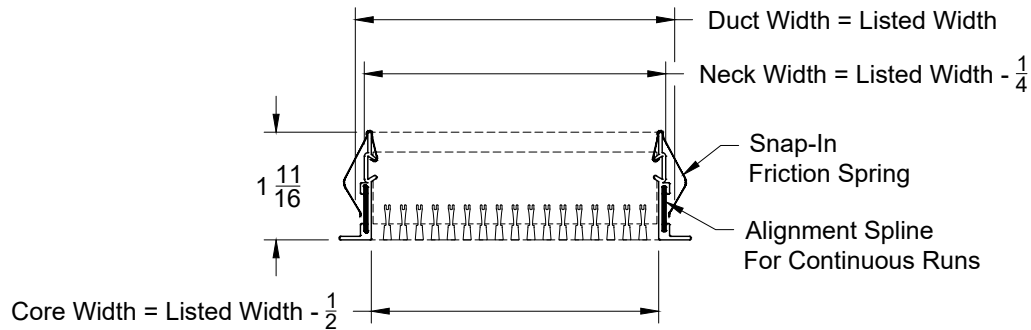

End View

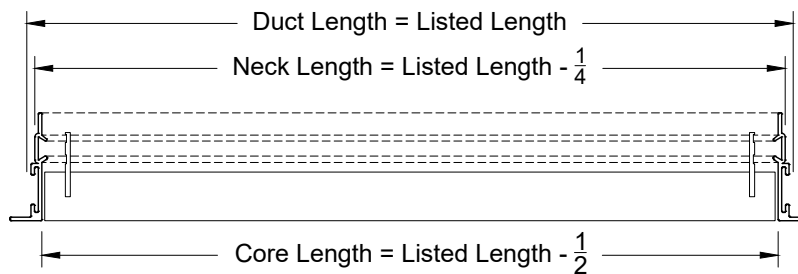


Side View

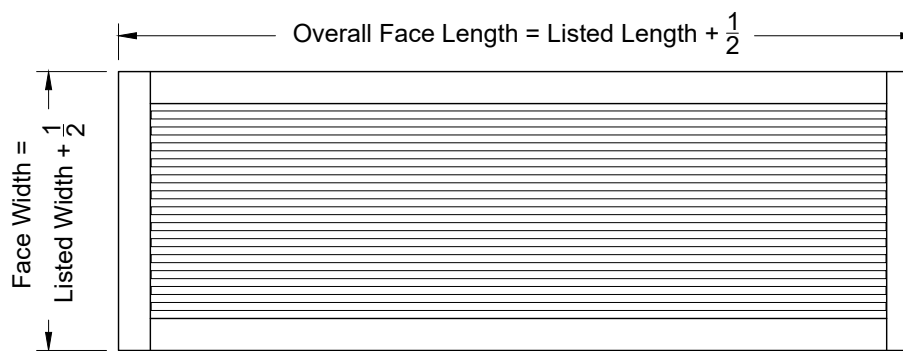


Face View

 
0° Deflection



15° Deflection

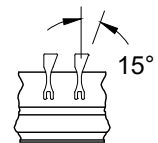

30° Deflection

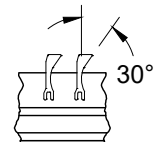

1. Available Finishes

- Standard Finish:
01 White
Optional Finish (extra charge)
02 Satin Silver
03 Black
04 Clear Anodized
28 Special/Setup Charge

2. Available Accessories

- L9 - Equalizing Grid
DA - Aluminum Damper

3. Available Options

4. Construction Details


- 0, 15, 30 degree deflection available
- Extruded Aluminum construction
- Widths available in 1/2" increments from 1 1/2" to 24"
- Lengths available in single pieces up to 72".
- Longer sections are available only as separate non-connected sections.

All Dimensions $\pm 1/16$ "

Model: XG-2400H

1/8" Bars on 1/4" Center - 0°, 15° and 30° Deflection - Concealed Mount Hangers

XG-2400H - Concealed Mounted

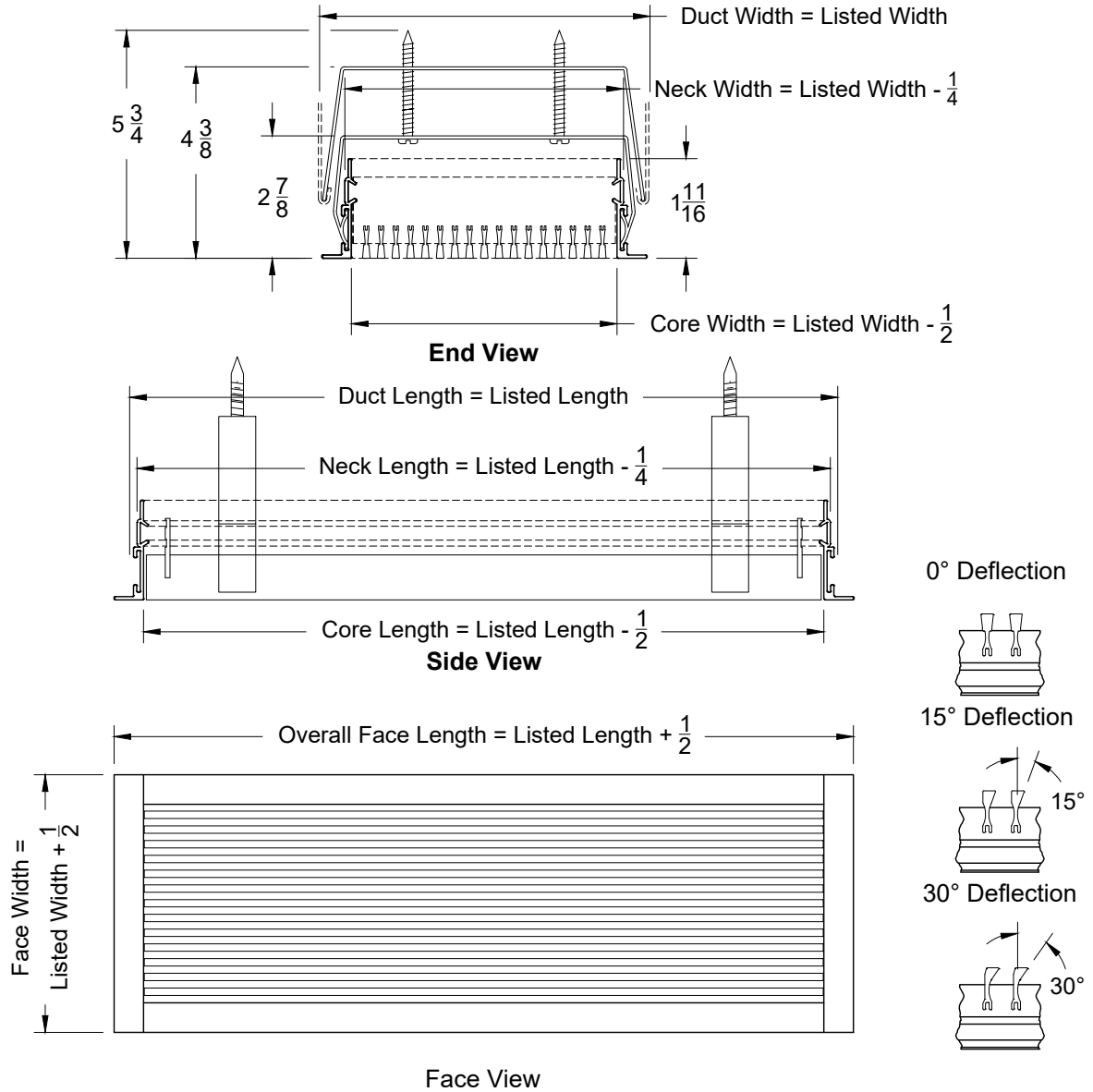

1. Available Finishes

- Standard Finish:
- 01 White
- Optional Finish (extra charge)
- 02 Satin Silver
 - 03 Black
 - 04 Clear Anodized
 - 28 Special/Setup Charge

2. Available Accessories

- L9 - Equalizing Grid
- DA - Aluminum Damper

3. Available Options


4. Construction Details

- 0, 15, 30 degree deflection available
- Extruded Aluminum construction
- Widths available in 1/2" increments from 1 1/2" to 24"
- Lengths available in single pieces up to 72".
- Longer sections are available only as separate non-connected sections.


All Dimensions $\pm 1/16"$

Model: XG-2400HC 1/8" Bars on 1/4" Center - 0°, 15° and 30° Deflection - Combination Narrow Mount


XG-2400HC - Combination Narrow Subframe Mount

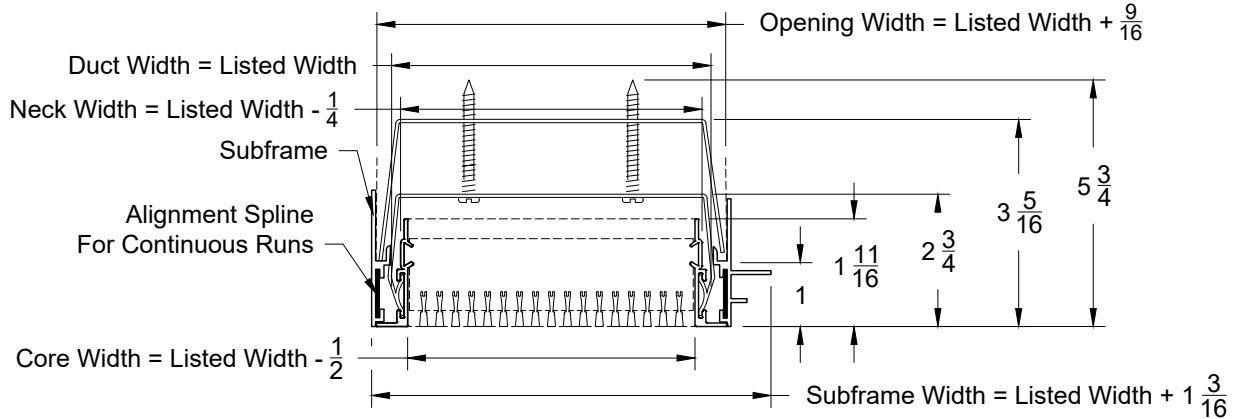

End View

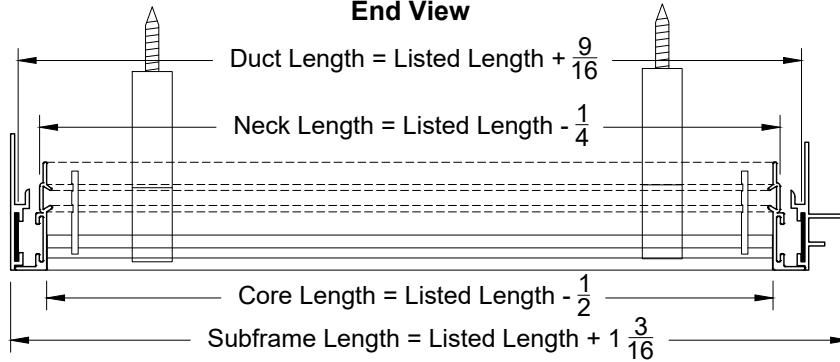


Side View

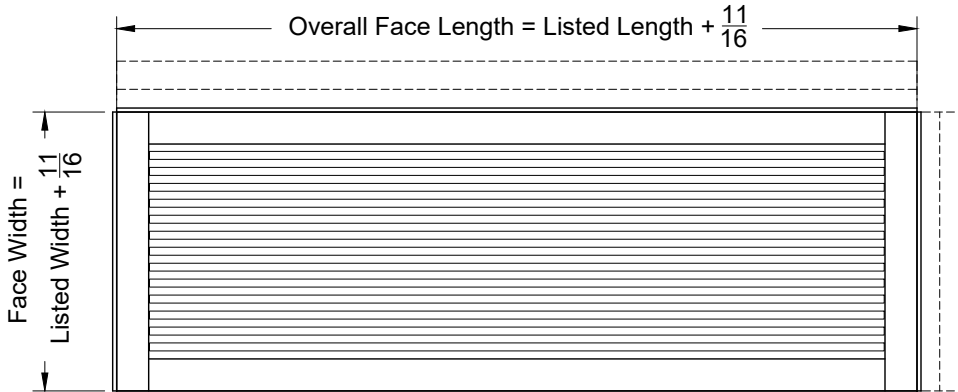


Face View

 
0° Deflection



15° Deflection

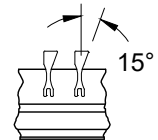

30° Deflection

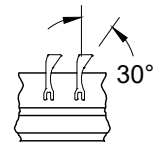

1. Available Finishes

Standard Finish:
 01 White
 Optional Finish (extra charge)
 02 Satin Silver
 03 Black
 28 Special/Setup Charge

2. Available Accessories

L9 - Equalizing Grid
 DA - Aluminum Damper

3. Available Options

4. Construction Details


- 0, 15, 30 degree deflection available
- Extruded Aluminum construction
- Widths available in 1/2" increments from 1 1/2" to 24"
- Lengths available in single pieces up to 72".
- Longer sections are available only as separate non-connected sections.

All Dimensions $\pm 1/16"$


Model: XG-2400HP

1/8" Bars on 1/4" Centers - 0°, 15° and 30° Deflection - Concealed Mount


XG-2400HP - Concealed Spline Subframe

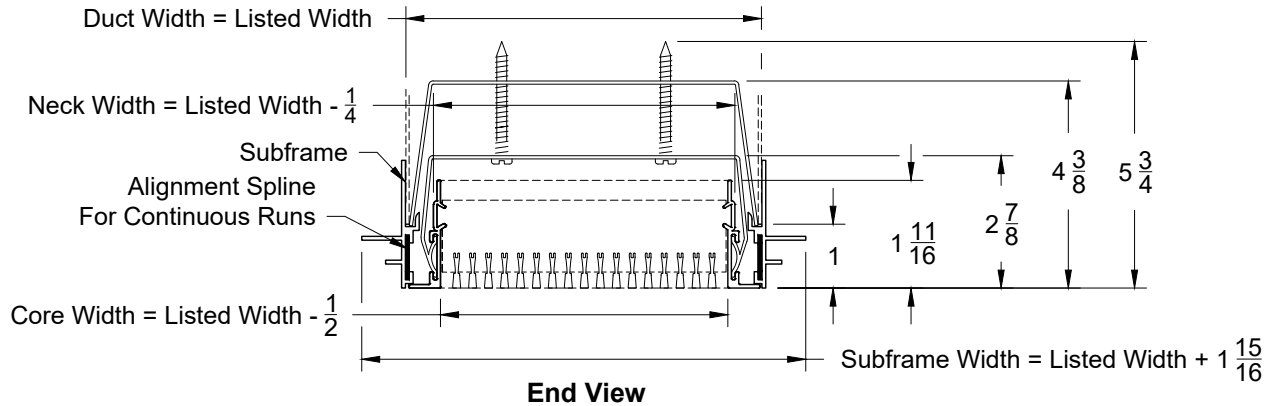

End View

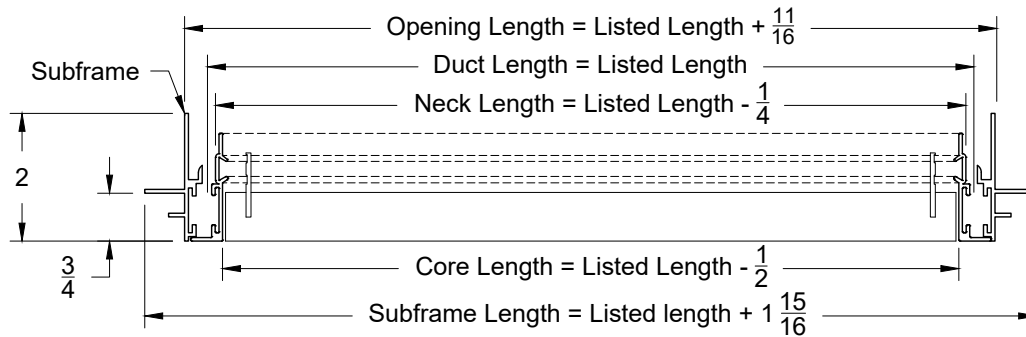


Side View

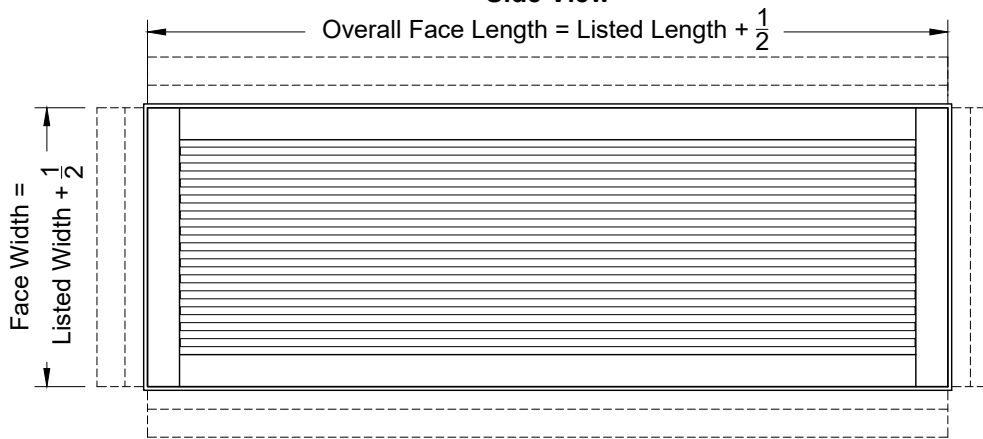


Face View

 
0° Deflection



15° Deflection

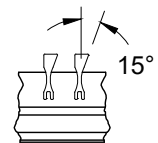

30° Deflection

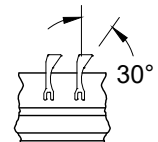

1. Available Finishes

- Standard Finish:
01 White
Optional Finish (extra charge)
02 Satin Silver
03 Black
28 Special/Setup Charge

2. Available Accessories

- L9 - Equalizing Grid
DA - Aluminum Damper

3. Available Options




4. Construction Details

- 0, 15, 30 degree deflection available
- Extruded Aluminum construction
- Widths available in 1/2" increments from 1 1/2" to 24"
- Lengths available in single pieces up to 72".
- Longer sections are available only as separate non-connected sections.


All Dimensions $\pm 1/16$ "

Model: XG-2400HW 1/8" Bars on 1/4" Centers - 0°, 15° and 30° Deflection - Narrow Mounted


XG-2400HW - Narrow Mounted Subframe

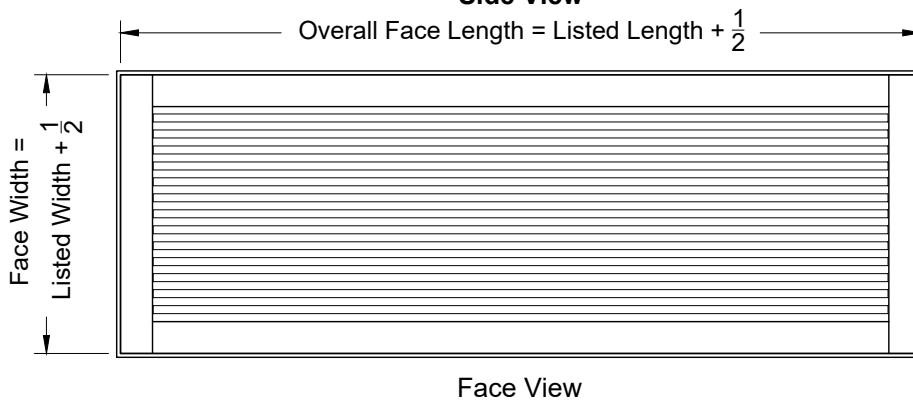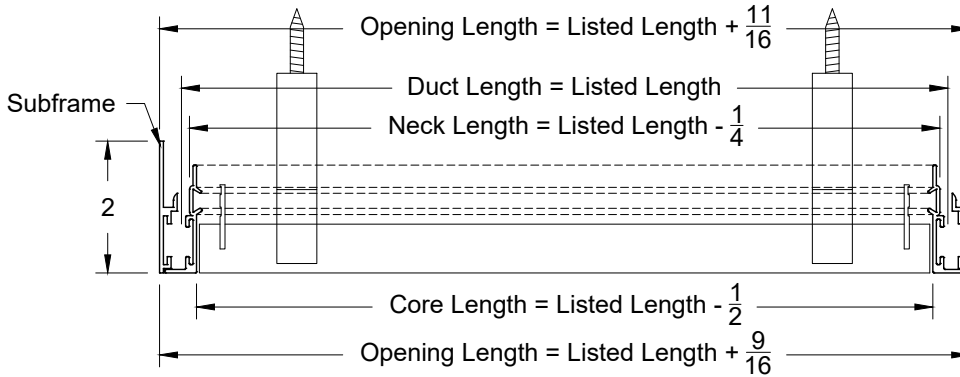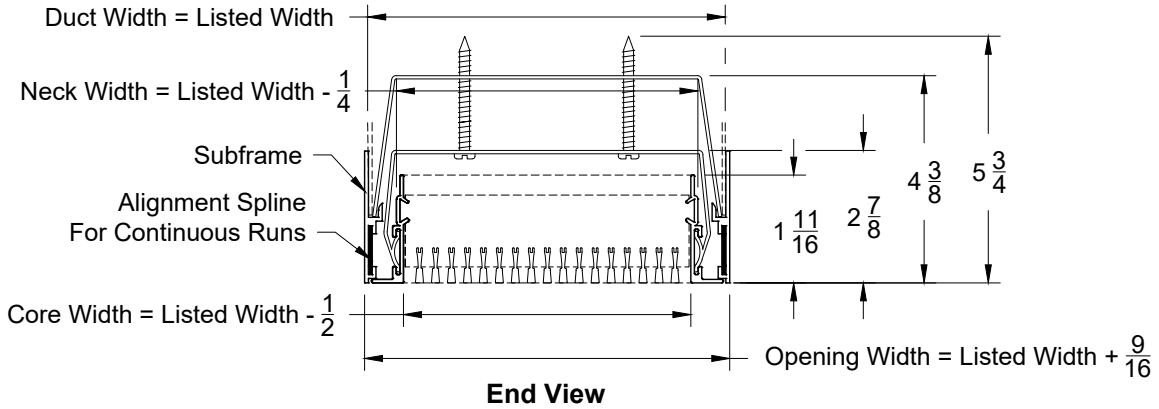


0° Deflection

 

15° Deflection

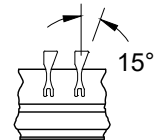

30° Deflection

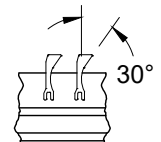

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish (extra charge) 02 Satin Silver 03 Black 28 Special/Setup Charge	L9 - Equalizing Grid DA - Aluminum Damper		<ul style="list-style-type: none"> • 0, 15, 30 degree deflection available • Extruded Aluminum construction • Widths available in 1/2" increments from 1 1/2" to 24" • Lengths available in single pieces up to 72". • Longer sections are available only as separate non-connected sections.

All Dimensions $\pm 1/16"$