



Return Heavy Duty Grilles and Registers
Aluminum Gym Grille

- Models: **XG-4500-1** 0° Deflection Grille - Horizontal Fixed Blades - Surface Mount
XG-4538-1 38° Deflection Grille - Horizontal Fixed Blades - Surface Mount
XG-4500-1 XG-OBDE 0° Deflection Grille - with Opposed Blade Damper - Horizontal Fixed Blades - Surface Mount
XG-4538-1 XG-OBDE 38° Deflection Grille - with Opposed Blade Damper - Horizontal Fixed Blades - Surface Mount


Model: XG-4500-1 (0° Deflection Grille - Surface Mount - Horizontal Fixed Blades)

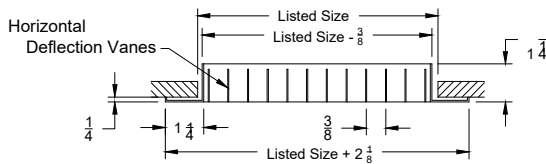


Face view (Models: XG-4500-1 & XG-4538-1)

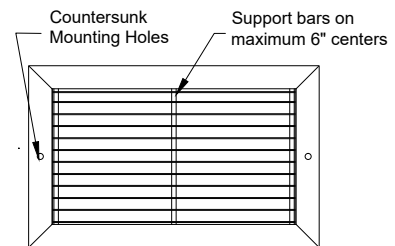



Model: XG-4538-1 (38° Deflection Grille - Surface Mount - Horizontal Fixed Blades)

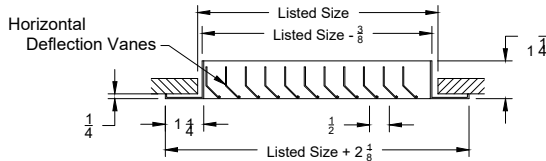

Model: XG-4500-1 (0° Deflection Register) with Opposed Blade Damper

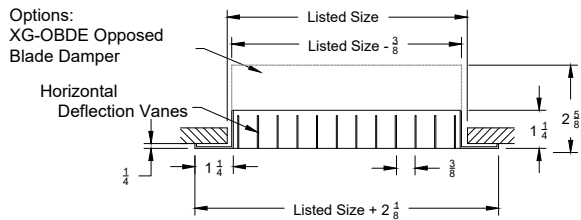

Model: XG-4500-1 (38° Deflection Register)

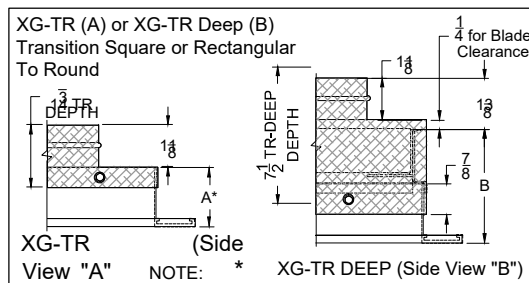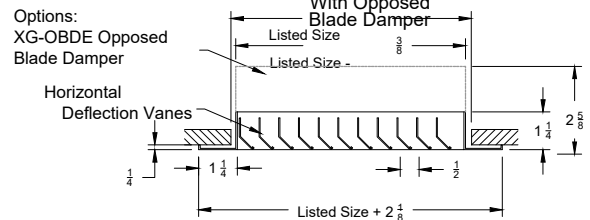

Notes: (check if provided)

Note: This product complies with the requirements of NFPA 90A-18, Sections 4.3.7.3.2 & 4.3.8.3.2.

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
<p>Standard Finish:</p> <p>01 White.</p> <p>Optional Finish (extra charge):</p> <p>02 Satin Silver</p> <p>03 Black</p> <p>28 Custom Color / Setup Charge</p>	<p>XG-OBDE - Extruded Aluminum Damper</p> <p>XG-L9 - Equalizing Grid</p> <p>XG-PF - Plaster Frame</p> <p>XG-SLIPF - Steel Lay-In Plaster Frame</p> <p>XG-TR - Square to Round Transition</p> <p>XG-TR-Deep - Deep Square to Round</p>	<p>NSH - No Screw Holes</p> <p>IS - Insect Screen</p>	<ul style="list-style-type: none"> ● Frame and blades are aluminum. Blades are fixed at either 0° or 38°. ● Odd Sizes: ● Only width can be odd size. Height must be in 2" increments as listed. No fractional sizes. ● Oversized units can not be odd sized. ● Oversized units made in multiple sections, each with full flanges. Mullion strips provided for joining units in field.