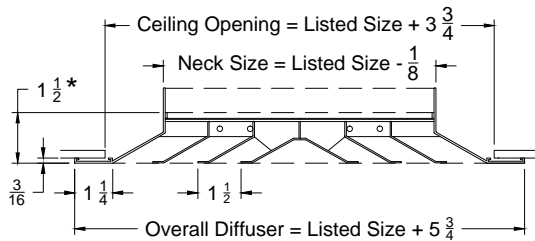
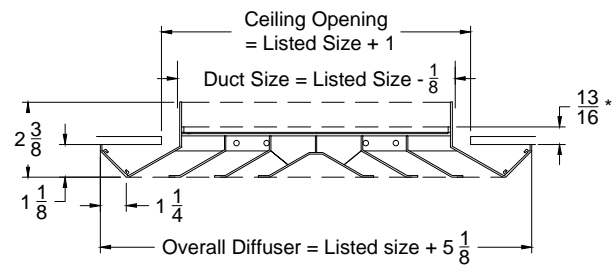
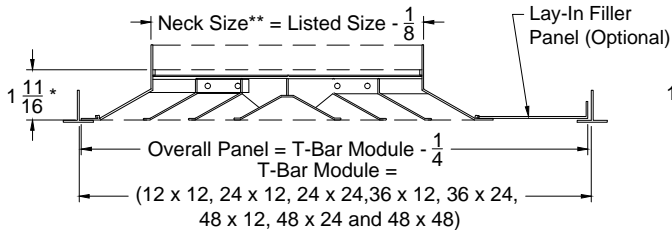
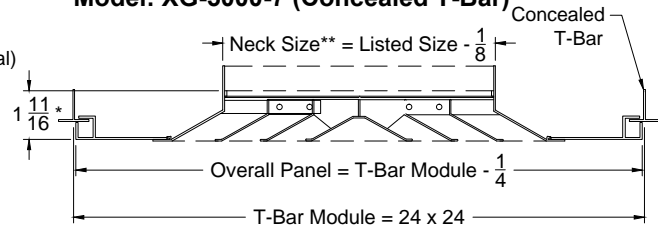


**Square / Rectangular Louver Face Ceiling Diffusers
Extruded Aluminum - Removable Core**

Models:	XG-5000-1	Flush Surface Mounting
	XG-5000-2	V-Beveled Drop Surface Mounting
	XG-5000-6	Lay in T-Bar
	XG-5000-7	Concealed T-Bar

Model: XG-5000-1 (Flush Surface Mounting)

Model: XG-5000-2 (V-Beveled Drop Surface Mounting)

Model: XG-5000-6 (Lay in T-Bar)

Model: XG-5000-7 (Concealed T-Bar)


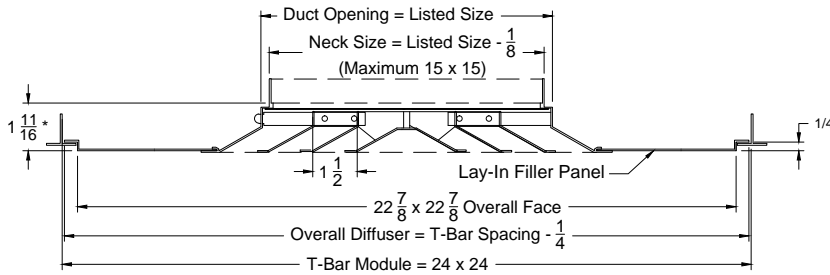
*** Dimension indicates the distance needed for Clearance from the bottom of the duct to the ceiling line and must be maintained for proper fit.**

**** Filler panel included for neck sizes under 18 x 18 to fit in 24 x 23, 24 x 24 T-bar grid, (6 x 6, 9 x 9, 12 x 12 and 15 x 15 include filler panel).**


Square / Rectangular Louver Face Ceiling Diffusers Extruded Aluminum - Removable Core

Models: **XG-5000-8** Tegular T-Bar (24X24 Module)
XG-5000-9 Bolt Slot / Donn Finline (24X24 Module)


Model: XG-5000-8 (Tegular T-Bar)



Model: XG-5000-9 (Bolt Slot / Donn Finline)

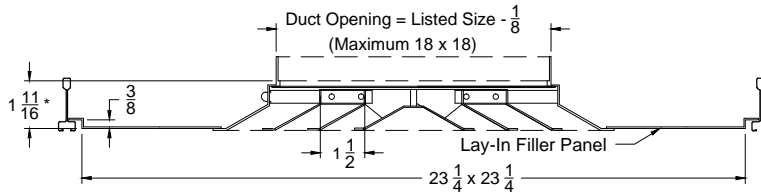


* Dimension indicates the distance needed for Clearance from the bottom of the duct to the ceiling line and must be maintained for proper fit.

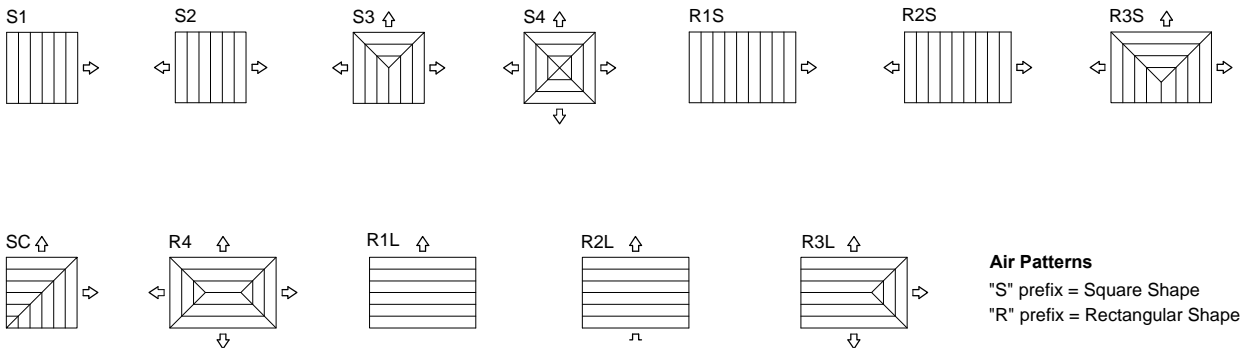

Options for Square / Rectangular Louver Face Ceiling Diffusers Extruded Aluminum - Removable Core


- Option: **XG-APD** Air Pattern Deflector
XG-D5 Steel Opposed Blade Damper
XG-D5A Aluminum Opposed Blade Damper
XG-IV Induction Vanes

 Option: XG-APD Air Pattern Deflector




- Optional XG-APD Adjustable Pattern Deflector Vane
 - Available for most 5000 series borders and sizes,
 - Cannot be used with XG-IV Induction Vanes option,
 - XG-APDs are factory mounted.

Option: XG-IV Induction Vanes

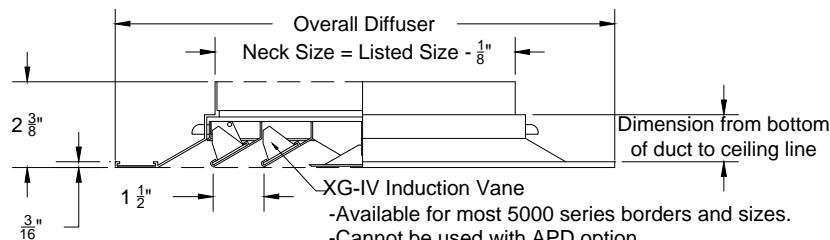


- Available for most 5000 series borders and sizes.
 -Cannot be used with APD option.
 -XG-IV Induction Vanes are factory mounted.


Option: XG-D5 Steel Opposed Blade Damper. DXG-5A Aluminum Opposed Blade Damper.

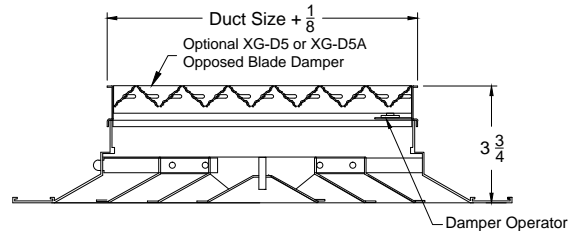

XG-IV (Face View)

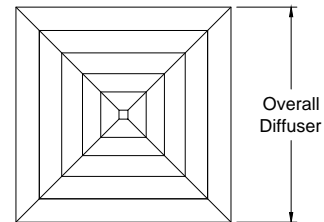

XG-FSM (Face Screw Mount)

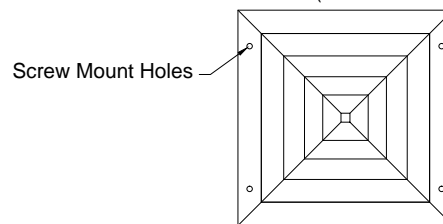

Notes: (check if provided)

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
<p>Standard Finish: 01 White</p> <p>Optional Finish (no extra charge): 24 Mill finish</p> <p>Optional Finish (extra charge): 02 Satin Silver 03 Black. 28 Custom Color / Setup Charge</p> <p>Note: Anodized Finish not available.</p>	<p>Square and Rectangular Neck: XG-D5 - Steel Opposed Blade Damper XG-D5A - Aluminum Opposed Blade Damper XG-L9 - Equalizing Grid XG-TR - Square to Round XG-TR - Deep</p> <p>Round Neck: XG-G3 - Equalizing Grid XG-BDS - Butterfly Damper XG-RSD - Radial Shutter Damper</p>	<p>XG-FSM: Face Screw Mount (-1 only)</p> <p>Factory Mounted: XG-IV Induction Vanes. XG-APD Air Pattern Deflectors XG-FGBP - Factory Installed R6 Fiberglass Insulation (24X24 only)</p>	<p>Sizes only as listed.</p> <ul style="list-style-type: none"> Available air patterns: S1, S2, S3, S4, R1S, R1L, R2S, R2L, R3S, R3L, R4 and SC. For 5000-6 (D5) Models Only: 21 x 21 Neck in 24 x 24 Module is available in S4 Pattern only.