



Architectural Deflection Diffusers Aluminum - Fixed Louvered Face

- Models: **XG-5500DD (DDI)-6** Supply - Non Insulated (Insulated) - T-Bar Lay in
XG-5500DD (DDI)-8 Supply - Non Insulated (Insulated) - Tegular T-Bar
XG-5500DD (DDI)-9 Supply - Non Insulated (Insulated) - 24x24 Donn (USG) Ceiling Grid
XG-5500 DDR-6 Return - Non Insulated - T-Bar Lay in
XG-5500 DDR-8 Return - Non Insulated - Tegular T-Bar
XG-5500 DDR-9 Return - Non Insulated - 24x24 Donn (USG) Ceiling Grid


Model: **XG-5500DD-6 = Lay in T-Bar Non Insulated**
 Model: **XG-5500DDI-6 = Lay in T-Bar Insulated**

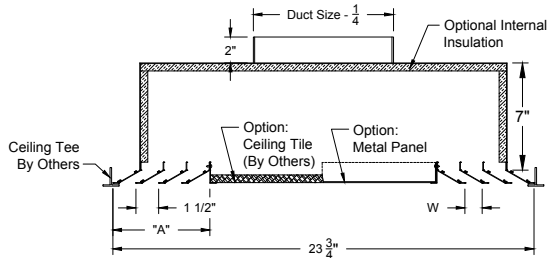


Model: **XG-5500DDR-6 = Lay in T-Bar**

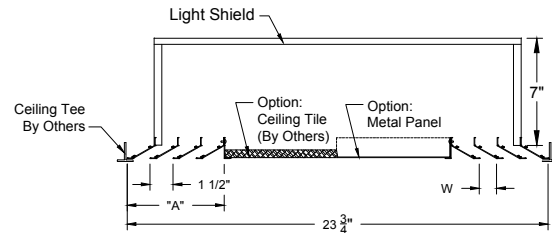


Model: **XG-5500DD-8 = Tegular T-Bar Non Insulated**
 Model: **XG-5500DDI-8 = Tegular T-Bar Insulated**

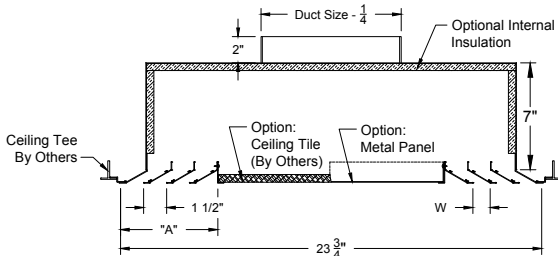


Model: **XG-5500DDR-8 = Tegular T-Bar**

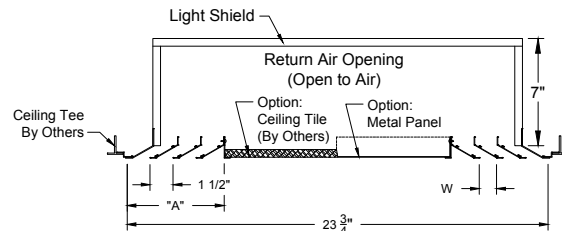

Model: **XG-5500DD-9 = 24x24 Donn (USG) Ceiling Grid Non Insulated**
 Model: **XG-5500DDI-9 = 24x24 Donn (USG) Ceiling Grid Insulated**

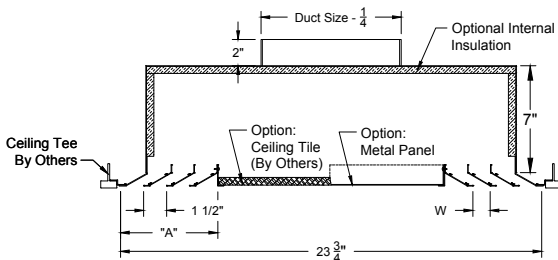


Model: **XG-5500DDR-9 = 24x24 Donn (USG) Ceiling Grid**

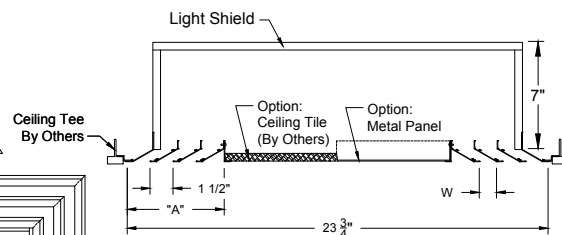

MODEL	Dim. W	1 Slot Dim. A	2 Slot Dim. A	3 Slot Dim. A	4 Slot Dim. A
XG-5500DD	1 1/8	3 5/16	4 13/16	6 5/16	7 13/16

Available with 1, 2, 3 and 4 Slots.
 (XG-5500DD 3 SLOT UNIT SHOWN)

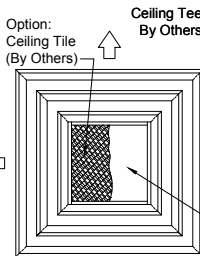

Air Patterns

Notes: (check if provided)

1. Available Finishes	2. Available Accessories	4. Construction Details
Standard Finish 01 White with Black Plenum. Optional Finishes (additional charge): 03 Black.	Aluminum Radial Opposed Blade Damper. XG-BDS - Round Damper. XG-RSD - Radial Shutter Round Damper. XG-TBPF - T-Bar Plaster Frame.	<ul style="list-style-type: none"> Insulated units have 1/2" Tuffskin insulation. Center Ceiling Tile supplied by others, field installed. Return units are non-ducted, with light shields. Available in 1 1/2" spacers with 1,2,3 and 4 slots (3 slot units shown above).