


Linear Slot Diffuser - Extruded Aluminum Return - No Pattern Controller Slots: 1/2" (XG-6650), 3/4" (XG-6675), 1" (XG-6610) and 1 1/2" (XG-6615)

 
Models: **XG-6600R-10-6** Lay in T-Bar - 1 1/8" Border - No Hardware
XG-6600R-12-6 Lay in T-Bar - 1 1/8" Border - With Hardware

Models: **XG-6600R-10-6**
 (Lay in T-Bar - 1 1/8" Border - No Hardware)

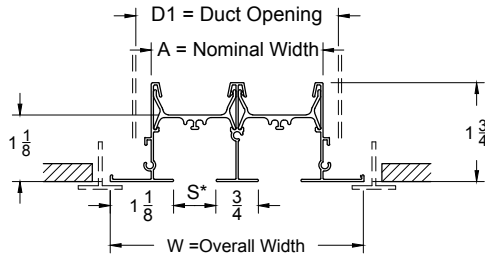


(XG-6600R-10-6 & XG-6600R-12-6 Models - End Border)

Option: End Border





(XG-6600R-10-6 & XG-6600R-12-6 Models - End Cap)

 Option: End Cap



Model: **XG-6600R-12-6**
 (Lay in T-Bar - 1 1/8" Border - With Hardware)

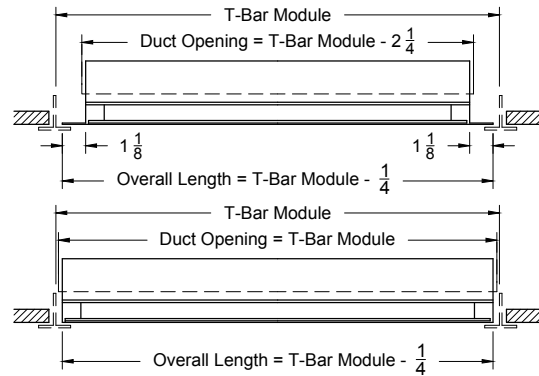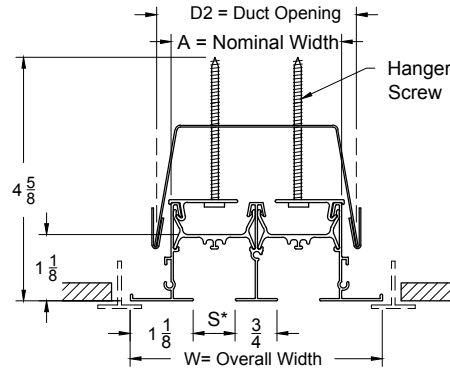

Model XG-6650 (10-6 & 12-6)								
S=1/2"	Number Of Slots							
Slot	1	2	3	4	5	6	7	8
A	1 5/16	2 9/16	3 13/16	5 1/16	6 5/16	7 9/16	8 13/16	10 1/16
D1	1 3/4	3	4 1/4	5 1/2	6 3/4	8	9 1/4	10 1/2
D2	2 1/4	3 1/2	4 3/4	6	7 1/4	8 1/2	9 3/4	11
W	2 3/4	4	5 1/4	6 1/2	7 3/4	9	10 1/4	11 1/2

Model XG-6610 (10-6 & 12-6)								
S=1"	Number Of Slots							
Slot	1	2	3	4	5	6	7	8
A	1 13/16	3 9/16	5 5/16	7 1/16	8 13/16	10 9/16	12 5/16	14 1/16
D1	2 1/4	4	5 5/8	7 1/2	9 1/4	11	12 3/4	14 1/2
D2	2 3/4	4 1/2	6 1/8	8	9 3/4	11 1/2	13 1/4	15
W	3 1/4	5	6 3/4	8 1/2	10 1/4	12	13 3/4	15 1/2

Model XG-6675 (10-6 & 12-6)								
S=3/4"	Number Of Slots							
Slot	1	2	3	4	5	6	7	8
A	1 9/16	3 1/16	4 9/16	6 1/16	7 9/16	9 1/16	10 9/16	12 1/16
D1	2	3 1/2	5	6 1/2	8	9 3/4	11	12 1/2
D2	2 1/2	4	5 1/2	7	8 1/2	10 1/4	11 1/2	13
W	3	4 1/2	6	7 1/2	9	10 1/2	12	13 1/2

Model XG-6615 (10-6 & 12-6)								
S=1 1/2"	Number Of Slots							
Slot	1	2	3	4	5	6	7	8
A	2 5/16	4 9/16	6 13/16	9 1/16	N/A	N/A	N/A	N/A
D1	2 3/4	5	7 1/4	9 1/2	N/A	N/A	N/A	N/A
D2	3 1/4	6	7 3/4	10	N/A	N/A	N/A	N/A
W	3 3/4	6	8 1/4	10 1/2	N/A	N/A	N/A	N/A

Notes: (check if provided)

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 20 White frame. Optional Finishes (additional charge) 21 Clear anodized Frame 28 Custom Color / Setup	XG-UP - Non-Insulated Boot Plenums XG-UPI - Insulated Boot Plenums		<input type="checkbox"/> Sizes available in only 1-8 slots. <input type="checkbox"/> Longest single section is 96" <input type="checkbox"/> Continuous lengths are made in sections.