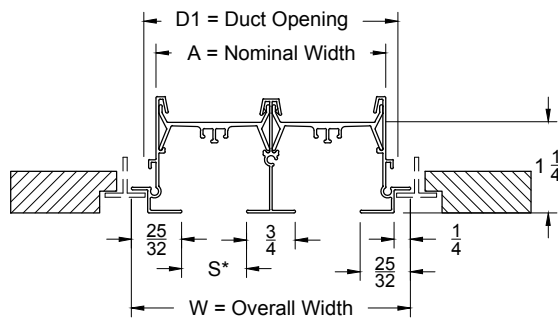
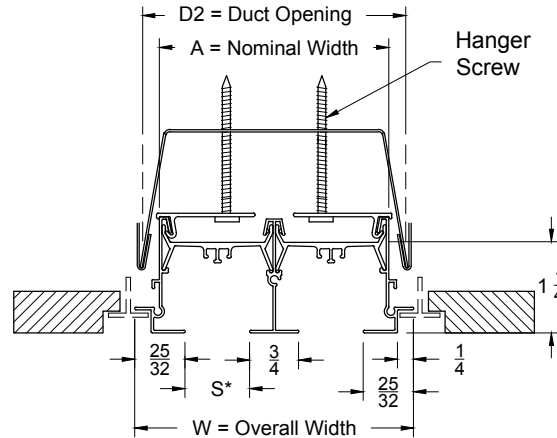
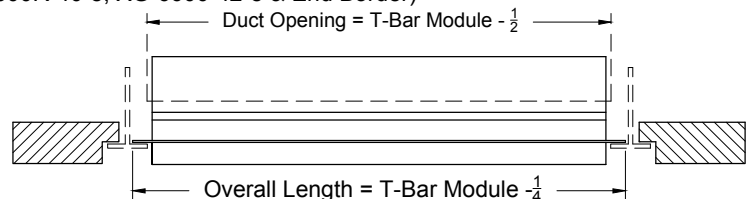
 


**Linear Slot Diffuser - Extruded Aluminum Return - No Pattern Controller**  
**Slots: 1/2" (XG-6650), 3/4" (XG-6675), 1" (XG-6610), and 1-1/2" (XG-6615)**

Models: **XG-6600R-40-8** Drop Face - No Hardware  
**XG-6600R-42-8** Drop Face - Concealed Mount With Hardware

**Model: XG-6600R-40-8**  
**(Drop Face - No Hardware)**

**Model: XG-6600R-42-8**  
**(Drop Face - With Concealed Mounting Hardware)**


Side View (XG-6600R-40-8, XG-6600-42-8 &amp; End Border)

**End Border**


\* For Slot Sizes Available See Tables

Model XG-6650 (40-8 & 42-8)									
S=1/2"	Number Of Slots								
Slot	1	2	3	4	5	6	7	8	10
A	1 5/16	2 9/16	3 13/16	5 1/16	6 5/16	7 9/16	8 13/16	10 1/16	
D1	1 9/16	2 13/16	4 1/16	5 5/16	6 9/16	7 13/16	9 1/16	10 5/16	
D2	1 7/8	3 1/8	4 3/8	5 5/8	6 7/8	8 1/8	9 3/8	10 5/8	
W	2 1/16	3 5/16	4 9/16	5 13/16	7 1/16	8 5/16	9 9/16	10 13/16	

Model XG-6675 (40-8 & 42-8)									
S=3/4"	Number Of Slots								
Slot	1	2	3	4	5	6	7	8	10
A	1 9/16	3 1/16	4 9/16	6 1/16	7 9/16	9 1/16	10 9/16	12 1/16	
D1	1 13/16	3 5/16	4 13/16	6 5/16	7 13/16	9 5/16	10 13/16	12 5/16	
D2	2 1/8	3 5/8	5 1/8	6 5/8	8 1/8	9 5/8	11 1/8	12 5/8	
W	2 5/16	3 13/16	5 5/16	6 13/16	8 5/16	9 13/16	11 5/16	12 13/16	

Model XG-6610 (40-8 & 42-8)									
S=1"	Number Of Slots								
Slot	1	2	3	4	5	6	7	8	10
A	1 13/16	3 9/16	5 5/16	7 1/16	8 13/16	10 9/16	12 5/16	14 1/16	
D1	2 1/16	3 13/16	5 9/16	7 5/16	9 1/16	10 13/16	12 9/16	14 5/16	
D2	2 3/8	4 1/8	5 7/8	7 5/8	9 3/8	11 1/8	12 7/8	14 5/8	
W	2 9/16	4 5/16	6 1/16	7 13/16	9 9/16	11 5/16	13 1/16	14 13/16	

Model XG-6615 (40-8 & 42-8)									
S=1 1/2"	Number Of Slots								
Slot	1	2	3	4	5	6	7	8	10
A	2 5/16	4 9/16	6 13/16	9 1/16	N/A	N/A	N/A	N/A	
D1	2 9/16	4 13/16	7 1/16	9 5/16	N/A	N/A	N/A	N/A	
D2	2 7/8	5 1/8	7 3/8	9 5/8	N/A	N/A	N/A	N/A	
W	3 1/16	5 5/16	7 9/16	9 13/16	N/A	N/A	N/A	N/A	

 Notes:  (check if provided)

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
<b>Standard Finish:</b> 20 White frame. <b>Optional Finishes (additional charge)</b> 21 Clear anodized Frame 28 Custom Color / Setup Charge	<b>Boot Plenums Available</b> XG-UP - Non-Insulated Boot Plenums XG-UPI - Insulated Boot Plenums		<input type="checkbox"/> Sizes available in only 1-8 slots. <input type="checkbox"/> Longest single section is 96" <input type="checkbox"/> Continuous lengths are made in sections.