
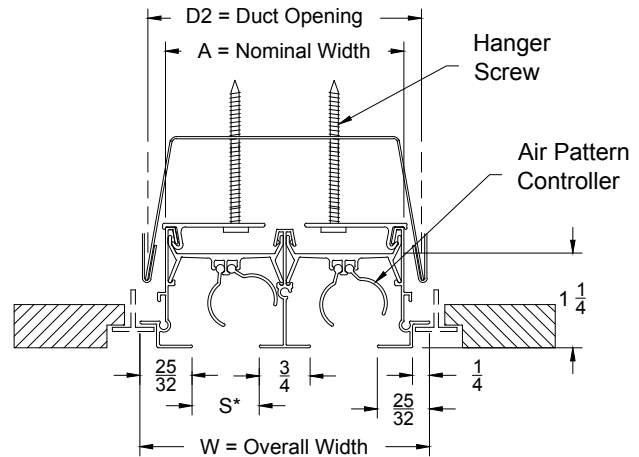


**Adjustable Linear Slot Diffuser -
Extruded Aluminum Pattern Controller**
Slots: 1/2" (6650), 3/4" (6675), 1" (6610), and 1-1/2" (6615)

Models: XG-6600-40-8 Drop Face - No Hardware
XG-6600-42-8 Drop Face - Concealed Mount With Hardware

 
Model: XG-6600-40-8
(Drop Face - No Hardware)

Model: XG-6600-42-8
(Drop Face - With Concealed Mounting Hardware)


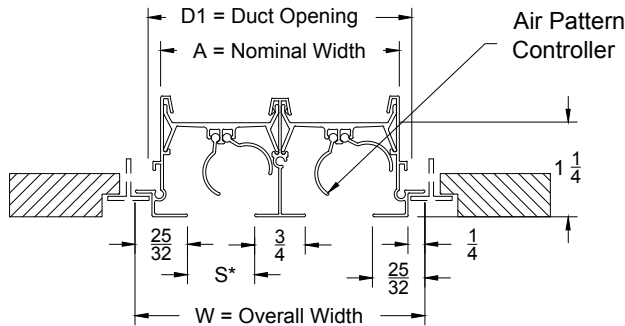


Side View (XG-6600-40-8, XG-6600-42-8 & End Border)

End Border



Air Deflection Patterns

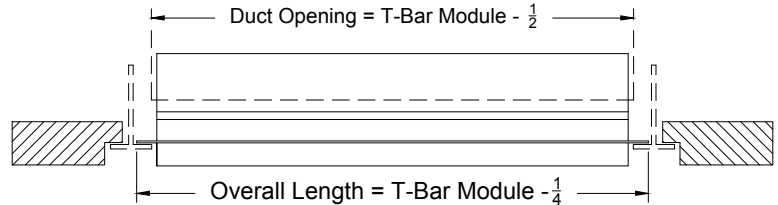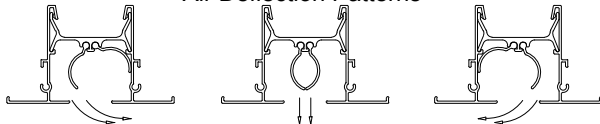

* For Slot Sizes Available See Tables

Model 6650 (40-8 & 42-8)								
S=1/2"	Number Of Slots							
Slot	1	2	3	4	5	6	7	8
A	1 5/16	2 9/16	3 13/16	5 1/16	6 5/16	7 9/16	8 13/16	10 1/16
D1	1 9/16	2 13/16	4 1/16	5 5/16	6 9/16	7 13/16	9 1/16	10 5/16
D2	1 7/8	3 1/8	4 3/8	5 5/8	6 7/8	8 1/8	9 3/8	10 5/8
W	2 1/16	3 5/16	4 9/16	5 13/16	7 1/16	8 5/16	9 9/16	10 13/16

Model 6675 (40-8 & 42-8)								
S=3/4"	Number Of Slots							
Slot	1	2	3	4	5	6	7	8
A	1 9/16	3 1/16	4 9/16	6 1/16	7 9/16	9 1/16	10 9/16	12 1/16
D1	1 13/16	3 5/16	4 13/16	6 5/16	7 13/16	9 5/16	10 13/16	12 5/16
D2	2 1/8	3 5/8	5 1/8	6 5/8	8 1/8	9 5/8	11 1/8	12 5/8
W	2 5/16	3 13/16	5 5/16	6 13/16	8 5/16	9 13/16	11 5/16	12 13/16

Model 6610 (40-8 & 42-8)								
S=1"	Number Of Slots							
Slot	1	2	3	4	5	6	7	8
A	1 13/16	3 9/16	5 5/16	7 1/16	8 13/16	10 9/16	12 5/16	14 1/16
D1	2 1/16	3 13/16	5 9/16	7 5/16	9 1/16	10 13/16	12 9/16	14 5/16
D2	2 3/8	4 1/8	5 7/8	7 5/8	9 3/8	11 1/8	12 7/8	14 5/8
W	2 9/16	4 5/16	6 1/16	7 13/16	9 9/16	11 5/16	13 1/16	14 13/16

Model 6615 (40-8 & 42-8)								
S=1 1/2"	Number Of Slots							
Slot	1	2	3	4	5	6	7	8
A	2 5/16	4 9/16	6 13/16	9 1/16	N/A	N/A	N/A	N/A
D1	2 9/16	4 13/16	7 1/16	9 5/16	N/A	N/A	N/A	N/A
D2	2 7/8	5 1/8	7 3/8	9 5/8	N/A	N/A	N/A	N/A
W	3 1/16	5 5/16	7 9/16	9 13/16	N/A	N/A	N/A	N/A

Notes: (check if provided)

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 20 White frame with black pattern controller. Optional Finishes (additional charge) 21 Clear anodized with black pattern controller 28 Custom Color / Setup Charge	Boot Plenums Available XG-UP - Non-Insulated Boot Plenums XG-UPI - Insulated Boot Plenums		<ul style="list-style-type: none"> Sizes available in only 1-8 slots. Longest single section is 96" Continuous lengths are made in sections.