


Model: XG-6675RTZ4-6      TechZone Border - 4" Width - Lay In T-Bar with No Hardware



### XG-6675RTZ4-6 - TechZone Lay In T-Bar

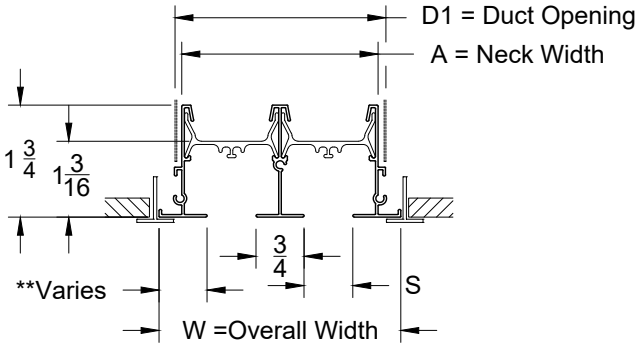


 
XG-6675RTZ4-6		
S=3/4"	Number of Slots	
Slot	1	2
A	1 $\frac{9}{16}$	3 $\frac{1}{16}$
D1	2	3 $\frac{1}{2}$
W	3 $\frac{3}{4}$	3 $\frac{3}{4}$

\*\* Side Frame Varies per Slots required.  
\* For Number of Slot Available See Table

#### Option: End Border

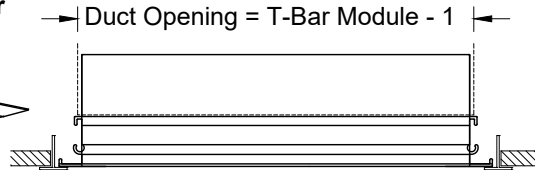

#### Option: End Cap

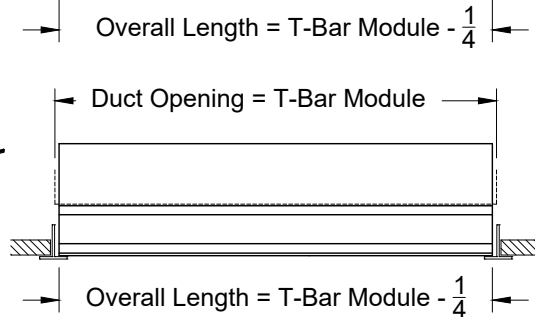 

#### 1. Available Finishes

Standard Finish:  
20 - White Face, Black Back  
02 - Satin Silver  
03 - Black  
Optional Finish:  
28 - Special/Setup Charge

#### 2. Available Accessories

#### 3. Available Options

1EC - (1) End Cap  
2EC - (2) End Caps  
1EB - (1) End Border  
2EB - (2) End Borders  
OO - Open / Open


#### 4. Construction Details

- Longest single section is 96"
- Continuous lengths are made in sections
- Extruded Aluminum

All Dimensions  $\pm 1/16"$

Model: XG-6675RTZ4-9      TechZone Border - 4" Width - Bolt Slot with No Hardware



### XG-6675RTZ4-9 - TechZone Bolt Slot

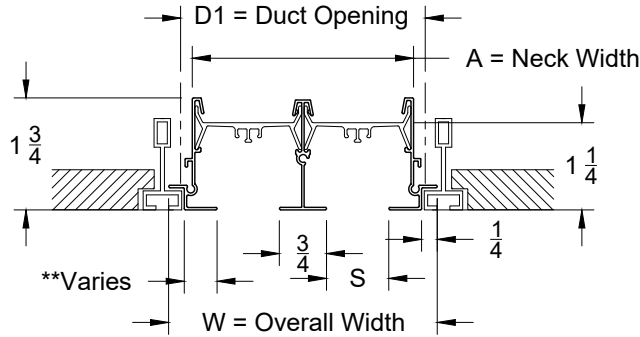



XG-6675RTZ4-9		
S=3/4"	Number of Slots	
Slot	1	2
A	1 9/16	3 1/16
D1	2	3 1/2
W	3 3/4	3 3/4

\*\* Side Frame Varies per Slots required.  
\* For Number of Slot Available See Table

#### Option: End Border

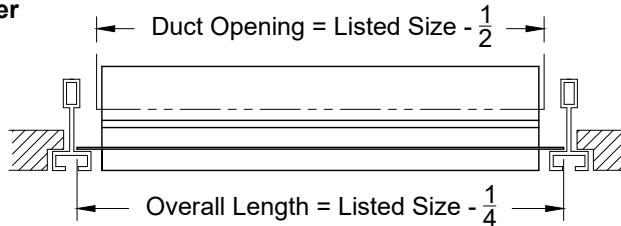 

#### Option: End Cap

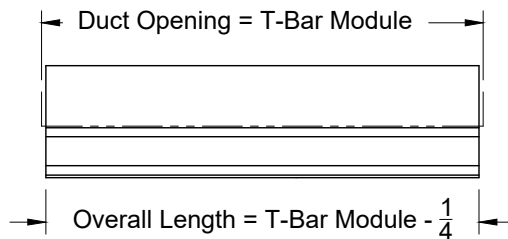 

#### 1. Available Finishes

Standard Finish:  
20 - White Face, Black Back  
02 - Satin Silver  
03 - Black  
Optional Finish:  
28 - Special/Setup Charge

#### 2. Available Accessories

#### 3. Available Options

1EC - (1) End Cap  
2EC - (2) End Caps  
1EB - (1) End Border  
2EB - (2) End Borders  
OO - Open / Open


#### 4. Construction Details

- Longest single section is 96"
- Continuous lengths are made in sections
- Extruded Aluminum

All Dimensions ±1/16"

Model: XG-6675RTZ4-NT TechZone Border - 4" Width - Narrow Tee with No Hardware



### XG-6675RTZ4-NT - TechZone Narrow Tee

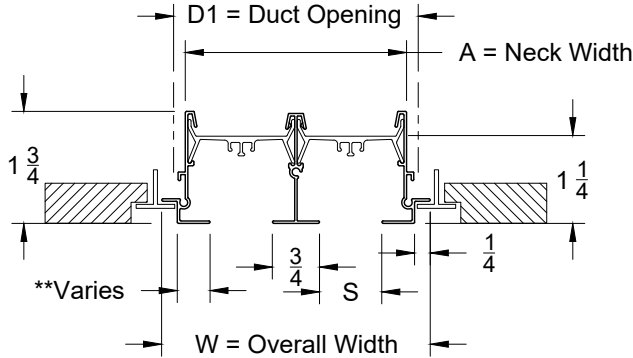



XG-6675RTZ4-NT		
S=3/4"	Number of Slots	
Slot	1	2
A	1 9/16	3 1/16
D1	2	3 1/2
W	3 3/4	3 3/4

\*\* Side Frame Varies per Slots required.  
\* For Number of Slot Available See Table

#### Option: End Border

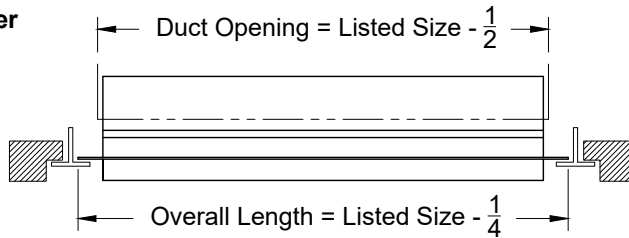 

#### Option: End Cap

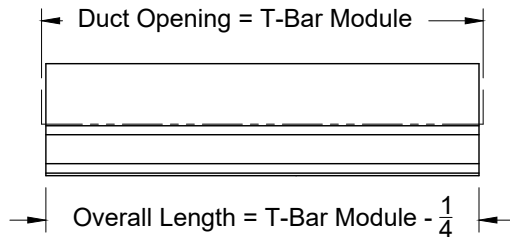 

#### 1. Available Finishes

Standard Finish:  
20 - White Face, Black Back  
02 - Satin Silver  
03 - Black  
Optional Finish:  
28 - Special/Setup Charge

#### 2. Available Accessories

#### 3. Available Options

1EC - (1) End Cap  
2EC - (2) End Caps  
1EB - (1) End Border  
2EB - (2) End Borders  
OO - Open / Open


#### 4. Construction Details

- Longest single section is 96"
- Continuous lengths are made in sections
- Extruded Aluminum

All Dimensions ±1/16"

Model: XG-6675RTZ6-6      TechZone Border - 6" Width - Lay In T-Bar with No Hardware



### XG-6675RTZ6-6 - TechZone Lay-In T-Bar

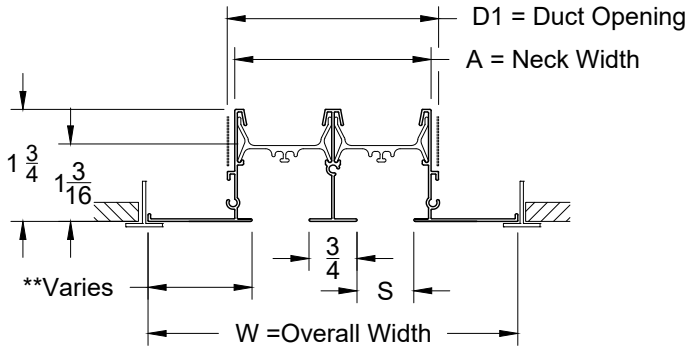



XG-6675RTZ6-6				
S=3/4"	Number of Slots			
Slot	1	2	3	4
A	1 9/16	3 1/16	4 9/16	5 9/16
D1	2	3 1/2	5	6
W	5 3/4	5 3/4	5 3/4	5 3/4

\* For Number of Slot Available See Table  
\*\* Side Frame Varies per Slots required.

#### Option: End Border

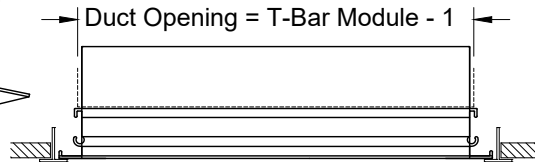 

#### Option: End Cap

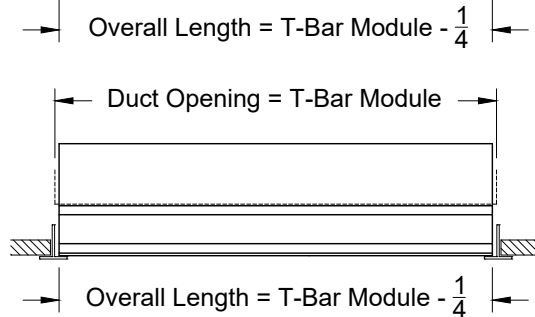 

#### 1. Available Finishes

Standard Finish:  
20 - White Face, Black Back  
02 - Satin Silver  
03 - Black  
Optional Finish:  
28 - Special/Setup Charge

#### 2. Available Accessories

#### 3. Available Options

1EC - (1) End Cap  
2EC - (2) End Caps  
1EB - (1) End Border  
2EB - (2) End Borders  
OO - Open / Open


#### 4. Construction Details

- Longest single section is 96"
- Continuous lengths are made in sections
- Extruded Aluminum

All Dimensions ±1/16"

Model: XG-6675RTZ6-9      TechZone Border - 6" Width - Bolt Slot with No Hardware


### XG-6675RTZ6-9 - TechZone Bolt Slot

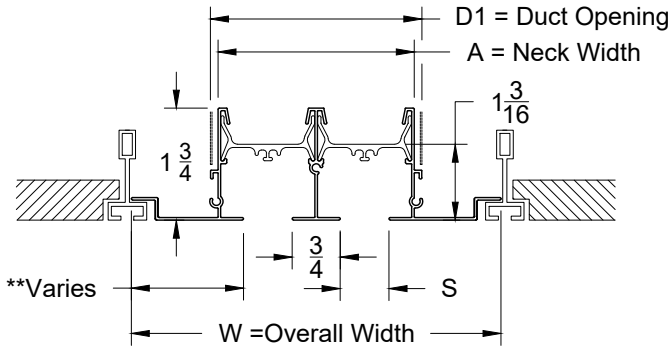


XG-6675RTZ6-9			
S=3/4"	Number of Slots		
Slot	1	2	3
A	1 9/16	3 1/16	4 9/16
D1	2	3 1/2	5
W	5 3/4	5 3/4	5 3/4

\* For Number of Slot Available See Table  
 \*\* Side Frame Varies per Slots required.

#### Option: End Border

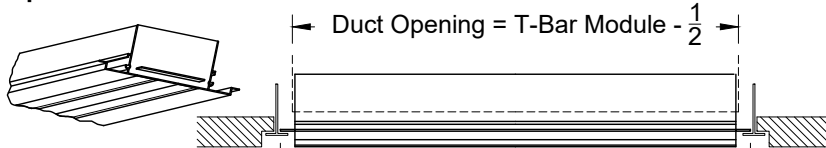

#### Option: End Cap

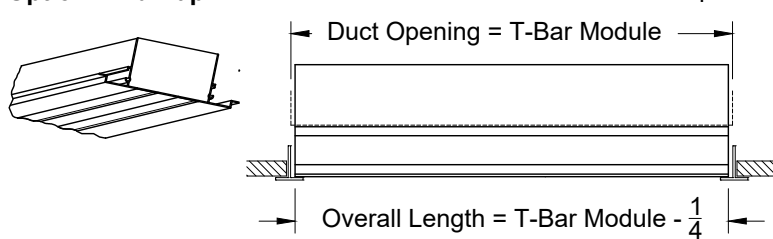


1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 20 - White Face, Black Back 02 - Satin Silver 03 - Black Optional Finish: 28 - Special/Setup Charge		1EC - (1) End Cap 2EC - (2) End Caps 1EB - (1) End Border 2EB - (2) End Borders OO - Open / Open	<ul style="list-style-type: none"> <li>Longest single section is 96"</li> <li>Continuous lengths are made in sections</li> <li>Extruded Aluminum</li> </ul>

All Dimensions ±1/16"

Model: XG-6675RTZ6-NT TechZone Border - 6" Width - Narrow Tee with No Hardware


### XG-6675RTZ6-NT - TechZone Narrow Tee

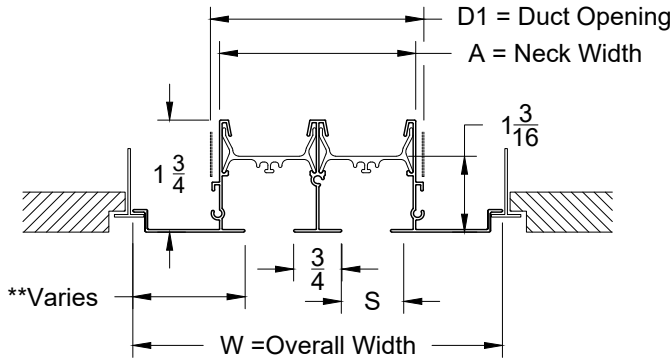


XG-6675RTZ6-NT			
S=3/4"	Number of Slots		
Slot	1	2	3
A	1 9/16	3 1/16	4 9/16
D1	2	3 1/2	5
W	5 3/4	5 3/4	5 3/4

\* For Number of Slot Available See Table  
\*\* Side Frame Varies per Slots required.

#### Option: End Border

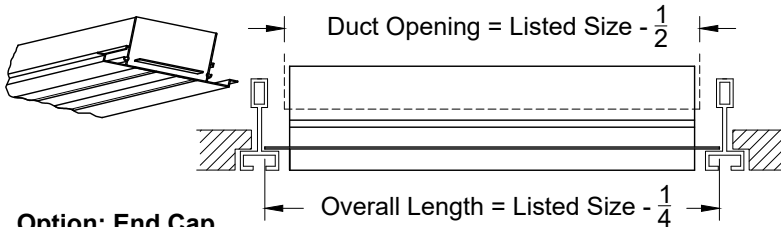

#### Option: End Cap

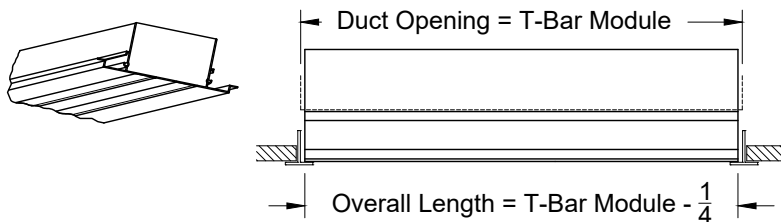

#### 1. Available Finishes

Standard Finish:  
20 - White Face, Black Back  
02 - Satin Silver  
03 - Black  
Optional Finish:  
28 - Special/Setup Charge

#### 2. Available Accessories

#### 3. Available Options

1EC - (1) End Cap  
2EC - (2) End Caps  
1EB - (1) End Border  
2EB - (2) End Borders  
OO - Open / Open

#### 4. Construction Details

- Longest single section is 96"
- Continuous lengths are made in sections
- Extruded Aluminum

All Dimensions  $\pm 1/16"$