


**Return - Linear Slot Diffuser - Extruded Aluminum**


Models: **XG-6675RTZ6-6** Lay-In - Return  
**XG-6675RTZ4-6** Lay-in - Return

**Model: XG-6675RTZ6-6 Lay-In (Return)**



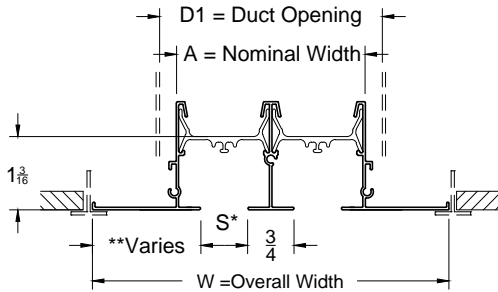


\* For Number of Slot Available See Table  
 \*\* Side Frame Varies per Slots required.

**Model: XG-6675RTZ4-6 Lay-In (Return)**

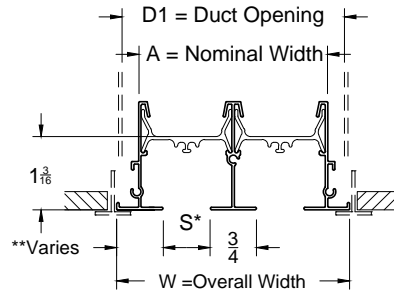

\* For Number of Slot Available See Table  
 \*\* Side Frame Varies per Slots required.

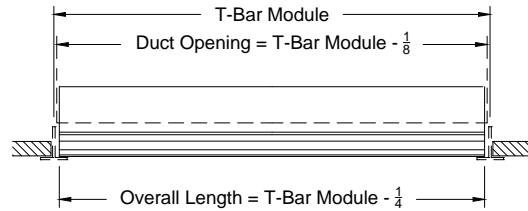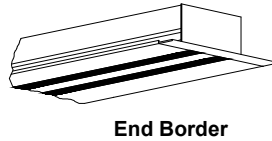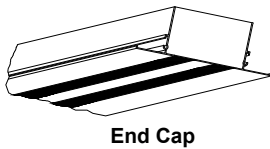

Model XG-6675RTZ6-6				
S=3/4"	Number Of Slots			
Slot	1	2	3	4
A	1 9/16	3 1/16	4 9/16	5 9/16
D1	2	3 1/2	5	6
W	5 3/4	5 3/4	5 3/4	5 3/4

Model XG-6675TZ4-6		
S=3/4"	Number Of Slots	
Slot	1	2
A	1 9/16	3 1/16
D1	2	3 1/2
W	3 3/4	3 3/4


Notes:  (check if provided)

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
<b>Standard Finish:</b> 20 White frame with. <b>Optional Finishes (additional charge)</b> 21 Clear anodized Rails (For Clear anodized, check with Sales dept. for availability) 28 Custom Color / Setup Charge	<b>Boot Plenums Available</b> XG-UP - Non-Insulated Boot Plenums XG- - Insulated Boot Plenums		<ul style="list-style-type: none"> <li>Sizes available 6675TZ4-6 in 1-2 slots and 6675TZ6-6 in 1-4 slots</li> <li>Longest single section is 96"</li> <li>Continuous lengths are made in sections.</li> </ul>

### Return - Linear Slot Diffuser - Extruded Aluminum


Models: **XG-6675RTZ6-9** Donn Fine Line - Return  
**XG-6675TRZ4-9** Donn Fine Line - Return

**Model: XG-6675RTZ6-9 Donn Fine Line (Return)**

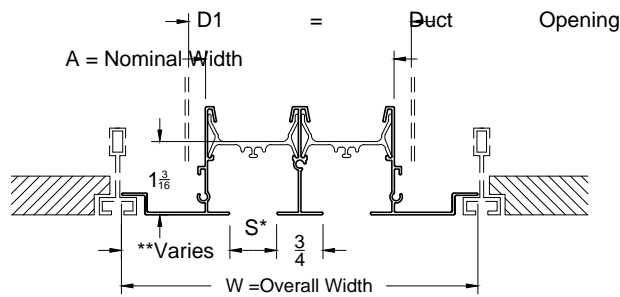


\* For Number of Slot Available See Table  
 \*\* Side Frame Varies per Slots required.


**Model: XG-6675RTZ4-9 Donn Fine Line (Return)**

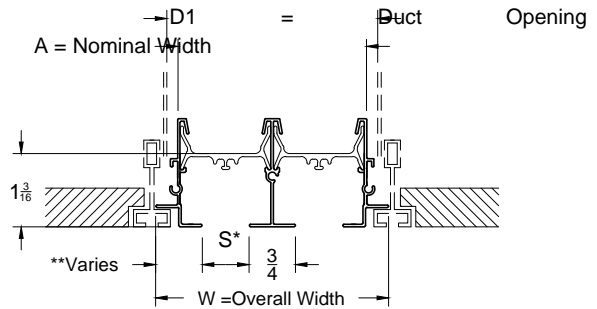

 \* For Number of Slot Available See Table  
 \*\* Side Frame Varies per Slots required.



**End Border**

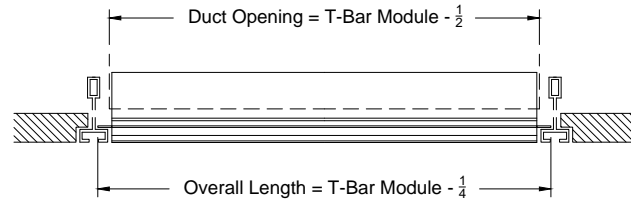

Model XG-6675RTZ6-9			
S=3/4"	Number Of Slots		
Slot	1	2	3
A	1 9/16	3 1/16	4 9/16
D1	2	3 1/2	5
W	5 3/4	5 3/4	5 3/4

Model XG-6675TZ4-9		
S=3/4"	Number Of Slots	
Slot	1	2
A	1 9/16	3 1/16
D1	2	3 1/2
W	3 3/4	3 3/4


Notes:  (check if provided)

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
<b>Standard Finish:</b> 20 White frame <b>Optional Finishes (additional charge)</b> 21 Clear anodized Rails (For Clear anodized, check with Sales dept. for availability) 28 Custom Color / Setup Charge	<b>Boot Plenums Available</b> XG-UP - Non-Insulated Boot Plenums XG-UPI - Insulated Boot Plenums		<ul style="list-style-type: none"> <li>Sizes available in only 1-3 slots.</li> <li>Longest single section is 96"</li> <li>Continuous lengths are made in sections.</li> </ul>

**Return - Linear Slot Diffuser - Extruded Aluminum**


Models: **XG-6675RTZ6-NT** Narrow Tee - Return  
**XG-6675RTZ4-NT** Narrow Tee - Return

**Model: XG-6675RTZ6-NT Narrow Tee (Return)**

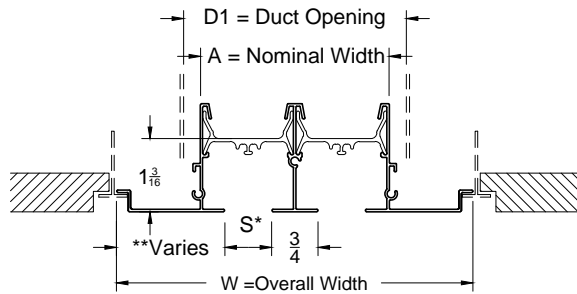


\* For Number of Slot Available See Table  
 \*\* Side Frame Varies per Slots required.


**Model: XG-6675RTZ4-NT Narrow Tee (Return)**

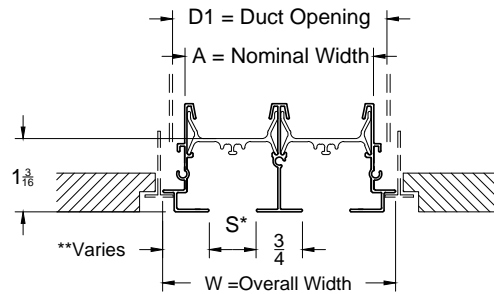

 \* For Number of Slot Available See Table  
 \*\* Side Frame Varies per Slots required.



**End Border**

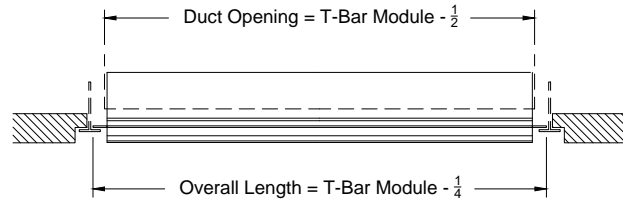

Model XG-675RTZ6-NT			
S=3/4"	Number Of Slots		
Slot	1	2	3
A	1 9/16	3 1/16	4 9/16
D1	2	3 1/2	5
W	5 3/4	5 3/4	5 3/4

Model XG-6675RTZ4-NT		
S=3/4"	Number Of Slots	
Slot	1	2
A	1 9/16	3 1/16
D1	2	3 1/2
W	3 3/4	3 3/4

Notes:  (check if provided)

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
<b>Standard Finish:</b> 20 White frame <b>Optional Finishes (additional charge)</b> 21 Clear anodized Rails (For Clear anodized, check with Sales dept. for availability) 28 Custom Color / Setup Charge	<b>Boot Plenums Available</b> XG-UP - Non-Insulated Boot Plenums XG-uPI - Insulated Boot Plenums		<ul style="list-style-type: none"> <li>Sizes available in only 1-3 slots.</li> <li>Longest single section is 96"</li> <li>Continuous lengths are made in sections.</li> </ul>