


Adjustable Linear Slot Diffuser - Extruded Aluminum Pattern Controller / Damper


Models: **XG-6675TZ6-6** Lay-In
XG-6675TZ4-6 Lay-in

Model: XG-6675TZ6-6 Lay-In

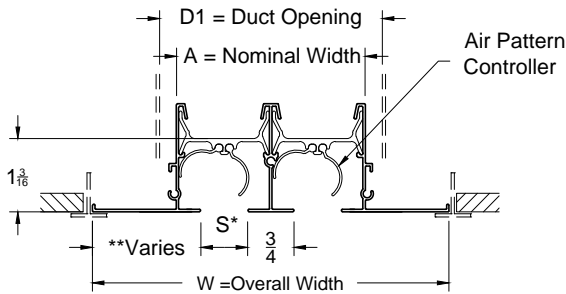


* For Number of Slot Available See Table.
** Side Frame Varies per Slots required.

Model: XG-6675TZ4-6 Lay-In


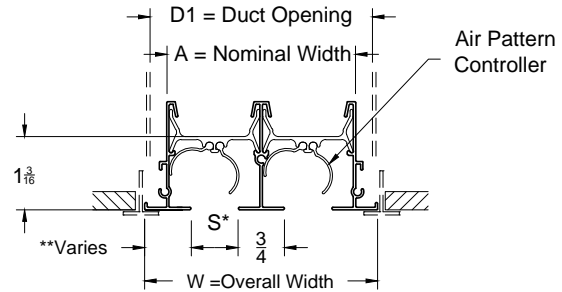


 * For Number of Slot Available See Table
** Side Frame Varies per Slots required.



End Cap

End Border

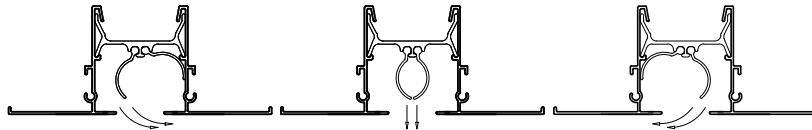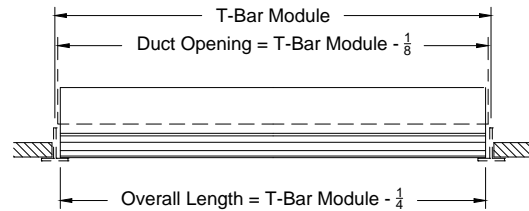

Air Deflection Patterns

Model XG-6675TZ6-6				
S=3/4"	Number Of Slots			
Slot	1	2	3	4
A	1 9/16	3 1/16	4 9/16	5 9/16
D1	2	3 1/2	5	6
W	5 3/4	5 3/4	5 3/4	5 3/4

Model XG-6675TZ4-6		
S=3/4"	Number Of Slots	
Slot	1	2
A	1 9/16	3 1/16
D1	2	3 1/2
W	3 3/4	3 3/4


Notes: (check if provided)

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 20 White frame with black pattern controller. Optional Finishes (additional charge) 21 Clear anodized Rails with black pattern controller (For Clear anodized, check with Sales dept. for availability) 28 Custom Color / Setup Charge	Boot Plenums Available XG-UP - Non-Insulated Boot Plenums XG-UPI - Insulated Boot Plenums		<ul style="list-style-type: none"> Sizes available 6675TZ4-6 in 1-2 slots and 6675TZ6-6 in 1-4 slots Longest single section is 96" Continuous lengths are made in sections.

**Adjustable Linear Slot Diffuser - Extruded Aluminum
Pattern Controller / Damper**


Models: **XG-6675TZ6-9** Donn Fine Line
XG-6675TZ4-9 Donn Fine Line

Model: XG-6675TZ6-9 Donn Fine Line

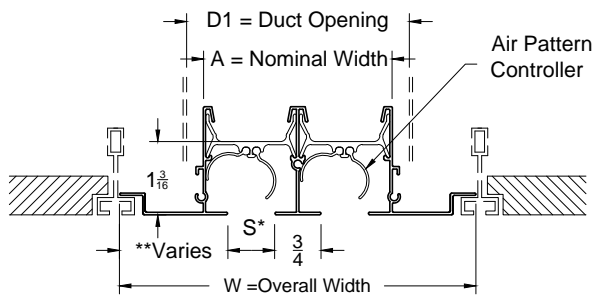


* For Number of Slot Available See Table
** Side Frame Varies per Slots required.



Model: XG-6675TZ4-9 Donn Fine Line

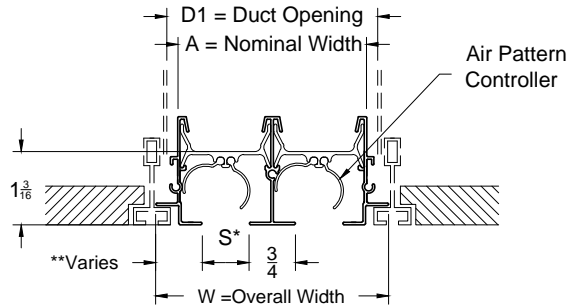

 * For Number of Slot Available See Table
** Side Frame Varies per Slots required.



End Border

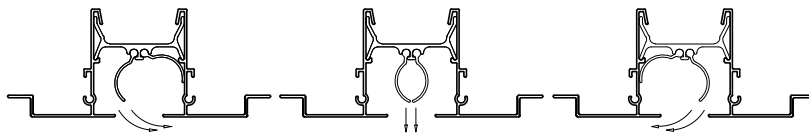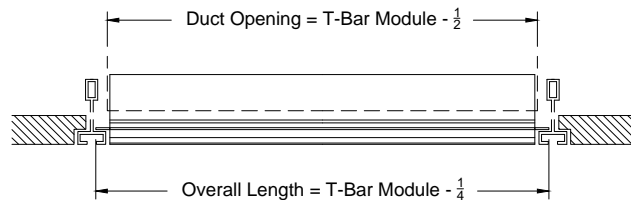

Air Deflection Patterns

Model XG-6675TZ6-9			
S=3/4"	Number Of Slots		
Slot	1	2	3
A	1 9/16	3 1/16	4 9/16
D1	2	3 1/2	5
W	5 3/4	5 3/4	5 3/4

Model XG-6675TZ4-9		
S=3/4"	Number Of Slots	
Slot	1	2
A	1 9/16	3 1/16
D1	2	3 1/2
W	3 3/4	3 3/4


Notes: (check if provided)

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 20 White frame with black pattern controller. Optional Finishes (additional charge) 21 Clear anodized Rails with black pattern controller (For Clear anodized, check with Sales dept. for availability) 28 Custom Color / Setup Charge	Boot Plenums Available XG-UP - Non-Insulated Boot Plenums XG-UPI - Insulated Boot Plenums		<ul style="list-style-type: none"> Sizes available in only 1-3 slots. Longest single section is 96" Continuous lengths are made in sections.

**Adjustable Linear Slot Diffuser - Extruded Aluminum
Pattern Controller / Damper**


Models: **XG-6675TZ6-NT** Narrow Tee
XG-6675TZ4-NT Narrow Tee

Model: XG-6675TZ6-NT Narrow Tee

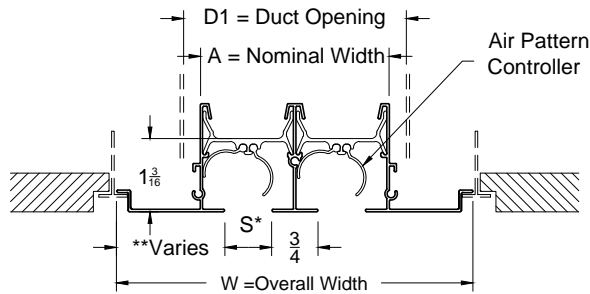


* For Number of Slot Available See Table
** Side Frame Varies per Slots required.



Model: XG-6675TZ4-NT Narrow Tee

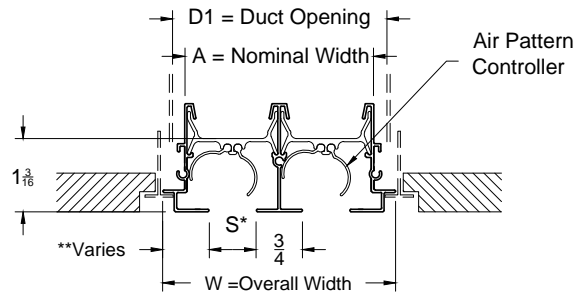

 * For Number of Slot Available See Table
** Side Frame Varies per Slots required.



End Border

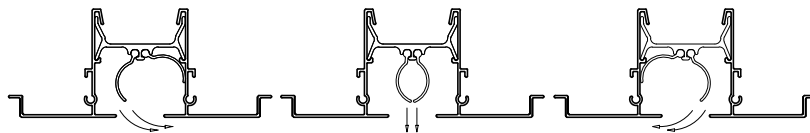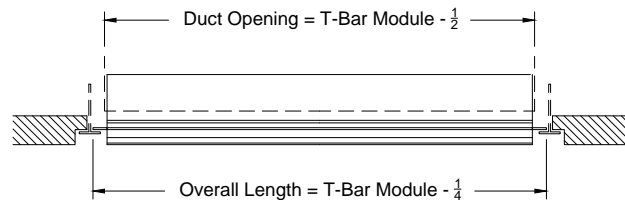

Air Deflection Patterns

Model XG-6675TZ6-NT			
S=3/4"	Number Of Slots		
Slot	1	2	3
A	1 9/16	3 1/16	4 9/16
D1	2	3 1/2	5
W	5 3/4	5 3/4	5 3/4

Model XG-6675TZ4-NT		
S=3/4"	Number Of Slots	
Slot	1	2
A	1 9/16	3 1/16
D1	2	3 1/2
W	3 3/4	3 3/4

Notes: (check if provided)

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 20 White frame with black pattern controller. Optional Finishes (additional charge) 21 Clear anodized Rails with black pattern controller (For Clear anodized, check with Sales dept. for availability) 28 Custom Color / Setup Charge	Boot Plenums Available XG-UP - Non-Insulated Boot Plenums XG-UPI - Insulated Boot Plenums		<ul style="list-style-type: none"> Sizes available in only 1-3 slots. Longest single section is 96" Continuous lengths are made in sections.