


XG-AFLIH High Capacity Return Models

Models: **XG-AFLIH-10** 1" Slot
XG-AFLIH-15 1 1/2" Slot
XG-AFLIH-20 2" Slot

Model: XG-AFLIH-10, 15, 20 - High Capacity Return

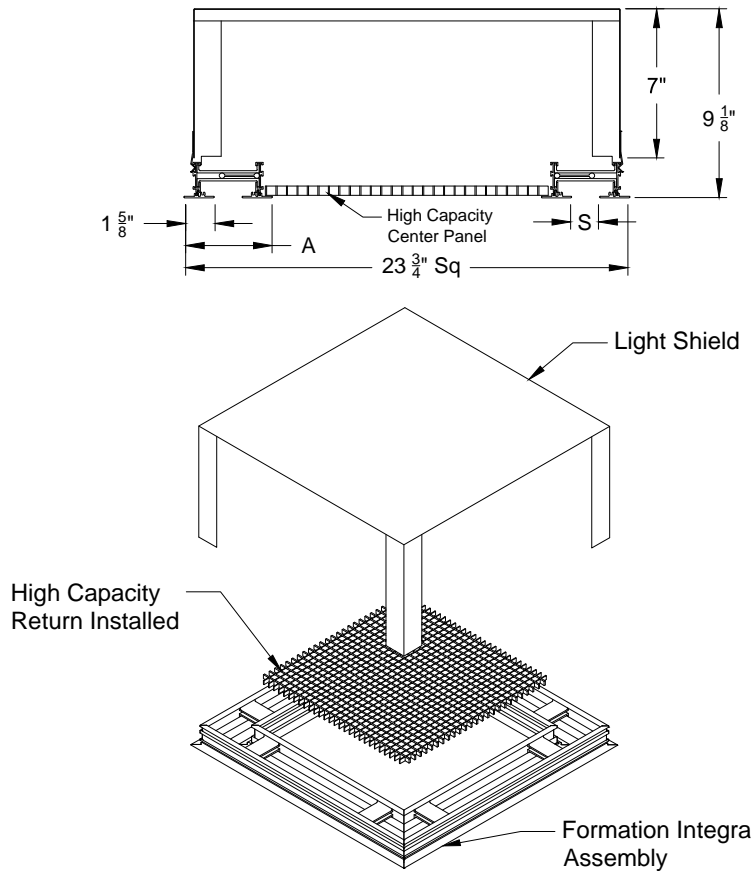

Integra Return High Capacity

Models	S Slot Width	# of Slots	"A" Face Width	Center Panel	Standard available inlets Round
XG-AFLIH - 10	1	1	4-1/4	17-1/8	6, 8, 10, 12
XG-AFLIH - 15	1-1/2	1	4-3/4	16-1/8	6, 8, 10, 12
XG-AFLIH - 20	2	1	5-1/4	15-1/8	6, 8, 10, 12

Notes: (check if provided)

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish 20 White Face with Black Frame.	15/16" & 9/16" Tee System, 9/16" Bolt Slot Tee System, Hard Ceiling.		<ul style="list-style-type: none"> Insulated units have 1/2" insulation. Center Ceiling Tile supplied by others, field installed. Return units are non-ducted, with light shields.