



**Architectural Formation Linear  
Accessories Mitered Corner 90**


Model:	<b>XG-AFLMC- 10 90</b> 1" Slot	<b>XG-AFLMCC-10 90</b> 1" Slot	<b>Concealed Mount</b>
	<b>XG-AFLMC- 15 90</b> 1 1/2" Slot	<b>XG-AFLMCC-15 90</b> 1 1/2" Slot	<b>Concealed Mount</b>
	<b>XG-AFLMC- 20 90</b> 2" Slot	<b>XG-AFLMCC-20 90</b> 2" Slot	<b>Concealed Mount</b>
	<b>XG-AFLMC- 25 90</b> 2 1/2" Slot	<b>XG-AFLMCC-25 90</b> 2 1/2" Slot	<b>Concealed Mount</b>
	<b>XG-AFLMC- 30 90</b> 3" Slot	<b>XG-AFLMCC-30 90</b> 3" Slot	<b>Concealed Mount</b>

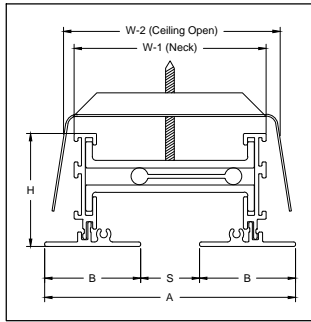


**1 Slot  
XG-AFLMCC**

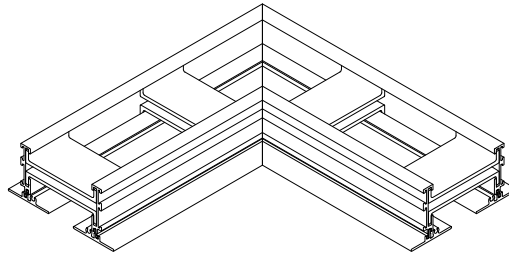


**Mitered Corner 90°  
1 Slot**

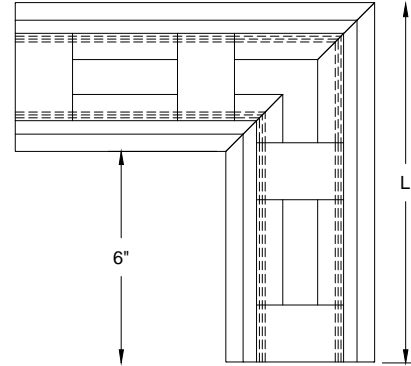


**Mitered Corner 90° - Top View**

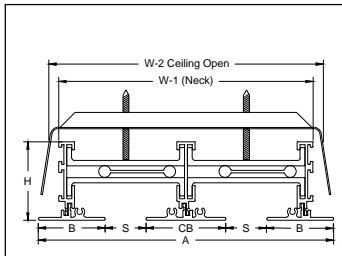

**2 Slot  
XG-AFLMCC**

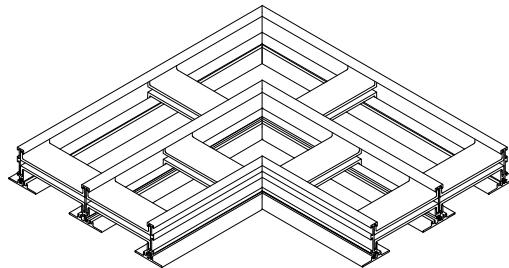

**Mitered Corner 90°  
2 Slot**

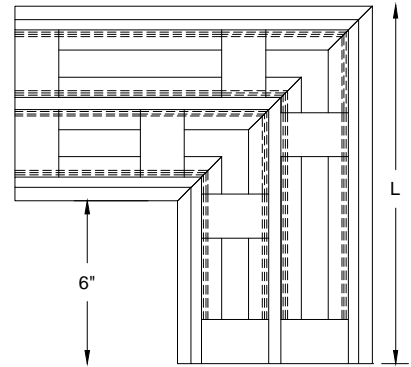

**Mitered Corner 90° - Top View**

Model: AFLMC/ AFLMCC 90 DEGREE									
Number of Slots	# of Slots	S	B	L	H	A	W-1	W-2 Ceiling Opening	
XG-AFLMC/AFLMCC-10-90	<b>1</b>	1	1 5/8	10 1/4	1 15/16	4 1/4	3 1/4	4	
XG-AFLMC/AFLMCC-15-90		1 1/2	1 5/8	10 3/4	1 15/16	4 3/4	3 3/4	4 1/2	
XG-AFLMC/AFLMCC-20-90		2	1 5/8	11 1/4	1 15/16	5 1/4	4 1/4	5	
XG-AFLMC/AFLMCC-25-90		2 1/2	2 1/8	12 3/4	2 9/16	6 3/4	5 3/4	6 1/2	
XG-AFLMC/AFLMCC-30-90		3	2 1/8	13 1/4	2 9/16	7 1/4	6 1/4	7	
Number of Slots	# of Slots	S	B	L	H	A	W-1	W-2 Ceiling Opening	CB
XG-AFLMC/AFLMCC-10-90	<b>2</b>	1	1 5/8	13 1/8	1 15/16	7 3/16	6 3/16	6 15/16	1 15/16
XG-AFLMC/AFLMCC-15-90		1 1/2	1 5/8	14 1/8	1 15/16	8 3/16	7 3/16	7 15/16	1 15/16
XG-AFLMC/AFLMCC-20-90		2	1 5/8	15 1/8	1 15/16	9 3/16	8 3/16	8 15/16	1 15/16
XG-AFLMC/AFLMCC-25-90		2 1/2	2 1/8	18 1/8	2 9/16	12 3/16	11 3/16	11 15/16	2 15/16
XG-AFLMC/AFLMCC-30-90		3	2 1/8	19 1/8	2 9/16	13 3/16	12 3/16	12 15/16	2 15/16

Notes:  (check if provided)

W-2 Ceiling opening dimension is used for concealed mount models only.  
For non-concealed mount models, please add 1/2" to the length and the width dimensions.