



Model: XG-DD-RD-90 Quarter Round - 90° Airflow - Surface Mount

XG-DD-RD-90 - Surface Mount

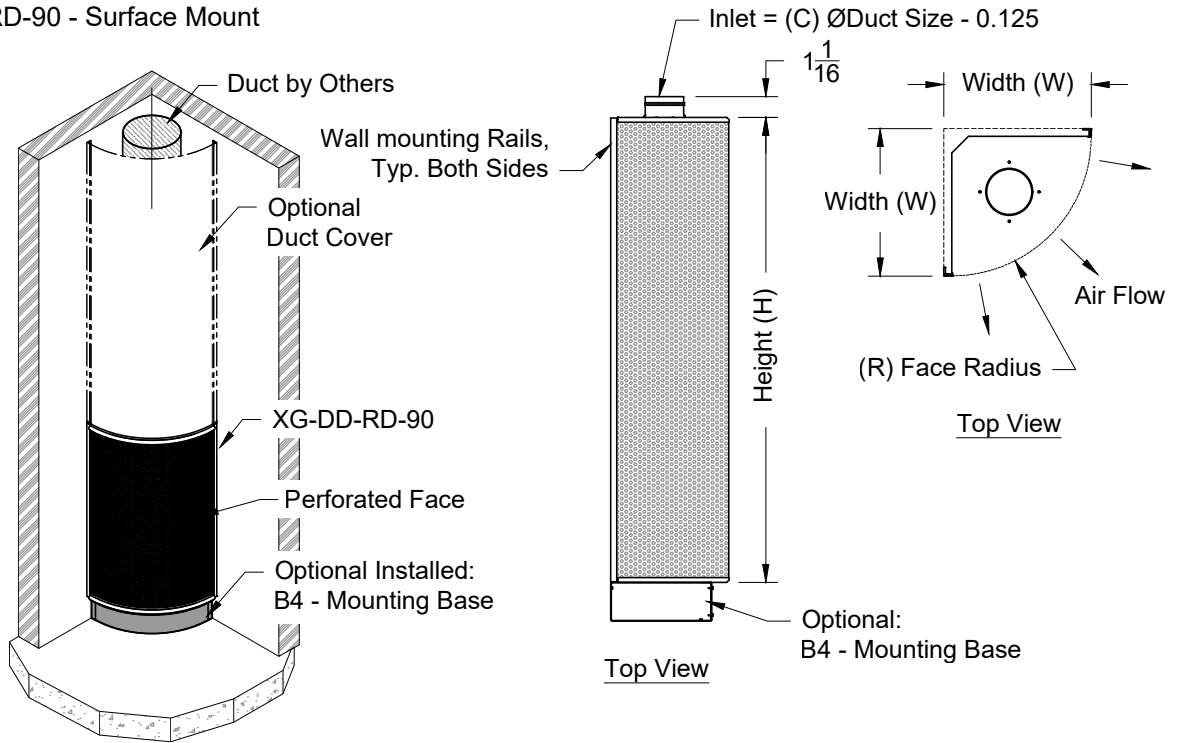

3D Installation View

Size (RxH)	R	W	H	C (Inlet Option)
12 x 24	12	12 3/4	24	4, 6, 8
12 x 30	12	12 3/4	30	4, 6, 8
12 x 36	12	12 3/4	36	4, 6, 8
12 x 48	12	12 3/4	48	4, 6, 8
15 x 24	15	15 3/4	24	6, 8, 10
15 x 30	15	15 3/4	30	6, 8, 10
15 x 36	15	15 3/4	36	6, 8, 10
15 x 48	15	15 3/4	48	6, 8, 10
18 x 24	18	18 3/4	24	6, 8, 10, 12
18 x 30	18	18 3/4	30	6, 8, 10, 12
18 x 36	18	18 3/4	36	6, 8, 10, 12
18 x 48	18	18 3/4	48	6, 8, 10, 12
24 x 24	24	24 3/4	24	8, 10, 12, 14
24 x 30	24	24 3/4	30	8, 10, 12, 14
24 x 36	24	24 3/4	36	8, 10, 12, 15
24 x 48	24	24 3/4	48	8, 10, 12, 15

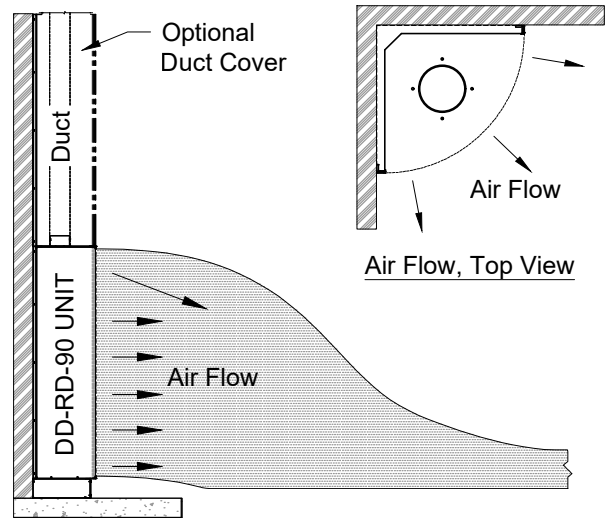

Air Flow, Top View

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish 02 Satin Silver 03 Black 28 Custom Color		B4 - Mounting Base	<ul style="list-style-type: none"> 23% Perforated Face .050" Aluminum 24ga. Steel Construction Duct covers for displacement diffusers have a max single section height of 48" Taller units will be made in multiple sections for structural rigidity

All Dimensions ±1/16"