


Model: XG-DD-REC-1W Rectangular - 1 Way Airflow


XG-DD-REC-1-WAY - Surface Mount

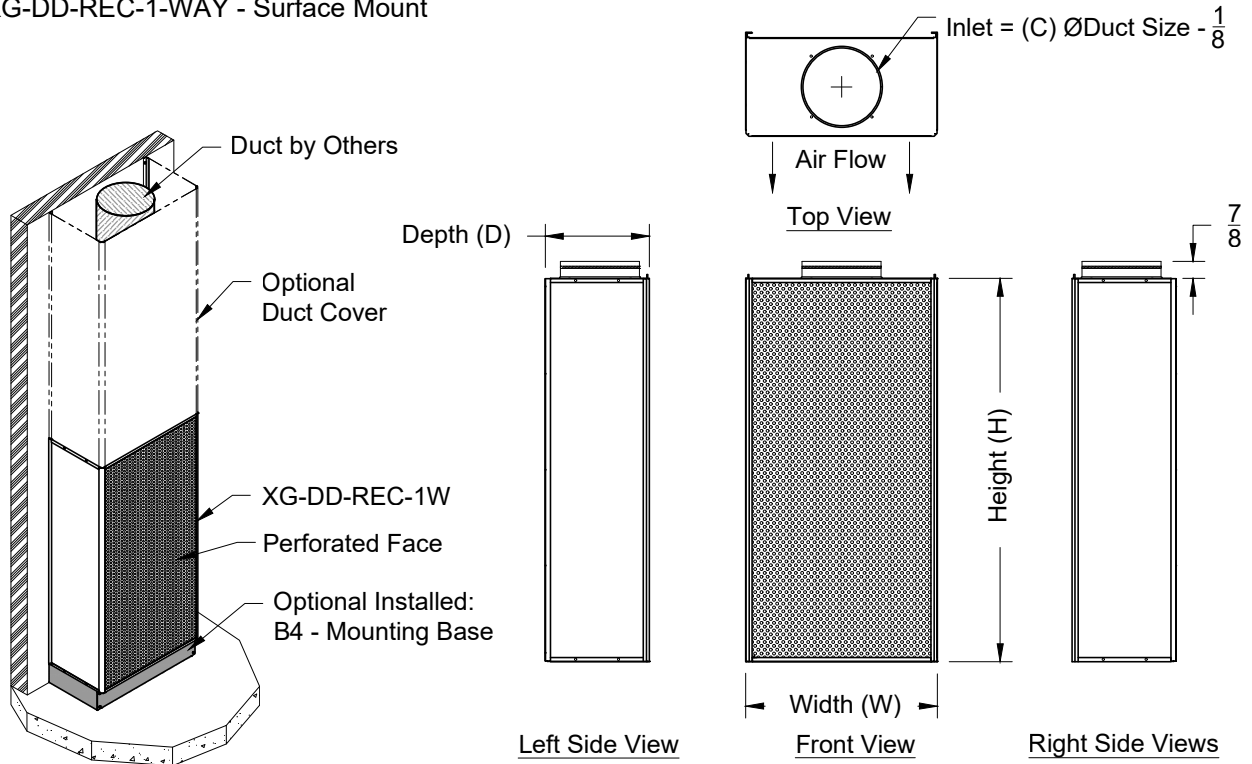

3D Installation View

C (Inlet Options)	
Round	Rectangular
6	8 x 8
7	10 x 8
8	12 x 8
10	20 x 8
12	-
14	-

Unit Sizes				
Size	W	H	D	
12 x 24 x 13	12	40	13	
12 x 36 x 13	12	36	13	
12 x 48 x 13	12	48	13	
12 x 60 x 13	12	60	13	
24 x 36 x 13	24	36	13	
24 x 48 x 13	24	48	13	
24 x 60 x 13	24	60	13	
36 x 48 x 16	36	48	16	
36 x 60 x 16	36	60	16	
48 x 60 x 16	48	60	16	

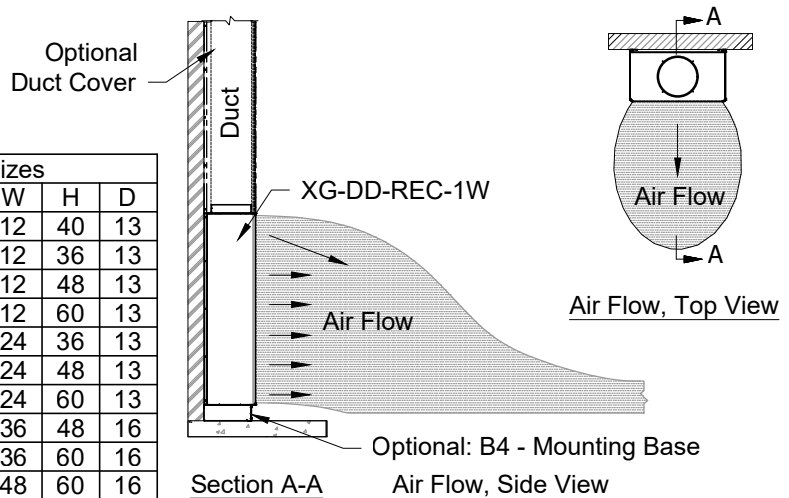


1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish 02 Satin Silver 03 Black 28 Custom Color		B4 - Mounting Base IB - Internal Perforated Baffle	<ul style="list-style-type: none"> • 23% Perforated Face .050" Aluminum • 24ga. Steel Construction • Duct covers for displacement diffusers have a max single section height of 48" • Taller units will be made in multiple sections for structural rigidity

All Dimensions ±1/16"


Model: XG-DD-REC-2L Rectangular - 2 Way Airflow Left - Surface Mount

XG-DD-REC-2L - Surface Mount

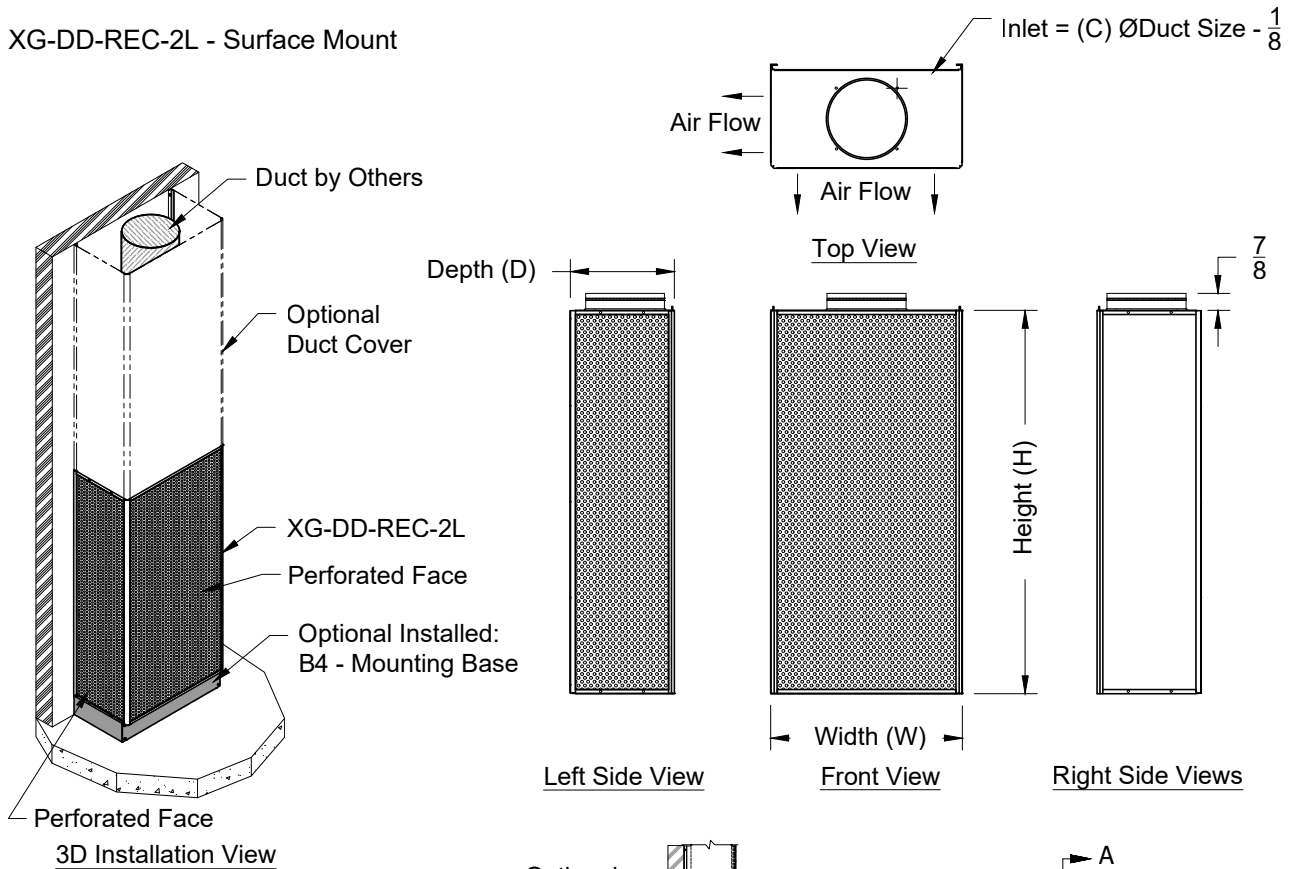

C (Inlet Options)	
Round	Rectangular
6	8 x 8
7	10 x 8
8	12 x 8
10	20 x 8
12	-
14	-

Unit Sizes				
Size	W	H	D	
12 x 24 x 13	12	40	13	
12 x 36 x 13	12	36	13	
12 x 48 x 13	12	48	13	
12 x 60 x 13	12	60	13	
24 x 36 x 13	24	36	13	
24 x 48 x 13	24	48	13	
24 x 60 x 13	24	60	13	
36 x 48 x 16	36	48	16	
36 x 60 x 16	36	60	16	
48 x 60 x 16	48	60	16	

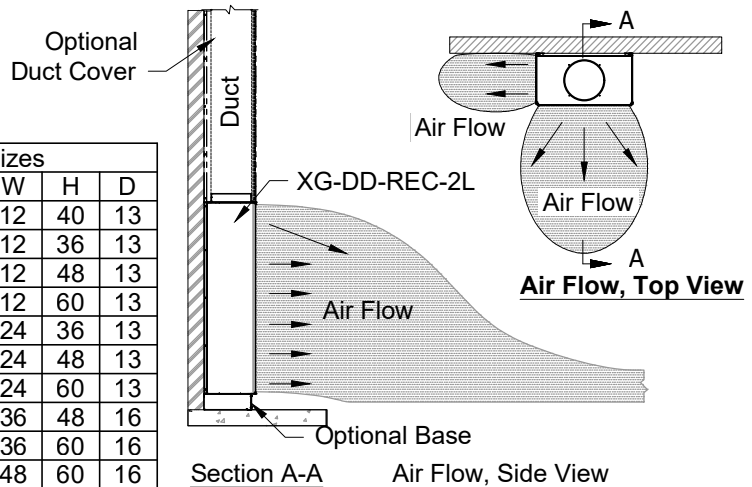


1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish 02 Satin Silver 03 Black 28 Custom Color		B4 - Mounting Base IB - Internal Perforated Baffle	<ul style="list-style-type: none"> 23% Perforated Face .050" Aluminum 24ga. Steel Construction Duct covers for displacement diffusers have a max single section height of 48" Taller units will be made in multiple sections for structural rigidity

All Dimensions ±1/16"

Model: XG-DD-REC-2R Rectangular - 2 Way Airflow Right - Surface Mount


XG-DD-REC-2R - Surface Mount

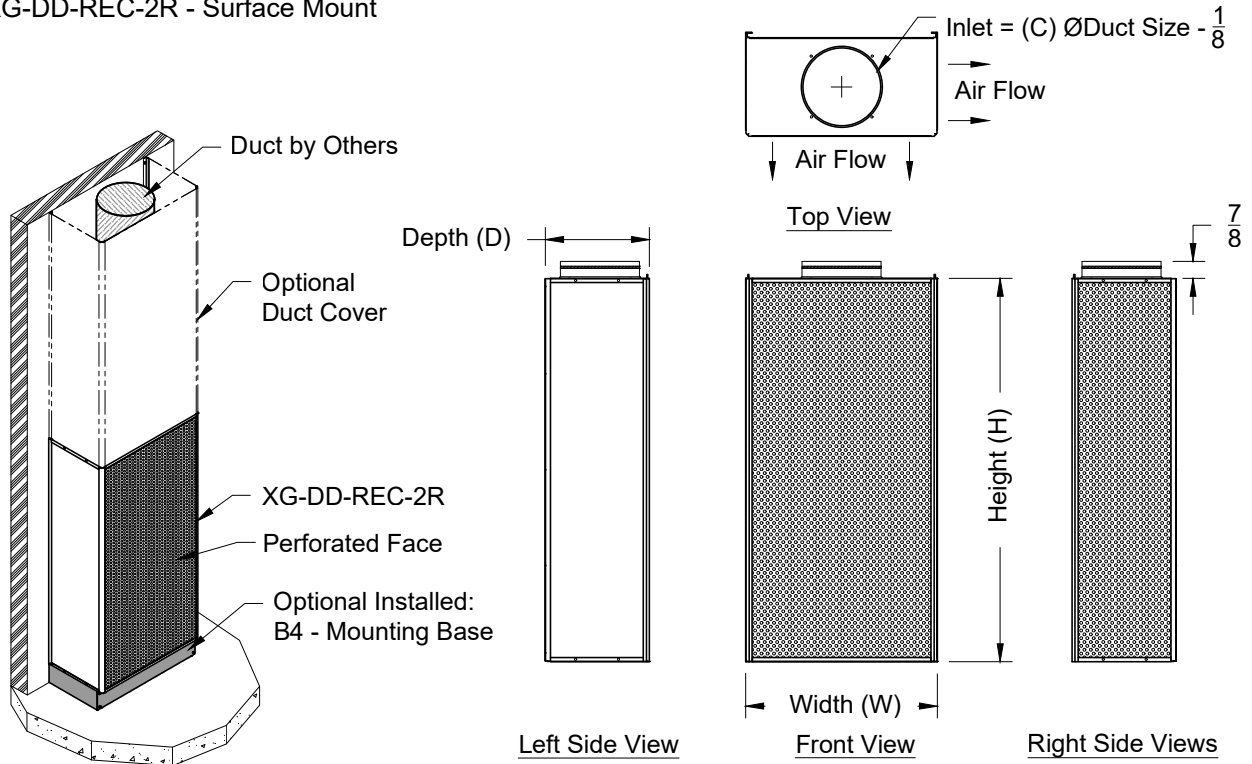

3D Installation View

C (Inlet Options)	
Round	Rectangular
6	8 x 8
7	10 x 8
8	12 x 8
10	20 x 8
12	-
14	-

Unit Sizes				
Size	W	H	D	
12 x 24 x 13	12	40	13	
12 x 36 x 13	12	36	13	
12 x 48 x 13	12	48	13	
12 x 60 x 13	12	60	13	
24 x 36 x 13	24	36	13	
24 x 48 x 13	24	48	13	
24 x 60 x 13	24	60	13	
36 x 48 x 16	36	48	16	
36 x 60 x 16	36	60	16	
48 x 60 x 16	48	60	16	


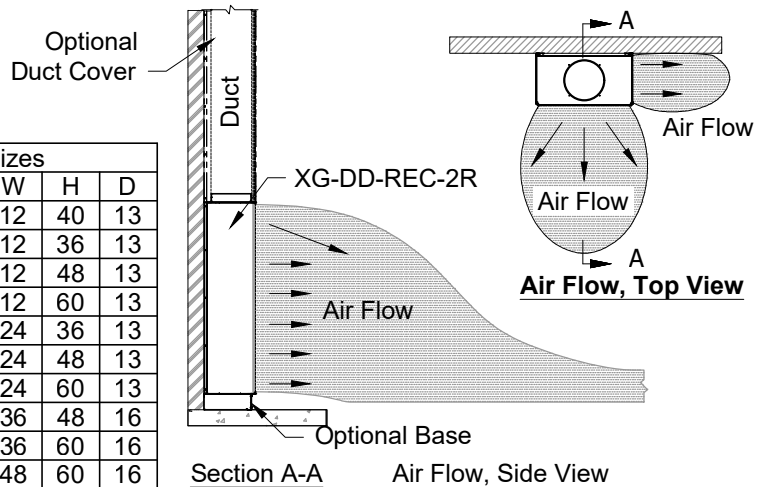


1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish 02 Satin Silver 03 Black 28 Custom Color		B4 - Mounting Base IB - Internal Perforated Baffle	<ul style="list-style-type: none"> • 23% Perforated Face .050" Aluminum • 24ga. Steel Construction • Duct covers for displacement diffusers have a max single section height of 48" • Taller units will be made in multiple sections for structural rigidity

All Dimensions ±1/16"

Model: XG-DD-REC-20 Rectangular - 2 Way Airflow - Surface Mount


XG-DD-REC-20 - Surface Mount

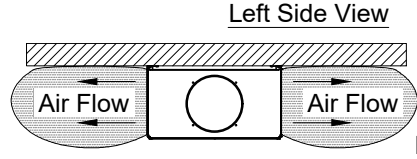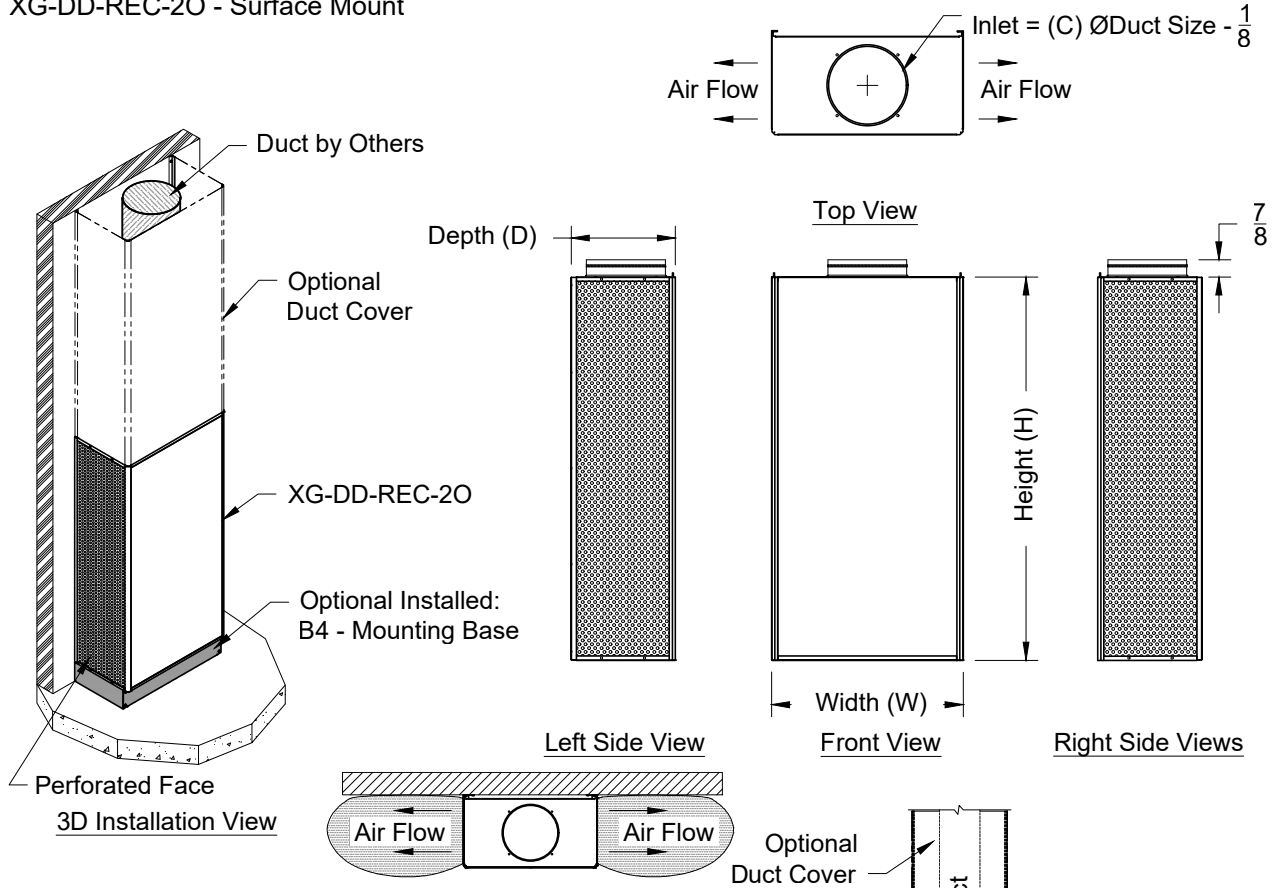

Air Flow, Top View

C (Inlet Options)	
Round	Rectangular
6	8 x 8
7	10 x 8
8	12 x 8
10	20 x 8
12	-
14	-

Unit Sizes			
Size	W	H	D
12 x 24 x 13	12	40	13
12 x 36 x 13	12	36	13
12 x 48 x 13	12	48	13
12 x 60 x 13	12	60	13
24 x 36 x 13	24	36	13
24 x 48 x 13	24	48	13
24 x 60 x 13	24	60	13
36 x 48 x 16	36	48	16
36 x 60 x 16	36	60	16
48 x 60 x 16	48	60	16

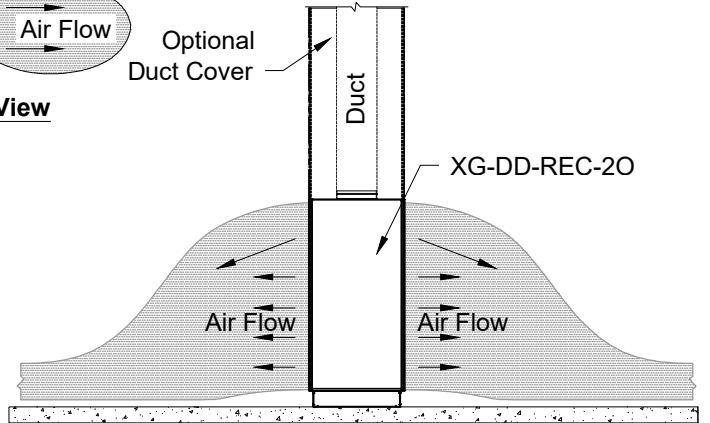


Air Flow, Front View Section A-A

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish 02 Satin Silver 03 Black 28 Custom Color		B4 - Mounting Base IB - Internal Perforated Baffle	<ul style="list-style-type: none"> • 23% Perforated Face .050" Aluminum • 24ga. Steel Construction • Duct covers for displacement diffusers have a max single section height of 48" • Taller units will be made in multiple sections for structural rigidity

All Dimensions ±1/16"


Model: XG-DD-REC-3W Rectangular - 3 Way Airflow - Surface Mount

XG-DD-REC-3W - Surface Mount

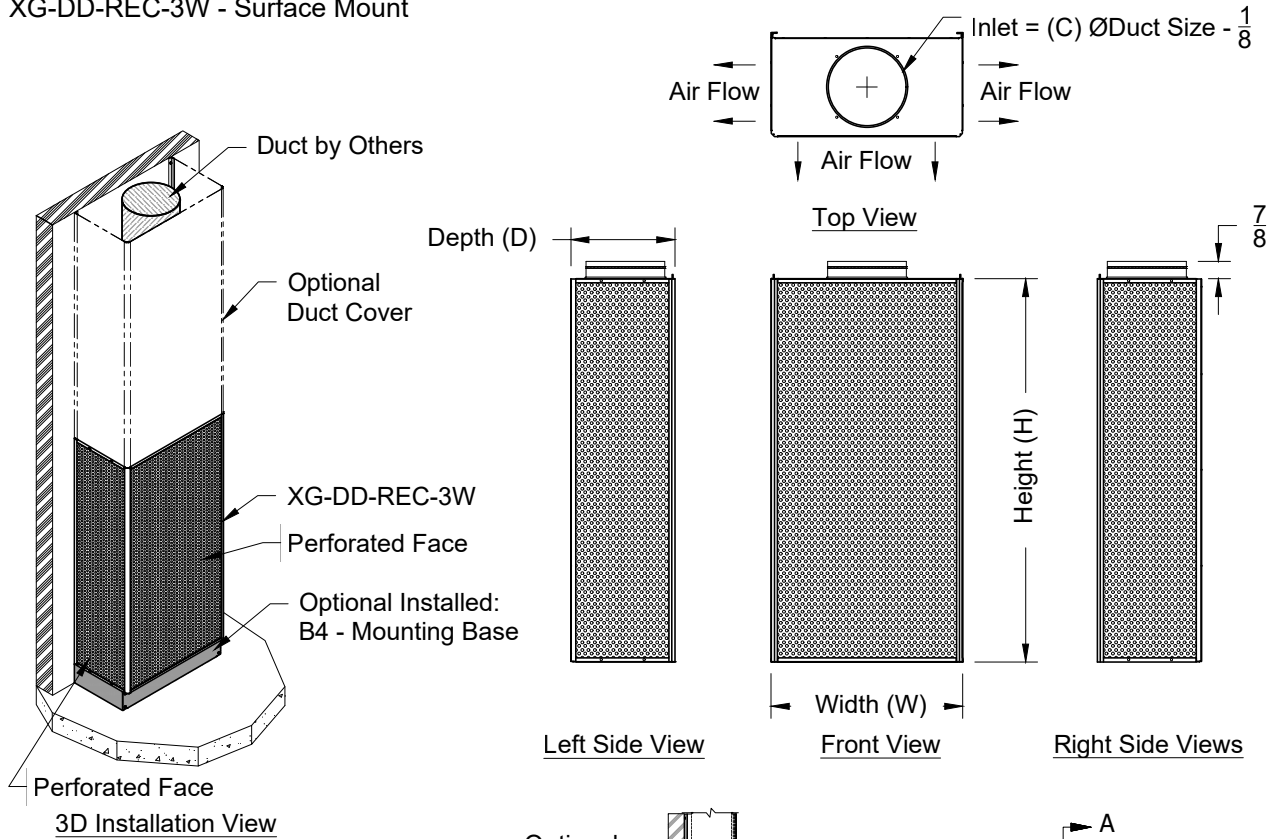

C (Inlet Options)	
Round	Rectangular
6	8 x 8
7	10 x 8
8	12 x 8
10	20 x 8
12	-
14	-

Unit Sizes			
Size	W	H	D
12 x 24 x 13	12	40	13
12 x 36 x 13	12	36	13
12 x 48 x 13	12	48	13
12 x 60 x 13	12	60	13
24 x 36 x 13	24	36	13
24 x 48 x 13	24	48	13
24 x 60 x 13	24	60	13
36 x 48 x 16	36	48	16
36 x 60 x 16	36	60	16
48 x 60 x 16	48	60	16

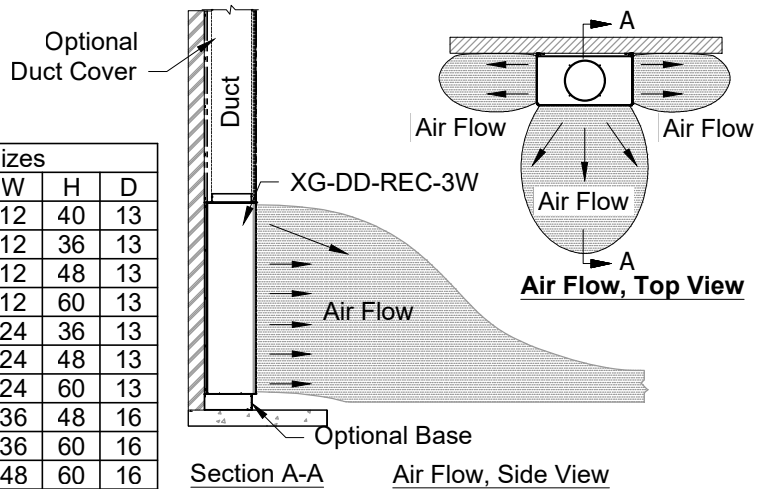

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish 02 Satin Silver 03 Black 28 Custom Color		B4 - Mounting Base IB - Internal Perforated Baffle	<ul style="list-style-type: none"> 23% Perforated Face .050" Aluminum 24ga. Steel Construction Duct covers for displacement diffusers have a max single section height of 48" Taller units will be made in multiple sections for structural rigidity

All Dimensions $\pm 1/16"$