

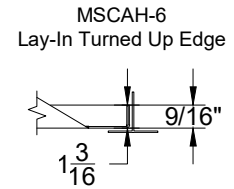


Model: XG-MSCAH AL Cooling & Adjustable Heating - Lay In T-Bar

### XG-MSCAH-6 AL - T-Bar Lay-In

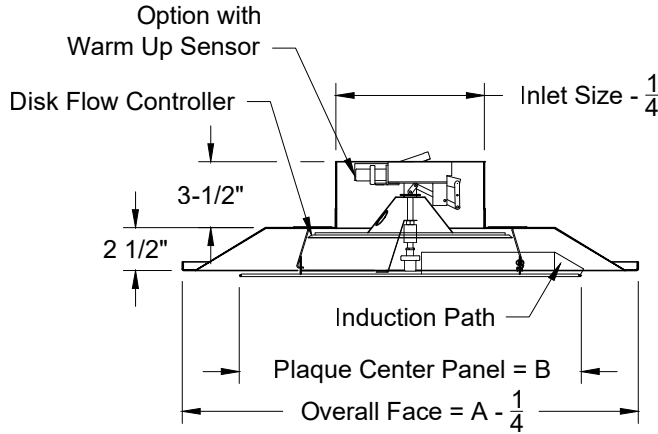

Side View

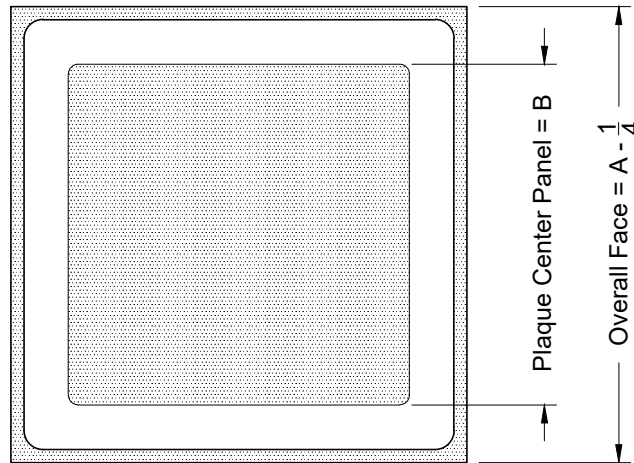

Face View


Listed Size Nominal Face	Plaque Center Panel	Available Round Inlets
12 x 12	9 x 9	6
24 x 24	18 x 18	8
		10
		12

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish 02 Satin Silver 03 Black	XG-BPRA - By-Pass Relief Damper XG-BAF - Directional Baffles XG-TBPF - T-Bar Plaster Frame	AH/1 - Full Closed Heating	<ul style="list-style-type: none"> <li>• 24ga Galvanized Steel Construction</li> <li>• Sizes Available only as listed</li> <li>• Available only for 24" x 24" Diffusers</li> </ul>


All Dimensions ±1/16"

Model: XG-MSCAH-9 AL Cooling & Adjustable Heating - Bolt Slot / Donn Finline Ceiling Grid

### XG-MSCAH-9 AL - Bolt Slot / Donn Finline Ceiling Grid

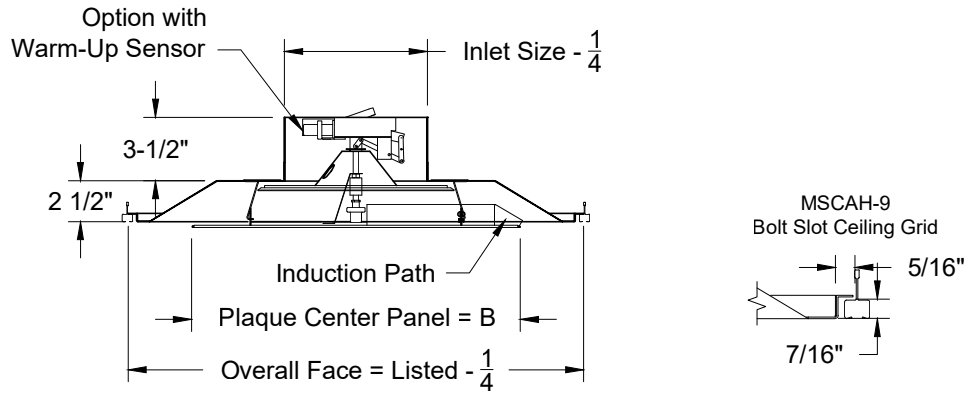

Side View

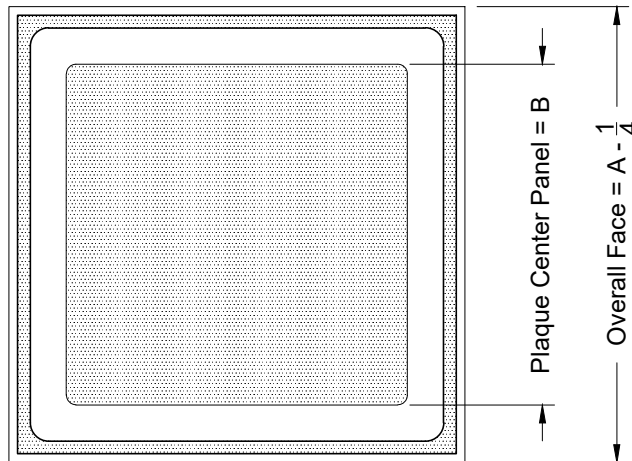

Face View

Listed Size Nominal Face	Plaque Center Panel	Available Round Inlets
12 x 12	9 x 9	6
24 x 24	18 x 18	8
		10
		12

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish 02 Satin Silver 03 Black	XG-BPRA - By-Pass Relief Damper XG-BAF - Directional Baffles XG-TBPF - T-Bar Plaster Frame	AH/1 - Full Closed Heating	<ul style="list-style-type: none"> <li>• 24ga Galvanized Steel Construction</li> <li>• Sizes Available only as listed</li> <li>• Available only for 24" x 24" Diffusers</li> </ul>

All Dimensions ±1/16"