

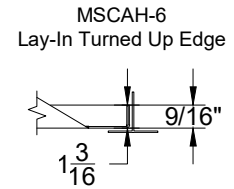


Model: XG-MSCAH Cooling & Adjustable Heating - Lay In T-Bar

XG-MSCAH-6 - T-Bar Lay-In

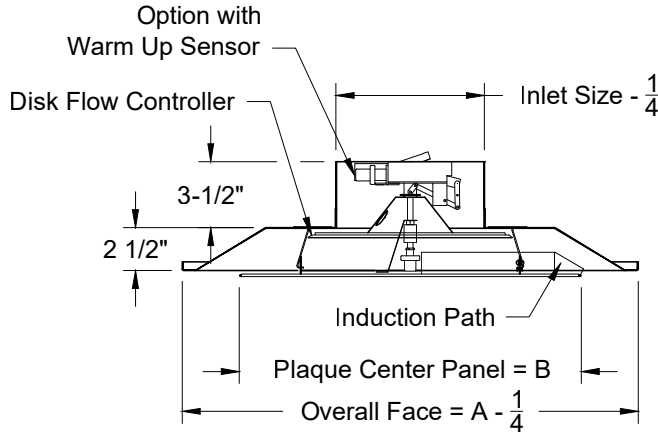

Side View

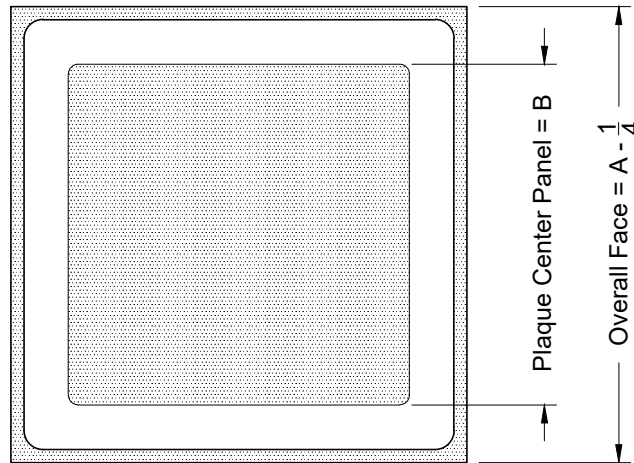

Face View


| Listed Size Nominal Face | Plaque Center Panel | Available Round Inlets |
|--------------------------|---------------------|------------------------|
| 12 x 12 | 9 x 9 | 6 |
| 24 x 24 | 18 x 18 | 8 |
| | | 10 |
| | | 12 |

| 1. Available Finishes | 2. Available Accessories | 3. Available Options | 4. Construction Details |
|--|--|----------------------------|--|
| Standard Finish: 01 White Optional Finish 02 Satin Silver 03 Black | XG-BPRA - By-Pass Relief Damper XG-BAF - Directional Baffles XG-TBPF - T-Bar Plaster Frame | AH/1 - Full Closed Heating | <ul style="list-style-type: none"> • 24ga Galvanized Steel Construction • Sizes Available only as listed • Available only for 24" x 24" Diffusers |


All Dimensions ±1/16"

Model: XG-MSCAH-9 Cooling & Adjustable Heating - Bolt Slot / Donn Finline Ceiling Grid

XG-MSCAH-9 - Bolt Slot / Donn Finline Ceiling Grid

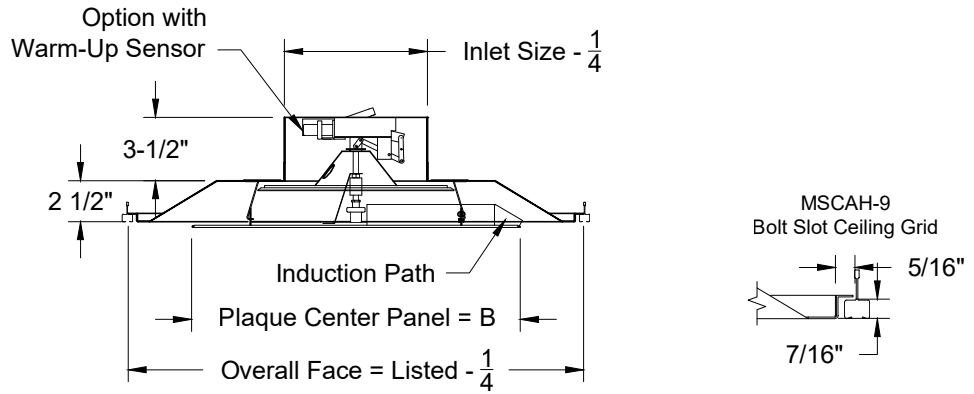

Side View

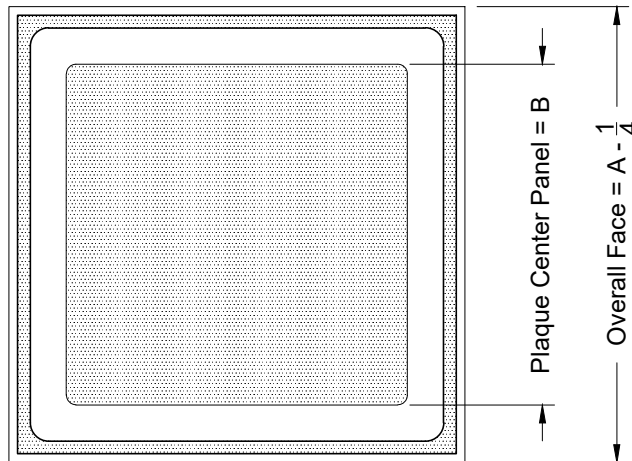

Face View

| Listed Size Nominal Face | Plaque Center Panel | Available Round Inlets |
|--------------------------|---------------------|------------------------|
| 12 x 12 | 9 x 9 | 6 |
| 24 x 24 | 18 x 18 | 8 |
| | | 10 |
| | | 12 |

| 1. Available Finishes | 2. Available Accessories | 3. Available Options | 4. Construction Details |
|--|--|----------------------------|--|
| Standard Finish: 01 White Optional Finish 02 Satin Silver 03 Black | XG-BPRA - By-Pass Relief Damper XG-BAF - Directional Baffles XG-TBPF - T-Bar Plaster Frame | AH/1 - Full Closed Heating | <ul style="list-style-type: none"> • 24ga Galvanized Steel Construction • Sizes Available only as listed • Available only for 24" x 24" Diffusers |

All Dimensions $\pm 1/16"$