

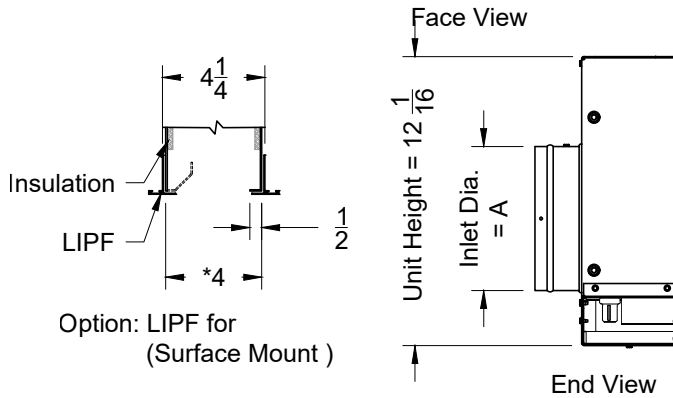


Model: XG-MVAC Horizontal Cooling Control - T-Bar Lay-In

XG-MVAC - Surface Mount

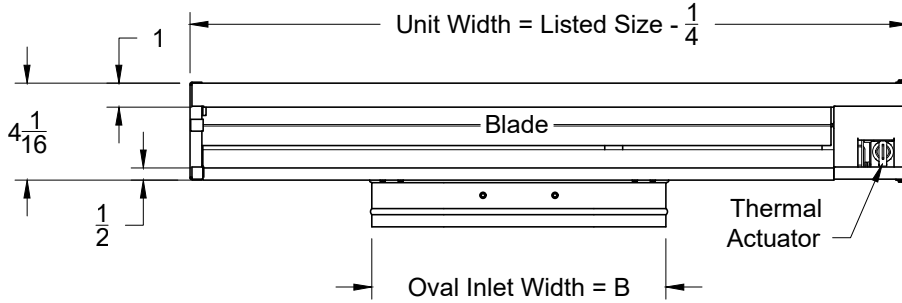

| Size | Type | A | B |
|------|------|-------|----------|
| 8 | Oval | 5 7/8 | 8 3/8 |
| 9 | Oval | 5 7/8 | 10 |
| 10 | Oval | 5 7/8 | 11 9/16 |
| 12 | Oval | 5 7/8 | 14 13/16 |

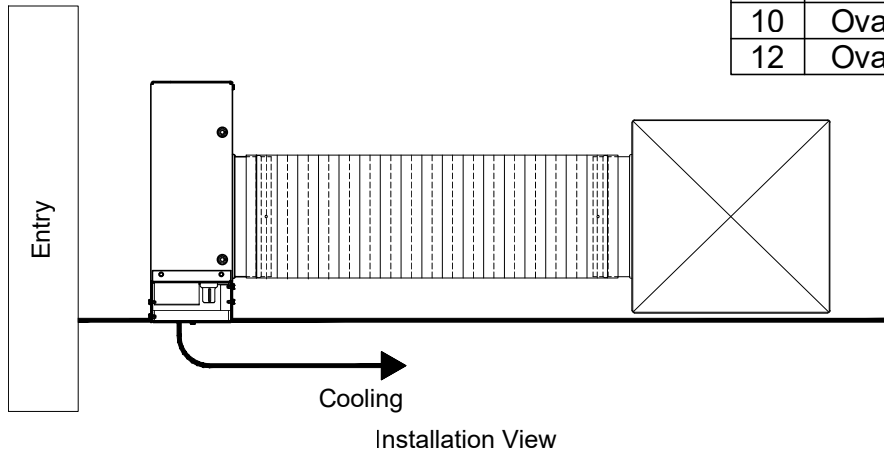




| |
|----|
| 24 |
| 36 |
| 48 |
| 60 |

| 1. Available Finishes | 2. Available Accessories | 3. Available Options | 4. Construction Details |
|---|--------------------------------|----------------------|--|
| Standard Finish: 01 White Optional Finish 03 Black | XG-LIPF - Lay-In Plaster Frame | | <ul style="list-style-type: none"> • 24ga Galvanized Steel Construction • Sizes Available only as listed • Controls: Self-contained, Thermally actuated control |


All Dimensions ±1/16"

Model: XG-MVAC Horizontal Cooling Control - T-Bar Lay-In

XG-MVACH - Surface Mount

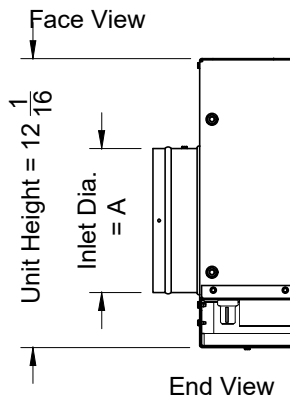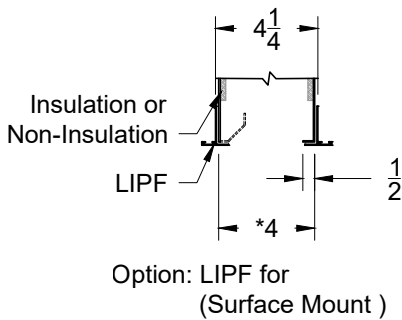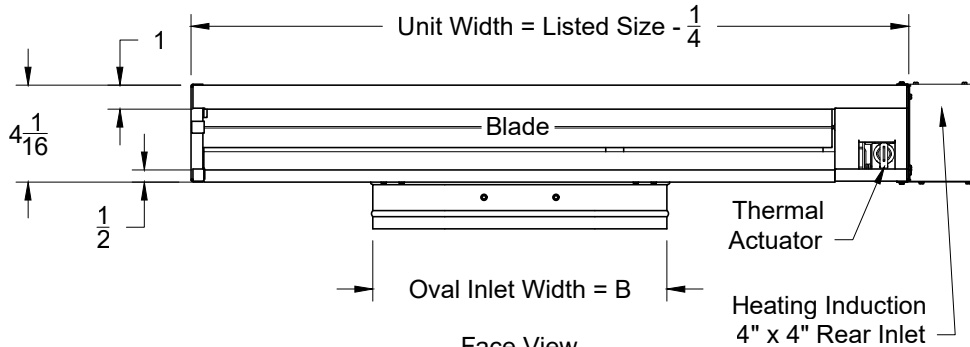

| Size | Type | A | B |
|------|------|-------|----------|
| 8 | Oval | 5 7/8 | 8 3/8 |
| 9 | Oval | 5 7/8 | 10 |
| 10 | Oval | 5 7/8 | 11 9/16 |
| 12 | Oval | 5 7/8 | 14 13/16 |

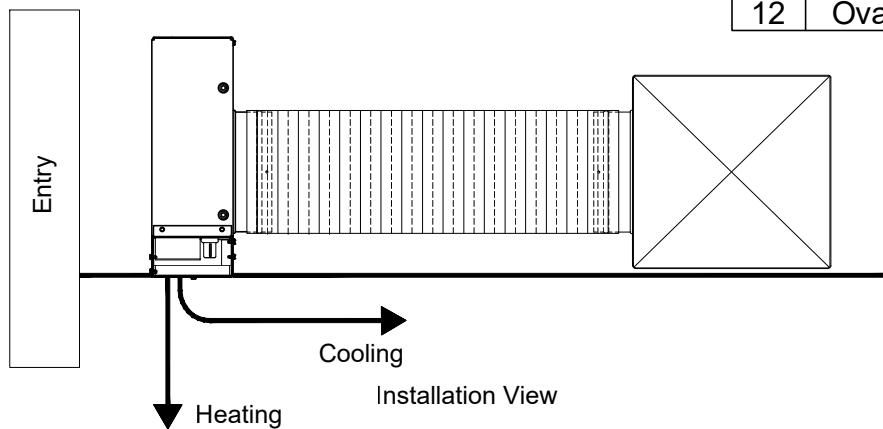

| |
|----|
| 24 |
| 36 |
| 48 |
| 60 |

| 1. Available Finishes | 2. Available Accessories | 3. Available Options | 4. Construction Details |
|---|--------------------------------|----------------------|--|
| Standard Finish: 01 White Optional Finish 03 Black | XG-LIPF - Lay-In Plaster Frame | | <ul style="list-style-type: none"> • 24ga Galvanized Steel Construction • Sizes Available only as listed |

All Dimensions ±1/16"