

Supply Perforated Models																						
Greenheck Model	Material Options			Neck		Face		Frame Style				Module Size Available (for Lay-in)*						Pattern Controllers			Fire Rated Option ²	
	Steel	Aluminum Face	Aluminum	Round Neck	Square Neck	Fixed Face	Hinged Face	Surface Mount (-1)	Lay-in (-6)	Tegular (-8)	Donn Finline / Bolt Slot (-9)	12x12	24x12	20X20	24x24	36x24	48x24	48x48	Face Mounted	Neck Mounted		Adjustable Pattern Controllers
XG-7000			X		X		X	X	X	X	X	X	X	X	X		X			X	X	
XG-7300	X		X	X ¹		X			X						X				X			
XG-7350	X	X		X ¹			X		X	X					X				X		X	
XG-7500	X	X	X	X			X	X	X	X	X	X			X				X		X	X
XG-7550	X	X	X		X		X	X	X	X	X				X				X		X	X
XG-7600	X	X	X	X			X	X	X	X	X				X					X	X	X
XG-7650	X	X	X		X		X								X					X	X	X
XG-7900			X		X		X	X	X	X	X				X					X	X	
XG-7950	X	X			X		X	X	X	X	X				X					X	X	
XG-SRP	X				X	X		X	X			X	X		X			X				
XG-RP			X		X	X		X	X			X	X		X			X	X			


¹ 7300 and 7350 have a Fiberglass Backpan with pre-scored holes for a round neck spin in

² Fire Rated Options are only available in all steel models - Model will be base model name with -FRS after (for example XG-7500-FRS)


* Module size is dependent on which "Lay-In" frame style chosen

FRAME STYLE


Surface Mount (-1)

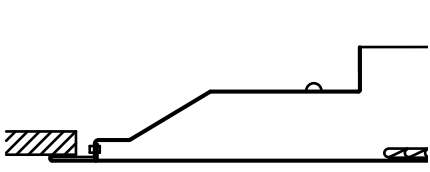


Lay-In (-6)

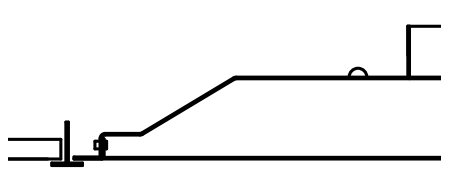

Tegular (-8)

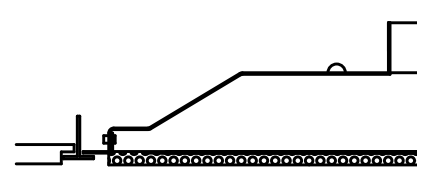

Donn Finline / Bolt Slot (-9)

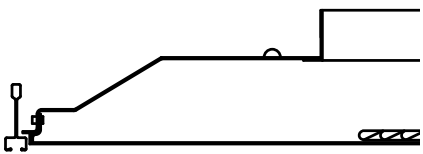

Return and Filter Return Perforated Models																					
Greenheck Model	Material Options			Neck		Face		Frame Style					Module Size Available (for Lay-in)*						Fire Rated Option ²		
	Steel	Aluminum Face	Aluminum	Round Neck	Square Neck	Fixed Face	Hinged Face	Surface Mount (-1)	Surface Mount - Removable Core (-RC-1)	Lay-in (-6)	Lay-In - Removable Core (-RC-6)	Tegular (-8)	Donn Finline / Bolt Slot (-9)	12x12	24x12	20X20	24x24	36x24		48x24	48x48
XG-7000R			X		X		X	X		X		X	X	X	X	X	X		X		
XG-7300R	X		X	X ¹		X				X							X				
XG-7350R	X	X		X ¹			X			X		X					X				
XG-7500R	X	X	X	X			X	X		X		X	X	X			X				X
XG-7550R	X	X	X		X		X	X		X		X	X		X ^{**}		X				X
XG-7600R	X	X	X	X			X	X		X		X	X				X				X
XG-7650R	X	X	X		X		X								X ^{**}		X				X
XG-PRTB			X		X	X				X		X	X	X	X		X	X	X		
XG-SPRTB	X				X	X				X		X	X	X	X		X	X	X		
Filter Return																					
XG-7550RF	X				X		X	X		X		X					X				
XG-7650RF	X				X		X	X		X		X					X				
XG-SRPF	X				X		X	X	X	X	X			X	X		X		X		
XG-RPF			X		X		X	X	X	X	X			X	X		X		X		

¹ 7300 and 7350 have a Fiberglass Backpan with pre-scored holes for a round neck spin in

² Fire Rated Options are only available in all steel models - Model will be base model name with -FRS after (for example XG-7500-FRS)

* Module size is dependent on which "Lay-In" frame style chosen


** Only valid on steel units and a neck size of 22x10

FRAME STYLE


Surface Mount (-1)




Lay-In (-6)

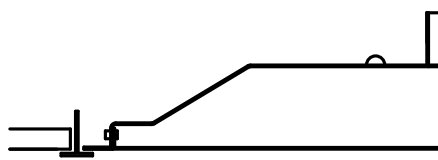

Tegular (-8)

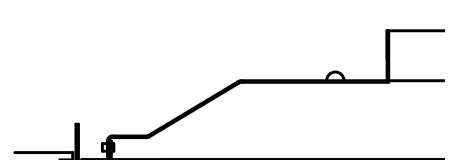


Donn Finline / Bolt Slot (-9)

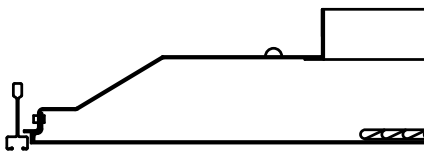

Greenheck Model	Material Options			Frame Style					Module Size Available (for Lay-in)		Fire Rated Option ¹
	Steel	Aluminized Steel	Aluminum	Surface Mount (-1)	Lay-in (-6)	Lay-In Panel (-6P)	Concealed Spline (-7)	Donn Finline / Bolt Slot (-9)	12x12	24x24	
XG-5700	X	X	X	X	X	X	X	X	X	X	X
XG-5700A	X	X	X	X	X				X	X	
XG-5750	X	X	X	X	X	X	X	X	X	X	
XG-5750RP	X	X	X	X	X			X	X	X	
XG-5750T	X	X	X	X	X		X	X		X	
XG-5800	X	X	X	X	X	X	X	X	X	X	X
XG-5800A	X	X	X	X	X					X	
XG-PHENOM	X	X	X	X	X		X	X		X	
XG-PHENOM-LF	X	X	X	X	X		X	X		X	

¹ Fire Rated Options are only available in all steel models - Model will be base model name with -FRS after (for example XG-5700-FRS)

FRAME STYLE

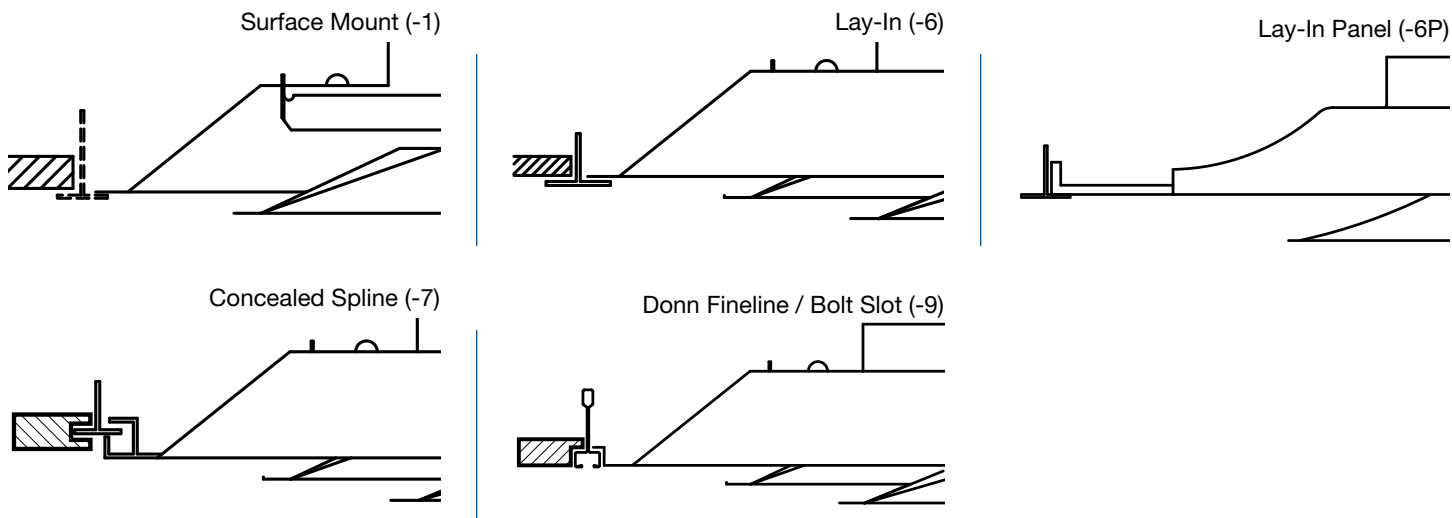


LOUVERED FACE DIFFUSER Selection Guide

Greenheck Model	Material Options		Frame Style					Module Size Available (for Lay-in)					Fire Rated Option ¹
	Steel	Aluminum	Surface Mount (-1)	Bevel Frame Surface Mount (-2)	Lay-in (-6)	Tegular (-8)	Donn Finline / Bolt Slot (-9)	12x12	24x24	36x24	48x24	48x48	
XG-5000		X	X	X	X	X	X	X	X	X	X	X	
XG-5500		X	X	X	X	X	X	X	X	X	X	X	
XG-5500CAD		X		X	X				X				
XG-5500DD		X			X	X	X		X				
XG-5500DDI		X			X	X	X		X				
XG-5500DDR		X			X	X	X		X				
XG-5500S	X		X	X	X	X	X	X	X				X
XG-9000		X	X	X	X	X	X	X	X				
XG-9000S	X		X	X	X	X	X	X	X				


¹ Fire Rated Options are only available in all steel models - Model will be base model name with -FRS after (for example XG-5700-FRS)

FRAME STYLE


Surface Mount (-1)

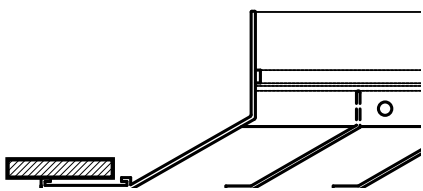

Bevel Frame Surface Mount (-2)

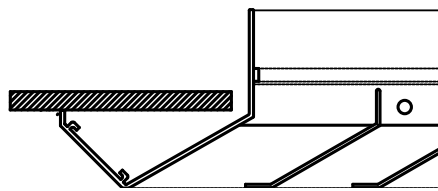

Lay-In (-6)

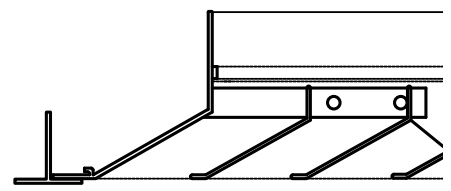

Tegular (-8)



Donn Finline / Bolt Slot (-9)




ROUND CEILING DIFFUSER Selection Guide

Greenheck Model	Material Options			Cones		Frame Style		Neck Size	
	Steel	Steel Backpan with Aluminum Face	Aluminum	Fixed	Adjustable	Surface Mount (-1)	Bevel Frame (-2)	Min (Inches)	Max (Inches)
XG-3000			X		X	X	X	6	24
XG-3100			X	X		X	X	6	36
XG-3100A			X		X	X	X	6	24
XG-3100S	X			X		X	X	6	24
XG-3100S-A	X				X	X	X	6	24
XG-3200			X	X		X		6	24
XG-R5750	X	X	X	X		X		6	16

FRAME STYLE

Surface Mount (-1)

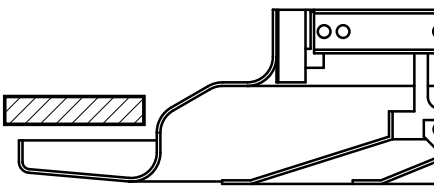

Bevel Mount (-2)

