


SUPPLY GRILLES Selection Guide

Sidewall Grilles (XG-4000 and XG-V Series)												
Greenheck Model	Material Options		Front Blade Orientation		Frame Style		Width and Height Sizes (Surface Mount)				Damper	
	Steel	Aluminum	Horizontal	Vertical	Surface Mount (-1)	Lay-in (-6)	Min Width (Inches)	Min Height (Inches)	Max Width (Inches)	Max Height (Inches)	OBD Optional	Multi-Shutter Standard
Single Deflection												
XG-H4002		X	X		X	X	6	4	144	144	X	
XG-H4002-AF		X	X		X	X	6	4	144	144	X	
XG-H4002M		X	X		X	X	6	4	24	24		X
XG-H4002S	X		X		X	X	6	4	144	144	X	
XG-H4002S-AF	X		X		X	X	6	4	144	144	X	
XG-H4002SM	X		X		X	X	6	4	24	24		X
XG-V4002		X		X	X	X	6	4	144	144	X	
XG-V4002-AF		X		X	X	X	6	4	144	144	X	
XG-V4002M		X		X	X	X	6	4	24	24		X
XG-V4002S	X			X	X	X	6	4	144	144	X	
XG-V4002S-AF	X			X	X	X	6	4	144	144	X	
XG-V4002SM	X			X	X	X	6	4	24	24		X
XG-V		X		X	X		6	6	14	12 ¹	X	
XG-VM		X		X	X		6	6	14	12 ¹		X
Double Deflection												
XG-H4004		X	X		X	X	6	4	144	144	X	
XG-H4004S	X		X		X	X	6	4	144	144	X	
XG-H4004-AF		X	X		X	X	6	4	144	144	X	
XG-H4004S-AF	X		X		X	X	6	4	144	144	X	
XG-V4004		X		X	X	X	6	4	144	144	X	
XG-V4004S	X			X	X	X	6	4	144	144	X	
XG-V4004-AF		X		X	X	X	6	4	144	144	X	
XG-V4004S-AF	X			X	X	X	6	4	144	144	X	
XG-VH		X		X	X		6	6	14	12 ¹	X	


¹ Models XG-V, XG-VM and XG-VH use a one-piece pan frame and have only specific WxH sizes

FRAME STYLE

Surface Mount (-1)

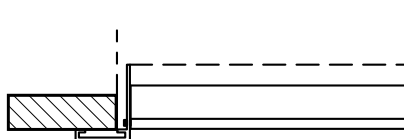

Lay-In (-6)

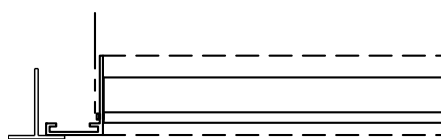


Ceiling Curved Blade Grilles (XG-L and XG-S Series)

Greenheck Model	Deflection		Frame Style		Width and Height Sizes (Surface Mount)				Damper		
	Single	Double	Surface Mount (-1)	Lay-in (-6)	Min Width (Inches)	Min Height (Inches)	Max Width (Inches)	Max Height (Inches)	OBD Optional	Multi-Shutter Standard	Multi-Shutter with Handle Standard
1 Way Air Pattern											
XG-L	X		X	X	6	4	48	48	X		
XG-LM	X		X		6	4	24	20		X	
XG-LMH	X		X		6	4	16	12			X
XG-LV		X	X	X	6	4	48	48	X		
XG-S	X		X	X	6	4	48	48	X		
XG-SH		X	X	X	6	4	48	48	X		
XG-SM	X		X		6	4	24	20		X	
2 Way Air Pattern											
XG-LT	X		X	X	6	4	48	48	X		
XG-LTC	X		X	X	6	4	48	48	X		
XG-LTCM	X		X		6	6	14	14		X	
XG-LTM	X		X		6	4	24	20		X	
XG-LTMH	X		X		6	4	16	12			X
XG-LTV		X	X	X	6	4	48	48	X		
XG-ST	X		X	X	6	4	48	48	X		
XG-STH		X	X	X	6	4	48	48	X		
XG-STM	X		X		6	4	24	20		X	
3 Way Air Pattern											
XG-LS3	X		X	X	6	4	48	48	X		
XG-LS3M	X		X		6	6	14	14		X	
XG-LTC3	X		X	X	6	4	48	48	X		
XG-LTC3M	X		X		6	6	14	14		X	
4 Way Air Pattern											
XG-LS4	X		X	X	6	4	48	48	X		
XG-LS4M	X		X		6	6	14	14		X	

FRAME STYLE

 Surface Mount (-1)



Lay-In (-6)

