


Model: XG-4500SS-0° Return - 0° Deflection Blades - Flush Surface Mount

XG-4500SS-1 - Flush Surface Mount

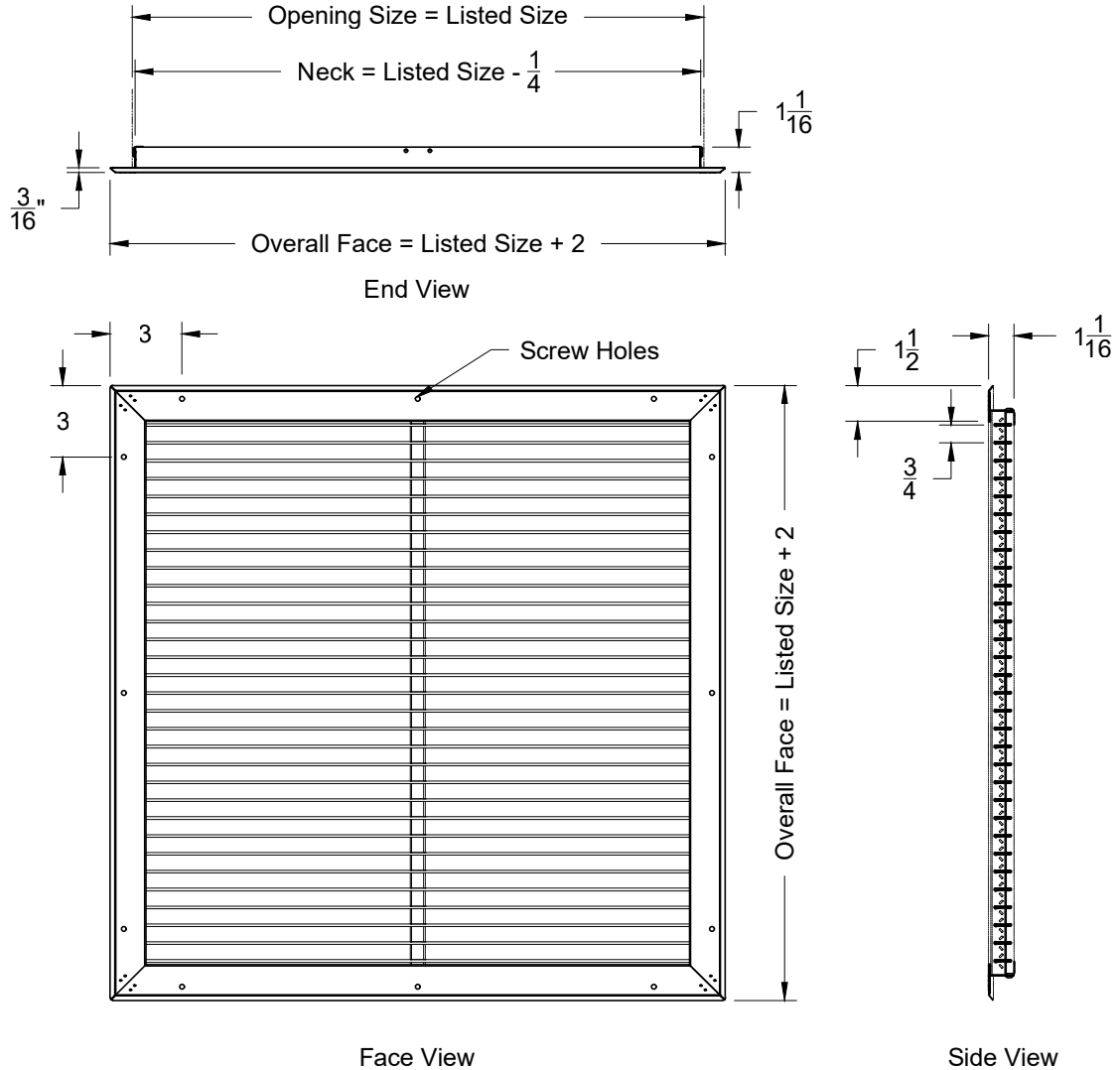




Neck Size		
	Min	Max
Width	4	48
Depth	4	48

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish: 23 Satin Polish	XG-OBSS - S.S. Opposed Blade Damper XG-PFSS - S.S. Plaster Frame XG-LIPSS - S.S. Lay-In Plaster Frame	IS-SS - Insect Screen NSH - No Screw Holes 316SS - 316 Stainless Steel	<ul style="list-style-type: none"> 304 Stainless Steel Construction (Standard) Only Available in Listed Sizes

All Dimensions $\pm 1/16$ "

Model: XG-4545SS-45° Return - 45° Deflection Blades - Flush Surface Mount

XG-4545SS-1 - Flush Surface Mount

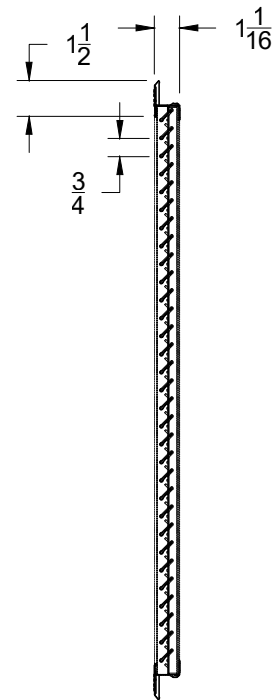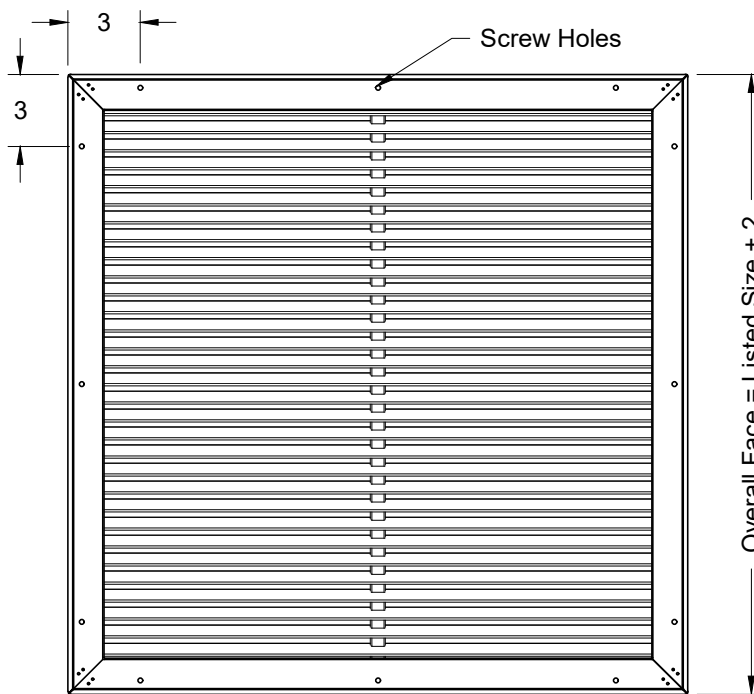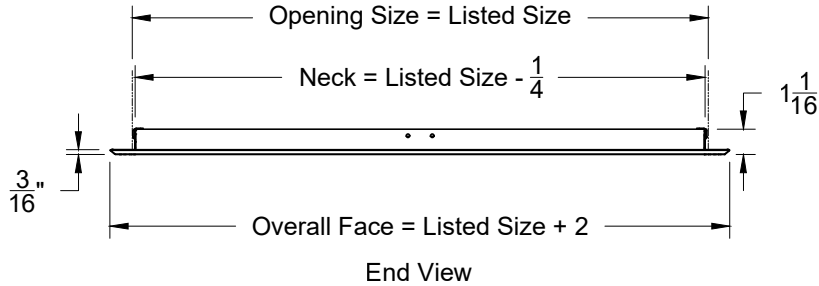

Neck Size		
	Min	Max
Width	4	48
Depth	4	48

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish: 23 Satin Polish	XG-OBSS - S.S. Opposed Blade Damper XG-PFSS - S.S. Plaster Frame XG-LIPSS - S.S. Lay-In Plaster Frame	IS-SS - Insect Screen NSH - No Screw Holes 316SS - 316 Stainless Steel	<ul style="list-style-type: none"> 304 Stainless Steel Construction (Standard) Only Available in Listed Sizes

All Dimensions $\pm 1/16$ "