



Model: XG-5800 FRS-6 Ceiling Diffuser - 4 Cone - 3 Hour Fire Rating - Lay in T-Bar

XG-5800 FRS-6 - Lay in T-Bar

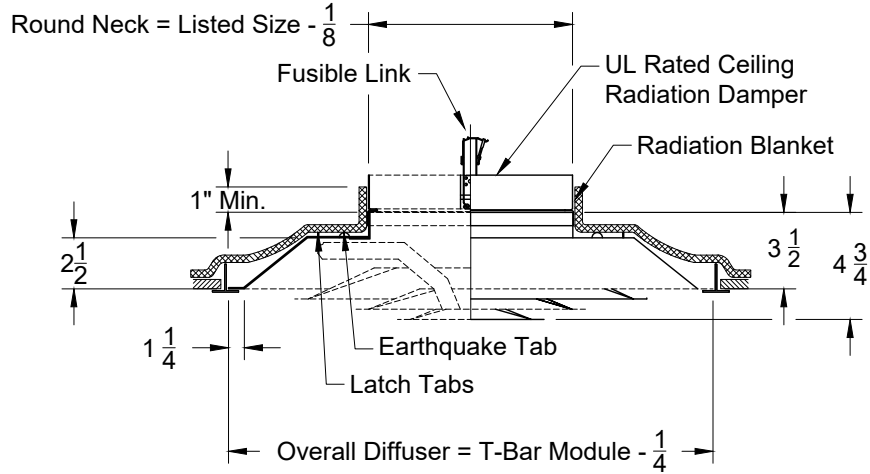

Side View

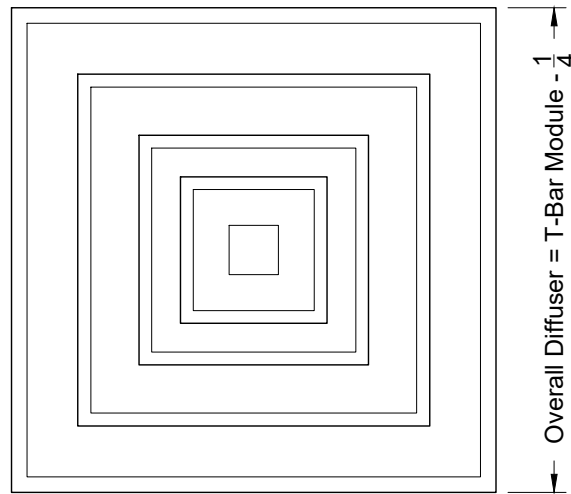

Face View


Round Neck Diameters
6
8
10
12
14
15

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Finish 02 Satin Silver 03 Black Optional Finish 28 Custom Color		APD - Air Pattern Deflectors	<ul style="list-style-type: none"> Steel Construction Sizes Available only as listed Available only in Lay in T-Bar 24" x 24" Fuse Links 165° Standard Diffuser provided with factory mounted UL555C CRD and thermal blanket Ceiling Radiation Damper must be installed per UL Installation Guidelines to maintain UL Rating


All Dimensions $\pm 1/16$ "

Model: XG-5800 FRSA-6 Ceiling Diffuser - 4 Cone - 3 Hour Fire Rating - Adjustable Damper - Lay in T-Bar

XG-5800 FRSA-6 - Lay in T-Bar

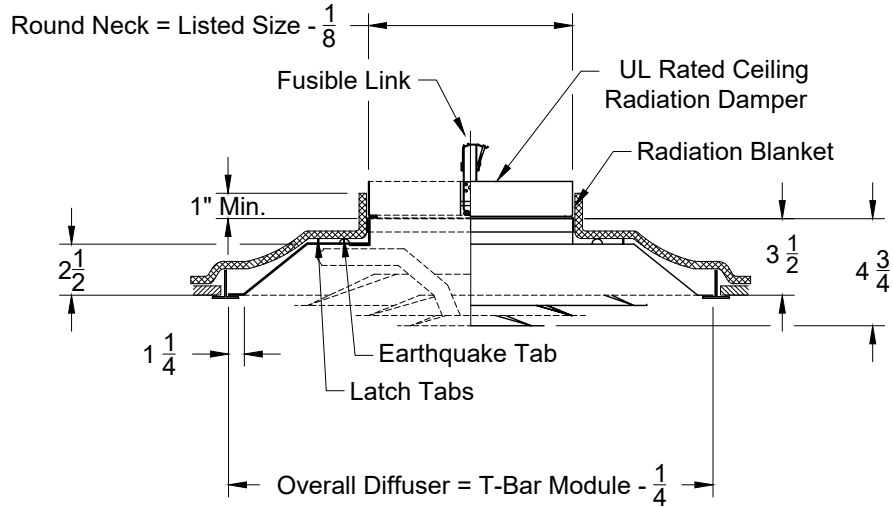

Side View

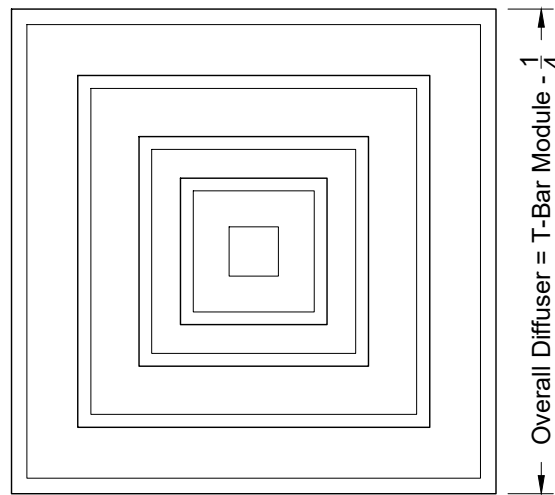

Face View

Round Neck Diameters
6
8
10
12
14
15

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Finish 02 Satin Silver 03 Black Optional Finish 28 Custom Color		APD - Air Pattern Deflectors	<ul style="list-style-type: none"> Steel Construction Sizes Available only as listed Available only in Lay in T-Bar 24" x 24" Fuse Links 165° Standard Diffuser provided with factory mounted UL555C CRD and thermal blanket Ceiling Radiation Damper must be installed per UL Installation Guidelines to maintain UL Rating

All Dimensions ±1/16"