



| | |
|-------------------|-------------------------|
| Model: XG-AFRI-10 | 1" Slot - Insulated |
| XG-AFRI-15 | 1 1/2" Slot - Insulated |
| XG-AFRI-20 | 2" Slot - Insulated |
| XG-AFRI-25 | 2 1/2" Slot - Insulated |
| XG-AFRI-30 | 3" Slot - Insulated |

XG-AFRI - Return Hood Light Shield - Insulated

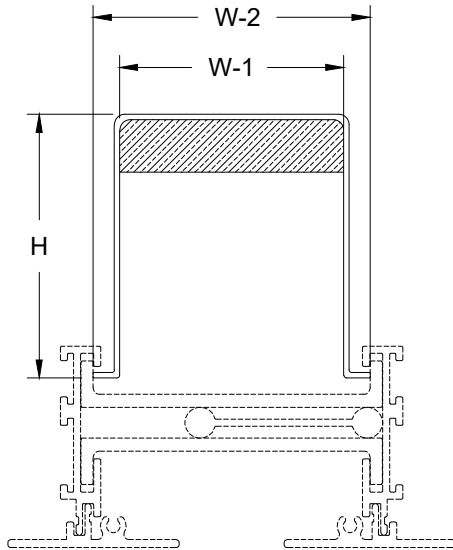

Installation End View

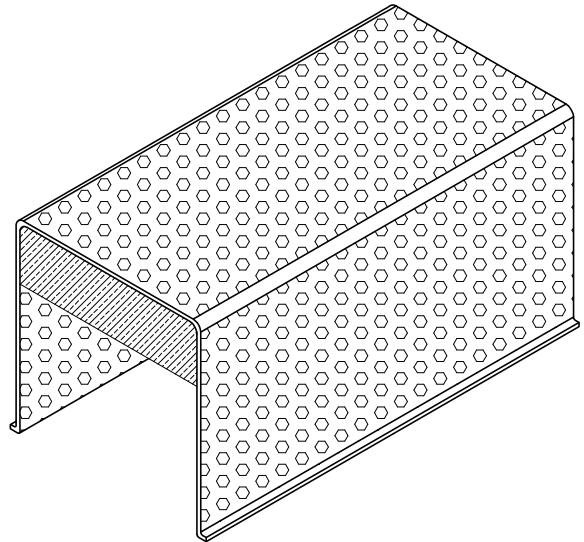

3D View

| 1 Slot | | | |
|------------|-------|---------|---------|
| Slot Width | Dim H | Dim W 1 | Dim W 2 |
| 1 | 2 1/2 | 2 1/8 | 2 5/8 |
| 1 1/2 | 2 1/2 | 2 7/8 | 3 1/8 |
| 2 | 2 1/2 | 3 3/8 | 3 5/8 |
| 2 1/2 | 2 1/2 | 4 7/8 | 5 1/8 |
| 3 | 2 1/2 | 5 3/8 | 5 5/8 |

| 2 Slot | | | |
|------------|-------|---------|---------|
| Slot Width | Dim H | Dim W 1 | Dim W 2 |
| 1 | 2 1/2 | 5 5/16 | 5 9/16 |
| 1 1/2 | 2 1/2 | 6 5/16 | 6 9/16 |
| 2 | 2 1/2 | 7 5/16 | 7 9/16 |
| 2 1/2 | 2 1/2 | 10 5/16 | 10 9/16 |
| 3 | 2 1/2 | 11 5/16 | 11 9/16 |

| 1. Available Finishes | 2. Available Accessories | 3. Available Options | 4. Construction Details |
|------------------------------|--------------------------|---|--|
| Standard Finish: 03 Black | | 15/16" Tee System 9/16" Tee System 9/16" Bolt Slot Tee System Hard Ceiling | <ul style="list-style-type: none"> ● Aluminum Construction ● Length 48" ● Field Cut to Fit ● Finish on interior only |
| All Dimensions ±1/16" | | | |