
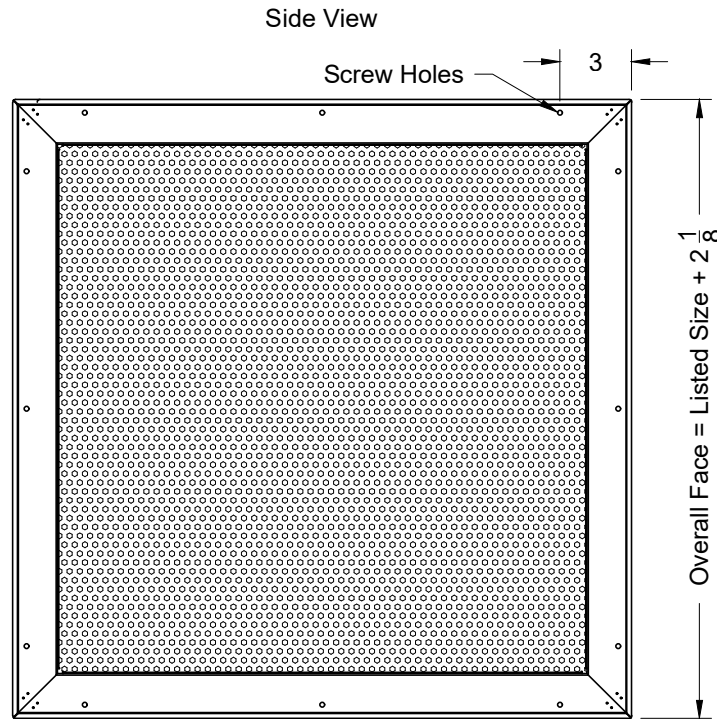


Model: XG-RPSS-1      Perforated Face - Flush Surface Mount

### XG-RPSS-1 - Flush Surface Mount

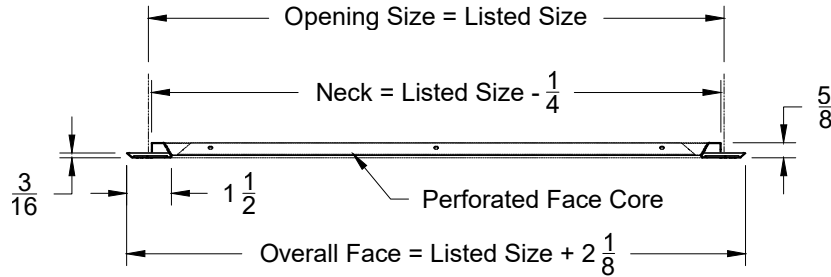


Neck Size		
	Min	Max
Width	4	48
Depth	4	48

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish: 23 Satin Polish	XG-OBDS - S.S. Opposed Blade Damper XG-PFSS - S.S. Plaster Frame XG-LIPFSS - S.S. Lay-In Plaster Frame	IS-SS - Insect Screen NSH - No Screw Holes 316SS - 316 Stainless Steel	<ul style="list-style-type: none"> <li>• 304 Stainless Steel Construction (Standard)</li> <li>• Only Available in Listed Sizes</li> <li>• 3/16" Round Perf. on 1/4" Staggered Centers (51% Free Area)</li> </ul>


All Dimensions ±1/16"

Model: XG-RPSS-6      Perforated Face - Lay In T-Bar

### XG-RPSS-6 - Lay In T-Bar

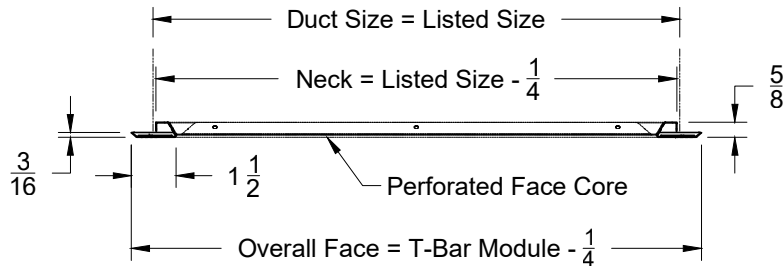

Side View

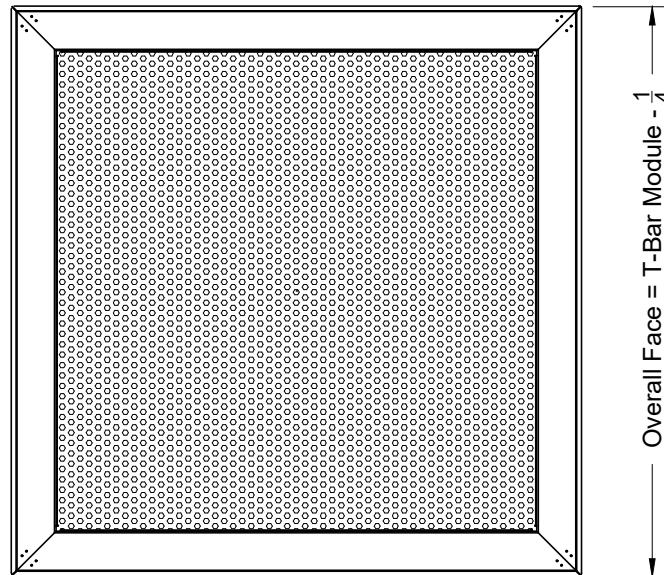

Face View

Listed Sizes
12 x 12
12 x 24
24 x 24
48 x 24

Neck Size		
	Min	Max
Width	4	46
Depth	4	22

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Optional Finish: 23 Satin Polish	XG-OBDS - S.S. Opposed Blade Damper XG-PFSS - S.S. Plaster Frame XG-LIPFSS - S.S. Lay-In Plaster Frame	IS-SS - Insect Screen 316SS - 316 Stainless Steel	<ul style="list-style-type: none"> <li>• 304 Stainless Steel Construction (Standard)</li> <li>• Only Available in Listed Sizes</li> <li>• 3/16" Round Perf. on 1/4" Staggered Centers (51% Free Area)</li> </ul>

All Dimensions ±1/16"