
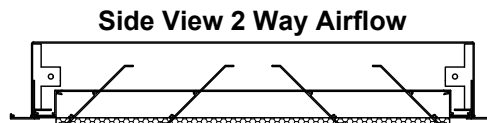
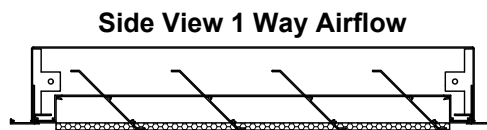
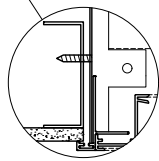
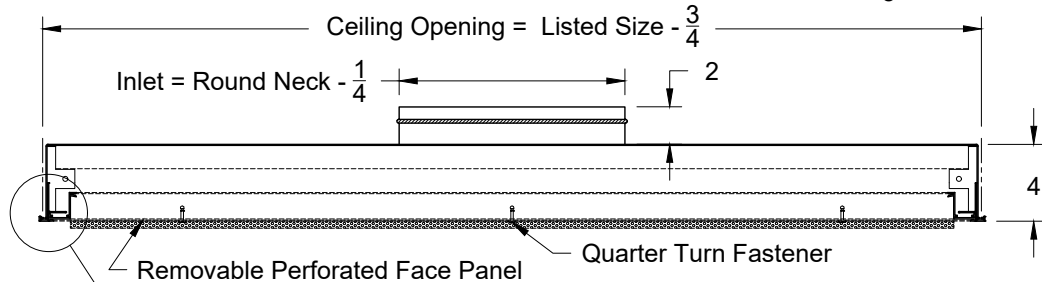


Model: HLC-FFR-AL-1 Aluminum Face and Backpan - Flush Surface Mount

HLC-FFR-AL-1 - Flush Surface Mount

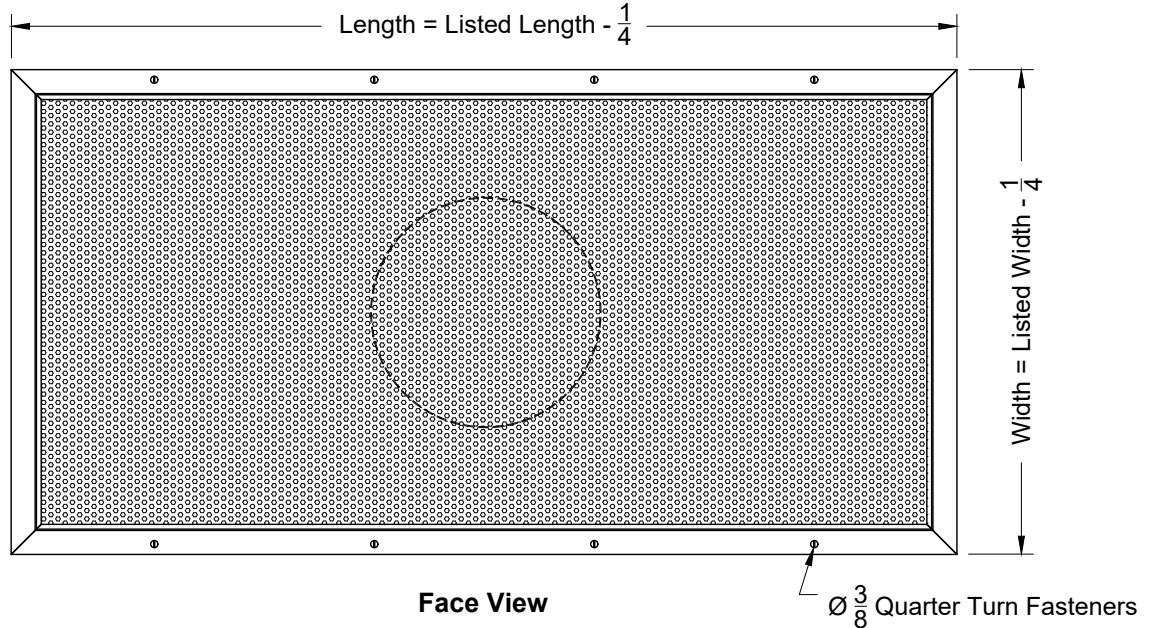

Available Sizes			
Widths	12	24	-
Lengths	-	24	48

Available Round Neck Sizes					
Neck	6	8	10	12	14



Flush Surface Mount Detail:
C-Channel, Wood Blocks,
Shims & Fastening Provided
By Others. Use Shims To
Center Diffuser In Opening.

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Finish 24 Mill Finish	XG-TBPF - T-Bar Plaster Frame XG-D3 - Radial Opposed Blade Damper	EI - External 1/2" Insulation	<ul style="list-style-type: none"> Spot Welded and Sealed Construction Perforated Panel Free Areas: 16%, 23% and 51% Available Available with 1 Way or 2 Way Air Flow Aluminum face and backpan

All Dimensions $\pm 1/16"$

Model: HLC-FFR-AL-6 Aluminum Face and Backpan - T-Bar Lay In

HLC-FFR-AL-6 - T-Bar Lay In

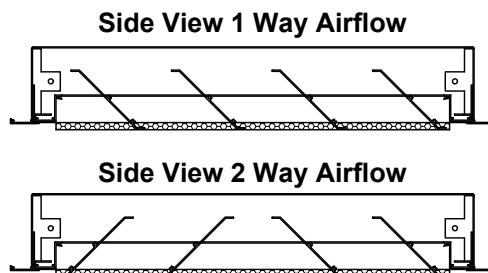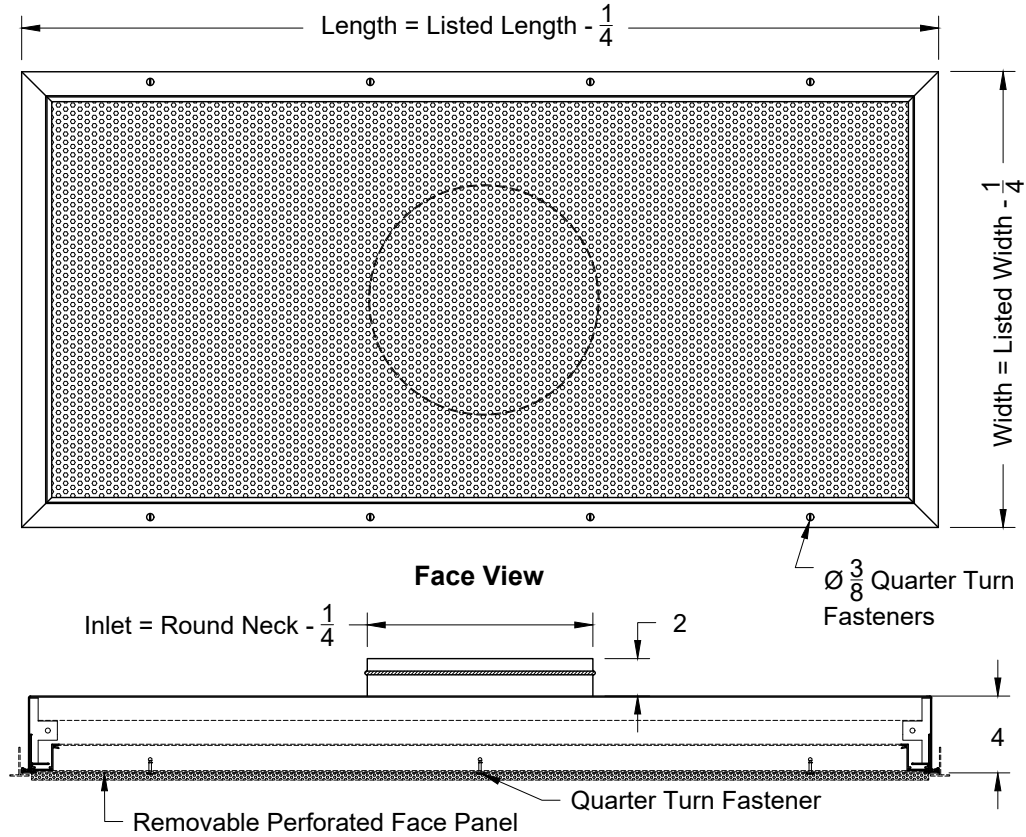

Available Sizes	
Widths	12 24
Lengths	- 24

Available Round Neck Sizes					
Neck	6	8	10	12	14

1. Available Finishes	2. Available Accessories	3. Available Options	4. Construction Details
Standard Finish: 01 White Finish 24 Mill Finish	XG-TBPF - T-Bar Plaster Frame XG-D3 - Radial Opposed Blade Damper	EI - External 1/2" Insulation	<ul style="list-style-type: none"> Spot Welded and Sealed Construction Perforated Panel Free Areas: 16%, 23% and 51% Available Available with 1 Way or 2 Way Air Flow Aluminum face and backpan

All Dimensions ±1/16"