



BELTED FAN AND BLOWER MOTOR


CUSTOMER P/N **328408**

MODEL C63HMR-1441 PH 1 INS B AMB 40 °C

ENC. OAO FRAME 56H CODE H DUTY CONT A.O.

HP	1.0	F.L.A.	14.0/7.0
RPM	1725	S.F.	1.25
VOLTS	115/208-230	S.F.A.	15.0/7.5
HZ	60		

SEE NOTE #7
328408

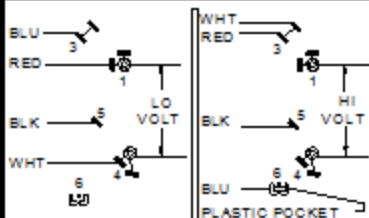

E22922

TO REVERSE ROTATION
INTERCHANGE RED & BLK LEADS

SUITABLE FOR FIELD WIRING, USE COPPER CONDUCTORS ONLY

INDEC MOTOR CORPORATION www.usmotors.com PRT. CODE MFG. NO.