


# Model RSQ

ROOF SUPPLY OR EXHAUST FANS

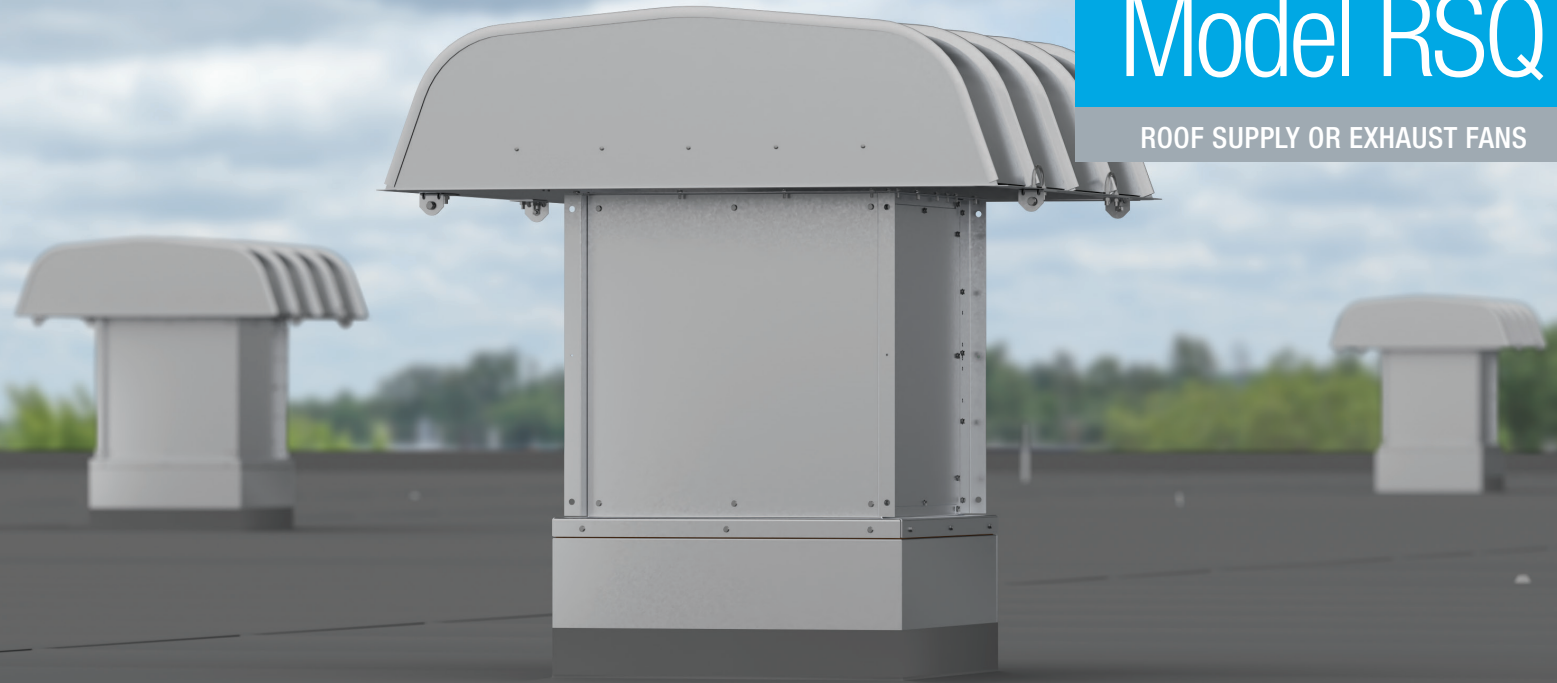

## Mixed Flow Hooded Rooftop Fans

Model RSQ direct drive fans take performance through the roof. Offering unparalleled installation flexibility and ease of maintenance, these compact fans are engineered for both roof supply and exhaust using our latest mixed flow technology—delivering both exceptional efficiency and quiet operation. Supply configurations can be equipped with washable aluminum filters or birdscreen while exhaust configurations are provided with birdscreen only. Elevate your projects with the RSQ.

### SIZES AND CONFIGURATIONS

- Direct drive sizes 7 - 33
- Supply available with birdscreen as standard or optional 1-inch washable aluminum filters
- Exhaust available with birdscreen as standard

### PERFORMANCE

- Supply: Up to 27,100 cfm
- Exhaust: Up to 25,200 cfm
- Up to 3 in. wg of static pressure

Supply Fan with  
Optional Filters



VIEW SUPPLY FAN

Exhaust Fan  
with Birdscreen



VIEW EXHAUST FAN


## PRIMARY APPLICATIONS

Filtered/Unfiltered Roof Supply | Roof Exhaust  
Clean Air Environments | Low Sound | High Efficiency

 **GREENHECK**  
Building Value in Air.

# Model RSQ

ROOF SUPPLY OR EXHAUST FANS

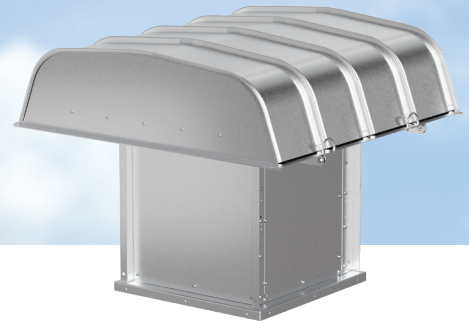


## FEATURES AND BENEFITS

- Mixed flow wheel improves airflow and efficiency while reducing sound and footprint
- Panels on either side of the unit provide quick access and inspection
- Totally enclosed motors eliminate the need for a motor cover and improve motor access
- Vari-Green® motor offering up to and including 10 hp
- Mounted and wired NEMA-3R disconnect
- Birdscreen is provided as standard with the option to switch to 1-inch aluminum filters on supply units
- Fabra style hoods constructed of galvanized steel are arched and precision roll-formed for strength and weather tightness (ships knocked down for field installation)
- Lifting lugs provide easy rigging and installation

## OPTIONS AND ACCESSORIES

- 1-inch aluminum filters (supply only)
- Roof curbs and accessories
- Aluminum hood
- Spark B & C resistant construction
- High Wind Rated (Miami-Dade NOA certified)
- Backdraft and control dampers
- Duct adapters
- Decorative and protective coatings
- Disconnect switches
- Multiple control options

## PERFORMANCE

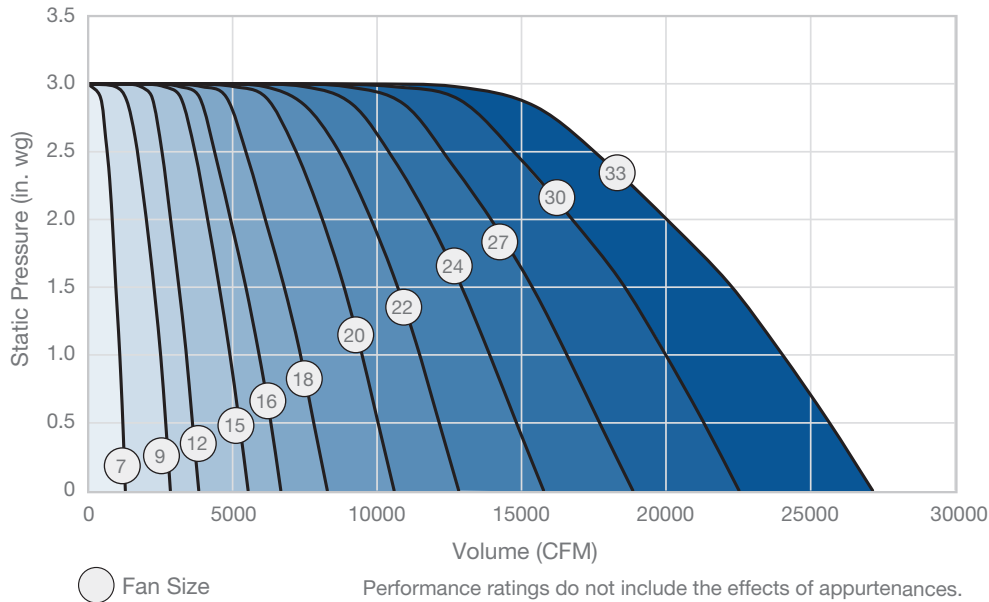

Greenheck Fan Corporation certifies the model RSQ fans shown herein are licensed to bear the AMCA Seal. The ratings shown are based on tests and procedures performed in accordance with AMCA Publication 211 and Publication 311 and comply with the requirements of the AMCA Certified Ratings Program.



Model RSQ is compliant with Miami-Dade NOA requirements and carries Florida Product Approval. Sizes 7 through 24 are rated to ±90 psf, while sizes 27 through 33 are rated to ±40 psf.



UL/cUL 705  
Listed for Electrical  
File no E40001

**Specify with Confidence. Specify Greenheck.**  
Connect with your local mechanical representative to learn more.

