



NEMA
Premium



MADE IN MÉXICO

MAT: 12675412 CC029A

W01.TE0IC0X0N

HT002506NPW01

12SEP2023 S/N:


For 60Hz: Class I, Zone 2, IIC

Class I, Div.2, Gr. A,B,C,D - T3

Div 2 Inverter Duty (SF1.00)

CT 2:1/VT 1000:1

PH 3	Hz 60	HP 2.0
FR 182/4T		kW 1.5
DUTY CONT.		V 575
ALT 1000 m.a.s.l		A 2.40
INS CL F ΔT 80K	IP55	SFA 2.76
AMB 40°C	DES B	SF 1.15
ENCL TEFC	CODE K	PF 0.71
		RPM 1170
		NEMA NOM. EFF 88.5%
For safe area-Inverter duty motor For use on VPWM 1000:1 VT, 4:1 CT		
DE 6206-ZZ	ODE 6205-ZZ	MOBIL POLYREX EM

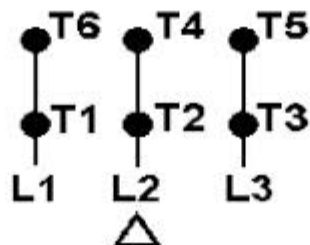

T1-BLU
T2-WHT
T3-ORG
T4-YEL
T5-BLK
T6-GRY

INTERCHANGE ANY TWO LINE WIRES TO REVERSE THE ROTATION



WARNING: Motor must be grounded in accordance with local and national electrical codes to prevent serious electrical shocks. Disconnect power source before servicing unit.



AVERTISSEMENT: Le moteur doit être mis à la terre conformément aux codes électriques locaux et nationaux afin d'éviter tout choc électrique grave. Déconnectez l'alimentation avant l'entretien de la machine.