

1 2 3 4 5 6 7 8

A





B

C

D

E

F

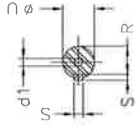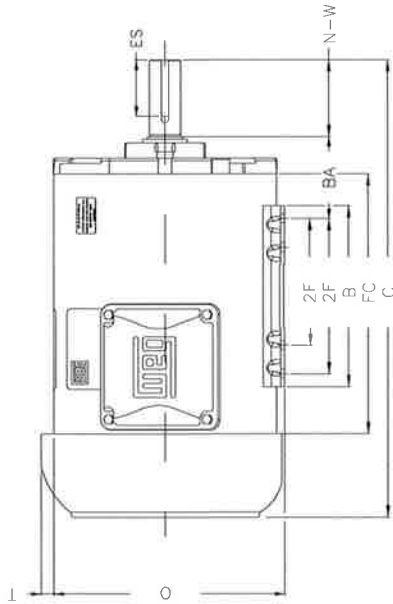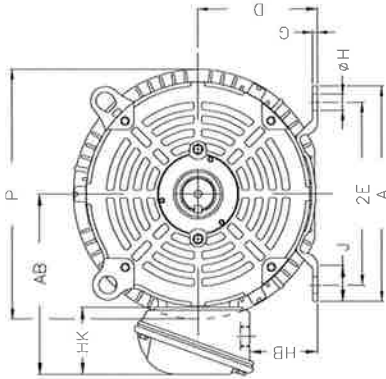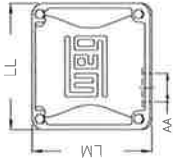

Notes:

Performed by:

Checked:

Customer:

Three Phase: W01 - TEFC - NEMA Premium Efficiency

Three-phase induction motor
Frame 182/4T - IP55


07-OCT-2014
316437



P	9.435	AB	6.696	J	1.299	2E	7.500	A	8.661
H	0.406	G	0.167	HB	2.784	HK	2.629	T	0.661
O	8.557	FC	10.236	2F	4.500/5.500	B	6.299	C	17.913
BA	2.750	N-W	2.750	ES	1.969	d1	A 3.15	S	0.250
U	1.125	AA	1.118"	depth	0.250	R	0.984	LL	4.563
LM	4.090	BB	0.661	D	4.500	CH	1.377		

LOW VOLTAGE

HIGH VOLTAGE

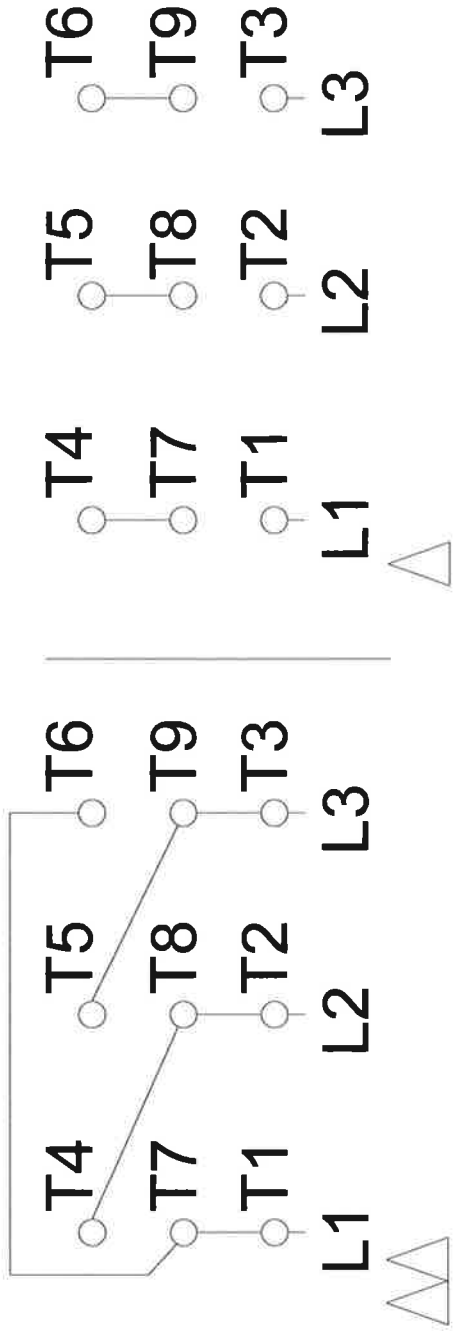

Notes:
Performed by:
Checked:
Customer:
Three Phase: W01 - TEFC - NEMA Premium Efficiency
Three-phase induction motor Frame 182/4T - IP55
07-OCT-2014 316437