



W01

W01 0UM00IC0X0X



MADE IN MEXICO

15136443

MODEL GFC-329548

THERMALLY PROTECTED

kW(HP) 0.25(0.33)

PH1 60Hz Fr. 48 1000m.a.s.l. ODP 83lb DUTY CONT.


AMB 50°C INS cl. F DT70K Code N DES N

V		Hz	RPM	A		SFA		SF	PF	IE code	NEMA NOM EFF
115	230	60	1735	6.24	3.12	8.38	4.19	1.35	0.58	-	60.0
-	-	-	-	-	-	-	-	-	-	-	-
-	-	-	-	-	-	-	-	-	-	-	-
-	-	-	-	-	-	-	-	-	-	-	-
-	-	-	-	-	-	-	-	-	-	-	-
-	-	-	-	-	-	-	-	-	-	-	-

B/N:

TO REVERSE ROTATION INVERT T5 AND T8

USABLE @208V 3.45A SF 1.00

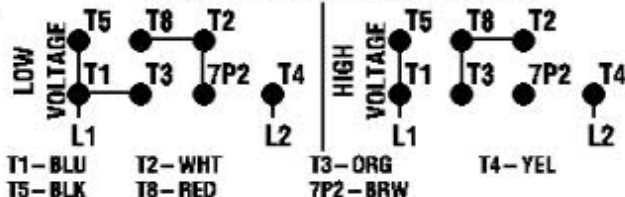

MOBIL POLYREX EM

-6203-ZZ

-6202-ZZ

Electric Motor

WARNING: Motor must be grounded in accordance with local and national electrical codes to prevent serious electrical shocks. Disconnect power source before servicing unit.



AVERTISSEMENT: Le moteur doit être mis à la terre conformément aux codes électriques locaux et nationaux afin d'éviter tout choc électrique grave. Déconnectez l'alimentation avant l'entretien de la machine.

