




MADE IN BRAZIL
MAT: 14201725
W01.T00IC0X0X
MODEL 002180T3E56Z-S
13AUG2024 B/N:

PH	3	Hz	60	HP	2.0
FR	56HZ			kW	1.5
DUTY	CONT.			V	230/460
ALT	1000 m.a.s.l			A	5.38/2.69
INS	CL F			SFA	6.19/3.09
AMB	40°C	DES	A	SF	1.15
ENCL	ODP	CODE	K	PF	0.81
				RPM	1740
				NEMA	
				NOM.EFF	86.5%

ALTERNATE RATING: 2.0HP 50Hz 190-220/380-415V SF1.00
8.52-5.79/3.28-3.07A 1410RPM EFF 82.2% (IE1) IEC 60034-1

Inverter duty motor For 80Hz use on VPMW 1000:1 VT, 5:1 CT
DE 6205-ZZ ODE 6202-ZZ MOBIL POLYREX EM

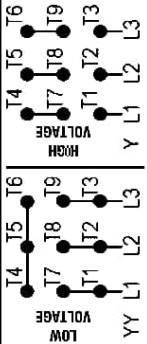

WARNING: Motor must be grounded in accordance with local and national electrical codes to prevent serious electrical shocks. Disconnect power source before servicing unit.

AVERTISSEMENT: Le moteur doit être mis à la terre conformément aux codes électriques locaux et nationaux afin d'éviter tout choc électrique grave. Déconnectez l'alimentation avant l'entretien de la machine.