



MODEL 03018ET3H286T-W22G


Inverter Duty Motor
Severe Duty

PH3	60Hz	Fr. 284/6T	1000m.a.s.l.	IP55	TEFC	465lb
V	575			A	28.1	
HP	30			kW	22	
SF	1.25			SFA	35.1	
RPM	1765			PF	0.84	
AMB	40°C			INS cl. F	DT80K	NEMA NOM EFF 93.6%
DUTY CONT.				DES B	Code G	



Mod.TE1BFOXON
CC029A

For use on PWM: VT 1000:1, CT 20:1,
1.00SF

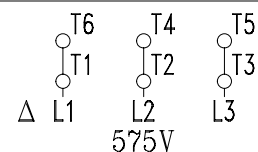

→ 6311-C3 (18g)

→ 6211-C3 (11g)



MOBIL POLYREX EM (20000h)

