

For use on 60Hz
Class I, Div 2, Gr A, B, C and D - T3
Class I, Zone 2, IIC - T3
Class II, Div 2, Gr F and G - T5
For use on PWM: Gr. A, B, C, D, F and G,
VT 1000:1, CT 20:1, 1.00SF - T4A



FOR SAFE AREA
Mod.TE1BFOXON
CC029A

MADE IN BRAZIL
11441933

HT002406NPW22

Inverter Duty Motor
Severe Duty

PH3 60Hz Fr. 182/4T 1000m.a.s.l. IP55 TEFC 98lb

V 230/460

A 6.44/3.22

HP 2.0

kW 1.5

SF 1.25

SFA 8.05/4.03

RPM 1170

PF 0.66

AMB 40°C

INS cl. F DT80K



NEMA NOM EFF 88.5%

DUTY CONT.

DES B Code L

USABLE @208V 7.13A SF 1.15 SFA 8.20

2.0HP 1.5kW 50Hz 380V 3.66A 960RPM SF 1.00 EFF 86.5% (IE4)

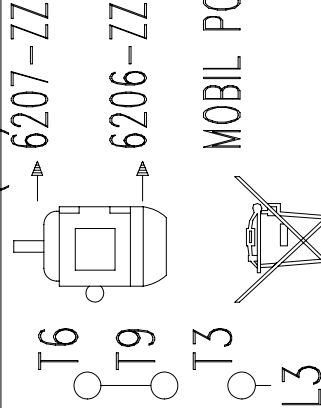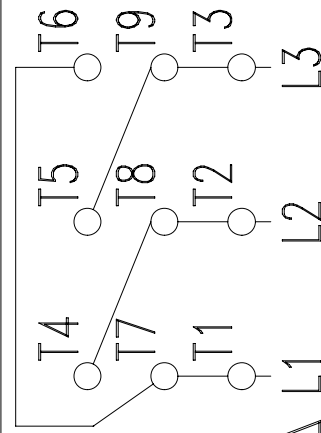

MOBIL POLYREX EM

