


Product Features:

- Horizontal blade orientation
- Steel construction (HDRG41-S)
- Aluminum construction (HDRG41-AL)
- Available in surface mount borders
- Fixed 0° or 38° blade deflection
- Largest single section size is 48x48"
- Built to withstand impacts and moderate abuse in high traffic areas
- Filter Racks ordered to fit either 1" or 2" Filters
- Filter size is equal to nominal neck size

Finishes

01 - White¹

 

03 - Black


¹ White Finish is suitable for a primer coat if field painting is required.

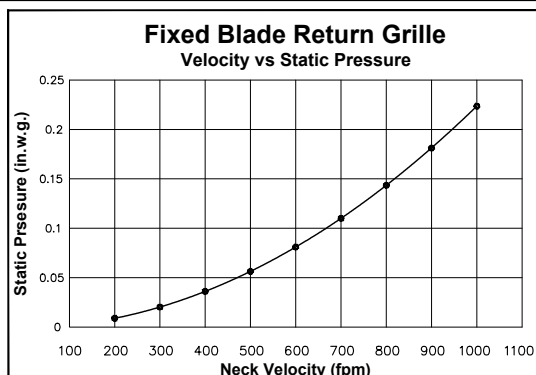
02 - Satin Silver



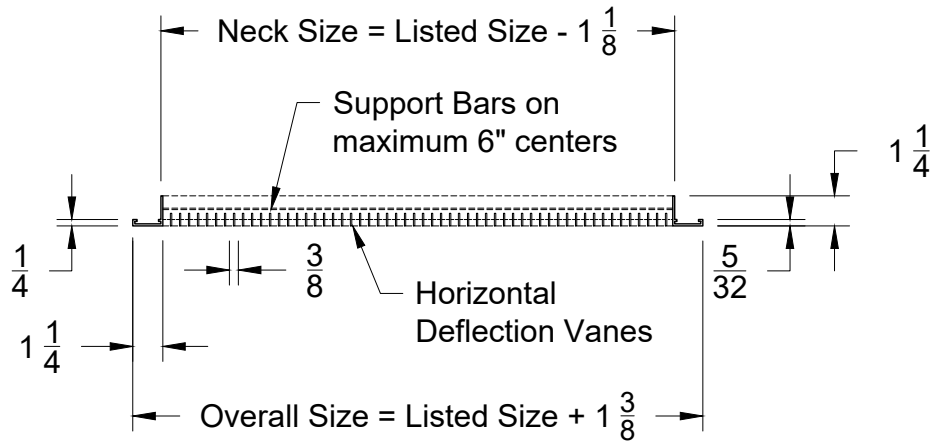
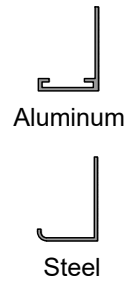
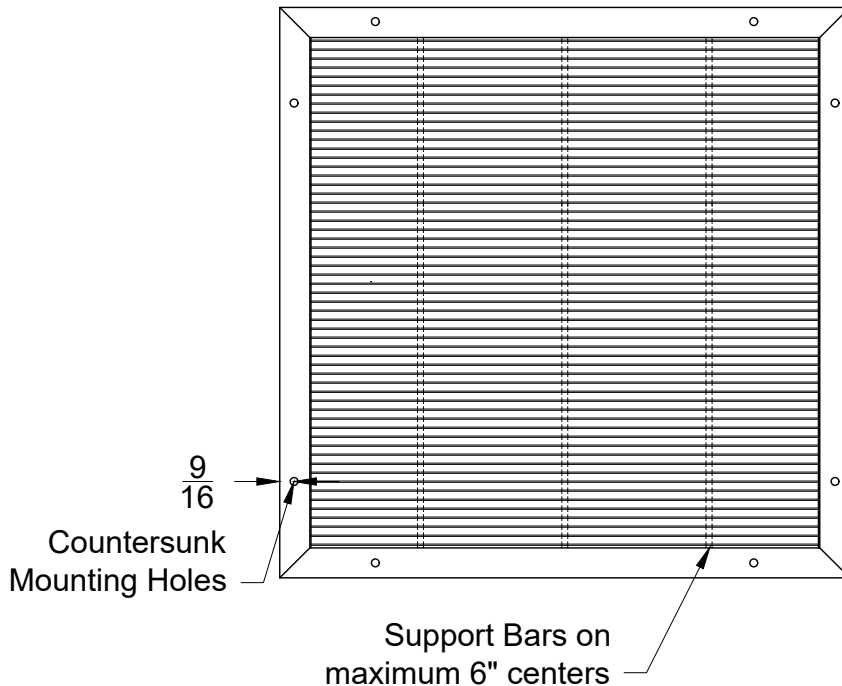
24 - Mill



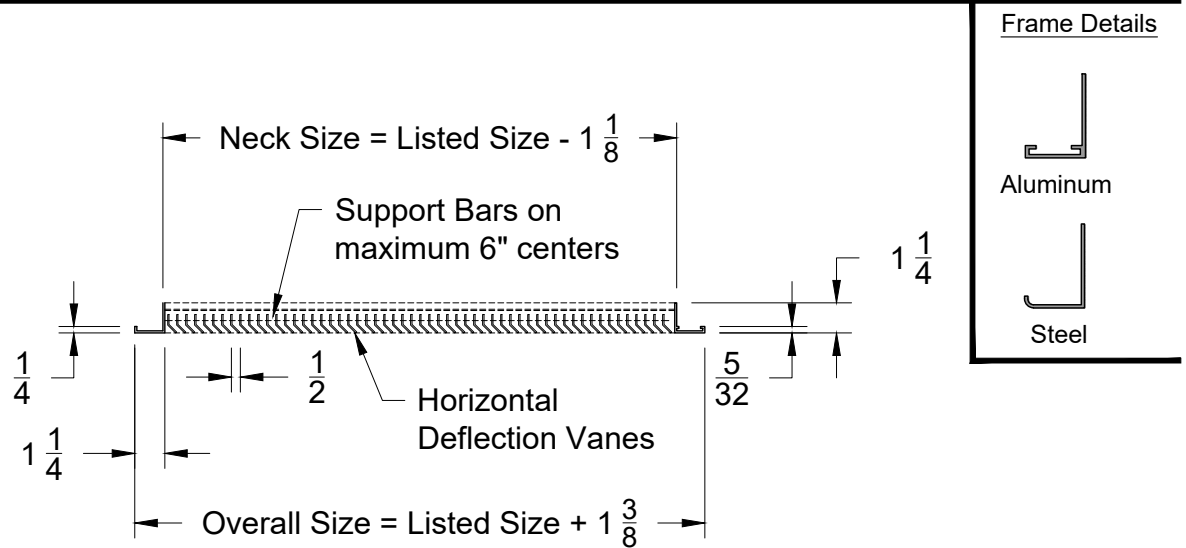
28 - Custom Color


Product Pressure Drop Performance

Optional Accessories:

OBDE - Extruded Aluminum
Opposed Blade Damper

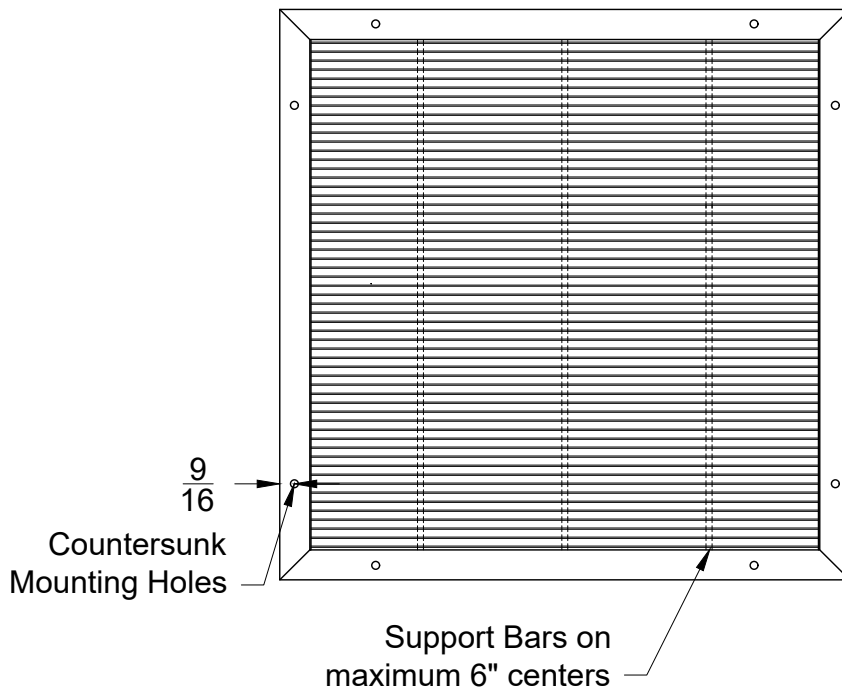
Frame Details

Side View
Face View


Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.



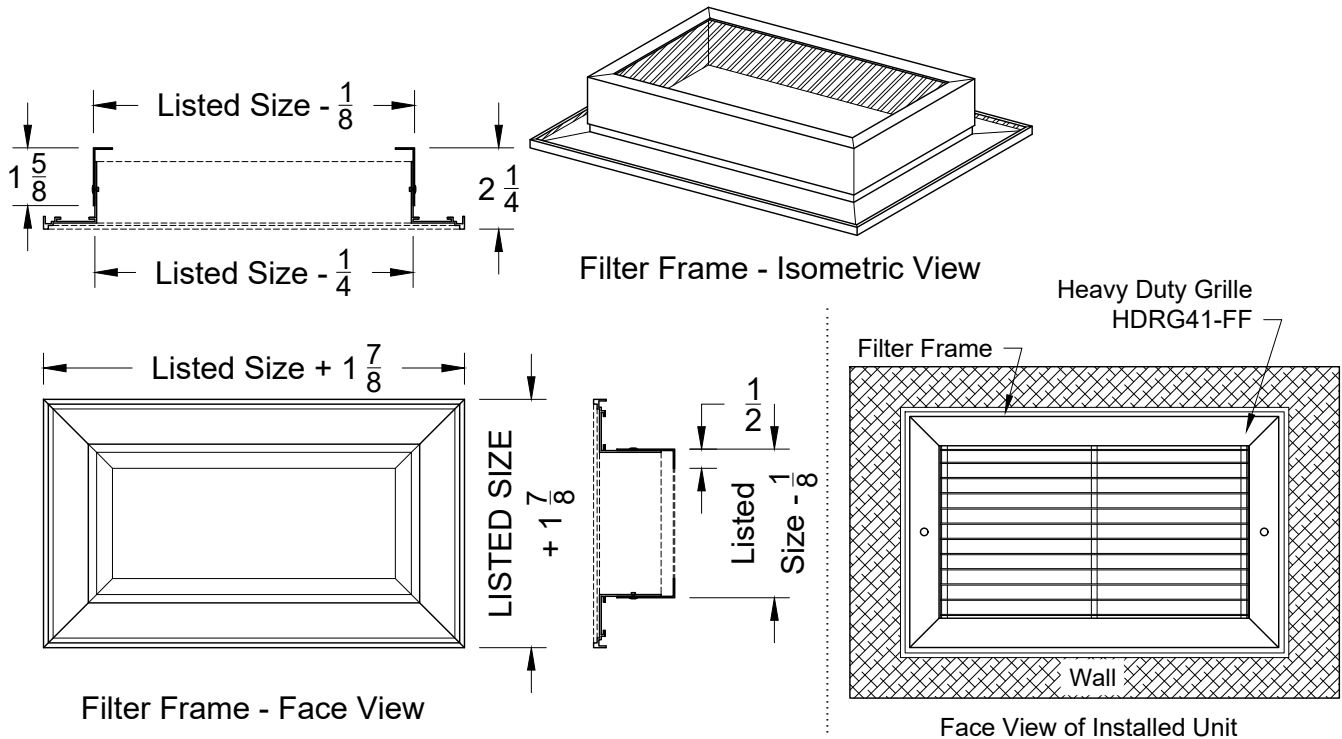
Side View

Face View

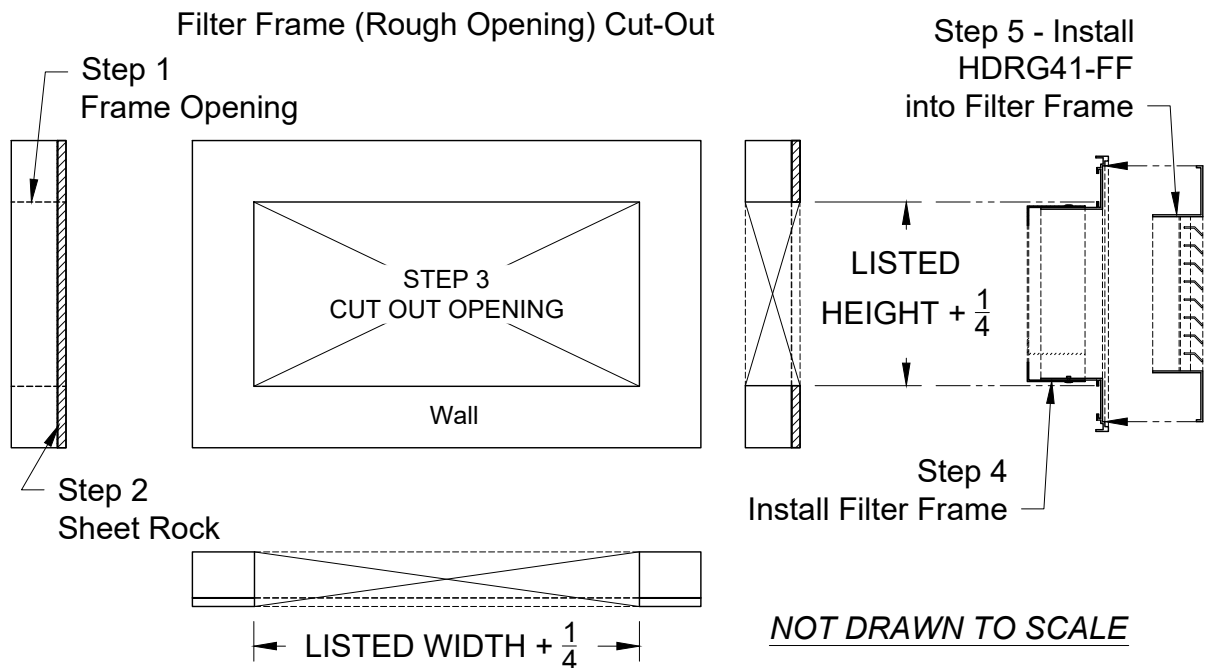


Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.

Note: HDRG41-FF Unit must be taken out to change the Filter



Installation Instructions



Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.