

MAT: 17794234 30AGO24

S/N




MADE IN MEXICO

NEMA
Premium[®]



W01 TO0IC0X0X

PH 3 HP (kW)2.0(1.5)
Hz 60 V208-230/460
RPM1745 A6.02-5.44/2.72
FR56HZ DESA
IP21 ENCLODP
AMB 40 °C CODE K
SF 1.00-1.15 INS F
SFA PF 0.74
DUTY CONT
NEMA NOM. EFF. 86.5%

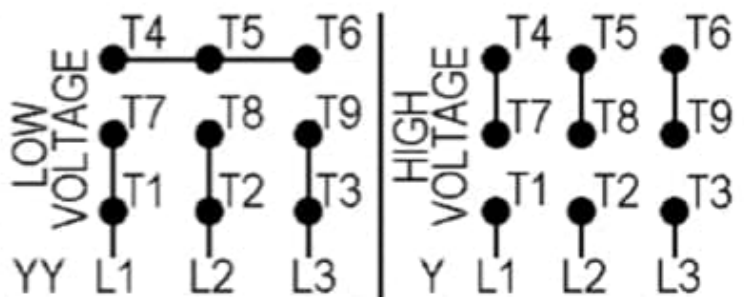

T1-BLU T2-WHT T3-ORG T4-YEL T5-BLK
T6-GRY T7-PNK T8-RED T9-BRK RED

ALT. RATING: 190-220/380-415V 50Hz
1.5 HP 5.42-4.68/2.71-2.84 A 1460 RPM S.F.1.0

Inverter Duty Motor
For 60Hz use on VPWM 1000:1VT; 5:1CT