 


MADE IN BRAZIL
13983258



Premium

W21 Tru-metric

MODEL 00518ET3EAL132S-W22

Electric Motor
Severe Duty



Class I, Div 2, Gr A, B, C and D - T3C
Class I, Zone 2, IIC - T3C
Class II, Div 2, Gr F - T3C






FOR SAFE AREA
Mod.TE0IA0X0\$
Type ET
CC029A



PH3 Fr. AL132S DUTY CONT. IP55 DES N Code M IEC 60034-1
127lb 1000m.a.s.l. INS cl. F DT 80K AMB 40°C SF 1.25//1.00

V		Hz	kW	HP	RPM	A		SFA		PF	IE code	NEMA NOM EFF η 100%/75%/50%		
230ΔΔ	460Δ	60	5.5	7.5	1770	18.1	9.07	22.6	11.3	0.83	IE3	91.7	91.0	88.5
380Δ	—	50	5.5	7.5	1460	10.6	—	10.6	—	0.87	IE3	90.3	90.7	90.4
415Δ	—	50	5.5	7.5	1465	10.1	—	10.1	—	0.83	IE3	90.8	90.7	89.6
—	—	—	—	—	—	—	—	—	—	—	—	—	—	—

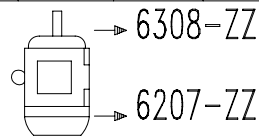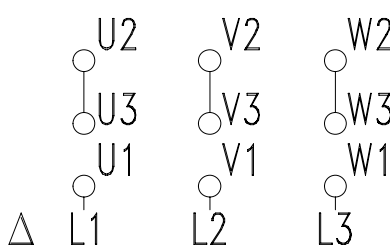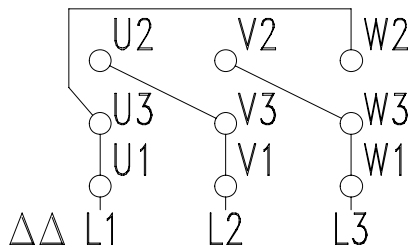

MOBIL POLYREX EM