



MODEL 050180T3E326T-W40G

Inverter Duty Motor
IEC 60034-1

60Hz: For use on PWM: VT 1000:1, CT 3:1,
1.00SF


Mod.T01#FOXON
CC029A



MADE IN BRAZIL
14504114

PH3 Fr. 324/6T DUTY CONT. ODP(IC01) IP23 DES B(N) Code G
509lb 1000m.a.s.l. INS cl. F DT 80K AMB 40°C SF 1.25//1.00

V		Hz	kW	HP	RPM	A		SFA		PF	IE code	NEMA NOM EFF η 100%/75%/50%		
230ΔΔ	460Δ	60	37	50	1775	117	58.5	146	73.1	0.84	IE3	94.5/94.5/94.1		
380Δ	—	50	30	40	1475	58.0	—	58.0	—	0.84	IE3	93.6/93.5/93.1		
—	—	—	—	—	—	—	—	—	—	—	—	—		
—	—	—	—	—	—	—	—	—	—	—	—	—		

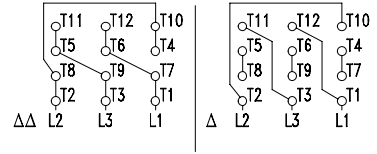

 → 6312-Z-C3 (21g)

 → 6211-Z-C3 (11g)

 MOBIL POLYREX EM (20000h)

