 


MADE IN BRAZIL
13982725



W21 Tru-metric


MODEL .2518EP3EAL71-W22

Electric Motor
Severe Duty






Class I, Div 2, Gr A, B, C and D - T3C
Class I, Zone 2, IIC - T3C
Class II, Div 2, Gr F - T3C

FOR SAFE AREA
Mod.TE01A0X0H
Type ET

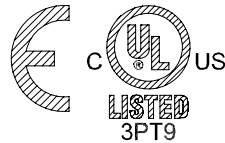

PH3 Fr. AL71 DUTY CONT. IP55 DES N Code L IEC 60034-1
1000m.a.s.l. INS cl. F DT 80K AMB 40°C SF 1.15//1.00

V		Hz	kW	HP	RPM	A		SFA		PF	IE code	NEMA NOM EFF η 100%/75%/50%		
230YY	460Y	60	0.25	0.33	1730	1.36	0.682	1.56	0.784	0.63	IE2	73.0/71.0/66.0		
-	380Y	50	0.25	0.33	1410	-	0.754	-	0.754	0.70	IE2	72.0/70.0/68.0		
-	415Y	50	0.25	0.33	1425	-	0.755	-	0.755	0.64	IE2	72.0/71.0/67.0		
-	-	-	-	-	-	-	-	-	-	-	-	-		

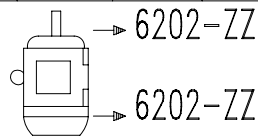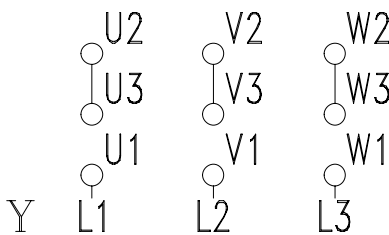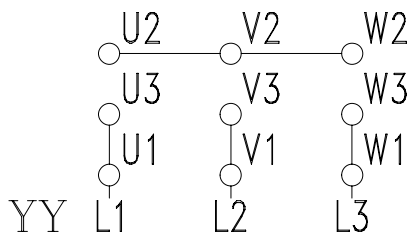

MOBIL POLYREX EM

