 


MADE IN BRAZIL
13983071



Premium

W21 Tru-metric

MODEL 00118ET3EAL90S-W22

Electric Motor
Severe Duty



Class I, Div 2, Gr A, B, C and D - T3C
Class I, Zone 2, IIC - T3C
Class II, Div 2, Gr F - T3C






FOR SAFE AREA
Mod.TE01A0X0\$
Type ET
CC029A



PH3 Fr. AL90S/L DUTY CONT. IP55 DES N Code L IEC 60034-1
40lb 1000m.a.s.l. INS cl. F DT 80K AMB 40°C SF 1.25//1.00

V		Hz	kW	HP	RPM	A		SFA		PF	IE code	NEMA NOM EFF η 100%/75%/50%		
230YY	460Y	60	1.1	1.5	1755	4.10	2.05	5.13	2.56	0.78	IE3	86.5/84.0/80.0		
-	380Y	50	1.1	1.5	1445	-	2.39	-	2.39	0.83	IE3	84.3/84.7/84.0		
-	415Y	50	1.1	1.5	1455	-	2.34	-	2.34	0.77	IE3	84.8/84.1/82.0		
-	-	-	-	-	-	-	-	-	-	-	-	-		

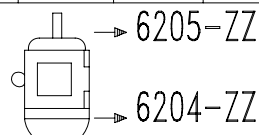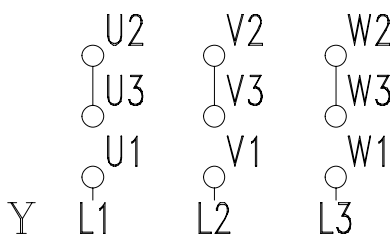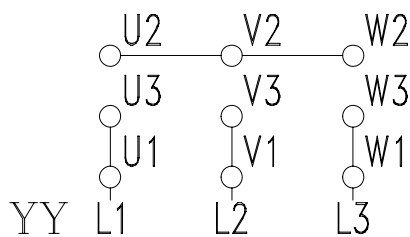

MOBIL POLYREX EM