

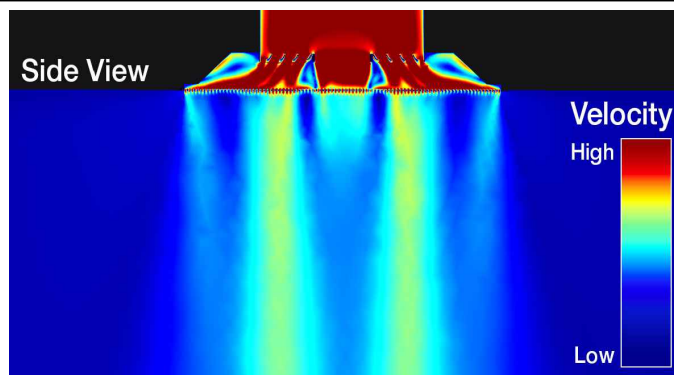
### Product Features:

- Perforated diffusers provide a smooth continuous ceiling aesthetic
- Neck mounted pattern deflectors enable optimal mixing
- Deflectors allow for adjustable airflow patterns
- Utilizes a hinged and fully removable face panel for easy cleaning
- Available in Extruded Aluminum
- Multiple border styles available for various ceiling applications
- Face panel uses 51% free area perforated metal



 


 
### Finishes

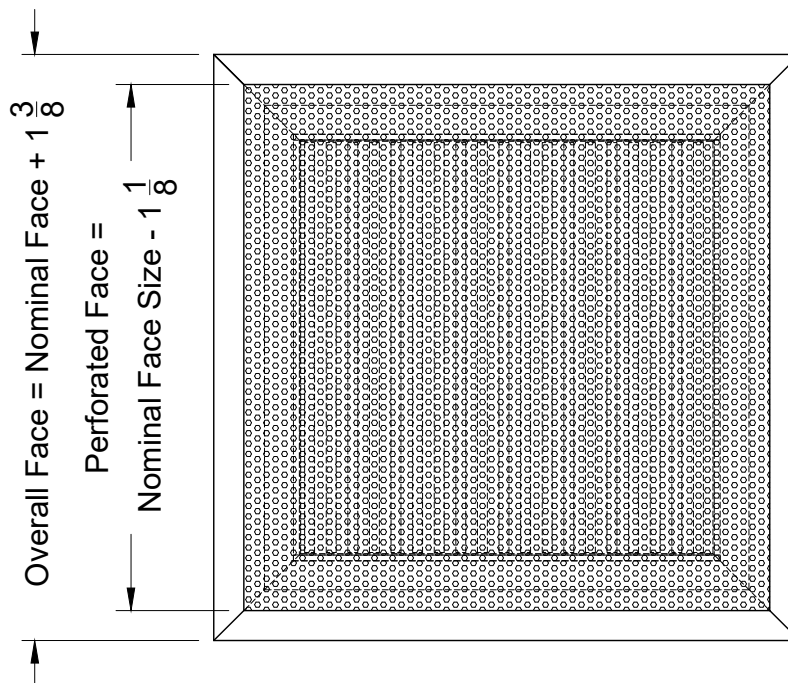
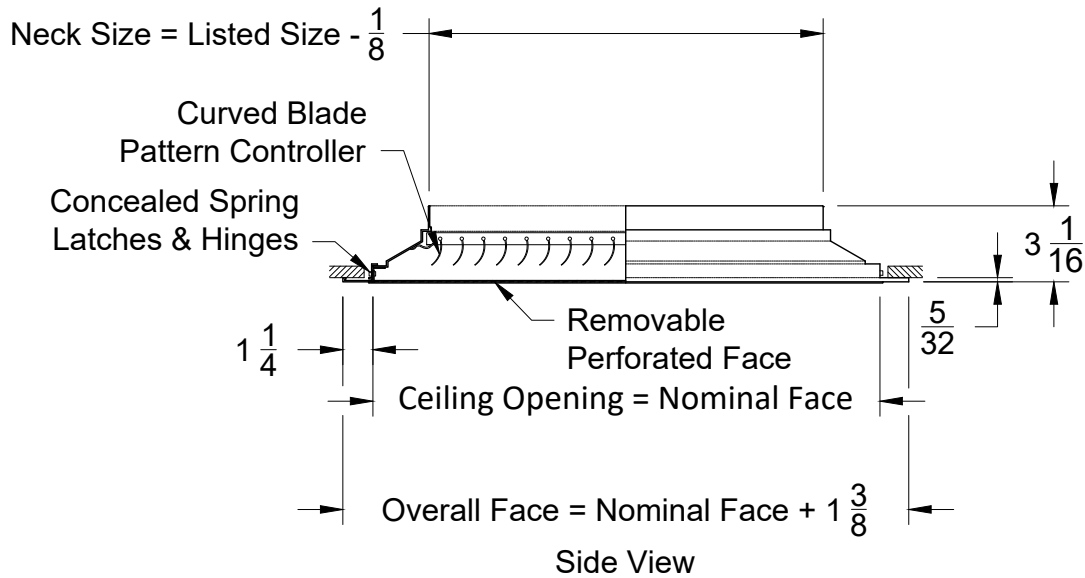
01 - White <sup>1</sup>	03 - Black	<sup>1</sup> White Finish is suitable for a primer coat if field painting is required.
02 - Satin Silver	24 - Mill	
28 - Custom Color	22 - BBP	
	Black Back Pan White Face	

### CFD Throw Pattern Visualization

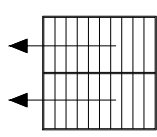
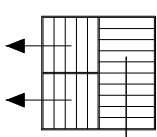
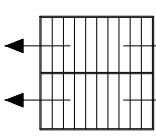
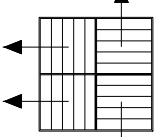
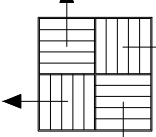


### Optional Accessories:

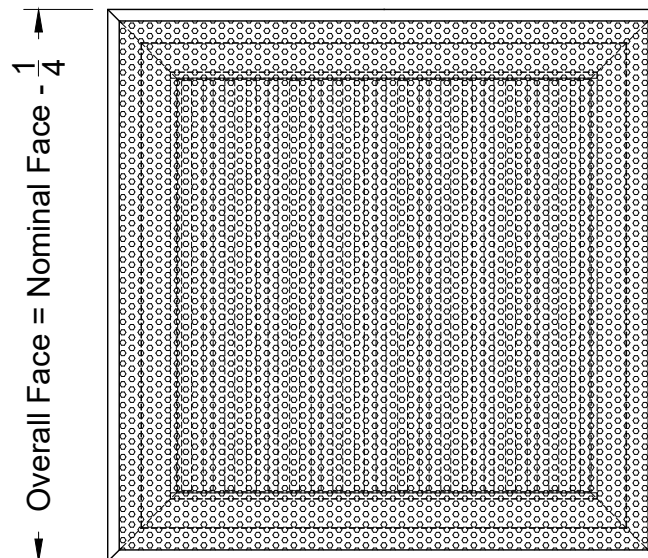
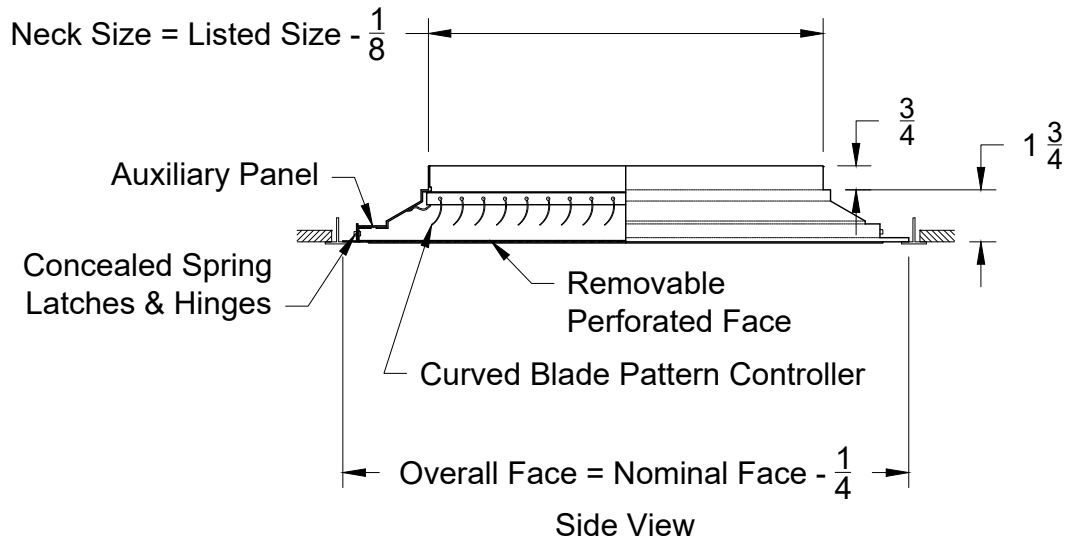
	Opposed Blade Damper D5 - Steel D5A - Aluminum
	TBPF - T-Bar Plaster Frame
	BDS - Butterfly Damper
	RSD - Radial Shutter Damper
	TR - Square to Round Transition
	TR-Deep - TR-Deep Transition



Listed Nominal	Largest Size
Face	Neck
12 x 12	6 x 6
14 x 14	8 x 8
15 x 15	9 x 9
16 x 16	10 x 10
18 x 18	12 x 12
20 x 20	14 x 14
21 x 21	15 x 15
24 x 12	18 x 6
24 x 24	18 x 18
36 x 12	18 x 6
36 x 24	18 x 18
48 x 12	18 x 6
48 x 24	18 x 18

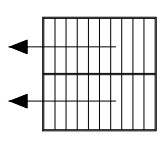
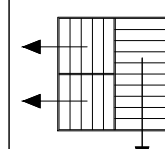
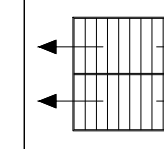
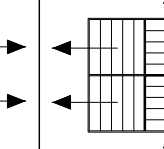
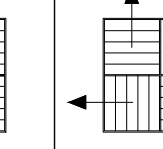
Air Pattern Options				
1 Way	2 Way Corner	2 Way	3 Way	4 Way
				

Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.

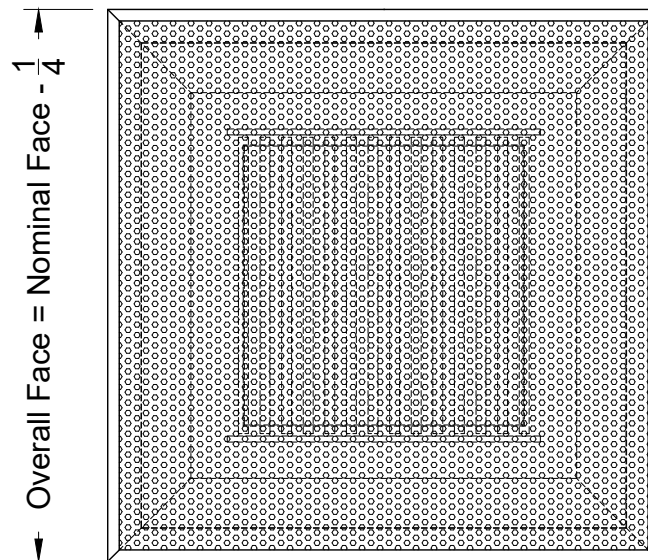
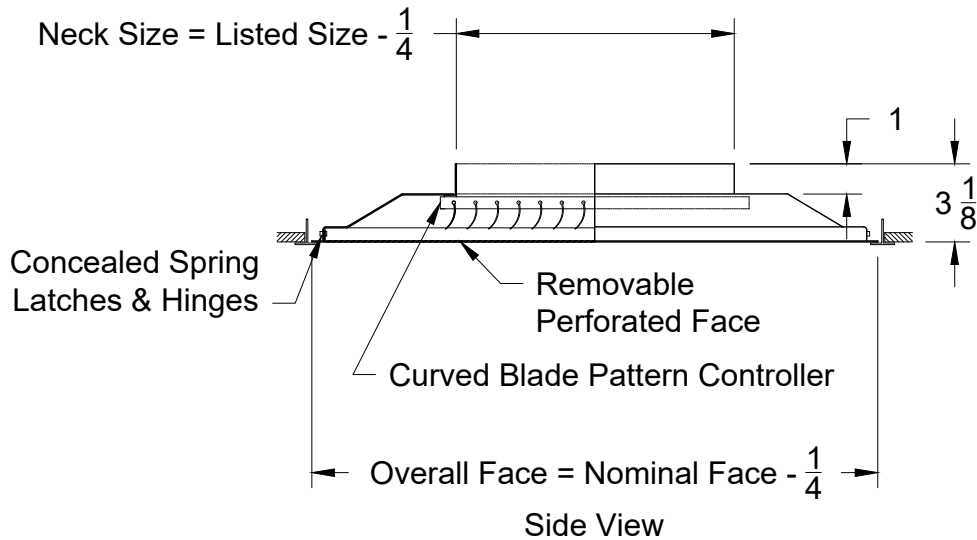


Listed Nominal	Largest Size
Face	Neck
12 x 12	6 x 6
20 x 20	18 x 18
24 x 24	18 x 18
48 x 12	18 x 6
48 x 24	18 x 18

\*\* This frame style is used on all sizes besides 24x24

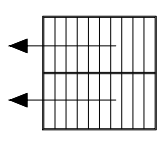
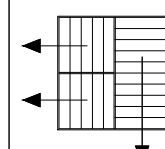
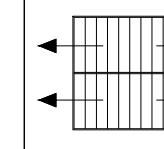
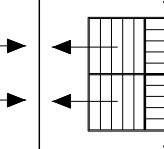
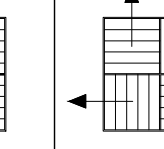
Air Pattern Options				
1 Way	2 Way Corner	2 Way	3 Way	4 Way
				

Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.

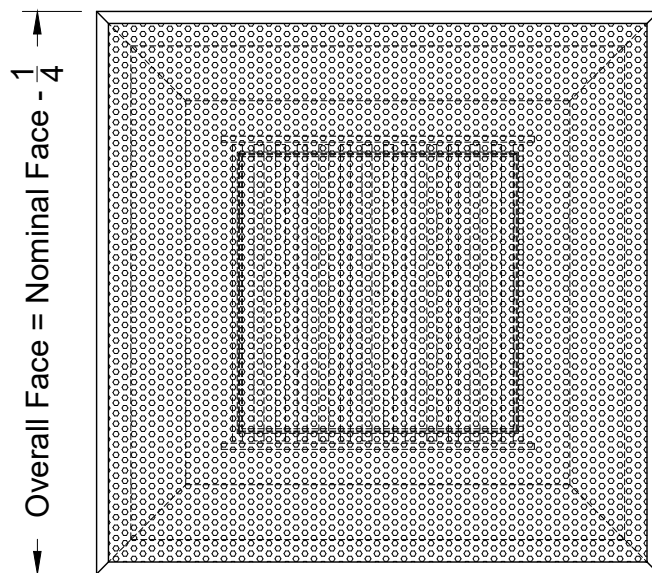
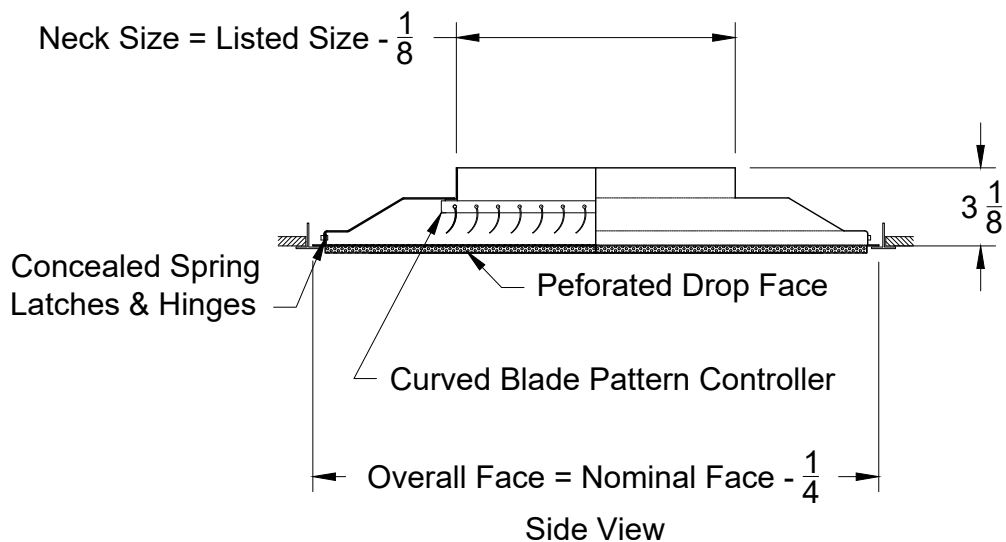


Listed Nominal	Largest Size
Face	Neck
24 x 24	18 x 18

\* Only available on 24x24 module size

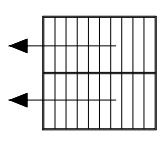
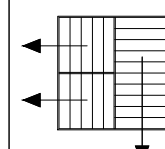
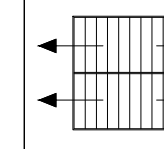
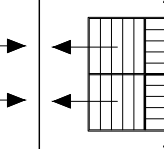
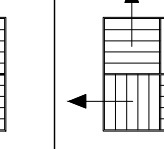
Air Pattern Options				
1 Way	2 Way Corner	2 Way	3 Way	4 Way
				

Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.

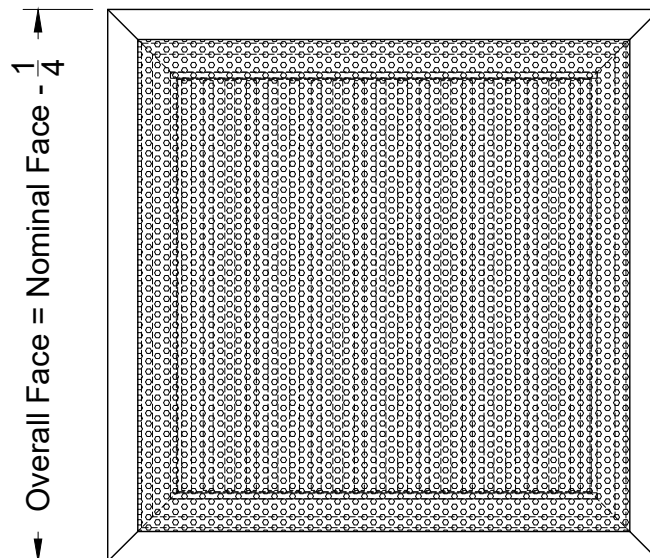
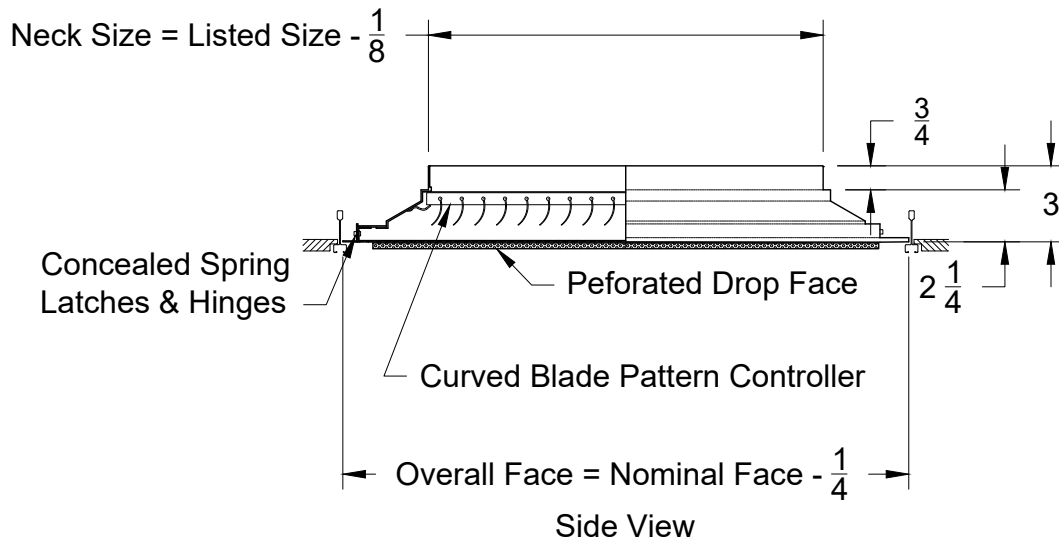


Listed Nominal	Largest Size
Face	Neck
24 x 24	14 x 14

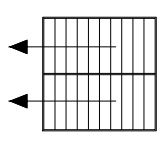
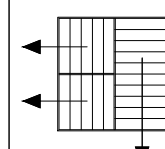
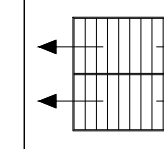
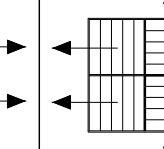
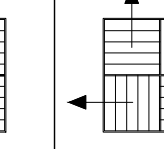
Face View

Air Pattern Options				
1 Way	2 Way Corner	2 Way	3 Way	4 Way
				

Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.



Listed Nominal	Largest Size
Face	Neck
24 x 24	18 x 18

Air Pattern Options				
1 Way	2 Way Corner	2 Way	3 Way	4 Way
				

Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.